

PHOENIX CONTACT DIN Rail Terminal Blocks



MT MICRO MINIATURE DIN RAIL TERMINAL BLOCKS

Micro DIN rail terminal block for NS 15 DIN Rail. Screw clamp connections.
 • RoHS compliant per Phoenix documentation



For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
							H	L	W	1	10	50	100
MT Micro Miniature Feed-Thru DIN Rail Terminal Blocks													
651-3100305	A	MT 1.5	Gray	30-14	300	15A	23.5	22.0	4.2	2.09	1.87	1.78	1.62
651-3003363	A	MT 1.5 BU	Blue	30-14	300	15A	23.5	22.0	4.2	2.08	1.86	1.77	1.61
651-3001679	B	MT 1.5 QUATTRO	Gray	30-14	300	15A	30.0	33.5	4.2	4.14	3.72	3.37	3.06
651-3001682	C	MT 1.5 TWIN	Gray	30-14	300	15A	30.0	28.0	4.2	3.67	3.26	3.12	2.85
651-3025532	C	MT 1.5 TWIN BU	Blue	30-14	300	15A	30.0	28.0	4.2	3.54	3.17	3.02	2.75
651-1414129	D	MTTB 1.5	Gray	30-14	300	15A	41.0	44.0	4.2	5.15	4.72	4.49	4.03
MT Micro Miniature Ground DIN Rail Terminal Blocks													
651-3100318	-	MT 1.5 PE	Gr/Yel	30-14	-	-	23.5	22.0	4.2	6.48	5.82	5.52	5.04
651-3001695	-	MT 1.5 QUATTRO PE	Gr/Yel	30-14	-	-	30.0	28.0	4.2	9.54	8.56	8.14	7.41
651-3001705	-	MT 1.5 TWIN PE	Gr/Yel	30-14	-	-	30.0	33.5	4.2	8.56	7.68	7.29	6.65

Accessories

MOUSER STOCK NO. Mfr. Mfr. Part No.	Phoenix Type	Color	Description	Price Each			
				1	10	50	100
651-3100321	D-MT 1.5	Gray	End Cover for MT 1.5	.64	.569	.527	.486
651-3025529	D-MT 1.5 BU	Blue	End Cover for MT 1.5 BU	.64	.569	.527	.486
651-3002982	D-MT 1.5 QUATTRO	Gray	End Cover for MT 1.5 QUATTRO	1.11	.987	.935	.852
651-3002979	D-MT 1.5 TWIN	Gray	End Cover for MT 1.5 TWIN	1.05	.946	.92	.845
651-3025545	D-MT 1.5 TWIN BU	Blue	End Cover for MT 1.5 TWIN BU	1.05	.946	.894	.821
651-3002678	DG-MTTB 1.5	Gray	Spacer Cover for MTTB 1.5	1.22	1.09	1.04	.94
651-3002665	D-MTTB 1.5	Gray	End Cover for MTTB 1.5	1.02	.907	.865	.782
651-3002681	DP-MTTB 1.5	Gray	Spacer Plate for MTTB 1.5	1.13	1.01	.955	.872

MBK MINIATURE DIN RAIL TERMINAL BLOCKS

• RoHS compliant per Phoenix documentation
 The "larger" miniature terminal block for NS 15 DIN rail. Screw clamp connections.



For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
							H	L	W	1	10	50	100
MBK Miniature Feed-Thru DIN Rail Terminal Blocks													
651-1413036	E	MBK 3/E Z	Gray	28-12	600	20A	32.0	28.0	5.2	2.52	2.26	2.15	1.96
651-1402940	F	MBK 5/E Z	Gray	26-10	600	30A	32.0	28.0	6.2	2.43	2.18	2.06	1.89
651-1414064	G	MBKKB 2.5	Gray	30-12	300	20A	48.0	62.0	5.2	4.89	4.39	4.11	3.79
MBK Miniature Ground DIN Rail Terminal Blocks													
651-1413117	-	MBK 3/E Z PE	Gr/Yel	28-12	-	-	31.5	28.0	5.2	5.83	5.23	4.98	4.53
651-0452043	-	MBK 5/E Z PE	Gr/Yel	26-10	-	-	32.0	28.0	5.2	6.29	5.65	5.24	4.89

Accessories

MOUSER STOCK NO. Mfr. Mfr. Part No.	Phoenix Type	Color	Description	Price Each			
				1	10	50	100
651-1413227	ATP-MBK	Gray	Partition Plate	1.27	1.14	1.08	.979
651-1415021	DMBK/E	Gray	End Cover for 3 & 5/ E Z	.78	.688	.657	.594
651-1401158	EB 2-5 N	Red	2 Pos. Insertion Bridge	.73	.658	.617	.564
651-1401145	EB 3-5 N	Red	3 Pos. Insertion Bridge	1.08	.967	.915	.832
651-1401132	EB 10-5 N	Red	10 Pos. Insertion Bridge	3.29	2.95	2.80	2.55
651-1413052	D-MBKKB 2.5	Gray	End Cover	.99	.877	.835	.762
651-1413065	DP-MBKKB 2.5	Gray	Spacer Plate	.87	.778	.737	.674

OTTA BOLT CONNECTION DIN RAIL TERMINAL BLOCKS

Bolt connection terminal blocks for ring lug terminals. Unique hinged cover wings which hold the terminal nuts. For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Color	Ring Lug Size	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
							H	L	W	1	10	50	100
OTTA Bolt Connection Feed-Thru DIN Rail Terminal Blocks													
651-0790530	H	OTTA 2.5	Gray	M3	600	20A	45.5	43.5	9.0	6.48	5.85	5.15	5.06
651-0790433	I	OTTA 6	Gray	M4	600	30A	52.0	43.5	9.0	5.47	4.61	4.33	4.25
* 651-0790462	J	OTTA 6-T-P/P	Gray	M4	600	30A	52.0	69.0	11.0	13.22	11.19	10.51	10.33
OTTA Bolt Connection Ground DIN Rail Terminal Blocks													
651-0790556	-	OTTA 2.5 PE	Gr/Yel	M3	-	-	45.5	43.5	9.0	13.88	11.75	11.02	10.83
651-0790527	-	OTTA 6 PE	Gr/Yel	M4	-	-	52.0	43.5	11.0	14.93	14.09	12.20	11.96

* Includes 4mm female test connector

End Covers

MOUSER STOCK NO. Mfr. Mfr. Part No.	Phoenix Type	Color	Description	Price Each			
				1	10	50	100
651-0790569	D-OTTA 2.5	Gray	End Cover for OTTA 2.5	1.34	1.21	1.14	1.03
651-0790417	D-OTTA 6	Gray	End Cover for OTTA 6	1.27	1.13	1.08	.98
651-0790459	D-OTTA 6-T	Gray	End Cover for OTTA 6-T	1.27	1.13	1.08	.98

MTK KNIFE DISCONNECT DIN RAIL TERMINAL BLOCKS

** Feed-through terminal block w/o knife disconnect.
 • RoHS Compliant per Phoenix documentation.




For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
							H	L	W	1	10	50	100
651-3101016	K	MTK	Gray	28-12	300	10A	51.5	46	5.2	6.16	5.70	5.65	5.14
651-3104013	K	MTK-P/P	Gray	28-12	300	10A	51.5	46	5.2	7.38	6.61	5.95	5.62
** 651-3100017	L	MTKD	Gray	28-12	300	10A	51.5	46	5.2	3.77	3.37	3.21	2.93
651-3004032	M	UK 5-MTK-P/P	Gray	22-12	600	15A	58.5	51	6.2	8.23	7.38	6.70	6.32
651-2775210	N	UDK 4-MTK-P/P	Gray	22-10	600	10A	47	63.5	6.2	8.64	7.75	6.98	6.59
651-2800004	O	UKK 5-MTK-P/P	Gray	26-12	300	15A	68	80	6.2	12.86	11.53	10.97	9.98
651-3101087	P	UDMTK 5-P/P	Gray	26-12	300	15A	68.5	93	6.2	18.45	18.10	17.20	15.66

Accessories

MOUSER STOCK NO. Mfr. Mfr. Part No.	Phoenix Type	Color	Description	Price Each			
				1	10	50	100
651-3101029	D-MTK	Gray	End Cover for MTK	1.12	.99	.954	.864
651-3101223	ATS-MTK	Gray	Partition Plate for MTK	1.16	1.04	.985	.892
651-3004210	ATP-UK 5-MTK	Gray	Partition Plate for UK 5-MTK	1.27	1.13	1.08	.98
651-2775113	D-UDK 4	Gray	End Cover for UDK 4-MTK	1.47	1.31	1.25	1.14
651-3100266	TP-UDMTK 5	Gray	Partition Plate for UDMTK 5	1.22	1.10	1.04	.949

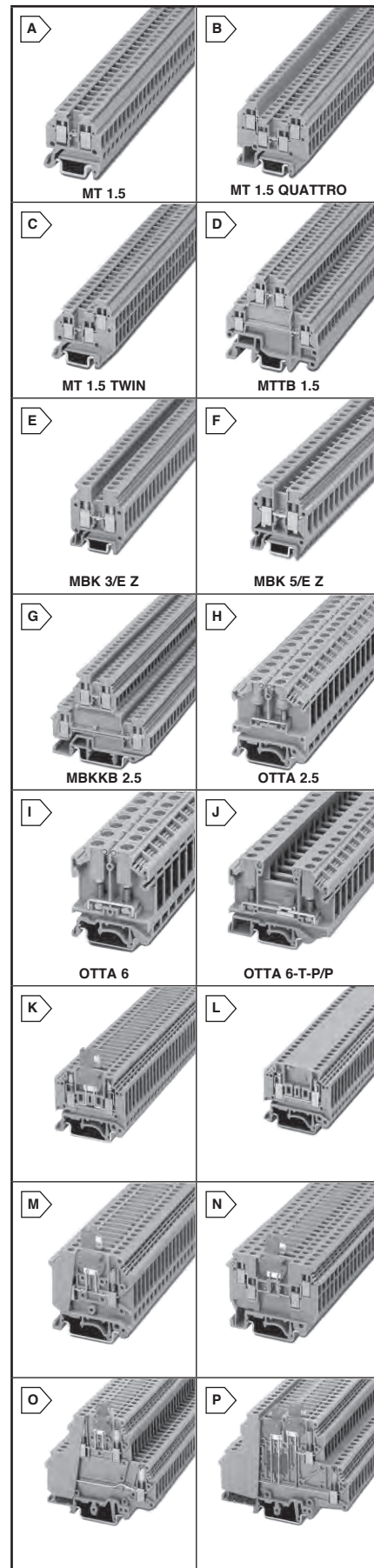

Terminal Blocks Phoenix Contact

