


# PHOENIX CONTACT DIN Rail Mounted Terminal Block Accessories

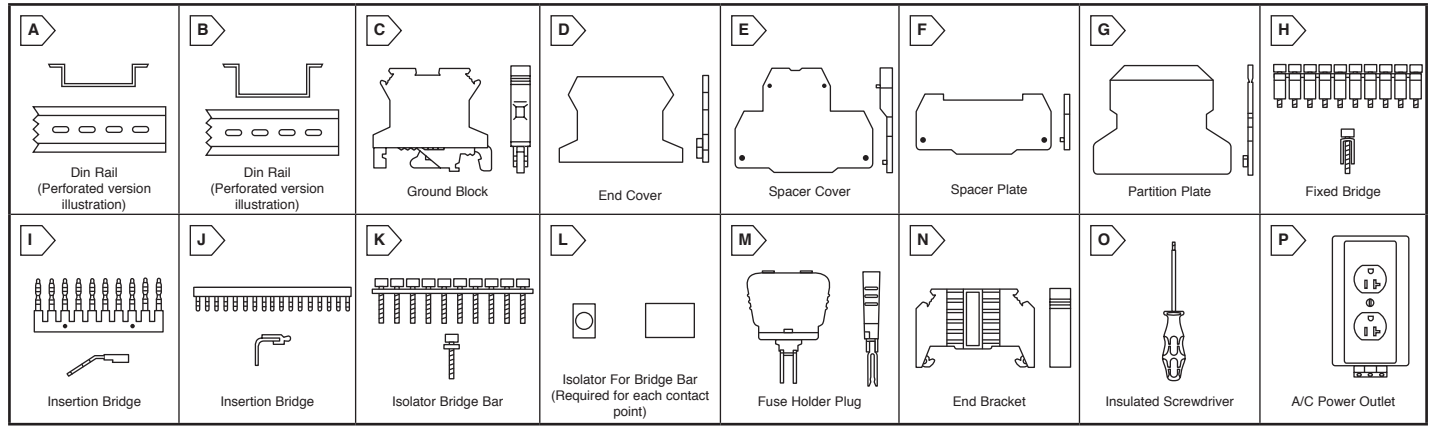

## DIN RAIL TERMINAL BLOCK ACCESSORIES

## DIN RAIL TERMINAL BLOCK ACCESSORIES

For quantities greater than listed, call for quote.


MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Description	Price Each		
				1	10	50
651-5602099	A	NS 15	15mmx5.5mmx1m DIN Rail Perf.	9.45	8.66	8.01
651-5602100	A	NS 35/7.5	35mmx7.5mmx1m DIN Rail Perf.	10.72	9.83	9.09
651-5603400	A	NS 35/7.5	35mmx7.5mmx1m DIN Rail Unperf.	11.27	10.35	9.54
* 651-0801733	A	NS 35/7.5	35mmx7.5mmx2m DIN Rail Perf.	12.13	10.66	9.27
651-5603401	B	NS 35/15	35mmx15mmx1m DIN Rail Perf.	17.40	15.95	14.75
* 651-5604188	-	NS 35/58 AL	35mmx58mmx2m DIN Rail Perf.	15.76	14.30	13.34
651-3100318	C	MT 1.5 PE	4.2mm Ground Block (30-14 AWG)	6.48	5.82	5.52
651-1413117	C	MBK 3/E-Z-PE	5.2mm Ground Block (30-12 AWG)	5.83	5.23	4.98
651-0452043	C	MBK 5/E-Z-PE	6.2mm Ground Block (24-10 AWG)	6.29	5.65	5.24
651-3005853	C	USLKG 1.5 N	4.2mm Ground Block (30-14 AWG)	14.19	13.47	12.39
651-0441119	C	USLKG 2.5 N	5.2mm Ground Block (30-12 AWG)	7.27	6.52	5.92
651-0441504	C	USLKG 5	6.2mm Ground Block (26-10 AWG)	6.94	6.23	5.64
651-0442079	C	USLKG 6 N	8.2mm Ground Block (26-8 AWG)	7.82	7.01	6.35
651-3003923	C	USLKG 10 N	10.2mm Ground Block (24-6 AWG)	8.50	7.62	6.90
651-2774211	C	UKK 5-PE	6.2mm Ground Bk. (26-10 AWG) 2 Pos.	14.49	12.99	12.35
651-3100321	D	D-MT 1.5	End Cover	.64	.569	.527
651-3002665	D	D-MTTB 1.5	End Cover	1.02	.907	.865
651-1415021	D	D-MBK/E	End Cover	.78	.688	.657
651-3001022	D	D-UK 2.5	End Cover	1.12	.99	.898
651-3003020	D	D-UK 4/10	End Cover	1.06	.947	.895
651-2770024	D	D-UKK 3/5	End Cover	1.73	1.50	1.43
651-2770277	D	D-UDK RELG	End Cover	3.03	2.73	2.58
651-3002678	E	DG-MTTB 1.5	Spacer Cover	1.22	1.09	1.04
651-2770817	E	DG-UKK 3/5	Spacer Cover	1.83	1.63	1.55
651-3002681	F	DP-MTTB 1.5	Spacer Plate	1.13	1.01	.955
651-2770794	F	DP-UKK 3/5	Spacer Plate	1.18	1.05	.995
651-3003224	G	ATP-UK	Partition Plate	1.23	1.10	.992
651-1413285	G	ATP-DIKD 1.5	Partition Plate	1.83	1.63	1.55

\* 2 meter length, priced per meter

For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Description	Price Each		
				1	10	50
651-1413272	G	ATP-DIK 1.5	Partition Plate	1.70	1.41	1.34
651-3001624	H	FBRN 10-4 N	10 Position Fixed Bridge Divisible	6.89	6.17	5.87
651-2770642	H	FBRN 10-5 N	10 Position Fixed Bridge Divisible	10.01	8.98	8.54
651-0203250	H	FBI 10-6	10 Position Fixed Bridge Divisible	7.90	7.08	6.37
651-0203263	H	FBI 10-8	10 Position Fixed Bridge Divisible	9.51	8.52	8.10
651-0203276	H	FBI 10-10	10 Position Fixed Bridge Divisible	12.33	11.05	10.08
651-2772080	H	FBRN 10-8N	10 Position Fixed Bridge Divisible	10.33	9.07	8.47
651-2303132	I	EBL 10-5	10 Pos. Insertion Bridge Divisible	2.84	2.55	2.42
651-0201139	I	EB 10-6	10 Pos. Insertion Bridge Divisible	4.55	4.07	3.87
651-0202138	I	EB 10-8	10 Pos. Insertion Bridge Divisible	5.62	5.04	4.57
651-0203137	I	EB 10-10	10 Pos. Insertion Bridge Divisible	7.53	6.75	6.12
651-3118135	I	EBS 10-8	10 Pos. Insertion Bridge Divisible	5.41	4.85	4.31
651-2715940	J	EB 80-DIK BU	80 Pos. Insertion Bdg. (Middle) Div.	51.29	44.20	40.85
651-2715953	J	EB 80-DIK RD	80 Pos. Insertion Bdg. (Lower) Div.	51.29	44.20	40.85
651-3009299	J	EB 56-18	56 Pos. Insertion Bridge Divisible	60.60	57.13	52.78
651-0301505	K	ISSBI 10-6	10 Position Isolator Bridge Bar	6.32	5.67	5.40
651-1302338	L	IS-K 4	Isolator for Bridge Bar	.57	.521	.49
651-0921037	M	ST-SI-UK4	Fuse Holder (5x20mm)	3.26	3.06	2.91
651-0921033	M	ST-SILED 24 UK4	Fuse Holder 30V Lamp (5x20mm)	12.13	11.37	10.85
651-0921057	M	ST-SILA 250-UK4	Fuse Holder 250V Lamp (5x20mm)	9.16	8.33	7.96
651-1421659	N	E/MK 1	End Bracket For NS 15 DIN Rail	1.02	.907	.865
651-0800886	N	E/NS 35 N	End Bracket For NS 35 DIN Rail	1.36	1.25	1.17
651-1205037	O	SZS 0.4x2.5	Screwdriver-Insulated Blade Shaft	13.58	13.05	12.46
651-1205056	O	SZS 0.6x3.5	Screwdriver-Insulated Blade Shaft	13.58	13.05	12.46
651-1205066	O	SZS 1.0x4.0	Screwdriver-Insulated Blade Shaft	20.00	18.78	18.00
651-5600525	P	EM-DUO 120/20	120 Outlet For NS 35 DIN Rail	32.35	27.34	25.78
651-1204384	-	Quick Wire Fox 6	Wire Strippers, AWG 30-10	93.80	-	-
651-2963860	-	SD-US/SC/LAGY	Single Outlet, 125V, 15 A	21.70	20.04	18.80

Terminal Blocks Phoenix Contact

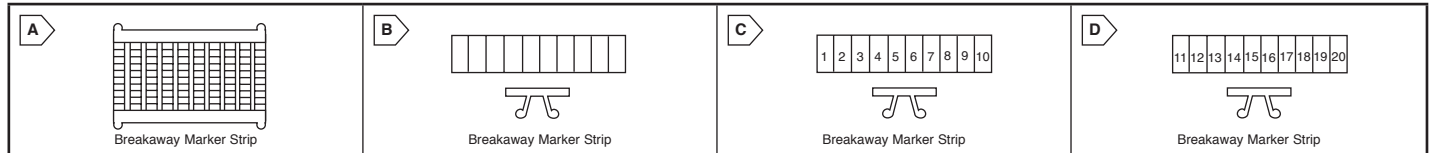

## MARKER STRIPS FOR DIN RAIL TERMINAL BLOCKS

For quantities greater than listed, call for quote.

MOUSER STOCK NO. Mfr. Mfr. Part No.	Fig.	Phoenix Type	Description	Use With Terminal Block	Price Each		
					1	10	50
651-0803579	A	ZBFM 4/WH: UNPRINTED	Unprinted marker strip for up to 100 positions	MT 1.5, MTTB 1.5	11.36	10.19	9.68
651-0800734	A	ZBFM 8/WH: UNPRINTED	Unprinted marker strip for up to 50 positions	UKK 5 HESI	12.66	11.35	10.79
651-0800268	A	ZBFM 4/WH, LGS: 1-100	Preprinted marker strip from 1 to 100	MT 1.5, MTTB 1.5	14.62	13.41	12.37
651-0805001	B	ZB 4: UNPRINTED	Unprinted marker strip for up to 10 positions	UK 1.5 N	1.79	1.61	1.53
651-1050004	B	ZB 5: UNPRINTED	Unprinted marker strip for up to 10 positions	MBK 3/EZ, UK 2.5 N	1.07	.96	.911
651-1051003	B	ZB 6: UNPRINTED	Unprinted marker strip for up to 10 positions	MBK 5/EZ, UK 5 N, UKK 5, SLKK 5, DIKD 1.5-TG, DIK 1.5, DIKD1.5, UK 4-TG, UDK 4-TG, UKK 5-TG, UT 4	1.12	1.00	.952
651-1052002	B	ZB 8: UNPRINTED	Unprinted marker strip for up to 10 positions	UK 6 N, UK 5 HESI, UK 5 HESILED 24, UK 5 HESILA 250	1.13	.955	.835
651-1053001	B	ZB 10: UNPRINTED	Unprinted marker strip for up to 10 positions	UK 10 N, UK 6.3 HESI, UK 10.3 HESI, UK 6.3 HESILED 24, UK 6.3 HESILA 250	1.70	1.53	1.45
651-0805807:0001	C	ZB 4: QR: 1-10	Preprinted marker strip from 1 to 10	UK 1.5 N	2.53	2.27	2.15
651-1050017:0001	C	ZB 5, LGS: 1-10	Preprinted marker strip from 1 to 10	MBK 3/EZ, UK 2.5 N	1.53	1.37	1.31
651-1051016:0001	C	ZB 6, LGS: 1-10	Preprinted marker strip from 1 to 10	MBK 5/EZ, UK 5 N, UKK 5, SLKK 5, DIKD 1.5-TG, DIK 1.5, DIKD1.5, UK 4-TG, UDK 4-TG, UKK 5-TG, UT 4	1.53	1.37	1.31
651-1052015:0001	C	ZB 8, LGS: 1-10	Preprinted marker strip from 1 to 10	UK 6 N, UK 5 HESI, UK 5 HESILED 24, UK 5 HESILA 250	2.26	2.11	2.02
651-1053014:0001	C	ZB 10, LGS: 1-10	Preprinted marker strip from 1 to 10	UK 10 N, UK 6.3 HESI, UK 10.3 HESI, UK 6.3 HESILED 24, UK 6.3 HESILA 250	2.60	2.34	2.23
651-0805807:0011	D	ZB 4: QR: 11-20	Preprinted marker strip from 11 to 20	UK 1.5 N	2.53	2.27	2.15
651-1050017:0011	D	ZB 5, LGS: 11-20	Preprinted marker strip from 11 to 20	MBK 3/EZ, UK 2.5 N	1.53	1.37	1.31
651-1051016:0011	D	ZB 6, LGS: 11-20	Preprinted marker strip from 11 to 20	MBK 5/EZ, UK 5 N, UKK 5, SLKK 5, DIKD 1.5-TG, DIK 1.5, DIKD1.5, UK 4-TG, UDK 4-TG, UKK 5-TG, UT 4	1.53	1.37	1.31
651-1052015:0011	D	ZB 8, LGS: 11-20	Preprinted marker strip from 11 to 20	UK 6 N, UK 5 HESI, UK 5 HESILED 24, UK 5 HESILA 250	2.26	2.11	2.02
651-1053014:0011	D	ZB 10, LGS: 11-20	Preprinted marker strip from 11 to 20	UK 10 N, UK 6.3 HESI, UK 10.3 HESI, UK 6.3 HESILED 24, UK 6.3 HESILA 250	2.23	1.98	1.80
651-1051993	-	M-PEN	Black Marking Pen	(Use with all unprinted marking strips)	18.26	16.38	15.58