


C&K Tactile Switches

RoHS Compliant. This page of product is compliant.

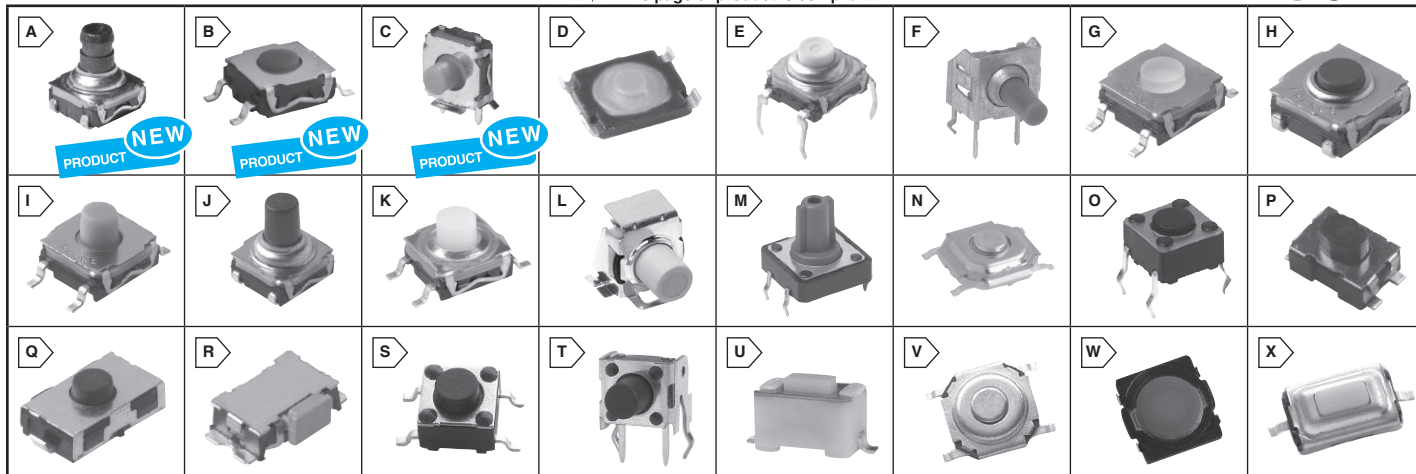

KSC9 SERIES SMD SEALED TACT SWITCH FOR ADJUSTABLE SWITCH

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Force	Height (mm)	Price Each	
Mfr.	Mfr. Part No.				1	25
J-Bend						
611—KSC921JLFS	A		170g	7.7	.41	.35
611—KSC931JLFS	A		255g	7.7	.41	.35
611—KSC941JLFS	A		340g	7.7	.41	.35
Gulfwing						
611—KSC921GLFS	A		170g	7.7	.41	.35
611—KSC931GLFS	A		255g	7.7	.41	.35
611—KSC941GLFS	A		340g	7.7	.41	.35

ACCESSORIES FOR SERIES KSC9

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	25
611—BTNKSC920		Button for KSC9, light gray, 15.4mm	.41	.35
611—BTNKSC940		Button for KSC9, red, 15.4mm	.41	.35
611—BTNKSC980		Button for KSC9, white, 15.4mm	.41	.35
611—BTNKSC990		Button for KSC9, black, 15.4mm	.41	.35

KSE SERIES LOW PROFILE TACT SWITCH

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Force	Height (mm)	Price Each	
Mfr.	Mfr. Part No.				1	25
611—KSEM31JLFS	B		150g	3.1	.31	.28
611—KSEM31GLFS	B		150g	3.1	.31	.28

KSCV2 SERIES SIDE ACTUATED SEALED TACT SWITCH

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No	Fig.	Operating Force	Height (mm)	Price Each	
					1	25
611-KSC441V2SPDELTA	KSC441V2 SP Delta LFS	C	200g	5.0	.65	.59

KMT0 SERIES NANO-MINIATURE SMT TOP ACTUATED

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Force	Height (mm)	Price Each	
Mfr.	Mfr. Part No.				1	25
611—KMT012NGJLHS	D		160g	0.65	.32	.27
611—KMT022NGJLHS	D		160g	0.65	.32	.27
611—KMT072NGJLHS	D		230g	0.65	.32	.27

KSA & KSL SERIES SEALED TACTILE SWITCH

Features:
 • Designed for automatic or manual insertion
 • Cambered terminals to ensure self retention
 • Top or side actuated

For quantities greater than listed, call for quote.

611—KSA0M211-LFT	E	130g	4.7	.50	.43
611—KSA0M411-LFT	F	300g	4.7	.50	.39
611—KSL0M412-LFT	F	300g	9.9	.47	.42
611—KSL0V411-LFT	F	300g	9.9	.77	.70
611—KSL0M212LFT	F	130gf	9.9	.57	.52
611—KSL0M312LFT	F	130gf	9.9	.57	.51
611—KSL0M411LFT	F	300gf	9.9	.58	.526
611—KSL0M431LFT	F	300gf	9.9	.74	.666
611—KSL0V311LFT	F	130gf	9.9	.55	.48
611—KSL1M411LFT	F	300gf	9.9	.49	.43

KSC SERIES TACTILE SWITCH FOR SMT

Features:
 • Positive tactile feeling
 • Range of 6 actuation forces
 • IP 67
 • J or G terminations

For quantities greater than listed, call for quote.

611—KSC221G-LFS	G	160g	3.5	.46	.38
611—KSC221J-LFS	G	160g	3.5	.41	.35
611—KSC241G-LFS	G	300g	3.5	.46	.37
611—KSC241J-LFS	G	300g	3.5	.43	.367
611—KSC341J-LFS	H	300g	3.5	.46	.37
611—KSC351J-LFS	H	550g	3.5	.47	.40
611—KSC421G70SH-LFS	I	160g	5.2	.53	.43
611—KSC441J70SH-LFS	I	300g	5.2	.55	.45
611—KSC641G-LFS	J	300g	7.7	.63	.51
611—KSC641J-LFS	J	300g	7.7	.64	.53
611—KSC721JLFS	J	300g	4.3	.52	.46

KSC SERIES TACTILE SWITCH FOR SMT (CONT.)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Force	Height (mm)	Price Each	
Mfr.	Mfr. Part No.				1	25
611—KSC721GLFS	J		160g	4.3	.52	.46
611—KSC741JLFS	J		400g	4.3	.52	.46
611—KSC741GLFS	J		400g	4.3	.52	.46

KST SERIES LONG TRAVEL TACT SWITCH FOR SMT

Features:
 • Rubber actuator
 • Silver contact material
 • J or G terminals
 • Compatible with pick and place machines
 • IP 40 sealed

For quantities greater than listed, call for quote.

611—KST241GLFS	K	350gf	5.0	1.41	.84
----------------	---	-------	-----	------	-----

KT SERIES RIGHT ANGLE SEALED TACTILE SWITCH FOR SMT

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Force	Terminal	Price Each	
Mfr.	Mfr. Part No.				1	25
611—KT1B2JM34-LFS	L		300gf	Top J Bend	2.24	2.10
611—KT1P2JM34-LFS	L		300gf	Top J Bend	2.08	1.95
611—KT1P2SM34-LFS	L		300gf	Top Gullwing	2.38	2.23
611—KT1B1SAM34LFS	M		300gf	Right Angle	2.24	2.10
611—KT1P2SA3M34LFS	M		300gf	Right Angle w/ pick & place tab	2.85	2.62
611—KT1P3SA1M34LFS	M		300gf	Right Angle w/ front solder pad	2.22	2.08
611—KT1P4SA1M34LFS	M		300gf	Right Angle w/ front solder pad	2.26	2.12
611—KT1P4SA2M35LFG	M		300gf	Right Angle w/ front solder pad and pick & place tab	2.93	2.69

KMR2/KSR/KSS SERIES TACTILE SWITCHES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Operating Force	Height (mm)	Price Each	
Mfr.	Mfr. Part No.				1	25
Microminiature SMT Top Actuated, Operating Temperature -40°C to 125°C						
611—KMR211G-LFS	N		120g	1.9	.37	.34
611—KMR221G-LFS	N		200g	1.9	.37	.34
611—KMR241GLFS	N		400gf	1.9	.51	.466
Subminiature SMT, IP 50 Sealed, Operating Temperature -40°C to 125°C						
611—KSR221G-LFS	O		200g	2.5	.55	.46
Subminiature SMT Side Actuated, IP 50 Sealed, Operating Temp. -40°C to 125°C						
611—KSS221GLFS	P		200g	1.7	.55	.45
611—KSS231G-LFS	P		250g	1.7	.55	.496
611—KSS331G-LFS	P		250g	1.7	.62	.52
611—KMS231GLFS	P		200gf	1.7	.32	.29
611—KMS233GLFG	P		200gf	1.7	.33	.29

PTS125/525/635/645 SERIES TACTILE SWITCHES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		C&K Part No	Fig.	Operating Force	Height (mm)	Price Each	
Mfr.	Mfr. Part No.					1	25
12mm, Operating Temperature: -40°C to 60°C							
611-PTS125SM43-LFS	PTS125SM43 LFS		M	160g	4.3	.35	.30
611-PTS125SM85-LFS	PTS125SM85 LFS		M	160g	8.5	.35	.28
Microminiature SMT, 5.25mm x 5.25mm, Operating Temperature: -40°C to 60°C							
611-PTS525SM10-LFS	PTS525SM10SMTR LFS		Q	160g	1.5	.57	.45
6x6 mm, Operating Temperature: -20°C to 60°C							
611-PTS645SL70LFS	PTS645SL70 LFS		R	130g	3.6	.19	.14
611-PTS645VL31LFS	PTS645VL31 LFS		R	130g	3.6	.29	.23

RS SERIES: SUB-MINIATURE SMT TACTILE SWITCHES

Features:
 • Contact Form: SPST-NO Off-Momentary
 • Contact Rating: 0.05 AMP @12VDC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		C&K Part No	Fig.	Operating Force	Price Each	
Mfr.	Mfr. Part No.				1	25
611-RS014R05B1SMA10R	RS-014R05B1-SMA10 RT		S	160gf	.43	.314
611-RS-022R05C1-PA	RS-022R05C1-PA		T	160gf	.28	.20
611-RS-032G05A3-SMRT	RS-032G05A3-SM RT		U	250gf	.52	.42
611-RS187R05A2DSMTRT	RS-187R05A2-DS MT RT		V	160gf	.52	.42
611-RS-197N05A1-DSRT	RS-197N05A1-DS RT		W	160gf	.62	.50
611-RS-282G05A3-SMRT	RS-282G05A3-SM RT		X	250gf	.70	.62