


# C&K Pushbutton Switches

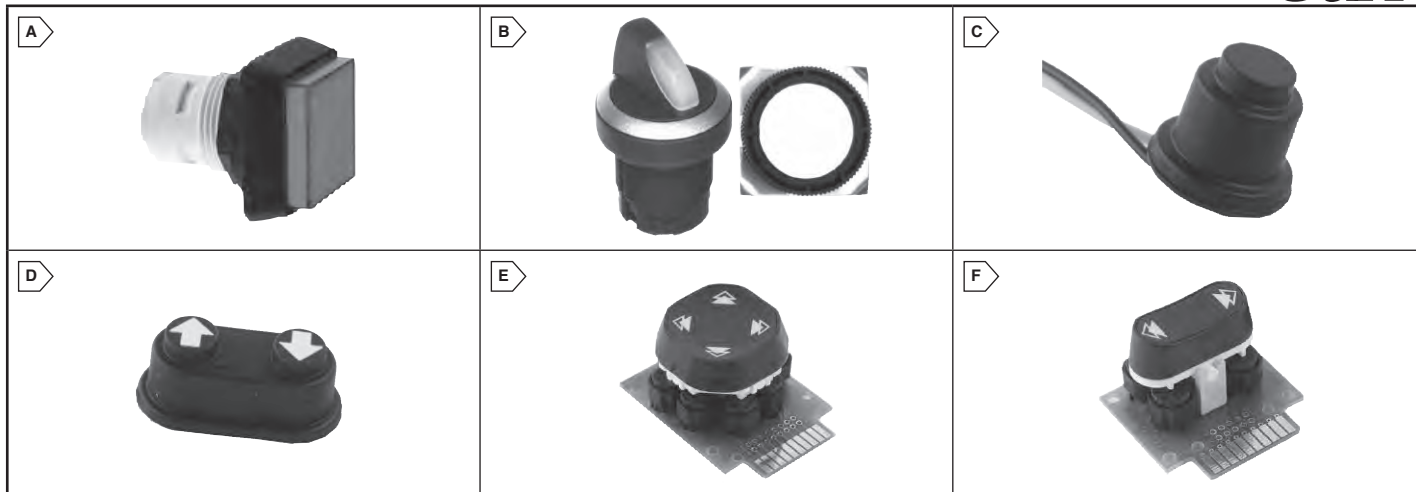

## C&K INDUSTRIAL CONTROL SWITCHES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Description	Price Each		
				1	25	50
611-1.10001.0110104	1.10001.0110104	-	Control Switch	9.71	7.76	6.98
611-1.15150.5060000	1.15150.5060000	-	Control Switch	28.51	26.59	25.28

## C&K RAFIX 16

RAFIX 16 is a complete control component series for a mounting hole diameter of 16.2mm. It enables you to design attractive control panels with minimum space requirements and at the same time sufficiently large actuating areas.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Description	Price Each		
				1	25	50
<b>Round Pushbutton Switches</b>						
611-1.30070.2510600	1.30070.2510600	A	square collar	17.59	16.40	15.59
611-1.30070.2710300	1.30070.2710300	A	round, 19.3mm dia.	18.32	17.08	16.25
611-1.30070.2710500	1.30070.2710500	A	round, 19.3mm dia.	18.32	17.08	16.25
611-1.30070.2710600	1.30070.2710600	A	round, 19.3mm dia.	18.32	17.08	16.25
611-1.30070.5010000	1.30070.5010000	A	square collar	16.49	15.37	14.63
611-1.20123.0030000	1.20123.0030000	A	contact blocks with silver contacts	23.31	18.39	16.91
611-1.20124.0190000	1.20124.0190000	A	contact blocks with silver contacts	26.52	20.95	19.25
611-1.20126.3030000	1.20126.3030000	A	contact blocks, 1NO 1NC	24.84	23.16	22.05
611-1.20126.3040000	1.20126.3040000	A	contact blocks, 2 NC	24.84	23.16	22.05
611-1.20126.3050000	1.20126.3050000	A	contact blocks, 2 NO	24.84	23.16	22.05
611-1.20126.7010000	1.20126.7010000	A	contact blocks, 1 NC	13.01	12.57	11.96
611-1.20126.7040000	1.20126.7040000	A	contact blocks, 2NC	24.84	23.16	22.05

## C&K RAFIX 22

RAFIX 22 FS control component range can be combined on a common printed circuit board together with short-travel keys and other components thanks to its extremely small mounting depth of 9.2mm. The actuators and signal indicators are fastened to a front panel with a threaded ring in a 22.3mm panel cut-out.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Description	Price Each		
				1	25	50
<b>Round Pushbutton, Momentary</b>						
611-1.30240.0211600	1.30240.0211600	B	Actuator, pushbutton, round	16.86	15.72	14.95
611-1.30240.0311300	1.30240.0311300	B	Actuator, pushbutton, round	29.61	27.60	26.27
611-1.30240.1210300	1.30240.1210300	B	Round, straight, pushbutton	10.84	10.44	9.36
611-1.30240.2211300	1.30240.2211300	B	Round, straight, pushbutton	16.00	15.62	14.56
611-1.30240.3210500	1.30240.3210500	B	Round, straight, pushbutton	10.84	10.44	9.36
<b>Selector Switches</b>						
611-1.30242.3022200	1.30242.3022200	B	60 degree latching selector switch	36.43	31.54	29.01
611-1.30242.4372200	1.30242.4372200	B	40 degree, 90 degree switch	44.81	35.84	32.59
<b>Keylock Switches</b>						
611-1.30245.2110300	1.30245.2110300	B	Keylock Switch	160.99	150.07	142.80
<b>Flush Round Pushbutton, Momentary</b>						
611-1.30250.1210300	1.30250.1210300	B	Actuator, pushbutton, round	9.98	8.94	8.62
611-1.30252.0022200	1.30252.0022200	B	Actuator, rotary switch	26.73	24.87	23.26
611-1.30252.0272200	1.30252.0272200	B	Actuator, rotary switch	26.73	24.87	23.26
611-1.30252.1022200	1.30252.1022200	B	Actuator, rotary switch	26.73	24.87	23.26
611-1.30252.2022200	1.30252.2022200	B	Actuator body switch	26.73	24.87	23.26

## C&K RS 76

The RS-76 full-travel keyswitches are designed for configuring keyboards. They offer very comfortable operation with an overall height of 15.5/15.9mm and a key travel of 4mm.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Description	Price Each		
				1	25	50
611-3.13001.2100000	3.13001.2100000	-	Square pushbutton	19.36	18.04	17.17
611-3.13002.5120000	3.13002.5120000	-	Square pushbutton	6.69	6.23	5.93
611-3.14002.0610000	3.14002.0610000	-	Square pushbutton	8.21	7.66	7.28

## Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Description	Price Each		
				1	25	50
611-1.90690.3410000	1.90690.3410000	-	RAFIX 22 multichip led red	23.21	20.00	18.70
611-1.90690.3420000	1.90690.3420000	-	RAFIX 22 multichip led green	33.93	33.11	30.87
611-5.04926.0081300	5.04926.0081300	-	Cap, round, 29.8mm dia.	1.54	1.51	1.40
611-5.04926.0081400	5.04926.0081400	-	Cap, round, 29.8mm dia.	1.54	1.51	1.40
611-5.04926.0081500	5.04926.0081500	-	Cap, round, 29.8mm dia.	1.54	1.51	1.40
611-5.04926.0081600	5.04926.0081600	-	Cap, blue round, 29.8mm dia.	1.60	1.52	1.44
611-5.46167.0440209	5.46167.0440209	-	Cap, round, plunger, 11.5mm dia.	.55	.444	.402
611-5.46168.0420209	5.46168.0420209	-	Cap, round, plunger, 11.5mm dia.	.56	.51	.45
611-5.46681.0211002	5.46681.0211002	-	-	.81	.766	.723
611-5.46681.0211403	5.46681.0211403	-	-	.81	.766	.723
611-5.49227.0041301	5.49227.0041301	-	-	1.33	1.22	1.17

## C&K ESM/DSM SINGLE & DOUBLE SWITCH MODULES

The single switch module ESM and the double switch module DSM are ready to install units.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Contact Form	Price Each		
				1	25	50
611-840110-1010	840110-1010	C	SPST ON - OFF	10.59	10.02	9.14
611-840210-2004	840210-2004	D	DPST ON - OFF	19.14	18.44	16.69
611-840210-2006	840210-2006	D	DPST ON - OFF	22.28	21.14	20.02
611-840210-2007	840210-2007	D	DPST ON - OFF	20.86	19.61	19.00
611-840210-2008	840210-2008	D	DPST ON - OFF	19.60	18.59	17.61

## C&K QS & RS SWITCH MODULES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Price Each		
			1	25	50
<b>Quadrant Switch</b>					
611-840300-0500	QS2 QQS1 BK N C	E	43.56	41.10	39.47
611-840300-0501	QS1 QQS1 BK N C	E	39.15	37.18	35.16
611-840300-0502	QS2 QQS1 BK S C	E	43.90	41.49	39.79
611-840300-0503	QS1 QQS1 BK S C	E	39.46	37.48	35.45
<b>Rocker Switch</b>					
611-840310-0500	RS2 KRSA BK N C	F	26.17	24.85	23.50
611-840310-0501	RS1 KRSA BK N C	F	26.09	24.78	23.43
611-840310-0503	RS1 KRSA BK S C	F	31.50	29.92	28.29