

NKK Pushbutton Switches



NKK PROCESS SEALED PUSHBUTTON SWITCHES

AB Series: Process Sealed Submini Pushbuttons

 
- Specifications:**
- Actuator: .213" length plunger
 - 0.4VA max. @ 28 VAC/DC max.




RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	NKK Part No.	Fig.	Circuit () = Momentary	Terminal	Price Each			
					1	25	50	100
633-AB11AP	AB11AP	A	SPST Off-(On)	PCB Straight	6.18	4.27	3.68	3.58
633-AB15AP	AB15AP	A	SPDT On-(On)	PCB Straight	4.14	3.57	3.06	2.98
633-AB25AP	AB25AP	A	DPDT On-(On)	PCB Straight	5.81	4.99	4.30	4.18
633-AB15AH	AB15AH	B	SPDT On-(On)	PCB R/A	5.16	5.06	4.78	4.33
Slip-On Caps for A Series		Description						
633-AT475A	AT475A	C	.201" X .157", black		.28	.27	.26	.23
633-AT475B	AT475B	C	.201" X .157", white		.29	.26	.25	.24
633-AT475C	AT475C	C	.201" X .157", red		.24	.22	.19	.18
633-AT496A	AT496A	D	.295" X .157", black		.32	.28	.24	.23
633-AT496B	AT496B	D	.295" X .157", white		.37	.33	.30	.28
633-AT496C	AT496C	D	.295" X .157", red		.36	.34	.32	.30



Shown w/optional cap AT475

 

Shown w/optional cap AT475

GB Series: Process Sealed Ultra-Mini Pushbuttons



- Specifications:**
- Actuator: .130" length plunger
 - 0.4VA max. @ 28 VAC/DC max.



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	NKK Part No.	Fig.	Circuit () = Momentary	Terminal	Price Each			
					1	25	50	100
633-GB15AP-RO	GB15AP	E	SPDT On-(On)	PCB Straight	4.26	4.04	3.46	3.31
633-GB25AP	GB25AP	E	DPDT On-(On)	PCB Straight	4.95	4.78	4.63	4.05
633-GB15AH-RO	GB15AH	F	SPDT On-(On)	PCB R/A	6.07	5.22	4.49	4.37
Slip-On Caps for G Series		Description						
633-AT4063A	AT4063A	G	.157" X .094", Black		.43	.36	.32	.29
633-AT4063B	AT4063B	G	.157" X .094", White		.72	.36	.32	.29
633-AT4063C	AT4063C	G	.157" X .094", Red		.72	.36	.32	.29

  

NKK FB SERIES: 0.5 AMP MOMENTARY PUSHBUTTONS


- Specifications:**
- Actuator: White plunger
 - Contacts: Silver 500mA@125VAC




RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	NKK Part No.	Fig.	Circuit () = Momentary	Terminal	Price Each			
					1	25	50	100
633-FB15ANEP2	FB15ANEP2	H	SPST Off-(On)	PC/Turret	3.69	3.16	3.01	2.62
Slip-on Caps for FB Series		Description						
633-AT475A	AT475A	C	.201" X .157", black		.28	.27	.26	.23
633-AT475B	AT475B	C	.201" X .157", white		.29	.26	.25	.24
633-AT475C	AT475C	C	.201" X .157", red		.24	.22	.19	.18
633-AT496A	AT496A	D	.295" X .157", black		.32	.28	.24	.23
633-AT496B	AT496B	D	.295" X .157", white		.37	.33	.30	.28
633-AT496C	AT496C	D	.295" X .157", red		.36	.34	.32	.30

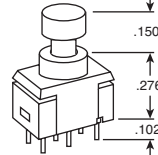

Shown w/optional cap AT4063

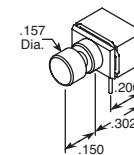

Shown w/optional cap AT4063

NKK SB SERIES: 3 AMP MOMENTARY PUSHBUTTONS


- Specifications:**
- Actuator: Black plunger
 - Contacts: Silver 3A @ 125VAC or 2A @ 30VDC




RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	NKK Part No.	Fig.	Circuit () = Momentary	Terminal	Price Each			
					1	25	50	100
633-SB4011NOM-RO	SB4011NOM	I	SPST Off-(On)	Solder Lug	3.58	3.53	3.31	3.04
633-SB4011NCM-RO	SB4011NCM	I	SPST On-(Off)	Solder Lug	3.58	3.55	3.33	3.11
Slip-on Caps for SB Series		Description						
633-AT422A	AT422A	J	.394" X .236", black		.41	.37	.35	.34
633-AT422B	AT422B	J	.394" X .236", white		.51	.47	.44	.43
633-AT422C	AT422C	J	.394" X .236", red		.41	.37	.36	.34

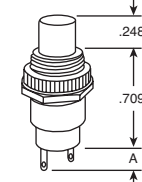

Dimension A:
SB4011NOM = .157
SB4011NCM = .197

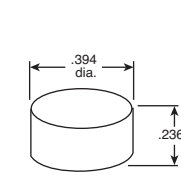

NKK ENVIRONMENTALLY SEALED PUSHBUTTON SWITCHES

- Specifications:**
- Power rating: 6A @ 125VAC, 3A @ 250VAC, 6A @ 30VDC
 - IP67 of IEC529
 - UL94V-0 rated
 - Wire leads: AWG 16 heat resistant PVC
 - .520" dia. black cap



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	NKK Part No.	Fig.	Circuit () = Momentary	Terminal	Price Each			
					1	25	50	100
633-WB12S-RO	WB12S-DA	K	SPDT On-None-On	Solder lug	18.02	16.53	15.41	15.20
633-WB12T-RO	WB12T-DA	K	SPDT On-None-On	Screw lug	20.97	19.21	17.92	15.90
633-WB12L-RO	WB12L-DA	K	SPDT On-None-On	Wire leads	31.64	29.01	27.06	25.65
633-WB15S-RO	WB15S-DA	K	SPDT On-None-(On)	Solder lug	20.77	19.02	17.75	17.50
633-WB15T-RO	WB15T-DA	K	SPDT On-None-(On)	Screw lug	21.77	19.96	18.62	18.40
633-WB15L-RO	WB15L-DA	K	SPDT On-None-(On)	Wire leads	32.48	29.76	27.74	24.56

