

HONEYWELL Toggle Switches


Honeywell

 This product is RoHS compliant.

MICRO SWITCH™ TOGGLE SWITCHES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Honeywell Part No.	Fig.	Contact Form	Circuitry	Action	Termination	Lever Type	Price Each		
								1	10	50
785-11TS115-3	11TS115-3	A	SPDT	ON-ON	2 position	Solder	Standard	15.56	12.95	11.53
785-11TS15-1	11TS15-1	A	SPDT	ON-OFF-ON	3 position	Screw	Standard	13.63	11.31	9.95
785-11TS15-2	11TS15-2	A	SPDT	OFF-ON	2 position	Screw	Standard	13.24	10.14	9.07
785-11TS15-5	11TS15-5	A	SPDT	(ON)-OFF-ON	3 position	Screw	Standard	17.56	16.54	12.94
785-11TS15-6	11TS15-6	A	SPST	(ON)-OFF	2 position	Screw	Standard	13.09	10.86	9.64
785-11TS15-7	11TS15-7	A	SPDT	(ON)-OFF-(ON)	3 position	Screw	Standard	14.71	12.92	11.65
785-11TS95-2	11TS95-2	A	SPDT	ON-OFF-ON	2 position	Quick Connect	Standard	10.71	9.06	8.01
785-11TS95-7	11TS95-7	A	SPDT	(ON)-OFF-(ON)	3 position	Quick Connect	Standard	13.50	12.01	9.95
785-11TW1-1	11TW1-1	B	SPDT	(ON)-OFF-(ON)	3 position	Quick Connect	Standard	36.58	34.30	31.82
785-11TW1-3	11TW1-3	B	SPDT	ON-ON	2 position	Solder	Standard	35.21	30.52	27.41
785-11TW8-3G	11TW8-3G	B	SPDT	ON-ON	2 position	Solder	Locking	106.92	101.33	95.74
785-12TW1-3	12TW1-3	B	DPDT	ON-ON	2 position	PCB	Standard	43.09	39.32	36.51
785-12TW1-5	12TW1-5	B	DPDT	(ON)-OFF-ON	3 position	Solder	Standard	43.82	36.41	32.63
785-12TW1-7	12TW1-7	B	DPDT	(ON)-OFF-(ON)	3 position	Solder	Standard	29.21	23.22	20.82
785-12TS115-1	12TS115-1	C	DPDT	ON-OFF-ON	3 position	Solder	Standard	16.04	13.30	11.82
785-12TS115-2	12TS115-2	C	DPST	OFF-ON	2 position	Solder	Standard	13.57	11.33	9.97
785-12TS115-3	12TS115-3	C	DPDT	ON-ON	2 position	Solder	Standard	18.87	15.66	13.77
785-12TS15-1	12TS15-1	C	DPDT	ON-OFF-ON	3 position	Screw	Standard	14.58	12.96	11.65
785-12TS15-2	12TS15-2	C	DPST	OFF-ON	2 position	Screw	Standard	17.77	14.73	12.96
785-12TS15-3	12TS15-3	C	DPDT	ON-ON	2 position	Screw	Standard	17.70	15.86	14.32
785-12TS15-6	12TS15-6	C	DPST	(ON)-OFF	2 position	Screw	Standard	21.61	19.40	15.78
785-12TS15-7	12TS15-7	C	DPDT	(ON)-OFF-(ON)	3 position	Screw	Standard	19.10	16.91	15.19
785-12TS95-3	12TS95-3	C	DPDT	ON-ON	2 position	Quick Connect	Standard	16.38	13.58	13.09
785-12TS95-70	12TS95-70	C	DPDT	(ON)-OFF-(ON)	3 position	Quick Connect	Standard	30.81	27.92	25.57
785-12TW8-7E	12TW8-7E	D	DPDT	(ON)-OFF-(ON)	3 position	Solder	Locking	111.34	101.93	95.13
785-1NT1-2	1NT1-2	E	SPST	OFF-ON	2 position	Screw	Standard	14.85	12.60	11.40
785-1NT1-3	1NT1-3	E	SPDT	ON-ON	2 position	Screw	Standard	16.64	15.83	15.08
785-1NT1-6	1NT1-6	E	SPST	(ON)-OFF	2 position	Screw	Standard	16.21	15.41	14.67
785-1NT1-7	1NT1-7	E	SPDT	(ON)-OFF-(ON)	3 position	Screw	Standard	16.34	14.73	12.91
785-1NT1-8	1NT1-8	E	SPDT	ON-ON	2 position	Screw	Standard	25.56	23.26	20.20
785-1NT1-3D	1NT1-3D	F	SPDT	ON-ON	2 position	Screw	Locking	47.52	45.06	42.95
785-1TL1-1	1TL1-1	F	SPDT	ON-OFF-ON	3 position	Screw	Standard	23.47	21.13	18.34
785-1TL1-1A	1TL1-1A	F	SPDT	ON-OFF-ON	3 position	Screw	Locking	39.60	36.69	31.45
785-1TL1-2	1TL1-2	F	SPST	OFF-ON	2 position	Screw	Standard	24.36	21.32	20.30
785-1TL1-2D	1TL1-2D	F	SPST	OFF-ON	2 position	Screw	Locking	37.03	34.69	33.16
785-1TL1-3	1TL1-3	F	SPDT	OFF-ON	2 position	Screw	Standard	23.96	20.47	18.34
785-1TL1-3D	1TL1-3D	F	SPDT	ON-ON	2 position	Screw	Locking	46.65	38.71	36.70
785-1TL1-4	1TL1-4	F	SPST	(OFF)-ON	2 position	Screw	Standard	24.59	22.78	19.54
785-1TL1-5	1TL1-5	F	SPDT	(ON)-OFF-ON	3 position	Screw	Standard	25.73	20.47	18.34
785-1TL1-6	1TL1-6	F	SPST	(ON)-OFF	2 position	Screw	Standard	24.72	22.26	19.25
785-1TL1-7	1TL1-7	F	SPDT	(ON)-OFF-(ON)	3 position	Screw	Standard	22.99	21.09	18.43
785-1TL1-7L	1TL1-7L	F	SPDT	(ON)-OFF-(ON)	3 position	Screw	Locking	43.96	41.74	39.59
785-1TL1-8	1TL1-8	F	SPDT	ON-ON	2 position	Screw	Standard	24.22	21.79	18.70
785-1TL1-8F	1TL1-8F	F	SPDT	ON-ON	2 position	Screw	Locking	62.63	60.17	57.23
785-1TW1-3	1TW1-3	G	SPDT	ON-ON	2 position	Solder	Standard	58.04	48.23	42.67
785-2NT1-1	2NT1-1	H	DPDT	ON-OFF-ON	3 position	Screw	Standard	36.82	34.37	29.88
785-2NT1-2	2NT1-2	H	DPST	OFF-ON	2 position	Screw	Standard	36.10	33.70	29.30
785-2NT1-3	2NT1-3	H	DPDT	ON-ON	2 position	Screw	Standard	33.86	30.47	26.87
785-2NT1-50	2NT1-50	H	DPDT	(ON)-ON-ON	3 position	Screw	Standard	43.52	34.74	31.21
785-2NT1-7	2NT1-7	H	DPDT	(ON)-OFF-(ON)	3 position	Screw	Standard	36.10	33.70	29.30
785-2NT1-70	2NT1-70	H	DPDT	(ON)-ON-(ON)	3 position	Screw	Standard	38.95	34.77	30.44
785-2NT1-8	2NT1-8	H	DPDT	ON-ON	2 position	Screw	Standard	35.75	33.51	31.07
785-2TL1-1A	2TL1-1A	H	DPDT	ON-OFF-ON	3 position	Screw	Locking	47.44	43.86	40.82
785-2TL1-1E	2TL1-1E	H	DPDT	ON-OFF-ON	3 position	Screw	Locking	52.81	49.46	45.17
785-2TL1-2D	2TL1-2D	H	DPST	OFF-ON	2 position	Screw	Locking	53.14	49.23	44.88
785-2TL1-3D	2TL1-3D	H	DPDT	ON-ON	3 position	Screw	Locking	51.62	47.82	43.60
785-2TL1-3G	2TL1-3G	H	DPDT	ON-ON	2 position	Screw	Locking	51.69	42.90	38.12
785-2TL1-6F	2TL1-6F	H	DPST	(ON)-OFF	2 position	Screw	Locking	48.58	45.50	41.54
785-2TL1-7E	2TL1-7E	H	DPDT	(ON)-OFF-(ON)	3 position	Screw	Locking	49.16	41.22	38.66
785-4TL1-3D	4TL1-3D	H	4PDT	ON-ON	2 position	Screw	Locking	81.15	67.21	61.81
785-4TL1-7	4TL1-7	H	4PDT	(ON)-OFF-(ON)	3 position	Screw	Standard	61.58	57.37	50.09
785-2TL1-1	2TL1-1	I	DPDT	ON-OFF-ON	3 position	Screw	Standard	34.89	27.90	25.01
785-2TL1-10	2TL1-10	I	DPDT	ON-ON-ON	3 position	Screw	Standard	35.75	32.15	28.10
785-2TL1-10A	2TL1-10A	I	DPDT	ON-ON-ON	3 position	Screw	Locking	56.68	51.02	44.58
785-2TL1-2	2TL1-2	I	DPST	OFF-ON	2 position	Screw	Standard	34.39	27.34	24.51
785-2TL1-3	2TL1-3	I	DPDT	ON-ON	3 position	Screw	Standard	31.43	27.34	24.51
785-2TL1-4	2TL1-4	I	DPST	(OFF)-ON	2 position	Screw	Standard	44.74	42.45	40.15
785-2TL1-5	2TL1-5	I	DPDT	(ON)-OFF-ON	3 position	Screw	Standard	37.56	29.87	26.77
785-2TL1-50	2TL1-50	I	DPDT	(ON)-ON-ON	3 position	Screw	Standard	35.06	31.63	27.61
785-2TL1-7	2TL1-7	I	DPDT	(ON)-OFF-(ON)	3 position	Screw	Standard	31.37	25.62	24.41
785-2TL1-70	2TL1-70	I	DPDT	(ON)-ON-(ON)	3 position	Screw	Standard	36.62	34.84	31.16
785-4NT1-1	4NT1-1	I	4PDT	ON-OFF-ON	3 position	Screw	Standard	57.98	50.63	47.15
785-4NT1-3	4NT1-3	I	4PDT	ON-ON	2 position	Screw	Standard	67.72	61.94	54.19
785-4NT1-7	4NT1-7	I	4PDT	ON-OFF-ON	3 position	Screw	Standard	61.25	57.40	54.93
785-4TL1-1	4TL1-1	I	4PDT	ON-OFF-ON	3 position	Screw	Standard	56.97	47.19	43.39
785-4TL1-12	4TL1-12	I	4PDT	ON-ON-ON	3 position	Screw	Standard	87.57	72.54	66.68
785-4TL1-2	4TL1-2	I	4PST	OFF-ON	2 position	Screw	Standard	53.23	51.02	46.90
785-4TL1-3	4TL1-3	I	4PDT	ON-ON	2 position	Screw	Standard	56.97	52.13	45.56
785-4TL1-5	4TL1-5	I	4PDT	(ON)-OFF-ON	3 position	Screw	Standard	57.59	53.93	49.25
785-4TL1-72	4TL1-72	I	4PDT	(ON)-ON-(ON)	3 position	Screw	Standard	70.04	64.90	51.11
785-4TL1-8	4TL1-8	I	4PDT	(ON)-ON	2 position	Screw	Standard	59.95	58.04	56.55
785-61NT1-2	61NT1-2	I	SPST	OFF-ON	2 position	Screw	Standard	28.93	25.04	22.95
785-2TW1-3	2TW1-3	J	DPDT	ON-ON	2 position	Solder	Standard	59.68	50.86	44.25
785-31NT391-7-C08	31NT391-7-C08	K	SPDT	(ON)-OFF-(ON)	3 position	Quick Connect	Tab	40.40	37.86	34.89
785-31NT91-2	31NT91-2	L	SPST	OFF-ON	2 position	Quick Connect	Standard	15.12	13.16	11.86
785-31NT91-3	31NT91-3	L	SPDT	ON-ON	2 position	Quick Connect	Standard	28.87	20.85	19.54
785-31NT91-7	31NT91-7	L	SPDT	(ON)-OFF-(ON)	3 position	Quick Connect	Standard	27.23	19.67	18.43
785-32NT91-70	32NT91-70	L	DPDT	(ON)-ON-(ON)	3 position	Quick Connect	Standard	32.09	31.20	28.44
785-32NT91-1	32NT91-1	M	DPDT	ON-OFF-ON	3 position	Quick Connect	Standard	31.47	30.59	27.89
785-32NT91-2	32NT91-2	M	DPST	OFF-ON	2 position	Quick Connect	Standard	33.37	32.44	29.57
785-32NT91-3	32NT91-3	M	DPDT	ON-ON	2 position	Quick Connect	Standard	32.72	31.81	29.00
785-32NT91-7	32NT91-7	M	DPDT	(ON)-OFF-(ON)	3 position	Quick Connect	Standard	30.86	30.00	27.35

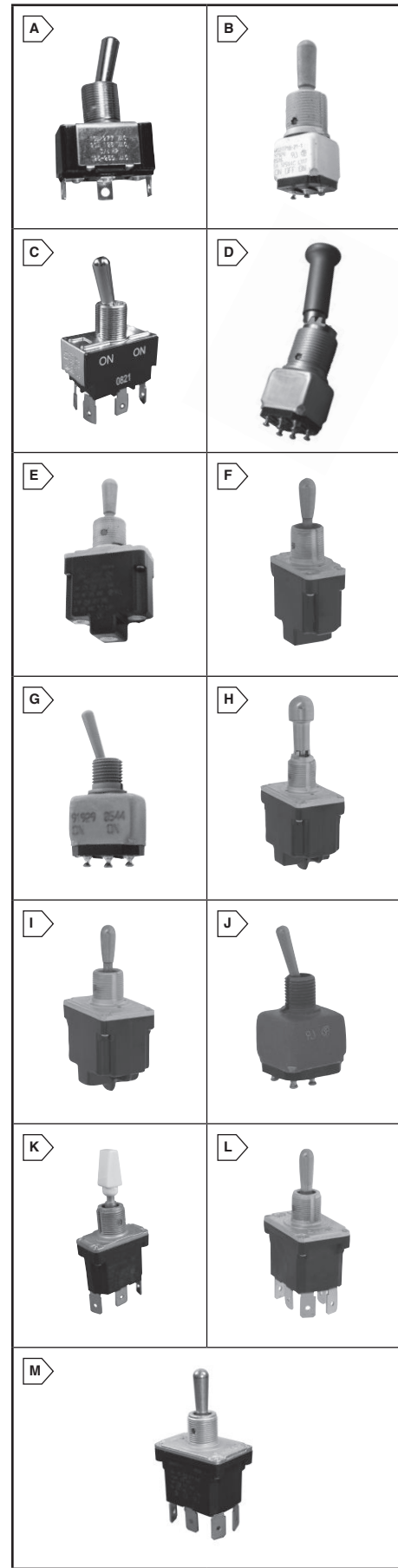

Honeywell Toggle Switches