


C&K Rocker Switches

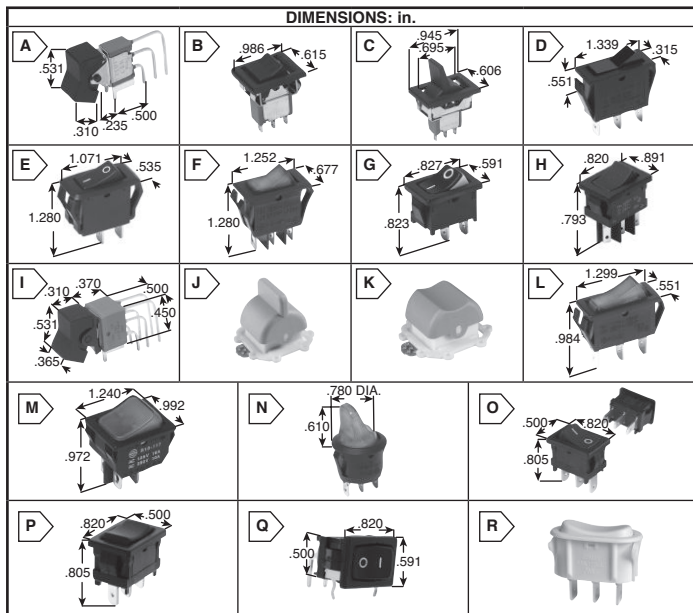

C&K 7000 SERIES: ROCKER SWITCHES

• Contact Material: End Contacts - Coin Ag over Ag plate
Center contact and all terminals - Cu alloy over Ag plate
• Contact Rating: 5A @ 120VAC or 28VDC, 2A @ 250VAC

• Termination: Solder lug
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each		
				1	25	100
611-7101J3V6BE3	7101J3V6BE3	A	SPDT On-None-On	8.27	7.73	7.01
611-7101J60CQE3	7101J60CQE3	A	SPDT On-None-On	7.28	6.77	6.14
611-7105J1ZQE2	7105J1ZQE2	A	SPDT (On)-Off-(On)	8.20	7.85	6.92
611-7105J3ZQE2	7105J3ZQE2	A	SPDT (On)-Off-(On)	9.01	8.62	7.05
611-7205J3ZQE2	7205J3ZQE2	A	DPDT (On)-Off-(On)	9.26	8.82	7.79
611-7101J51ZQE22	7101J51ZQE22	B	SPDT (On)-None-On	6.61	6.08	5.38
611-7105J51ZQE22	7105J51ZQE22	B	SPDT (On)-Off-(On)	7.27	7.00	6.00
611-7107-022	7107J51ZQE22	B	SPDT On-Off-(On)	7.27	6.71	6.00
611-7108J51ZQE22	7108J51ZQE22	B	SPDT On-None-(On)	9.01	8.62	7.59
611-7201J51ZQE22	7201J51ZQE22	B	DPDT On-None-On	8.57	7.72	6.77
611-7205J51ZQE22	7205J51ZQE22	B	DPDT (On)-Off-(On)	11.83	11.34	9.91
611-7203J51ZQE22	7203J51ZQE22	B	DPDT On-Off-(On)	9.69	9.33	7.79
611-7201J61ZQE2	7201J61ZQE22	C	DPDT On-None-On	8.87	8.62	7.13
611-7203J61ZQE2	7203J61ZQE22	C	DPDT On-Off-(On)	9.69	9.33	7.79
611-7205J61ZQE22	7205J61ZQE22	C	DPDT (On)-Off-(On)	9.37	8.43	7.40

C&K CA SERIES: POWER ROCKER SWITCHES

• 15AMPS @ 125VAC • Positive detent (non-illuminated rocker)

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each		
				1	25	100
611-CA01J12207HQ	CA01J12207HQ	D	SPDT, On-On	2.09	1.94	1.77
611-CA02J11207Q	CA02J11207Q	D	SPST, On-Off	1.87	1.75	1.59
611-CA22J76207PQ	CA22J76207PQ	D	DPST, On-Off	4.24	4.03	3.56
611-CA04J137107DQ	CA04J137107DQ	D	SPST, On-Off	3.27	3.04	2.77
611-CA24J167207DQ	CA24J167207DQ	D	DPST, On-Off	4.36	3.79	3.40
611-CA24J737207Q	CA24J737207Q	D	DPST, On-Off	4.20	3.91	3.56

C&K CG/CL SERIES: SINGLE POLE POWER ROCKER SWITCHES

• Bevelled frame • Easy panel mount installation • Positive detent (CL Series)

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each		
				1	25	100
611-CG102J11S205QF	CG102J11S205QF	E	SPDT On-None-On	1.75	1.55	1.23
611-CG102J11S205PQF	CG102J11S205PQF	E	SPST On-None-Off	1.68	1.49	1.19
611-CG102J11S205QF	CG102J11S205QF	E	SPST On-None-Off	1.54	1.38	1.09
611-CG102J25S205QF	CG102J25S205QF	E	SPST On-None-Off	1.98	1.85	1.56
611-CG102J3AS205QF7	CG102J3AS205QF7	E	SPST On-None-Off	2.12	2.03	1.83
611-CL101J71S205QA	CL101J71S205QA	F	SPDT On-None-On	1.41	1.34	1.21
611-CL101J72S205QA	CL101J72S205QA	F	SPDT On-None-On	1.42	1.25	1.01
611-CL102J71S205QA	CL102J71S205QA	F	SPST On-None-Off	1.27	1.22	1.11
611-CL102J72S205HQA	CL102J72S205HQA	F	SPST On-None-Off	1.36	1.20	.971
611-CL102J72S205PQA	CL102J72S205PQA	F	SPST On-None-Off	1.42	1.25	1.00
611-CL102J9GS205QA7	CL102J9GS205QA7	F	SPST On-None-Off	1.75	1.55	1.24

C&K DA SERIES: MINIATURE SINGLE POLE ROCKER SWITCHES

• Contact Rating: UL/CSA: 16AMPS @ 125VAC, 1/3 HP; 10AMPS @ 250VAC, 1/2 HP VDC; 10AMPS @ 125VAC, 6AMPS @ 250VAC

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each		
				1	25	100
611-DA101J11B215PQF	DA101J11B215PQF	G	SPDT On-None-On	1.60	1.50	1.35
611-DA101J11S115QF	DA101J11S115QF	G	SPDT On-None-On	1.29	1.23	1.12
611-DA101J11S215QF	DA101J11S215QF	G	SPDT On-None-On	1.18	1.13	1.02
611-DA101J11S2APQF	DA101J11S2APQF	G	SPDT On-None-On	1.39	1.28	1.16
611-DA101J12S215QF	DA101J12S215QF	G	SPDT On-None-On	1.07	.99	.875
611-DA101J12S2APQF	DA101J12S2APQF	G	SPDT On-None-On	1.33	1.23	1.12
611-DA102J11S215PQF	DA102J11S215PQF	G	SPST On-None-Off	1.16	1.11	1.01
611-DA102J11S215QF	DA102J11S215QF	G	SPST On-None-Off	1.02	.959	.87
611-DA102J12S215DQF	DA102J12S215DQF	G	SPST On-None-Off	1.07	.99	.875
611-DA102J12S215PQF	DA102J12S215PQF	G	SPST On-None-Off	1.07	.99	.875
611-DA102J12S217QF	DA102J12S217QF	G	SPST On-None-Off	1.25	1.16	1.03
611-DA102J3GS215QF8	DA102J3GS215QF8	G	SPST On-None-Off	1.39	1.33	1.19
611-DA12J3GS215HQF6	DA12J3GS215HQF6	G	SPST ON-None-Off	1.30	1.20	1.09

C&K DM SERIES: MINIATURE POWER ROCKER SWITCHES

• Contact Material: Q: Cu alloy, Ag Plated
• Contact Rating: 10AMPS @ 125VAC; 5AMPS @ 250VAC

RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each		
				1	25	100
Non-Illuminated						
611-DM61-122	DM61J12S205Q	H	DPDT On-On	4.78	4.49	4.07
611-DM61J12S205PQ	DM61J12S205PQ	H	DPDT On-On	5.70	4.90	3.99
611-DM62J12S205PQ	DM62J12S205PQ	H	DPST On-Off	5.33	4.68	4.31
Illuminated						
611-DM54J72S205Q3	DM54J72S205Q3	H	SPST On-Off	4.24	4.02	3.55
611-DM64J72S205Q3	DM64J72S205Q3	H	DPST On-Off	5.76	5.45	4.53

C&K E SERIES: SEALED MINIATURE ROCKER AND LEVER HANDLE SWITCHES

• Contact Rating: B contact material: 0.4 VA max. @20 vac or DC max. Q contact material (E1XX & E2XX Models): 7.5AMPS @ 125VAC or 28VDC; 3AMPS @ 250 VAC. (E3XX Models): 5AMPS @ 125VAC or 28VDC; 2AMPS @ 250VAC

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each		
				1	25	100
611-E101J1V3SE2	E101J1V3SE2	I	SPDT On-None-On	7.94	7.41	6.72
611-E203J1AV2QE2	E203J1AV2QE2	I	DPDT Off-Off-On	11.79	11.01	9.99
611-ET05J6SAPE2	ET05J6SAPE2	I	DPDT On-Off-On	6.90	6.42	5.83

C&K ANALOG ROCKER SWITCHES

• Analog was developed to provide the reliability required in demanding environments

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Operating Force	Price Each	
				1	25
AR3 and AR5 Series Hall Effect					
611-890003-0101	AR3S 01 GY 30/30 4N 0 V200	J	4N	115.60	100.98
611-890003-0102	AR3S 02 GY 30/30 5N 0 V202	J	5N	108.05	97.83
611-890003-0115	AR3S 05 GY 30/30 6N 1 V200	J	6N	102.00	92.35
611-890003-0121	AR3S 01 GY 30/30 4N 0 V102	J	6N	71.68	64.90
611-890003-0122	AR3S 02 GY 30/30 5N 0 V102	J	5N	88.25	79.90
611-890003-0125	AR3S 05 GY 30/30 6N 0 V102	J	6N	88.25	79.90
611-8G5022C0106	AR5S DTC BN	J	6N	102.76	98.00
SR3 Series					
611-890003-0002	SR3S 02 GY 5N/5N 01 R00 M	K	5 N Left / 5N Right	19.69	16.20
611-890003-0005	SR3S 05 GY 5N/5N 01 R00 M	K	6 N Left / 5N Right	30.19	27.33

C&K CM/CN SERIES: POWER ROCKER SWITCHES

• Robust design-CN Series • Illumination available

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each	
				1	25
611-CM101J11S205QA	CM101J11S205QA	L	SPDT On-None-On	1.51	1.44
611-CM101J12S207QA	CM101J12S207QA	L	SPDT On-None-On	1.86	1.64
611-CM102J11S205QA	CM102J11S205QA	L	SPDT On-Off-On	1.28	1.22
611-CM102J12S207QA	CM102J12S207QA	L	SPDT On-Off-On	1.60	1.43
611-CM102J12S405QA	CM102J12S405QA	L	SPDT On-Off-On	1.27	1.13
611-CM102J3AS205QA8	CM102J3AS205QA8	L	SPDT On-Off-On	1.84	1.75
611-CM103J12S205QA	CM103J12S205QA	L	SPDT On-Off-On	1.59	1.52
Double Pole					
611-CN201J11S115Q	CN201J11S115Q	M	DPDT On-None-On	3.42	3.10
611-CN201J11S215Q	CN201J11S215Q	M	DPDT On-None-On	2.54	2.42
611-CN201J62S405QA	CN201J62S405QA	M	DPDT On-None-On	2.22	2.07
611-CN202J11S215PQ	CN202J11S215PQ	M	DPST On-None-Off	2.45	2.33
611-CN202J3AS215Q7	CN202J3AS215Q7	M	DPST On-None-Off	2.46	2.34
611-CN202J62S405QA	CN202J62S405QA	M	DPST On-None-Off	2.54	2.48
611-CN22J3RS215HQ8	CN22J3RS215HQ8	M	DPST On-None-Off	2.52	2.35

C&K CR SERIES: ROUND SINGLE POLE SPECIALTY ROCKER SWITCHES

• Round actuator and body • Nice styling

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each	
				1	25
611-CR101J11S215QF	CR101J11S215QF	N	SPDT On-None-On	1.48	1.31
611-CR102J3AS215QF7	CR102J3AS215QF7	N	SPST On-None-Off	1.70	1.61
611-CR102J3AS215QF8	CR102J3AS215QF8	N	SPST On-None-Off	1.75	1.55
611-CR102J3GS215QF8	CR102J3GS215QF8	N	SPST On-None-Off	1.75	1.55
611-CR102J4RS215QF7	CR102J4RS215QF7	N	SPST On-None-Off	1.89	1.66
611-CR102JPRS215QF7	CR102JPRS215QF7	N	SPST On-None-Off	2.56	2.27

C&K ANALOG ROCKER SWITCHES

• Contact Rating: D10X: 4AMPS @ 125VAC; 2AMPS @ 250VAC
D50X & D60X: 10AMPS @ 125VAC; 5AMPS @ 250VAC

RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each	
				1	25
Quick Connect					
611-D102J12S215PQA	D102J12S215PQA	O	SPST On-None-Off	2.49	2.20
611-D501001	D501J12S215PQF	O	SPDT On-None-On	3.95	3.43
611-D501J12S215QA	D501J12S215QA	O	SPDT On-None-On	2.81	2.45
611-D502J12S215PQF	D502J12S215PQF	O	SPST On-None-Off	2.85	2.48
611-D502J12S215PQA	D502J12S215PQA	O	SPST On-None-Off	2.32	2.22
611-D601J12S215PQF	D601J12S215PQF	O	DPDT On-None-On	4.88	4.09
611-D602J12S215PQF	D602J12S215PQF	O	DPST On-None-Off	5.08	4.68
Twisted Quick Connect					
611-D105J12S205QA	D105J12S205QA	P	SPDT (On)-Off-(On)	6.30	6.01
611-D508J12S205QA	D508J12S205QA	P	SPDT (On)-None-(On)	3.73	3.24
RVA PC Thru-Hole					
611-D501J12S2AHQF	D501J12S2AHQF	Q	SPDT On-None-On	4.91	4.26
611-D501J12S2APQF	D501J12S2APQF	Q	SPDT On-None-On	5.47	4.28

C&K SW SERIES: ROCKER AND PADDLE SWITCH

• Contact Rating: 6.5 AMPS @ 125VAC
• Different colors available
• Oval Shape

Typical Applications
• Designed for overhead oven/range hoods

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	Switch Function	Price Each
611-SW-13A65N-A01BK	SW-13A65N-A01 BK	R	SPDT On-Off-On	2.40 2.12 1.81

