

CHERRY Rocker Switches

RoHS Compliant This product is RoHS compliant.



CHERRY MINIATURE ROCKER SWITCHES

Specifications:

- Dielectric Strength: 1000VAC for 1 minute
- Insulation Resistance: 10⁸ Ω min at 500VDC
- All part numbers have a black bezel.
- .187" Q.C. Terminals



LR Series - Power Rating: 10A 125 VAC and 8A 250 VAC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-LRA32H2FBBNN	LRA32H2FBBNN	A	DPST On-Off	Black / O -	1.03	.83	.70	.64
540-LRA22H2BBRLN	LRA22H2BBRLN	A	SPST On-Off	Red Illuminated / Blank	1.10	.88	.72	.66
540-LRA32H2BBRLN	LRA32H2BBRLN	A	DPST On-Off	Red Illuminated / Blank	1.24	1.04	.85	.78

SR Series - Power Rating: 10A 125 VAC and 6A 250 VAC

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-SRB22A2FBBNN	SRB22A2FBBNN	B	SPST On-Off	Black / O -	.75	.60	.53	.49
540-SRB23A2BBNN	SRB23A2BBNN	B	SPDT On-On	Black / Blank	.86	.72	.59	.54
540-SRB24A2HBBNN	SRB24A2HBBNN	B	SPDT On-Off-On	Black / I O II	1.00	.84	.69	.63
540-SRB22A2DBNN	SRB22A2DBNN	B	SPST On-Off	Black / ON OFF	.79	.66	.54	.49

CHERRY POWER ROCKER SWITCHES

Specifications:

- Dielectric Strength: 1000VAC for 1 minute
- Insulation Resistance: 10⁸ Ω min at 500VDC
- All part numbers have a black bezel.
- .250" Q.C. Terminals



CR Series - Power Rating: 20A 125 VAC and 16A 250 VAC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-CRE22F2FBBNE	CRE22F2FBBNE	C	SPST On-Off	Black / O -	.98	.82	.67	.61
540-CRE22F4BBBNE	CRE22F4BBBNE	C	SPST On-Off	Black-Red / Blank	1.00	.84	.69	.63
540-CRE24F2HBBNE	CRE24F2HBBNE	C	SPDT On-Off-On	Black / I O II	1.12	.94	.77	.70
540-CRE22F2BBRLE	CRE22F2BBRLE	C	SPST On-Off	Red Illuminated / Blank	1.22	1.02	.84	.76

PR Series - Power Rating: 6A 125 VAC and 3A 250 VAC

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-PRK22J5BBBNN	PRK22J5BBBNN	D	SPST On-Off	Black / Blank	1.08	.90	.74	.67
540-PRK22J5DBBNN	PRK22J5DBBNN	D	SPST On-Off	Black / On-Off	1.03	.82	.68	.62

TR Series - Power Rating: 16A 125 VAC and 16A 250 VAC

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-TRG22F2FBBNN	TRG22F2FBBNN	E	SPST On-Off	Black / O -	1.08	.90	.74	.67

WR Series - Power Rating: 16A 125 VAC and 16A 250 VAC

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-WRG32F2FBBNN	WRG32F2FBBNN	F	DPST On-Off	Black / O -	1.39	1.16	.95	.87

YR Series - Power Rating: 20A 125 VAC and 16A 250 VAC

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Price Each			
					1	50	100	250
540-YRM32F2FBBNN	YRM32F2FBBNN	G	DPST On-Off	Black / O -	1.89	1.58	1.30	1.18
540-YRM33F2BBBNN	YRM33F2BBBNN	G	DPDT On-On	Black / Blank	2.00	1.64	1.35	1.25
540-YRM32F2BBRLN	YRM32F2BBRLN	G	DPST On-Off/Lighted	Black / Blank	2.35	1.96	1.61	1.47

CHERRY ROUND ROCKER SWITCHES

Specifications:

- Dielectric Strength: 1000VAC for 1 minute
- Insulation Resistance: 10⁸ Ω min at 500VDC
- .187" Q.C. Terminals




RR Series - Power Rating: 10A 125 VAC and 8A 250 VAC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Bezel Color	Lamp	Price Each			
							1	50	100	250
540-RAA22H3FBRNN	RAA22H3FBRNN	H	SPST On-Off	Red / O -	Black	-	1.03	.83	.70	.64
540-RAA32H3FBBNN	RAA32H3FBBNN	H	DPST On-Off	Black / O -	Black	-	1.45	1.16	.95	.87
540-RAA22H3BBRLN	RAA22H3BBRLN	H	SPST On-Off	Red Illuminated / Blank	Black	125 VAC	1.31	1.05	.86	.79
540-RAA22H3BBGLN	RAA22H3BBGLN	H	SPST On-Off	Green Illuminated / Blank	Black	125 VAC	1.36	1.14	.94	.85
540-RAA22H3BBALN	RAA22H3BBALN	H	SPST On-Off	Amber Illuminated / Blank	Black	125 VAC	1.36	1.14	.94	.85
540-RAA32H3BBRLN	RAA32H3BBRLN	H	DPST On-Off	Red Illuminated / Blank	Black	125 VAC	1.82	1.52	1.25	1.14
540-RAA22H3BBRHN	RAA22H3BBRHN	H	SPST On-Off	Red Illuminated / Blank	Black	12 VDC	1.31	1.05	.86	.79

SR Series - Power Rating: 20A 125 VAC and 12A 250 VAC

MOUSER STOCK NO.	Cherry Part No.	Fig.	Circuit	Rocker Color / Legend	Bezel Color	Lamp	Price Each			
							1	50	100	250
540-SRJ22A3BBBNN	SRJ22A3BBBNN	I	SPST On-Off	Black / Blank	Black	-	1.15	.96	.79	.72
540-SRJ23A3BBBNN	SRJ23A3BBBNN	I	SPST On-On	Black / Blank	Black	-	1.34	1.12	.92	.84
540-SRJ24A3BBBNN	SRJ24A3BBBNN	I	SPDT On-Off-On	Black / Blank	Black	-	1.46	1.22	1.00	.91
540-SRJ24A3HBBNN	SRJ24A3HBBNN	I	SPDT On-Off-On	Black / I O II	Black	-	1.46	1.22	1.00	.91

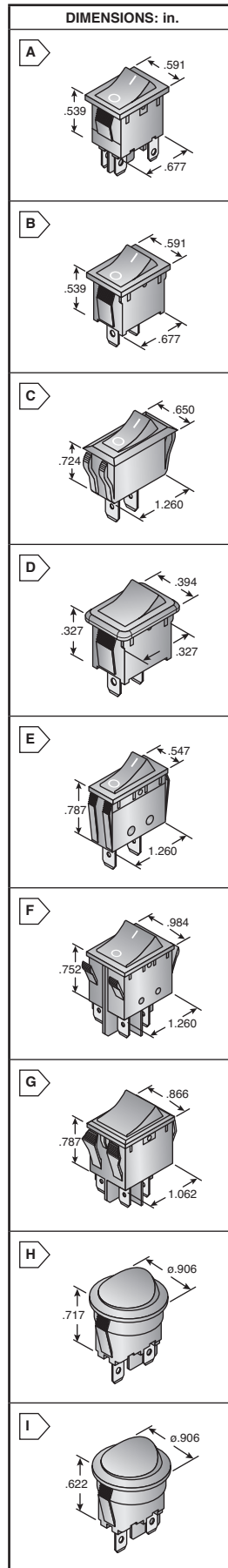

Cherry Rocker Switches