

MOUNTAIN SWITCH Slide Switches



RoHS Compliant This product is RoHS compliant.

MINIATURE PC TERMINAL SLIDE SWITCHES

Specifications:

- Contact Resistance: 10mΩ max.
- Insulation Resistance: 1000MΩ min.
- Electrical Life: 30,000 cycles
- Operating Temperature: -30°C to +85°C




RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Rating	Knob Ht. (in.)	Price Each		
						1	50	100
103-12100-EV	A	SPDT	On-On	.5A/50VDC	.12	.45	.37	.34
103-1256-EV	B	SPDT	On-On	.5A/50VDC	.157	.51	.42	.39

DIMENSIONS: in.

A

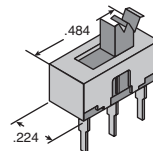

SUB-MINIATURE PC TERMINAL SLIDE SWITCH

Specifications:


- Contact Resistance: 10mΩ max.
- Insulation Resistance: 1000MΩ min.
- Electrical Life: 30,000 cycles
- Operating Temperature: -30°C to +85°C




RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Rating	Knob Ht. (in.)	Price Each		
						1	50	100
103-12123-EV	C	SPDT	On-On	.5A/50VDC	.157	1.05	.87	.80

B

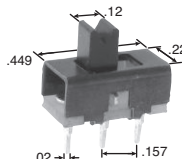

C

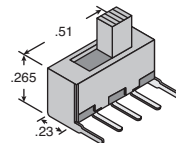

SOLDER TERMINAL SLIDE SWITCH

Specifications:


- Contact Resistance: 10mΩ max.
- Insulation Resistance: 1000MΩ min.
- Electrical Life: 30,000 cycles
- Operating Temperature: -30°C to +85°C




RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Rating	Knob Ht. (in.)	Price Each		
						1	50	100
10SS002-EV	D	DPDT	On-On	.5A/125VAC	.35	1.13	.93	.86

D

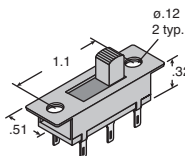

E

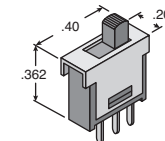

Mountain Switch

SLIDE SWITCHES

Sub-Miniature Slide Switches

Specifications:


- Rating: 1A/250VAC, 3A/120VAC or 28VDC
- Contact Resistance: 20mΩ max.
- Insulation Resistance: 1000MΩ min.




RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Price Each			
				1	50	100	500
103-5000-EV	E	SPDT	On-On	2.90	2.48	2.14	2.04
103-5001-EV	F	SPDT	On-On	2.90	2.48	2.14	2.04

 F



G

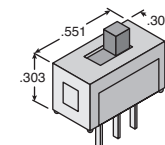

Slide Switches

Miniature Slide Switches

Specifications:


- Rating: 1A/250VAC, 3A/120VAC or 28VDC
- Contact Resistance: 50mΩ max.
- Insulation Resistance: 1000MΩ min.




RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Price Each			
				1	50	100	500
103-5005-EV	G	DPDT	On-On	2.90	2.48	2.14	2.04
103-5002-EV	G	SPDT	On-On	2.58	2.23	1.92	1.75
103-5004-EV	G	SPDT	On-Off-On	2.90	2.48	2.14	2.04


H

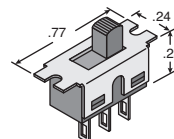


I

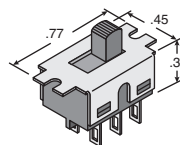

J

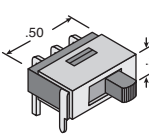

K

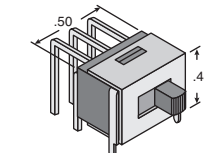

Slide Switches

Specifications:


- Rating: 2A/250VAC, 5A/120VAC or 28VDC
- Contact Resistance: 10mΩ max.
- Insulation Resistance: 1000MΩ min.




RoHS Compliant
For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Type	Circuit	Price Each			
				1	50	100	500
103-5006-EV	H	SPDT	On-On	2.58	2.23	1.92	1.75
103-5008-EV	H	SPDT	On-(On)	2.58	2.23	1.92	1.75
103-5012-EV	I	DPDT	On-On	3.12	2.70	2.32	2.12
103-5007-EV	J	SPDT	On-On	2.58	2.23	1.92	1.75
103-5014-EV	K	DPDT	On-Off-On	4.00	3.45	2.97	2.70
103-5009-EV	L	SPDT	On-(On)	3.12	2.70	2.32	2.12
103-5010-EV	H	SPDT	On-Off-On	3.12	2.70	2.32	2.12
103-5011-EV	M	SPDT	On-Off-On	2.90	2.48	2.14	2.04
103-5013-EV	N	DPDT	On-On	3.31	2.83	2.43	2.32
103-5016-EV	O	SPDT	On-On	2.58	2.23	1.92	1.75


L

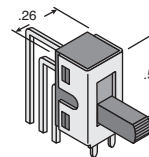

M

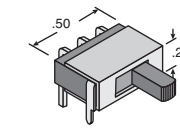

N

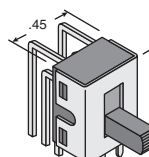

O

