


C&K DIP Switches

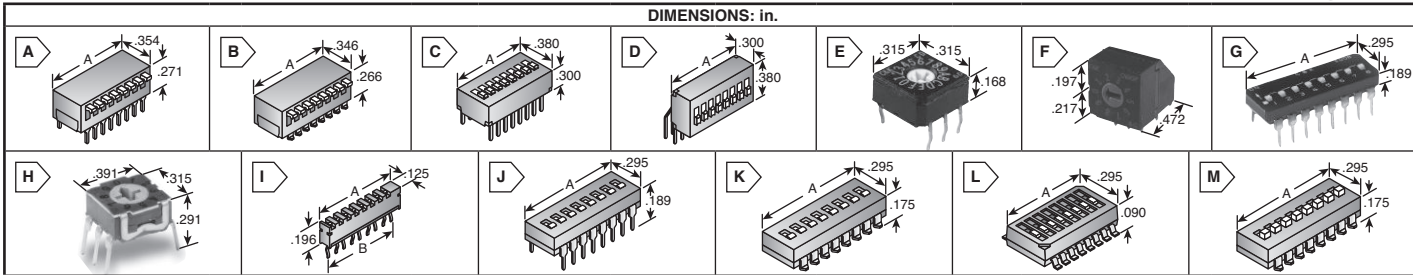

C&K BPA SERIES: SIDE ACTUATED

Specifications:

- Contact rating: 100mA max. @ 5VDC or 25mA max. @ 24VDC
- SPST



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Positions	Dim. A (in.)	Price Each			
					1	25	50	100
Thru-hole								
611-BPA02B	BPA02B	A	2	.28	1.27	1.13	1.08	1.02
611-BPA04B	BPA04B	A	4	.48	2.31	1.84	1.49	1.42
611-BPA05B	BPA05B	A	5	.578	1.63	1.35	1.32	1.07
611-BPA06B	BPA06B	A	6	.68	1.99	1.57	1.52	1.25
611-BPA08B	BPA08B	A	8	.878	1.77	1.57	1.51	1.42
611-BPA10B	BPA10B	A	10	1.078	3.18	2.53	2.07	2.01
Surface Mount								
611-BPA02SB	BPA02SB	B	2	.28	1.17	1.03	.963	.865
611-BPA04SB	BPA04SB	B	4	.48	1.55	1.43	1.39	1.33
611-BPA05SB	BPA05SB	B	5	.578	1.64	1.51	1.47	1.40
611-BPA07SB	BPA07SB	B	7	.778	2.83	2.72	2.59	2.36
611-BPA08SB	BPA08SB	B	8	.878	1.90	1.80	1.70	1.63
611-BPA09SB	BPA09SB	B	9	.978	2.07	1.93	1.79	1.60
611-BPA10SB	BPA10SB	B	10	1.078	2.16	2.00	1.94	1.85

C&K BD SERIES: STANDARD PROFILE

Specifications:

- Traditional full profile with extended actuator
- SPST

- Contact rating: Carry: 100mA max. @ 50 VDC
- Switch: 100mA max. @ 5 VDC or 25mA max. @ 25 VDC

For quantities greater than listed, call for quote.

Open Base								
MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Positions	Dim. A (in.)	1	25	50	100
611-BD01	BD01	C	1	.18	1.13	1.01	.972	.923
611-BD02	BD02	C	2	.28	1.54	1.37	1.31	1.23
611-BD03	BD03	C	3	.38	1.54	1.37	1.31	1.23
611-BD04	BD04	C	4	.48	1.71	1.50	1.47	1.40
611-BD05	BD05	C	5	.58	2.73	1.85	1.76	1.72
611-BD06	BD06	C	6	.68	1.77	1.57	1.50	1.41
611-BD07	BD07	C	7	.78	1.81	1.67	1.62	1.55
611-BD08	BD08	C	8	.88	1.95	1.70	1.67	1.60
611-BD09	BD09	C	9	.98	1.95	1.80	1.75	1.67
611-BD10	BD10	C	10	1.08	2.07	1.82	1.76	1.69
611-BD12	BD12	C	12	1.28	3.51	2.80	2.28	2.22
Open Base and Right Angle Terminal Style								
611-BD02AV	BD02AV	D	2	.28	2.65	2.46	2.22	2.11
611-BD04AV	BD04AV	D	4	.48	4.25	3.40	2.77	2.68
611-BD08AV	BD08AV	D	8	.88	4.66	3.72	3.02	2.94

C&K CD/CRD SERIES: 8MM-10MM DIP CODED ROTARY SWITCHES

Features:

- Process sealed - withstands soldering and cleaning

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Pos.	Actuator	Price Each			
					1	25	50	100
CD Series								
611-CD08RM0CB	CD08RM0CB	E	8	PC Thru-hole	3.53	3.29	3.13	2.99
611-CD10CM0SB	CD10CM0SB	E	10	Surface Mt.	4.10	3.84	3.64	3.48
CRD Series								
611-CRD10CM0AB	CRD10CM0AB	F	10	Rt. Angle, PC Thru-hole	5.71	5.52	4.79	4.56
611-CRD16RL1AB	CRD16RL1AB	F	16	Rt. Angle, PC Thru-hole	6.73	6.27	5.97	5.70

C&K SD SERIES: LOW PROFILE DIP SWITCHES

Specifications:

- Contact rating: Carry: 100mA @ 50VDC max.
- Switch: 0.1mA @ 5VDC min to 100mA @ 25VDC max.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Positions	Dim. A (in.)	Price Each			
					1	25	50	100
611-SD04HOSBD	SD04HOSBD	G	4	0.458	2.68	2.50	2.37	2.26
611-SD04H1BD	SD04H1BD	G	4	0.429	1.87	1.73	1.65	1.57
611-SD05H1SB	SD05H1SB	G	5	0.555	3.07	2.87	2.72	2.60
611-SD06HOSBD	SD06HOSBD	G	6	0.658	3.21	2.99	2.85	2.71
611-SD06H1SB	SD06H1SB	G	6	0.658	3.30	3.07	2.92	2.78
611-SD08H1B	SD08H1B	G	8	0.858	2.53	2.36	2.25	2.14
611-SD08H1BD	SD08H1BD	G	8	0.406	2.42	2.26	2.14	2.05
611-SD10H1B	SD10H1B	G	10	1.058	2.90	2.69	2.56	2.44
611-SD10H1SBD	SD10H1SBD	G	10	1.058	4.03	3.75	3.57	3.41

C&K RTE SERIES: LOW PROFILE ROTARY DIP SWITCHES

Features/Benefits:

- Thru-hole and surface mount models
- Rotary SPDT, SP3T, SP4T functions



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Pos.	Switch Function	Termination	Price Each			
						1	25	50	100
611-RTE1600G44	RTE1600G44	H	16	Hexadecimal	Surface Mt.	2.24	2.10	2.01	1.92

C&K SP SERIES: VERTICAL SINGLE IN-LINE SWITCH

Specifications:

- High pressure contact system does not require tape sealing
- Contact rating: Carry: 0.1mA @ 1mV min.; Switching: 10mA @ 5VDC
- SPST

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Positions	Dim. (in.)		Price Each			
				A	B	1	25	50	100
611-SPA08B	SPA08B	I	9	.898	.700	5.91	4.53	3.96	3.58

C&K SDA/TDA SERIES: LOW PROFILE

Specifications (SDA Series):

- Contact rating: 25mA @ 24VDC or 100mA @ 50VDC
- Dielectric strength: 300VDC min. for 1 minute
- SPST

Specifications (TDA Series):

- .05" lead spacing
- Contact rating: 24VDC @ 25mA (switching); 50VDC @ 100mA (steady state)
- SPST



RoHS Compliant

For quantities greater than listed, call for quote.

Flush Actuator								
MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Positions	Dim. A (in.)	Price Each			
					1	25	50	100
No Tape, Thru-Hole Terminals								
611-SDA02H0BD	SDA02H0BD	J	2	.278	.84	.814	.774	.676
611-SDA03H0BD	SDA03H0BD	J	3	.378	1.05	.921	.864	.775
611-SDA04H0BD	SDA04H0BD	J	4	.476	1.25	1.15	1.05	1.00
611-SDA05H0BD	SDA05H0BD	J	5	.578	1.23	1.14	1.11	1.06
611-SDA06H0BD	SDA06H0BD	J	6	.676	1.43	1.18	1.13	1.08
611-SDA08H0BD	SDA08H0BD	J	8	.876	1.70	1.58	1.49	1.39
611-SDA09H0BD	SDA09H0BD	J	9	.978	1.71	1.44	1.31	1.23
With Top Tape, Thru-Hole Terminals								
611-SDA01H0B	SDA01H0B	J	1	0.178	1.02	.949	.907	.864
611-SDA04H0B	SDA04H0B	J	4	.476	1.24	1.14	1.11	1.06
611-SDA07H0B	SDA07H0B	J	7	0.778	1.65	1.58	1.49	1.17
611-SDA08H0B	SDA08H0B	J	8	.876	1.58	1.53	1.42	1.35
611-SDA09H0B	SDA09H0B	J	9	0.978	2.96	2.35	1.91	1.38
With Top Tape, SMT								
611-SDA12H0B	SDA12H0B	K	12	1.279	1.98	1.81	1.78	1.70
611-SDA02H0SB	SDA02H0SB	K	2	.278	1.65	1.31	1.24	1.04
611-SDA04H0SB	SDA04H0SB	K	4	.476	1.75	1.61	1.57	1.50
611-SDA07H0SB	SDA07H0SB	K	7	0.778	2.01	1.83	1.81	1.73
611-SDA08H0SB	SDA08H0SB	K	8	.876	2.22	2.15	1.99	1.90
611-SDA10H0SB	SDA10H0SB	K	10	1.076	2.51	2.20	2.10	1.97
No Tape, SMT								
611-SDA02H0SBD	SDA02H0SBD	K	2	.278	1.44	1.20	1.14	1.08
611-SDA07H0SBD	SDA07H0SBD	K	7	0.778	3.20	2.54	2.08	1.54
611-SDA08H0SBD	SDA08H0SBD	K	8	.876	2.13	2.06	1.81	1.74
611-SDA09H0SBD	SDA09H0SBD	K	9	0.978	4.02	3.20	2.60	1.87
611-SDA10H0SBD	SDA10H0SBD	K	10	1.076	2.40	2.17	2.10	2.00
Half Pitch, SMT								
611-TDA02H0SB1	TDA02H0SB1	L	2	.144	2.00	1.78	1.71	1.54
611-TDA04H0SB1	TDA04H0SB1	L	4	.244	2.50	1.99	1.82	1.73
611-TDA06H0SB1	TDA06H0SB1	L	6	.344	2.43	2.18	2.10	1.98
611-TDA08H0SB1	TDA08H0SB1	L	8	.444	2.85	2.76	2.40	2.29
611-TDA08H0SB1R	TDA08H0SB1R	L	8	.444	3.34	2.95	2.81	2.63
611-TDA10H0SB1	TDA10H0SB1	L	10	.544	7.00	5.59	5.45	4.42

Extended Actuator

For quantities greater than listed, call for quote.

No Top Tape, Thru-Hole Terminals								
MOUSER STOCK NO.	C&K Part No.	Fig.	No. of Positions	Dim. A (in.)	Price Each			
					1	25	50	100
611-SDA02H1BD	SDA02H1BD	G	2	.278	.99	.88	.804	.723
611-SDA03H1BD	SDA03H1BD	G	3	.378	1.79	1.43	1.16	1.13
611-SDA04H1BD	SDA04H1BD	G	4	.476	1.25	1.08	1.00	.95
611-SDA05H1BD	SDA05H1BD	G	5	.578	1.23	1.19	1.11	1.06
611-SDA06H1BD	SDA06H1BD	G	6	.676	1.42	1.12	1.09	.90
611-SDA07H1BD	SDA07H1BD	G	7	.778	2.19	1.74	1.50	1.38
611-SDA08H1BD	SDA08H1BD	G	8	.876	1.48	1.43	1.26	1.18
611-SDA09H1BD	SDA09H1BD	G	9	.978	1.58	1.45	1.42	1.35
611-SDA10H1BD	SDA10H1BD	G	10	1.076	1.70	1.56	1.52	1.45
611-SDA12H1BD	SDA12H1BD	G	12	1.279	1.87	1.72	1.68	1.60
No Top Tape, SMT								
611-SDA02H1SBD	SDA02H1SBD	M	2	.278	.98	.852	.805	.746
611-SDA03H1SBD	SDA03H1SBD	M	3	.378	2.55	2.02	1.66	1.60
611-SDA04H1SBD	SDA04H1SBD	M	4	.476	1.68	1.53	1.46	1.40
611-SDA05H1SBD	SDA05H1SBD	M	5	.578	1.78	1.63	1.60	1.53
611-SDA06H1SBD	SDA06H1SBD	M	6	.676	2.10	1.78		