


HONEYWELL Limit Switches

RoHS Compliant This product is RoHS compliant.

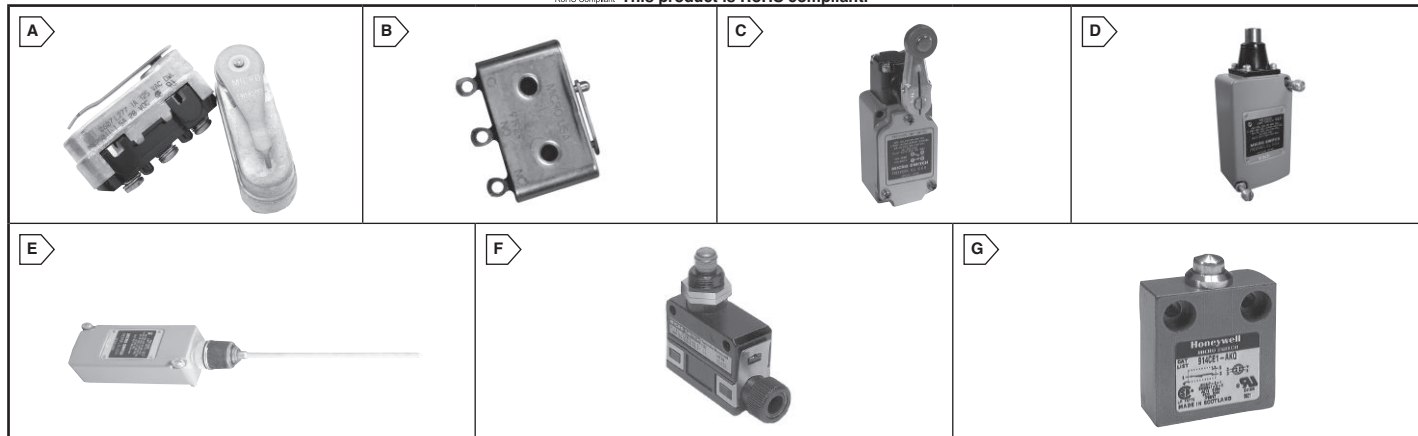

MICRO SWITCH™ SEALED AND HIGH TEMPERATURE SWITCHES

Contain a spring and set of contacts that convert mechanical energy applied to an actuator into an electrical output. Environmentally sealed switches are basic precision switches enclosed within a corrosion-resistant aluminum housing that seals the switch contacts from contamination. Hermetically sealed switches include those that maintain the contact in a gas-tight seal while transmitting force and motion to the switch mechanism through a metal diaphragm. High temperature versions have the switching element mounted on a ceramic base with a stainless steel enclosure. Wide variety of actuators, terminations, circuitry configurations, electrical ratings, contact materials and operating characteristics provide application flexibility. Meet military standards. U.S., European and other approval agency allow global use.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Honeywell Part No.	Fig.	Contact Rating & Voltage	Actuator Type	Operating Force (max.)	Lever Style	Price Each		
							1	10	50
785-1HS3	1HS3	A	115 Vac	Roller Lever	2.78 N	Screw	200.67	175.59	170.81
785-1SE1-T	1SE1-T	A	250 Vac	Pin Plunger	1.39 N	Solder	57.01	54.06	48.99
785-1SE1	1SE1	A	250 Vac	Pin Plunger	1.39 N	Leadwire	95.97	92.86	90.79
785-9HM1	9HM1	B	28 Vdc	Integral Lever	1.95 N	Solder	517.09	491.47	465.85
785-11HM1	11HM1	B	28 Vdc	Integral Lever	1.95 N	Solder	213.79	202.09	191.09

MICRO SWITCH™ COMPACT LIMIT SWITCHES

Small package size. These metal or plastic switches are available with a variety of actuators, electrical specifications, terminations, circuitry and sealing ratings.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Honeywell Part No.	Fig.	Circuit or Switch Function	Actuator Type	Operating Force (max.)	Lever Style	Price Each		
							1	10	50
785-1LS2	1LS2	C	1 NC 1 NO	Side Rotary	0.51 N	Not Included	139.98	127.32	117.64
785-1LS3	1LS3	C	1 NC 1 NO	Side Rotary	0.51 N	Roller-adj.	168.89	158.17	144.41
785-1LS3-L	1LS3-L	C	1 NC 1 NO	Side Rotary	0.51 N	Roller-adj.	176.18	151.64	149.16
785-1LS53	1LS53	C	1 NC 1 NO	Side Rotary	0.11 N	Rod-adj.	155.90	151.44	146.66
785-1LS56	1LS56	C	1 NC 1 NO	Side Rotary	0.11 N	Not Included	138.43	120.21	118.43
785-1LS9	1LS9	C	1 NC 1 NO	Side Rotary	0.51 N	Not Included	141.35	132.37	120.87
785-201LS1	201LS1	C	1 NC 1 NO	Side Rotary	0.51 N	Roller-fixed	174.39	163.32	149.12
785-201LS3	201LS3	C	1 NC 1 NO	Side Rotary	0.51 N	Roller-adj.	195.03	183.92	178.52
785-3LS1	3LS1	C	1 NC 1 NO	Side Roller Plunger	40.03 N	None	177.97	172.20	151.03
785-4LS1	4LS1	C	1 NC 1 NO	Side Plunger	40.03 N	None	152.87	141.30	130.89
785-6LS1	6LS1	C	1 NC 1 NO	Side Rotary	0.34 N	Roller-yolk	188.90	182.56	178.66
785-202LS1	202LS1	D	1 NC 1 NO	Top Plunger	31.14 N	None	155.86	134.04	118.15
785-2LS1	2LS1	D	1 NC 1 NO	Top Plunger	31.14 N	None	138.66	132.32	126.54
785-2LS1-L	2LS1-L	D	1 NC 1 NO	Top Plunger	31.14 N	None	138.66	132.32	126.54
785-208LS1	208LS1	E	1 NC 1 NO	Wobble-Flex Cable	1.39 N	None	138.43	125.61	118.88
785-208LS152	208LS152	E	1 NC 1 NO	Wobble-Coil Spring	1.39 N	None	149.30	134.27	121.45
785-8LS1	8LS1	E	1 NC 1 NO	Wobble-Flex Cable	1.39 N	None	137.41	127.21	121.65
785-8LS152	8LS152	E	1 NC 1 NO	Wobble-Coil Spring	1.39 N	None	129.75	124.08	119.53
785-8LS1-L	8LS1-L	E	1 NC 1 NO	Wobble-Cable	1.39 N	None	138.66	132.32	126.54
785-SL1-A	SL1-A	F	1 NC 1 NO	Top Roller Plunger	11.76 N	None	99.83	95.67	89.46
785-SL1-AK	SL1-AK	F	1 NC 1 NO	Top Roller Plunger	11.76 N	None	114.20	112.81	110.36
785-SL1-D	SL1-D	F	1 NC 1 NO	Cross Roll Plunger	11.76 N	None	93.11	91.90	89.08
785-SL1-E	SL1-E	F	1 NC 1 NO	Top Roll Plunger-Long	11.76 N	None	136.39	129.35	117.22
785-SL1-EK	SL1-EK	F	1 NC 1 NO	Top Roll Plunger-Long	11.76 N	None	126.44	118.42	111.40
785-SL1-H	SL1-H	F	1 NC 1 NO	Top Plunger-Short	11.76 N	None	82.55	73.12	70.87
785-SL1-KK	SL1-KK	F	1 NC 1 NO	Cross Roll Plunger-long	11.76 N	None	136.32	132.32	128.35
785-SL1-P	SL1-P	F	1 NC 1 NO	Top Roller Arm	3.92 N	None	104.38	92.30	89.62
785-914CE1-3	914CE1-3	G	1 NC 1 NO	Top Plunger	11.8 N	None	63.28	59.26	54.11
785-914CE1-3A	914CE1-3A	G	1 NC 1 NO	Top Plunger	11.8 N	None	77.34	73.33	62.90
785-914CE1-6	914CE1-6	G	1 NC 1 NO	Top Plunger	11.8 N	None	77.25	72.34	66.06
785-914CE1-6A	914CE1-6A	G	1 NC 1 NO	Top Plunger	11.8 N	None	84.61	75.67	69.36
785-914CE18-3	914CE18-3	G	1 NC 1 NO	Top Plunger	22.5 N	None	83.07	77.80	71.04
785-914CE18-3AL1	914CE18-3AL1	G	1 NC 1 NO	Top Plunger	22.5 N	None	106.53	102.52	99.32
785-914CE18-6	914CE18-6	G	1 NC 1 NO	Top Plunger	22.5 N	None	91.65	85.84	78.39
785-914CE18-9	914CE18-9	G	1 NC 1 NO	Top Plunger	22.5 N	None	95.68	75.86	72.90
785-914CE18-Q	914CE18-Q	G	1 NC 1 NO	Top Plunger	22.5 N	None	87.28	80.49	69.83
785-914CE1-9	914CE1-9	G	1 NC 1 NO	Top Plunger	11.8 N	None	83.62	78.31	71.51
785-914CE1-Q	914CE1-Q	G	1 NC 1 NO	Top Plunger	11.8 N	None	75.81	71.00	64.83
785-914CE2-3	914CE2-3	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	79.98	74.91	68.40
785-914CE2-3A	914CE2-3A	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	83.62	78.31	71.51
785-914CE2-6	914CE2-6	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	86.21	80.73	73.71
785-914CE2-6A	914CE2-6A	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	89.52	77.47	71.02
785-914CE28-3	914CE28-3	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	115.95	101.99	99.19
785-914CE2-9	914CE2-9	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	94.53	88.55	80.84
785-914CE2-AQ	914CE2-AQ	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	124.99	121.40	117.98
785-914CE2-Q	914CE2-Q	G	1 NC 1 NO	Top Roller Plunger	11.8 N	None	86.51	81.00	73.96
785-914CE31-6	914CE31-6	G	1 NC 1 NO	Top Roller Plunger	17.5 N	None	104.36	97.74	89.23
785-914CE3-3	914CE3-3	G	1 NC 1 NO	Cross Roll Plunger	11.8 N	None	81.56	76.39	69.75
785-914CE3-6	914CE3-6	G	1 NC 1 NO	Cross Roll Plunger	11.8 N	None	87.96	82.36	75.19
785-914CE3-9	914CE3-9	G	1 NC 1 NO	Cross Roll Plunger	11.8 N	None	83.39	78.10	71.31
785-914CE3-Q	914CE3-Q	G	1 NC 1 NO	Cross Roll Plunger	11.8 N	None	88.76	78.28	75.65
785-914CE66-3	914CE66-3	G	1 NC 1 NO	Ball Bearing Plunger	11.8 N	None	85.93	83.92	81.74