

CROUZET Input/Output Modules



CROUZET C4 SERIES I/O MODULES

- New Industry Standard Package
- Replaceable Fuse in Output Modules
- Color Coded Housing for AC or DC Input

Input Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Input Voltage	Max. Input Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	C4IAC	90-140VAC	14mA	4.5-30VDC	50mA	15.42	14.95
874	C4IACA	140-280VAC	50mA	4.5-30VDC	50mA	16.28	15.79
874	C4IDC	10-32VDC	20mA	4.5-30VDC	50mA	15.42	14.95

Output Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Input Voltage	Max. Input Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	C4OAC	12-140VAC	3.0 Amps	4-32VDC	22mA	17.77	16.99
874	C4OACA	12-280VAC	3.0 Amps	4-32VDC	22mA	18.28	17.73
874	C4ODC	5-60VDC	3.0 Amps	4-32VDC	16mA	17.77	17.27
874	C4ODCA	1-250VDC	1.0 Amps	4-32VDC	16mA	21.30	20.66



Mounting Boards for C4 Series I/O Modules

※ Including I/O modules and standoffs

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Max. No. of I/O	Dimensions (LxWxH)*	Logic Connection	Load Connection	Price Each	
Mfr.	Mfr. Part No.					1	5
874	PB4C4	4	6.4 x 3.5 x 2.57	Screw Term.	Screw Term.	60.69	58.92
874	PB16C4	16	10 x 3.25 x 2.57	50-Pin Header	Screw Term.	150.84	148.22
874	PB16C4T	16	9.5 x 3.25 x 2.57	Screw Term.	Screw Term.	175.55	169.89



RoHS Compliant

CROUZET SM SERIES 0.6" I/O MODULES

- New Industry Standard Package
- Output Ratings up to 5Amps
- Color Coded Housing for AC or DC Input

Input Modules


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Input Voltage	Max. Input Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	SMIAC5	90-140VAC/DC	5mA rms	5VDC	50mA	14.25	13.82
874	SMIAC5A	180-280VAC	5mA rms	5VDC	50mA	14.60	14.16
874	SMIDC5	3.3-32VDC	35mA	5VDC	50mA	16.39	15.86

Output Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Max. Output Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	SMOAC5	12-140VAC	3.5Arms	5VDC	20mA	14.25	13.82
874	SMOAC5A	24-280VAC	3.5Arms	5VDC	20mA	14.76	14.34
874	SMOAC5AH	24-280VAC	5Arms	5VDC	20mA	16.79	16.31
874	SMODC5	3-60VDC	3.0A	5VDC	18mA	14.25	13.82

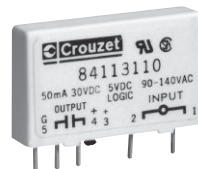

Mounting Boards for SM Series I/O Modules

※ Including I/O modules and standoffs

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Max. No. of I/O	Dimensions (LxWxH)*	Logic Connection	Load Connection	Price Each	
Mfr.	Mfr. Part No.					1	5
874	PB8SM	8	6.4 x 3.5 x 1.9	Card-Edge	Screw Term.	84.87	83.40
874	PB16SM	16	10.4 x 3.5 x 1.9	Card-Edge	Screw Term.	150.84	148.22
874	PB24SM	24	13 x 3.75 x 1.9	Card-Edge	Screw Term.	221.96	218.54



RoHS Compliant

CROUZET QUAD SERIES I/O MODULES

- Industry Standard Package
- Color Coded Housing for AC or DC Input
- Built in LED Status Indicator
- 4 Modules in one package

Input Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Input Voltage	Max. Input Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	IAC5Q	90-140VAC	6mA	5VDC	50mA	106.33	105.37
874	IAC5AQ	140-280VAC	5mA	5VDC	50mA	111.01	110.00
874	IDC5Q	10-60VDC	34mA	5VDC	50mA	106.33	105.37
874	IDC5BQ	4-32VDC	68mA	5VDC	50mA	76.83	74.53

Output Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Maximum Output Current	Nominal Input Voltage	Maximum Input Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	OAC5Q	12-140VAC	3.5Amps	5VDC	20mA	69.27	67.18
874	OAC5AQ	24-280VAC	3.5Amps	5VDC	20mA	109.59	108.60
874	ODC5Q	3-60VDC	3.0Amps	5VDC	18mA	109.59	108.60
874	ODC5Q.11	3-60VDC	3.0Amps	5VDC	18mA	75.05	73.02



Mounting Boards for Quad Series I/O Modules

※ Including I/O modules and standoffs

For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Max. No. of I/O	Dimensions (LxWxH)*	Logic Connection	Load Connection	Price Each	
Mfr.	Mfr. Part No.					1	5
874	PB16Q	4	5.8 x 6.0 x 3.9	Edge Card	Screw Term.	168.21	165.30
874	PB24Q	6	8 x 6 x 3.9	Edge Card	Screw Term.	230.55	224.06
874	PB32Q	8	10.2 x 6.2 x 3.9	Edge Card	Screw Term.	286.96	282.53



RoHS Compliant

CROUZET EPOXY ENCAPSULATED DIN RAIL INPUT MODULES

- DIN Rail Mountable I/O Modules
- Color Coded Housing for AC or DC Input
- Built in LED Status Indicator

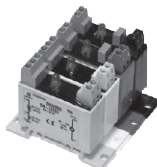

RoHS Compliant

Input Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Input Voltage	Maximum Input Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	DRIAC5	90-140VAC/DC	5mArms	5VDC	50mA	32.56	32.27
874	DRIDC5	4-32VDC	34mA	5VDC	50mA	32.59	31.61

Output Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Maximum Output Current	Nominal Input Voltage	Maximum Input Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	DRODC5	3-60VDC	3A	5VDC	18mA	35.62	34.55

CROUZET 17.5MM DIN RAIL INPUT MODULES

- DIN Rail Mountable I/O Modules
- Color Coded Housing for AC or DC Input
- Built in LED Status Indicator



RoHS Compliant

Input Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Input Voltage	Maximum Input Current	Logic Supply Voltage	Max. Logic Supply Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	84115501	90-140VAC/DC	14mA	4.5-30VDC	50mA	36.90	35.79
874	84115503	4-32VDC	35mA	4.5-30VDC	50mA	40.97	39.74

Output Modules

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Maximum Output Current	Nominal Input Voltage	Maximum Input Current	Price Each	
Mfr.	Mfr. Part No.					1	5
874	84130104	5-48V	5Arms	4-32VDC	22mA	33.02	31.96
874	84130105	3-60VDC	3A	4-32VDC	22mA	40.28	39.07