

P&B General Purpose Relays

KRPA SERIES: OCTAL-TYPE ENCLOSED GENERAL PURPOSE RELAYS

Specifications:






- Enclosure: Clear polycarbonate cover
- Expected Mechanical life: 100,000 operations min.
- 3W
- Contact material: 5A - Silver; 10A - AgCdO



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	P&B Part No.	Fig.	Coil Voltage	Contact Form	Contact Rating	Price Each			
						1	25	50	100
655-KRPA-11AG-12	KRPA-11AG-12	A1	12VAC	DPDT	10A	17.86	15.62	14.13	11.26
655-KRPA-11AG-24	KRPA-11AG-24	A1	24VAC	DPDT	10A	15.36	13.44	12.16	10.52
655-KRPA-11AG-120	KRPA-11AG-120	A1	120VAC	DPDT	10A	19.10	16.70	15.12	11.94
655-KRPA-11AG-240	KRPA-11AG-240	A1	240VAC	DPDT	10A	20.33	17.78	16.09	12.70
655-KRPA-11DG-12	KRPA-11DG-12	A1	12VDC	DPDT	10A	15.36	13.44	12.16	10.52
655-KRPA-11DG-24	KRPA-11DG-24	A1	24VDC	DPDT	10A	15.43	13.49	12.21	10.52
655-KRPA-11DG-48	KRPA-11DG-48	A1	48VDC	DPDT	10A	19.10	16.70	15.12	11.94
655-KRPA-11DG-110	KRPA-11DG-110	A1	110VDC	DPDT	10A	19.10	16.71	15.12	11.94
655-KRPA-11DN-12	KRPA-11DN-12	A1	12VDC	DPDT	10A	16.67	14.58	13.18	10.48
655-KRPA-11DN-24	KRPA-11DN-24	A1	24VDC	DPDT	10A	15.96	13.96	12.63	10.88
655-KRPA-11DN-110	KRPA-11DN-110	A1	110VDC	DPDT	10A	26.46	22.05	20.35	19.46
655-KRPA-11AN-24	KRPA-11AN-24	A1	24VAC	DPDT	10A	18.46	16.14	14.61	11.53
655-KRPA-11AN-120	KRPA-11AN-120	A1	120VAC	DPDT	10A	17.99	16.14	14.61	11.53
655-KRPA-11AN-240	KRPA-11AN-240	A1	240VAC	DPDT	10A	20.95	18.33	16.58	13.09
655-KRPA-11AY-12	KRPA-11AY-12	A1	12VAC	DPDT	5A	29.36	25.68	23.23	18.33
655-KRPA-11AY-24	KRPA-11AY-24	A1	24VAC	DPDT	5A	15.43	13.49	12.21	10.52
655-KRPA-11AY-120	KRPA-11AY-120	A1	120VAC	DPDT	5A	19.10	16.70	15.12	11.94
655-KRPA-11DY-12	KRPA-11DY-12	A1	12VDC	DPDT	5A	15.43	13.49	12.21	10.52
655-KRPA-11DY-24	KRPA-11DY-24	A1	24VDC	DPDT	5A	15.43	13.49	12.21	10.52
655-KRPA-14AG-12	KRPA-14AG-12	A2	12VAC	3PDT	10A	35.42	30.98	28.03	22.13
655-KRPA-14AG-24	KRPA-14AG-24	A2	24VAC	3PDT	10A	17.99	16.14	14.61	11.53
655-KRPA-14AG-120	KRPA-14AG-120	A2	120VAC	3PDT	10A	20.95	18.33	16.58	13.09
655-KRPA-14AG-240	KRPA-14AG-240	A2	240VAC	3PDT	10A	19.09	16.70	15.11	13.08
655-KRPA-14DG-12	KRPA-14DG-12	A2	12VDC	3PDT	10A	17.22	15.07	13.64	11.80
655-KRPA-14DG-24	KRPA-14DG-24	A2	24VDC	3PDT	10A	20.04	17.53	15.86	12.52
655-KRPA-14DG-48	KRPA-14DG-48	A2	48VDC	3PDT	10A	32.23	28.20	25.49	20.13
655-KRPA-14DG-110	KRPA-14DG-110	A2	110VDC	3PDT	10A	20.44	17.88	16.18	14.29
655-KRPA-14AN-24	KRPA-14AN-24	A2	24VAC	3PDT	10A	38.18	33.39	30.21	23.86
655-KRPA-14AN-120	KRPA-14AN-120	A2	120VAC	3PDT	10A	18.65	16.31	14.76	12.72
655-KRPA-14AN-240	KRPA-14AN-240	A2	240VAC	3PDT	10A	22.43	19.61	17.75	14.00
655-KRPA-14DN-24	KRPA-14DN-24	A2	24VDC	3PDT	10A	18.84	16.46	14.90	13.17
655-KRPA-14AY-24	KRPA-14AY-24	A2	24VAC	3PDT	5A	19.58	17.12	15.49	12.22
655-KRPA-14AY-120	KRPA-14AY-120	A2	120VAC	3PDT	5A	36.54	31.96	28.92	22.84
655-KRPA-14AY-240	KRPA-14AY-240	A2	240VAC	3PDT	5A	37.29	32.64	29.51	23.32
655-KRPA-14DY-24	KRPA-14DY-24	A2	24VDC	3PDT	5A	19.81	17.32	15.68	12.37

DIMENSIONS: mm

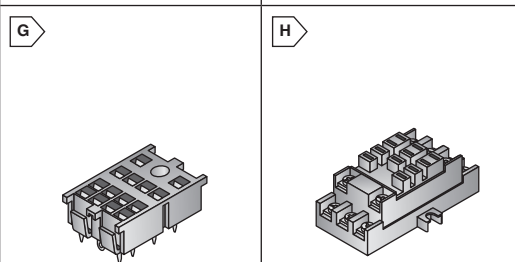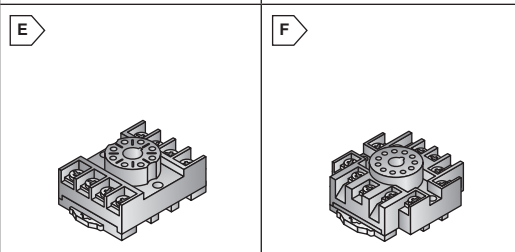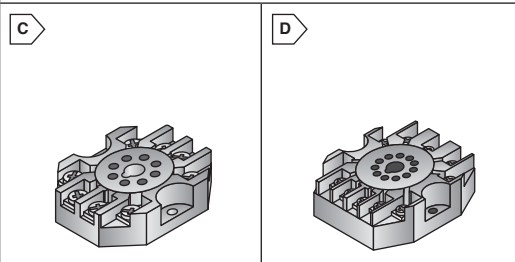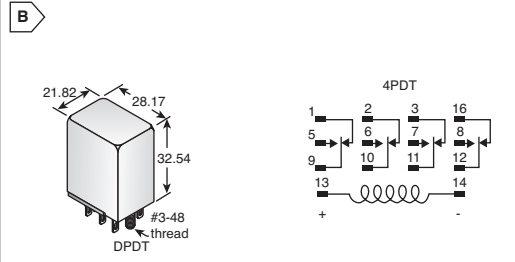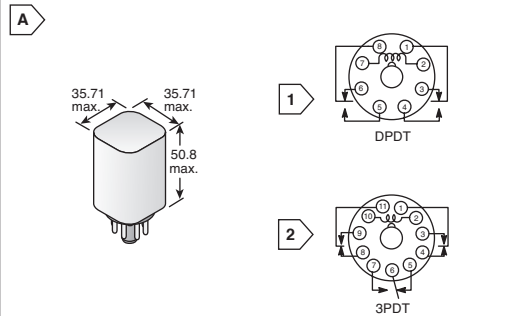

TE Connectivity

General Purpose Relays

KHAU SERIES: MULTICONTACT GENERAL PURPOSE RELAYS

Specifications:

- Enclosure: Clear polycarbonate cover
- Expected life: 100,000 operations at rated load
- Socket mount, solder terminals
- Contact material: 1A - Bifurcated cross bar, Au over Ag; 3A - Ag; 5A-AgCdO



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	P&B Part No.	Fig.	Coil Voltage	Contact Form	Contact Rating	Price Each			
						1	25	50	100
655-KHAU-17A11-24	KHAU-17A11-24	B	24VAC	4PDT	3A	13.27	11.59	10.43	9.12
655-KHAU-17A11-120	KHAU-17A11-120	B	120VAC	4PDT	3A	15.82	13.83	12.52	9.88
* 655-KHAU-17A11N-120	KHAU-17A11N-120	B	120VAC	4PDT	3A	17.29	15.10	13.59	11.88
655-KHAU-17A12-120	KHAU-17A12-120	B	120VAC	4PDT	5A	16.01	14.00	12.63	10.00
655-KHAU-17D12-24	KHAU-17D12-24	B	24VDC	4PDT	5A	14.01	12.29	11.12	8.80
655-KHAU-17D11-12	KHAU-17D11-12	B	12VDC	4PDT	3A	13.92	12.18	11.02	8.70
655-KHAU-17D11-24	KHAU-17D11-24	B	24VDC	4PDT	3A	11.93	10.41	9.37	8.20
655-KHAU-17A16-24	KHAU-17A16-24	B	24VAC	4PDT	1A	59.12	51.92	51.00	48.95

* neon indicator

SOCKETS AND ACCESSORIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Description	Price Each			
				1	25	50	100
KRPA Series							
655-27E122	27E122	C	8-pin screw terminal socket, 10A, for KRPA11	6.46	5.64	5.11	4.03
655-27E123	27E123	D	11-pin screw terminal socket, 10A, for KRPA14	5.99	5.23	4.74	3.74
655-27E891	27E891	E	8-pin DIN rail snap mount socket, 10A, for KRPA11	6.89	6.02	5.45	4.30
655-27E892	27E892	F	11-pin DIN rail snap mount socket, 10A, for KRPA14	10.42	9.11	8.24	6.51
655-20C176	20C176	--	Hold down spring. Mounts to socket with socket screws	2.38	2.07	1.88	1.48
655-20C318	20C318	--	Hold down spring for use with 27E891, 27E892	.29	.25	.22	.19
655-24A110	24A110	--	Aluminum DIN rail track, 36"	13.51	11.82	10.70	8.45
655-24A071	24A071	--	Steel mounting clip with screw	2.38	2.07	1.88	1.48
655-24A072	24A072	--	Plastic twist mounting clip	.94	.82	.741	.585
655-40G432	40G432	--	Plastic insulator	1.87	1.63	1.48	1.17
KHAU Series							
655-27E006	27E006	G	Solder socket with grounding provision for KHAU, KHS	1.86	1.62	1.46	1.16
655-27E007	27E007	G	PCB terminals socket with grounding provision, for KHAU, KHS	1.74	1.51	1.37	1.11
655-27E023	27E023	G	PCB terminals socket w/out grounding provision, for KHAU, KHS	1.61	1.40	1.27	1.00
655-27E166	27E166	H	Screw terminal socket with grounding provision for KHAU, KHS	12.65	11.00	10.01	8.95
655-27E894	27E894	H	Screw terminal, DIN rail snap-mount socket, for KHAU, KHS	10.35	9.05	8.18	6.47
655-24A110	24A110	--	Aluminum DIN rail track, 36"	13.51	11.82	10.70	8.45
655-20C217	20C217	--	Hold down spring for 27E006, 27E007, and 27E023	.29	.27	.251	.223
655-20C297	20C297	--	Hold down spring for 27E166 and 27E894	.29	.25	.22	.19