

SCHURTER Circuit Breakers



SCHURTER TA35 SERIES: THERMAL CIRCUIT BREAKER WITH ROCKER ACTUATOR

- TA35 is positively trip-free
- Ratings: 240VAC (3-pole: 415Y/240)
- Snap-in mount from front
- Quick-connect terminals
- Illuminated types available with red, green, yellow and blue transparent rockers



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	No. of Poles	No. of Terminals	Rated Current	Switch Color/Markings	Price Each			
							1	10	25	50
693-CFTWKJ20C0	CFTWKJ20C0	A	1	1	2A	White/ON-OFF	9.37	8.33	7.49	7.08
693-CFTWF030C0	CFTWF030C0	A	1	1	3A	White/I-0	8.22	7.30	6.58	6.22
693-CFTBF040C0	CFTBF040C0	A	1	1	4A	Black/I-0	7.31	6.49	5.85	5.53
693-CFTRF050C0	CFTRF050C0	A	1	1	5A	Red/I-0	8.22	7.30	6.58	6.22
693-CFTWF070C0	CFTWF070C0	A	1	1	7A	White/I-0	7.31	6.49	5.85	5.53
693-CFTRF100C0	CFTRF100C0	A	1	1	10A	Red/I-0	8.22	7.30	6.58	6.22
693-CFTWF150C0	CFTWF150C0	A	1	1	15A	White/I-0	8.22	7.30	6.58	6.22
693-CFTWF200C0	CFTWF200C0	A	1	1	20A	White/I-0	7.31	6.49	5.85	5.53
693-CBTWF060C0	CBTWF060C0	B	2	1	6A	White/I-0	11.50	10.23	9.20	8.69
693-CBTWF080C0	CBTWF080C0	B	2	1	8A	White/I-0	12.93	11.50	10.34	9.77
693-CBTWF160C0	CBTWF160C0	B	2	1	16A	White/I-0	12.93	11.50	10.34	9.77
693-CBDWF030C0	CBDWF030C0	B	2	2	3A	White/I-0	13.08	11.63	10.47	9.88
693-CBDWF050C0	CBDWF050C0	B	2	2	5A	White/I-0	14.71	13.08	11.77	11.11
693-CBDWF070C0	CBDWF070C0	B	2	2	7A	White/I-0	14.71	13.08	11.77	11.11
693-CKDWF050C0	CKDWF050C0	C	3	3	5A	White/I-0	20.96	18.62	16.77	15.85
693-CKDWF100C0	CKDWF100C0	C	3	3	10A	White/I-0	20.96	18.62	16.77	15.85

Accessories




For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Description	Price Each			
			1	10	25	50
693-CZZ11	CZZ11	Waterproof cover - 1 pole	.93	.83	.75	.71
693-CZZ21	CZZ21	Waterproof cover - 2 pole	1.10	.97	.877	.832


DIMENSIONS: mm

A

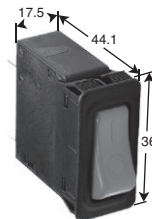


1-Pole

B

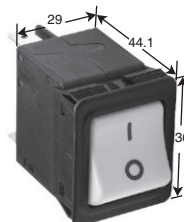


2-Pole

C

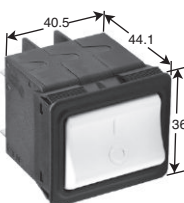

3-Pole

D

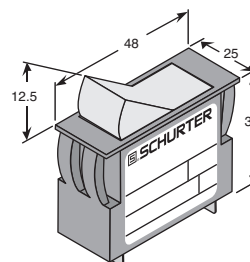

SCHURTER TA45 SERIES: THERMAL CIRCUIT BREAKERS WITH ROCKER ACTUATOR

- TA45 is positively trip-free
- Ratings: 240VAC/60VDC
- Black switch has white printed I/O legend
- Orange switch is transparent illuminated with white printed I/O legend
- Other rocker switch colors and legends available. Call for more information.

- Snap-in mount
- IP40 degree of protection on front side
- Terminals: .250" quick connect
- DPST switch (On-Off); 3-pole also available, Call for more information
- I-Pole units use 120 Volt illumination; Z-Pole units use 240 Volt



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Rated Current	Thermal Overload Protection	Switch Color	Price Each			
						1	10	25	50
693-ABTBLJ05C0	ABTBLJ05C0	D	0.5A	1-pole	Black	16.12	14.32	12.89	12.19
693-A126LJ05C0	A126LJ05C0	D	0.5A	1-pole	Orange	22.64	20.13	18.11	17.09
693-ABDBLJ05C0	ABDBLJ05C0	D	0.5A	2-pole	Black	21.57	19.17	17.25	16.28
693-ABTBLJ20C0	ABTBLJ20C0	D	2A	1-pole	Black	14.33	12.73	11.46	10.84
693-A126LJ20C0	A126LJ20C0	D	2A	1-pole	Orange	21.57	19.17	17.25	16.28
693-ABDBLJ20C0	ABDBLJ20C0	D	2A	2-pole	Black	18.73	16.65	14.98	14.14
693-A326LJ20C0	A326LJ20C0	D	2A	2-pole	Orange	26.20	23.45	21.15	19.89
693-ABTBL050C0	ABTBL050C0	D	5A	1-pole	Black	17.86	17.00	15.99	15.15
693-ABDBL050C0	ABDBL050C0	D	5A	2-pole	Black	18.26	16.23	14.61	13.80
693-A326L050C0	A326L050C0	D	5A	2-pole	Orange	31.14	27.69	24.90	23.52
693-ABTBL100C0	ABTBL100C0	D	10A	1-pole	Black	20.09	19.12	17.98	17.04
693-A126L100C0	A126L100C0	D	10A	1-pole	Orange	18.73	16.65	14.98	14.14
693-ABDBL100C0	ABDBL100C0	D	10A	2-pole	Black	17.84	15.86	15.23	14.47
693-A326L100C0	A326L100C0	D	10A	2-pole	Orange	27.69	24.43	22.14	20.90
693-ABTBL150C0	ABTBL150C0	D	15A	1-pole	Black	17.86	17.00	15.99	15.15
693-A126L150C0	A126L150C0	D	15A	1-pole	Orange	21.07	18.73	16.85	15.90
693-ABDBL150C0	ABDBL150C0	D	15A	2-pole	Black	18.10	16.15	14.50	13.73
693-A326L150C0	A326L150C0	D	15A	2-pole	Orange	26.23	23.72	21.17	20.00
693-ABTBL200C0	ABTBL200C0	D	20A	1-pole	Black	17.86	17.00	15.99	15.15
693-A126L200C0	A126L200C0	D	20A	1-pole	Orange	18.73	16.65	14.98	14.14
693-ABDBL200C0	ABDBL200C0	D	20A	2-pole	Black	20.54	18.25	16.42	15.51
693-A326L200C0	A326L200C0	D	20A	2-pole	Orange	27.69	24.61	22.14	20.90