


KOBITONE Speakers

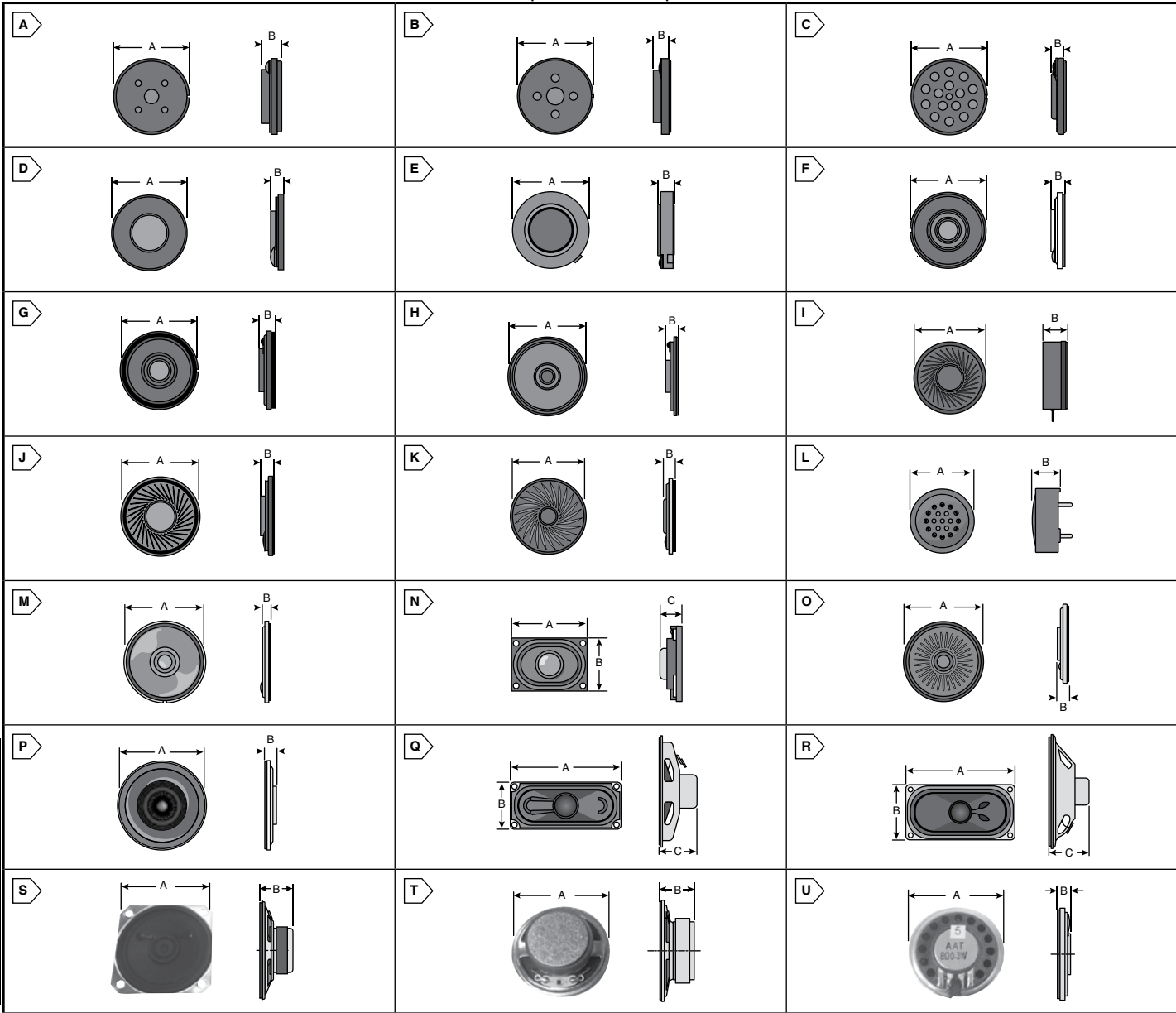

RoHS Compliant. This product is RoHS compliant.



Kobitone
Audio

DYNAMIC SPEAKERS

Applications:

- Digital Cameras
- Communications Devices
- Media Players
- LCD Displays
- PCs

PRODUCT NEW

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Impedance (Ω)	Rated Power (W)	Frequency Response (Hz)	Magnet Type	Dimensions (mm) A x B x C	Price Each			
							1	25	50	100
254-DS108-RO	A	8	0.15	1200-6K	Nd-Fe-B	∅10 x 2.7	2.62	2.26	2.05	1.71
254-DS136-RO	B	16	0.5	1000-20K	Nd-Fe-B	∅13 x 3.0	2.62	2.26	2.05	1.71
254-DS152-RO	C	32	0.5	920-20K	Nd-Fe-B	∅15 x 2.9	2.94	2.26	2.05	1.86
254-DS1886-RO	D	8	1.0	1000-5K	Nd-Fe-B	∅18 x 3.2	2.94	2.26	2.05	1.86
254-DS1808-RO	E	8	0.5	850-20K	Nd-Fe-B	∅18 x 4.3	2.94	2.26	2.05	1.86
254-DS206-RO	F	16	0.25	1000-10K	Nd-Fe-B	∅20 x 3.8	2.94	2.26	2.05	1.86
254-DS202-RO	G	32	0.5	870-7.5K	Ferrite	∅20 x 4.1	2.94	2.26	2.05	1.86
254-DS238-RO	H	8	1.0	820-5K	Ferrite	∅23 x 4	2.25	2.07	1.88	1.60
254-DS268-RO	I	8	0.5	550-20K	Nd-Fe-B	∅25.6 x 9.2	2.55	1.96	1.78	1.62
254-DS2686-RO	J	8	1.0	800-20K	Nd-Fe-B	∅26 x 4.5	2.25	2.07	1.88	1.60
254-DS288-RO	K	8	0.5	500-10K	Nd-Fe-B	∅28 x 5.0	5.83	4.48	4.07	3.70
254-DS308-RO	L	8	0.15	1300-5K	Nd-Fe-B	∅29.2 x 11.8	1.78	1.37	1.24	1.13
254-DS368-RO	M	8	1.0	550-6K	Nd-Fe-B	∅36 x 4.6	2.72	2.09	1.90	1.73
254-DS4028-RO	N	8	2.0	530-16.5K	Nd-Fe-B	40 x 28.3 x 11.5	3.81	2.93	2.66	2.42
254-DS4020-RO	N	8	2.0	400-2.2K	Nd-Fe-B	40 x 20 x 5.8	2.92	2.24	2.04	1.85
254-DS408-RO	O	8	1.0	600-6K	Nd-Fe-B	∅40 x 5.1	2.76	2.12	1.93	1.75
254-DS458-RO	P	8	1.0	500-6K	Nd-Fe-B	∅45 x 5.3	3.12	2.40	2.18	1.98
254-DS708-RO	Q	8	2.0	300-20K	Nd-Fe-B	70 x 30 x 23.0	3.58	2.81	2.63	2.50
254-DS718-RO	R	8	4.0	380-20K	Nd-Fe-B	71 x 41 x 25.0	3.94	3.03	2.75	2.50
254-DS5053-RO	S	8	0.2	550-4.5K	Ferrite	∅50 x 16.5	5.69	4.38	3.98	3.69
254-DS5084-RO	T	8	0.25	450-4.5K	Ferrite	∅50 x 16.9	3.81	2.93	2.66	2.42
254-DS2812-RO	U	8	0.3	600-20K	Nd-Fe-B	∅28 x 3.9	3.10	2.58	2.34	2.13

