


EAGLE PLASTIC DEVICES Control and Instrument Knobs



SLIDE CONTROL KNOBS

Stylish and functional, these slide control knobs are available in several color combinations.


MOUSER STOCK NO.	Fig.	Body Color	Line Color	Shaft Size	Dimensions: in.			Price Each			
					A	B	C	1	10	100	500
450-SL2112	A1	Red	Black	1.2x8	.945	.591	.445	.52	.422	.388	.355
450-SL2212	A1	Yellow	Black	1.2x8	.945	.591	.445	.52	.422	.388	.355
450-SL2312	A1	Blue	Black	1.2x8	.945	.591	.445	.52	.422	.388	.355
450-SL2412	A1	Green	Black	1.2x8	.945	.591	.445	.52	.422	.388	.355
450-SL2512	A1	Gray	Black	1.2x8	.945	.591	.445	.52	.422	.388	.355
450-SL2612	A1	Black	White	1.2x8	.945	.591	.445	.52	.422	.388	.355
450-SL4512	B1	Gray	Black	1.2x8	1.02	.433	.433	.52	.422	.388	.355
450-SL4514	B2	Gray	Black	1.2x4	1.02	.433	.433	.52	.422	.388	.355
450-SL5512	B2	Gray	Black	1.2x4	.945	.354	.425	.52	.422	.388	.355
450-SL6112	B3	Red	White	1.2x18	.953	.453	.406	.55	.444	.40	.377
450-SL6312	B3	Blue	White	1.2x18	.953	.453	.406	.55	.444	.40	.377
450-SL6512	B3	Gray	Black	1.2x18	.953	.453	.406	.55	.444	.40	.377
450-SL6612	B3	Black	White	1.2x18	.953	.453	.406	.55	.444	.40	.377
450-SL6712	B3	White	Black	1.2x18	.953	.453	.406	.55	.444	.40	.377

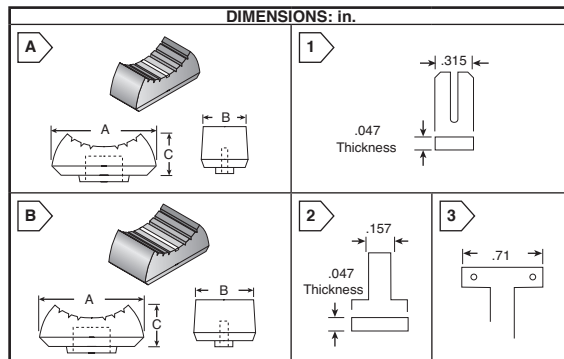

TWO-COLOR RUBBERIZED KNOBS

These rubberized two color knobs provide a clean, modern look with precise control. Available in several color combinations, these knobs provide a stylish look to any front panel.


MOUSER STOCK NO.	Fig.	Body Color	Line Color	Dimensions: in.			Price Each			
				Shaft	Dia.	Height	1	10	100	500
D Shaft (6mm)										
450-4660	A	Gray	Black	.236	.52	.61	.66	.443	.408	.373
450-4661	A	Gray	Red	.236	.52	.61	.66	.443	.408	.373
450-4662	A	Gray	Yellow	.236	.52	.61	.49	.426	.373	.341
450-4663	A	Gray	Blue	.236	.52	.61	.49	.426	.373	.341
450-4667	A	Gray	Gray	.236	.52	.61	.49	.426	.373	.341
450-4760	A	Black	White	.236	.52	.61	.66	.443	.408	.373
450-4761	A	Black	Red	.236	.52	.61	.49	.426	.373	.341
450-4762	A	Black	Yellow	.236	.52	.61	.49	.426	.373	.341
450-4763	A	Black	Blue	.236	.52	.61	.49	.426	.373	.341
450-4764	A	Black	Green	.236	.52	.61	.49	.426	.373	.341
450-4765	A	Black	Gray	.236	.52	.61	.49	.426	.373	.341
D Shaft (6.4mm)										
450-4641	B	Gray	Red	.252	.52	.61	.49	.426	.373	.341
450-4642	B	Gray	Yellow	.252	.52	.61	.49	.426	.373	.341
450-4643	B	Gray	Blue	.252	.52	.61	.49	.426	.373	.341
450-4646	B	Gray	Black	.252	.52	.61	.49	.426	.373	.341
450-4647	B	Gray	Gray	.252	.52	.61	.49	.426	.373	.341
450-4741	B	Black	Red	.252	.52	.61	.49	.426	.373	.341
450-4742	B	Black	Yellow	.252	.52	.61	.49	.426	.373	.341
450-4743	B	Black	Blue	.252	.52	.61	.49	.426	.373	.341
450-4745	B	Black	Gray	.252	.52	.61	.49	.426	.373	.341
450-4747	B	Black	White	.252	.52	.61	.49	.426	.373	.341

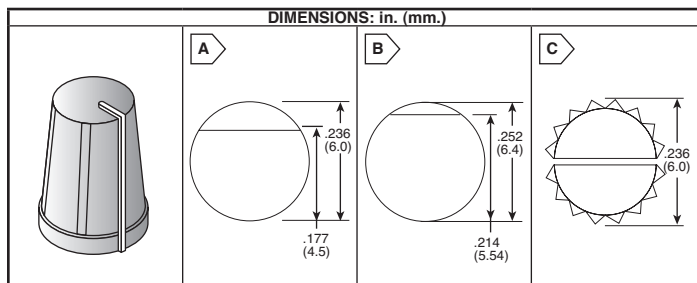

MOUSER STOCK NO.	Fig.	Body Color	Line Color	Dimensions: in.			Price Each			
				Shaft	Dia.	Height	1	10	100	500
T18 (6mm, 18 Tooth Knurled Shaft)										
450-1518	C	Gray	Red	.236	.52	.61	.49	.426	.373	.341
450-2518	C	Gray	Yellow	.236	.52	.61	.49	.426	.373	.341
450-3518	C	Gray	Blue	.236	.52	.61	.49	.426	.373	.341
450-6518	C	Gray	Black	.236	.52	.61	.49	.426	.373	.341
450-7518	C	Gray	Gray	.236	.52	.61	.49	.426	.373	.341
450-1C618	C	Black	Red	.236	.52	.61	.49	.426	.373	.341
450-2C618	C	Black	Yellow	.236	.52	.61	.49	.426	.373	.341
450-3C618	C	Black	Blue	.236	.52	.61	.49	.426	.373	.341
450-5C618	C	Black	Gray	.236	.52	.61	.49	.426	.373	.341
450-7618	C	Black	White	.236	.52	.61	.63	.425	.392	.358

Eagle Plastic Devices

Knobs

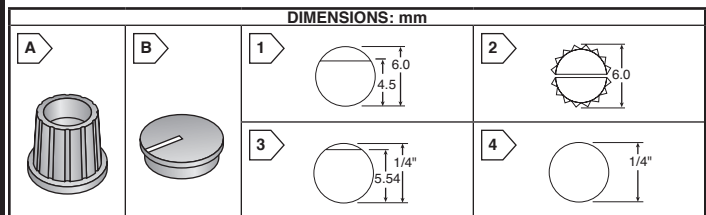

COLOR-CODED PLASTIC KNOBS AND CAPS


Knobs
These push on control knobs can be customized by using color coded caps. Multiple colors are available from stock. Order color coded caps separately.



* T18 is a 6mm, 18 tooth knurled shaft.

MOUSER STOCK NO.	Fig.	Color	Shaft Type	Dimensions: in.			Price Each			
				Shaft	Dia.	Height	1	10	100	500
450-AA150	A1	Black	D Shaft	.236	.59	.75	.34	.288	.244	.222
450-AA150C	A1	Clear	D Shaft	.24	.59	.75	.45	.386	.319	.293
450-AA151	A1	Lt. Grey	D Shaft	.236	.59	.75	.34	.288	.244	.222
450-AA152	A2	Lt. Grey	T18 *	.236	.59	.75	.34	.288	.244	.222
450-AA152C	A2	Clear	T18 *	.24	.59	.75	.45	.386	.319	.293
450-AA180	A3	Black	D Shaft	.252	.71	.63	.34	.288	.244	.222
450-AA181	A2	Black	T18 *	.236	.71	.63	.34	.288	.244	.222
450-AA190	A3	Black	D Shaft	.252	.79	.75	.34	.288	.244	.222
450-AA191	A2	Dk. Grey	T18 *	.252	.79	.75	.34	.288	.244	.222
450-AA192	A2	Black	T18 *	.252	.79	.75	.34	.288	.244	.222
450-AA193	A4	Black	set screw	.252	.79	.75	.84	.702	.637	.583

MOUSER STOCK NO.	Fig.	Cap Color	Pointer Color	Fits Knob	Price Each			
					1	10	100	500
450-CP151	B	Red	White		.28	.233	.166	.133
450-CP153	B	Blue	White		.28	.233	.166	.133
450-CP155	B	Grey	White	450-AA150, 450-AA151, 450-AA152	.28	.233	.166	.133
450-CP156	B	Black	White		.28	.233	.166	.133
450-CP157	B	White	Black		.28	.233	.166	.133
450-CP158	B	Clear	White	450-AA150C, 450-AA152C	.34	.279	.201	.159
450-CP185	B	Grey	Black		.28	.233	.166	.133
450-CP186	B	Black	White	450-AA180, 450-AA181	.28	.233	.166	.133
450-CP191	B	Red	White		.28	.233	.166	.133
450-CP192	B	Yellow	White		.28	.233	.166	.133
450-CP193	B	Blue	White		.28	.233	.166	.133
450-CP194	B	Green	White	450-AA190, 450-AA191, 450-AA192, 450-AA193	.28	.233	.166	.133
450-CP195	B	Grey	White		.28	.233	.166	.133
450-CP196	B	Black	White		.28	.233	.166	.133

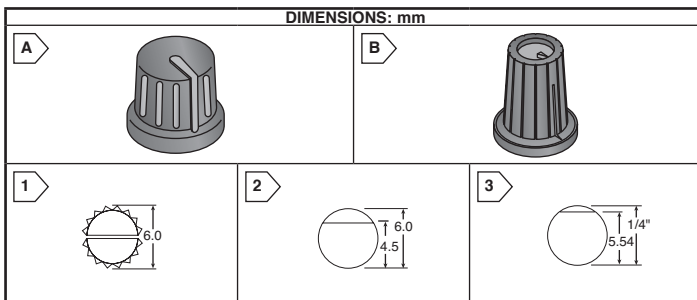

TWO-COLOR KNOBS

"Soft Touch" Knobs

These rubberized "soft touch" two color knobs provide a clean look with tactile control. Available in several pointer colors, these knobs provide a stylish look to any front panel.

MOUSER STOCK NO.	Fig.	Color	Pointer Color	Dimensions: in.			Price Each			
				Shaft	Dia.	Height	1	10	100	500
T18 (6mm, 18 Tooth Knurled Shaft)										
450-BA160	A1	Black	Red	.236	.63	.57	.60	.444	.40	.377
450-BA260	A1	Black	Yellow	.236	.63	.57	.60	.444	.40	.377
450-BA360	A1	Black	Blue	.236	.63	.57	.60	.444	.40	.377
450-BA460	A1	Black	Green	.236	.63	.57	.60	.444	.40	.377
450-BA760	A1	Black	White	.236	.63	.57	.60	.444	.40	.377
D Shaft										
450-BA161	A2	Black	Red	.236	.63	.57	.60	.444	.40	.377
450-BA261	A2	Black	Yellow	.236	.63	.57	.60	.444	.40	.377
450-BA361	A2	Black	Blue	.236	.63	.57	.60	.444	.40	.377
450-BA461	A2	Black	Green	.236	.63	.57	.60	.444	.40	.377
450-BA761	A2	Black	White	.236	.63	.57	.60	.444	.40	.377
450-BA600	A2	Black	None	.236	.63	.57	.60	.444	.40	.377

D Shaft Control Knobs

These two color plastic knobs combine a marker line on the body with an arrow on the top for precise control.

MOUSER STOCK NO.	Fig.	Color	Pointer Color	Dimensions: in.			Price Each			
				Shaft	Dia.	Height	1	10	100	500
450-WB118	B3	Black	Red line/top	.252	.67	.76	.75	.501	.457	.412
450-WB218	B3	Black	Yellow line/top	.252	.67	.76	.75	.501	.457	.412
450-WB318	B3	Black	Blue line/top	.252	.67	.76	.75	.501	.457	.412
450-WB418	B3	Black	Green line/top	.252	.67	.76	.75	.501	.457	.412