

EAGLE PLASTIC DEVICES Control and Instrument Knobs



CLEAR PLASTIC KNOBS



 
PRODUCT **NEW**

*T18 is a 6mm, 18 tooth knurled shaft

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Shaft Type	Dimension: in.		Price Each		
				Dia.	H	1	10	100
450-5300C	A	Clear/Black	Set Screw	.75	.57	.80	.74	.68
450-5310C	A	Clear/Black	T18*	.75	.57	.80	.74	.68
450-5320C	A	Clear/Black	D Shaft	.75	.57	.80	.74	.68
450-5100C	A	Clear/Black	Set Screw	1.06	.63	.80	.74	.68
450-5110C	A	Clear/Black	T18*	1.06	.63	.80	.74	.68
450-5120C	A	Clear/Black	D Shaft	1.06	.63	.80	.74	.68
45KN010C	B	Clear/Black	T18*	1.26	.54	.81	.54	.47
45KN011C	B	Clear/Black	Set Screw	1.26	.54	1.53	1.02	.90

COLOR CONTROL KNOBS



Fits .25 shafts
Black Indicator

- Black plastic with white indicator except where noted
- Brass insert with set screw .25" knob only

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Dimension: in.		Price Each		
			Dia.	H	1	10	100
450-2040-GRX	A	BLK/RED	.52	.62	1.33	1.05	.928
450-2050-GRX	A	BLK/YEL	.52	.62	1.33	1.05	.928
450-2060-GRX	A	BLK/GRN	.52	.62	.99	.78	.69
450-2070-GRX	A	BLK/BLU	.52	.62	.99	.78	.69
450-3180-GRX	A	BLK/GRN	.75	.64	1.08	.83	.75
450-3181-GRX	A	BLK/RED	.75	.64	1.29	.994	.898
450-3182-GRX	A	BLK/YEL	.75	.64	1.08	.83	.75
450-3183-GRX	A	BLK/BLU	.75	.64	1.08	.83	.75
450-3021	B	BLK/RED	.52	.65	.59	.396	.363
450-3022	B	BLK/YEL	.52	.65	.59	.396	.363
450-3023	B	BLK/BLU	.52	.65	.59	.396	.363
450-3024	B	BLK/GRN	.52	.65	.59	.396	.363
450-3031	C	BLK/RED	.63	.59	.59	.396	.363
450-3033	C	BLK/BLU	.63	.59	.59	.396	.363
450-3034	C	BLK/GRN	.63	.59	.59	.396	.363

SOLID COLOR KNOBS

- Knob fits 6mm, 18 tooth shaft
- Fits 313-2401, 31VF, 31CA, 31CB and 31CR Series

For quantities greater than listed, call for quote.



MOUSER STOCK NO.	Color	Dimension: in.		Price Each		
		Dia.	H	1	10	100
450-2051	Gray	.80	.64	.50	.342	.31
450-2061	Black	.80	.64	.60	.414	.375
450-2062	Black	.60	.59	.48	.327	.291

KNOBS FOR SLIDE POTENTIOMETERS

- Fits 312-9000, 9100, and 9302 series



Shaft Configuration



For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Color	Dimension: in.			Price Each		
		L	W	H	1	10	100
450-3051	Black	.79	.68	.62	.54	.366	.333
450-3052	Gray	.79	.68	.62	.54	.366	.333

POINTER KNOB

- Brass insert
- Set screw included
- Knobs fit .25" shafts





 
For quantities greater than listed, call for quote.



MOUSER STOCK NO.	Color	Dimension: in.		Price Each		
		Dia.	H	1	10	100
45KN012-GRX	Black	1.25	.65	.69	.46	.42

ALUMINUM CONTROL KNOBS

   - Brass inserts
- Knobs fit .25" shafts
- Set screw included



MOUSER STOCK NO.	Fig.	Color	Dimension: in.		Price Each		
			Dia.	H	1	10	100
45KN030	A	Mirror	.79	.77	2.77	2.49	2.25
45KN031	A	Mirror	.61	.65	2.33	2.10	1.90
45KN032	A	Mirror	.87	.75	3.21	2.87	2.60
450-7030	A	Black	.79	.77	2.77	2.50	2.27
450-7031	A	Black	.61	.65	2.55	2.13	1.94
450-7032	A	Black	.87	.75	3.70	3.10	2.81
450-6015	B	Natural	.63	.55	2.35	2.12	1.92
450-6016	B	Natural	.87	.55	2.62	2.38	2.16
450-6017	B	Natural	1.10	.55	3.32	3.02	2.74
450-7015	B	Black	.63	.55	2.70	2.45	2.23
450-7016	B	Black	.87	.55	2.77	2.51	2.27
450-3000	C	Natural	1.00	1.00	6.35	5.61	5.23
450-6003	D	Natural	.50	.62	2.09	1.85	1.68
450-6005	D	Natural	.75	.62	2.50	2.27	2.07
450-6006	D	Natural	.94	.62	2.90	2.65	2.41
450-6007	D	Natural	1.25	.62	3.55	3.22	2.92
450-6008	D	Black	1.25	.62	3.55	3.22	2.92
450-7005	D	Black	.75	.62	2.72	2.44	2.21
450-6009	D	Black	.50	.62	2.19	1.94	1.76
450-6010	D	Black	.94	.62	3.10	2.78	2.52

KNOBS FOR 1/8" SHAFTS

- Fits 148, 248, and PRV6 series
- Brass insert




For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Color Top	Dimension: in.		Price Each		
		Dia.	H	1	10	100
450-0125	Body BLK/Top BLK	.46	.41	1.27	.981	.895
450-0126	Body BLK/Top RED	.46	.41	1.27	.981	.895

SOFT TOUCH KNOBS

 - Plastic shell covered by a thick rubber finish
- Knob fits 6mm, 18 tooth knurled shaft
- Diameter measured at knob base



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Color	Dimension: in.		Price Each		
		Dia.	H	1	10	100
450-4010	Gray	.51	.71	.70	.466	.42
450-4011	Black	.51	.71	.70	.466	.42


CONTROL AND INSTRUMENT KNOBS

- Brass inserts
- Set screw included with spun aluminum inlay

*Note: 45KN021-GRX - 0 to 10 Scale
450-1170-GRX - 1 to 10 Scale



RoHS Compliant

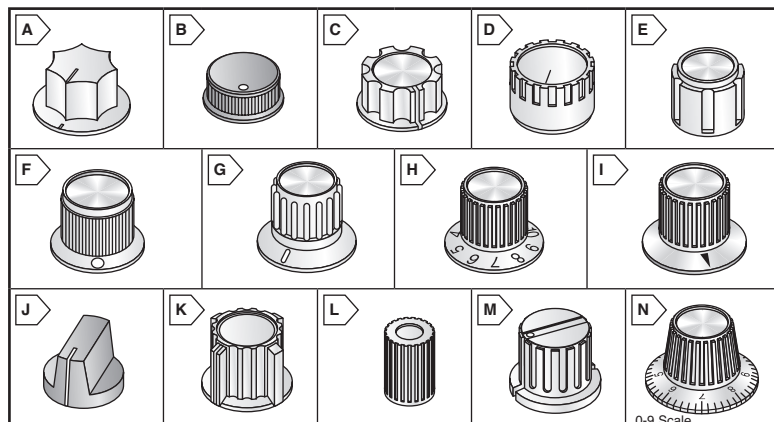

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Dimension: in.		Price Each		
			Dia.	H	1	10	100
45KN013-GRX	A	Black	.94	.59	.84	.57	.52
45KN014-GRX	A	Black	1.32	.69	.80	.61	.56
45KN015-GRX	B	Black	.70	.38	.96	.733	.673
45KN016-GRX	C	Black	1.29	.63	1.35	1.04	.947
45KN017-GRX	C	Black	1.04	.56	1.09	.85	.769
45KN018-GRX	C	Black	.75	.46	.96	.742	.679
45KN019-GRX	D	Black	1.00	.60	1.15	.965	.883
45KN023-GRX	E	Black	.75	.63	1.09	.85	.773
45KN026-GRX	E	Black	.78	.63	1.08	.843	.766
45KN024-GRX	F	Black	.98	.57	1.38	1.15	1.05
45KN025-GRX	G	Black	1.31	.87	1.05	.88	.80
* 45KN021-GRX	H	Black	1.45	.90	1.60	1.36	1.22
* 450-1170-GRX	I	Black	1.45	.90	1.32	1.12	1.01
450-1171-GRX	H	Black	.93	.56	1.34	1.03	.94
450-1017-GRX	I	Black	.93	.56	1.34	1.03	.94
450-2016-GRX	J	Black	1.04	.62	1.18	.792	.66
450-2023-GRX	K	Black	.90	.71	.97	.75	.68
450-2034-GRX	L	Black	.50	.61	.65	.44	.40
450-2035-GRX	M	Black	.59	.55	.77	.59	.54
450-2036-GRX	M	Black	.77	.59	1.06	.792	.72
450-2039-GRX	M	Black	.95	.78	1.09	.76	.68
450-2037-GRX	M	Black	1.39	.71	1.39	1.11	1.00
	N	Black	1.16	.71	1.55	1.32	1.19