


HEYCO Rubber Grommets


 This product is RoHS compliant.



HEYCO® RUBBER GROMMETS

Features:

- Used to protect or cover through holes
- Helps eliminate sharp edges so your wires are protected
- Material: Styrene Butadiene Rubber
- Adds aesthetic value to your application
- Good water resistance
- Operating Temp: -40°F to 221°F

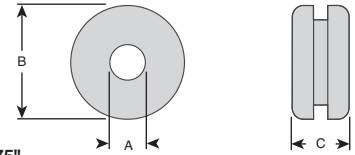

Mounting Diameter: 0.250" to 0.562"

MOUSER STOCK NO.	Heyco Part No.	Description	Dimensions			Thickness (in.)	Price Each		
			A	B	C		1	100	500
836-G1004	G1004	RG 250-4-2	0.125	0.344	0.188	.063	.12	.09	.07
836-G1005	G1005	RG 250-5-2	0.156	0.375	0.188	.063	.11	.084	.063
836-G1006	G1006	RG 250-5-2A	0.156	0.438	0.375	.063	.16	.12	.10
836-G1010	G1010	RG 281-6-3	0.188	0.438	0.219	.940	.15	.11	.08
836-G1017	G1017	RG 312-6-2	0.188	0.406	0.219	.063	.18	.12	.10
836-G1018	G1018	RG 312-6-2A	0.188	0.438	0.188	.063	.11	.07	.058
836-G1019	G1019	RG 312-6-2B	0.188	0.500	0.250	.063	.17	.11	.096
836-G1014	G1014	RG 312-6-3	0.188	0.500	0.281	.094	.20	.14	.11
836-G1020	G1020	RG 312-6-4	0.188	0.438	0.250	.125	.10	.07	.05
836-G1022	G1022	RG 312-6-6	0.188	0.438	0.313	.188	.09	.06	.05
836-G1023	G1023	RG 312-6-8	0.188	0.438	0.375	.250	.19	.13	.11
836-G1026	G1026	RG 312-7-2	0.219	0.438	0.188	.063	.09	.063	.053
836-G1033	G1033	RG 375-4-3	0.125	0.500	0.313	.094	.11	.08	.06
836-G1034	G1034	RG 375-6-6	0.188	0.625	0.375	.188	.15	.114	.083
836-G1037	G1037	RG 375-8-2	0.250	0.563	0.250	.063	.19	.13	.11
836-G1038	G1038	RG 375-8-3	0.250	0.500	0.250	.094	.33	.23	.18
836-G1039	G1039	RG 375-8-3A	0.250	0.563	0.281	.094	.18	.12	.10
836-G1042	G1042	RG 375-9-2	0.281	0.563	0.250	.063	.14	.10	.08
836-G1043	G1043	RG 375-10-12	0.313	0.63	0.500	.375	.18	.12	.10
836-G1047	G1047	RG 406-9-4	0.281	0.625	0.375	.125	.12	.09	.07
836-G1052	G1052	RG 437-8-2	0.250	0.625	0.188	.063	.11	.07	.06
836-G1053	G1053	RG 437-8-2A	0.250	0.625	0.313	.063	.22	.15	.12
836-G1056	G1056	RG 437-8-4	0.250	0.625	0.250	.125	.12	.08	.07
836-G1057	G1057	RG 437-8-6	0.250	0.625	0.313	.188	.14	.10	.08
836-G1058	G1058	RG 437-8-8	0.250	0.625	0.375	.250	.15	.11	.08
836-G1061	G1061	RG 437-10-2	0.313	0.625	0.281	.063	.12	.09	.07
836-G1062	G1062	RG 437-10-3	0.313	0.625	0.313	.094	.25	.17	.135
836-G1086	G1086	RG 500-10-8	0.313	0.625	0.625	.250	.38	.27	.21
836-G1089	G1089	RG 500-12-2	0.375	0.625	0.250	.063	.11	.08	.06
836-G1090	G1090	RG 500-12-2A	0.375	0.688	0.281	.630	.19	.127	.106
836-G1092	G1092	RG 500-12-4	0.375	0.625	0.313	.125	.52	.37	.29
836-G1093	G1093	RG 500-12-4A	0.375	0.625	0.406	.125	.10	.07	.05
836-G1094	G1094	RG 500-12-5	0.375	0.688	0.313	.155	.22	.154	.123
836-G1095	G1095	RG 500-12-8	0.375	0.500	0.500	.025	.19	.13	.10
836-G1096	G1096	RG 500-12-12	0.375	0.625	0.625	.375	.23	.164	.133
836-G1110	G1110	RG 562-6-6	0.188	0.750	0.312	.188	.40	.372	.342
836-G1112	G1112	RG 562-10-2	0.313	0.813	0.313	.063	.27	.194	.153
836-G1114	G1114	RG 562-10-4	0.313	0.813	0.375	.125	.34	.243	.19
836-G1115	G1115	RG 562-10-6	0.313	0.813	0.375	.188	.41	.29	.232
836-G1116	G1116	RG 562-10-6A	0.313	0.813	0.438	.188	.25	.173	.146

Mounting Diameter: 0.562" to 0.875"

MOUSER STOCK NO.	Heyco Part No.	Description	Dimensions			Thickness (in.)	Price Each		
			A	B	C		1	100	500
836-G1117	G1117	RG 562-10-8	0.313	0.813	0.500	.250	.63	.433	.352
836-G1120	G1120	RG 562-12-6	0.375	0.813	0.375	.188	.25	.17	.135
836-G1121	G1121	RG 562-12-12	0.375	0.750	0.750	.375	.30	.215	.176
836-G1123	G1123	RG 562-14-2	0.438	0.750	0.250	.063	.16	.11	.09
836-G1127	G1127	RG 625-6-4	0.188	0.875	0.250	.125	.92	.646	.509
836-G1130	G1130	RG 625-12-2	0.375	0.875	0.313	.063	.14	.10	.077
836-G1132	G1132	RG 625-12-4	0.375	0.875	0.375	.125	.21	.14	.11
836-G1133	G1133	RG 625-12-6	0.375	0.875	0.438	.188	.22	.15	.12
836-G1134	G1134	RG 625-12-8	0.375	0.875	0.500	.250	.23	.163	.13
836-G1135	G1135	RG 625-13-6	0.400	1.100	0.435	.187	.34	.247	.193
836-G1136	G1136	RG 625-13-12	0.406	0.813	0.625	.375	.38	.269	.215
836-G1137	G1137	RG 625-16-2	0.500	0.813	0.281	.063	.39	.28	.223
836-G1140	G1140	RG 630-16-4	0.500	0.810	0.300	.110	1.36	.953	.752
836-G1150	G1150	RG 687-14-2	0.438	0.938	0.313	.063	.29	.20	.164
836-G1151	G1151	RG 687-14-2A	0.438	0.938	0.348	.063	.25	.173	.146
836-G1152	G1152	RG 687-14-4	0.438	0.938	0.375	.125	.65	.454	.363
836-G1153	G1153	RG 687-14-6	0.438	0.938	0.438	.188	.30	.215	.176
836-G1154	G1154	RG 687-14-8	0.438	0.938	0.500	.250	.28	.198	.159
836-G1155	G1155	RG 687-16-2	0.500	0.875	0.250	.063	.22	.15	.12
836-G1172	G1172	RG 750-10-6	0.313	1.000	0.438	.188	.40	.28	.22
836-G1174	G1174	RG 750-12-2	0.375	1.000	0.375	.063	.69	.491	.393
836-G1176	G1176	RG 750-16-2	0.500	0.875	0.250	.063	.45	.31	.25
836-G1177	G1177	RG 750-16-2A	0.500	1.000	0.250	.063	.65	.453	.361
836-G1178	G1178	RG 750-16-3	0.500	0.875	0.344	.094	.26	.18	.14
836-G1179	G1179	RG 750-16-3A	0.500	0.969	0.281	.094	.22	.15	.12
836-G1181	G1181	RG 750-16-5	0.500	0.938	0.406	.156	.31	.212	.176
836-G1182	G1182	RG 750-16-12	0.500	1.000	0.625	.375	.51	.313	.177
836-G1188	G1188	RG 812-12-4	0.375	1.063	0.375	.125	1.03	.958	.888
836-G1191	G1191	RG 812-14-10	0.438	1.063	0.625	.313	.56	.385	.31
836-G1192	G1192	RG 812-16-2	0.500	1.063	0.313	.063	.26	.183	.148
836-G1193	G1193	RG 812-16-4	0.500	1.063	0.375	.125	.41	.29	.23
836-G1194	G1194	RG 812-16-6	0.500	1.063	0.438	.188	.31	.223	.177
836-G1195	G1195	RG 812-16-8	0.500	1.063	0.500	.250	.41	.296	.233
836-G1197	G1197	RG 812-18-2	0.563	1.063	0.313	.063	.22	.15	.126
836-G1198	G1198	RG 812-18-4	0.563	1.062	0.375	.125	.65	.45	.36
836-G1199	G1199	RG 812-18-6	0.563	1.063	0.438	.188	.29	.203	.167
836-G1200	G1200	RG 812-18-8	0.563	1.063	0.500	.250	.46	.31	.252
836-G1208	G1208	RG 875-10-2	0.313	1.375	0.250	.063	.61	.423	.339
836-G1213	G1213	RG 875-18-6	0.563	1.063	0.438	.188	.27	.194	.153
836-G1214	G1214	RG 875-18-12	0.563	1.063	0.625	.375	.45	.32	.25

Mounting Diameter: 0.875" to 1.250"

MOUSER STOCK NO.	Heyco Part No.	Description	Dimensions			Thickness (in.)	Price Each		
			A	B	C		1	100	500
836-G1215	G1215	RG875-20-2	0.625	1.125	0.313	.063	.24	.16	.135
836-G1218	G1218	RG 875-20-4	0.625	1.125	0.375	.125	.26	.18	.145
836-G1219	G1219	RG 875-20-6	0.625	1.125	0.438	.188	.29	.203	.167
836-G1220	G1220	RG 875-20-8	0.625	1.125	0.500	.250	.32	.233	.184
836-G1224	G1224	RG 906-20-10	0.625	1.125	0.625	.313	.34	.24	.19
836-G1232	G1232	RG 968-22-12	0.688	1.313	0.625	.375	.74	.523	.413
836-G1242	G1242	RG 1000-12-2	0.375	1.250	0.250	.063	.58	.403	.323
836-G1244	G1244	RG 1000-12-4	0.375	1.313	0.375	.125	1.10	.774	.603
836-G1246	G1246	RG 1000-16-2	0.500	1.250	0.250	.063	.34	.247	.193
836-G1247	G1247	RG 1000-16-4	0.500	1.250	0.313	.125	.52	.37	.286
836-G1248	G1248	RG 1000-16-8	0.500	1.375	0.500	.266	.58	.403	.323
836-G1249	G1249	RG 1000-18-12	0.563	1.250	0.625	.375	1.82	1.28	1.00
836-G1252	G1252	RG 1000-22-2	0.688	1.313	0.375	.063	.34	.254	.195
836-G1253	G1253	RG 1000-22-3	0.688	1.312	0.375	.078	.63	.444	.353
836-G1255	G1255	RG 1000-22-4	0.688	1.313	0.438	.125	.41	.30	.238
836-G1256	G1256	RG 1000-22-6	0.688	1.313	0.500	.188	.50	.353	.29
836-G1257	G1257	RG 1000-22-8	0.688	1.313	0.563	.250	.36	.258	.207
836-G1258	G1258	RG 1000-24-2	0.750	1.250	0.297	.063	.33	.234	.183
836-G1259	G1259	RG 1000-24-4	0.750	1.188	0.375	.125	1.00	.699	.554
836-G1260	G1260	RG 1000-24-4A	0.750	1.250	0.375	.125	1.59	1.10	.876
836-G1261	G1261	RG 1000-24-6	0.750	1.250	0.563	.188	.42	.30	.236
836-G1264	G1264	RG 1000-28-8	0.875	1.250	0.625	.250	.43	.30	.24
836-G1269	G1269	RG 1062-24-2	0.750	1.375	0.375	.063	.35	.25	.194
836-G1272	G1272	RG 1062-24-6	0.750	1.375	0.500	.188	.50	.353	.284
836-G1273	G1273	RG 1062-24-8	0.750	1.375	0.563	.250	.41	.30	.239
836-G1278	G1278	RG 1125-24-12	0.750	1.625	1.125	.375	1.22	.864	.673
836-G1279	G1279	RG 1125-26-8	0.804	1.375	0.506	.257	2.18	1.52	1.19
836-G1281	G1281	RG 1125-28-3	0.875	1.500	0.344	.094	.55	.38	.30
836-G1288	G1288	RG 1187-28-5	0.875	1.375	0.406	.141	.60	.413	