

RAF HARDWARE Metric Spacers and Thumb Nuts



RoHS Compliant This product is RoHS compliant.

METRIC FEMALE ROUND SPACERS 6MM - 8MM

M3 Thread - 6 mm

| "L" (mm) | Aluminum Material | | | Stainless Steel Material | | | Nylon Material | | |
|-------------|-------------------|------------|-----|--------------------------|------------|-----|------------------|------------|-----|
| | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | |
| | | 1 | 100 | | 1 | 100 | | 1 | 100 |
| 1 | ---- | --- | --- | ---- | --- | --- | 761-M0530-3-N | .46 | .43 |
| 2 | 761-M0531-3-AL | .33 | .28 | 761-M0531-3-SS | .57 | .49 | 761-M0531-3-N | .46 | .44 |
| 3 | 761-M0532-3-AL | .33 | .29 | ---- | --- | --- | 761-M0532-3-N | .48 | .45 |
| 4 | 761-M0533-3-AL | .34 | .29 | 761-M0533-3-SS | .62 | .53 | 761-M0533-3-N | .49 | .46 |
| 5 | 761-M0534-3-AL | .34 | .29 | ---- | --- | --- | 761-M0534-3-N | .50 | .47 |
| 6 | 761-M0535-3-AL | .35 | .30 | 761-M0535-3-SS | .65 | .56 | 761-M0535-3-N | .52 | .48 |
| 7 | 761-M0536-3-AL | .35 | .30 | ---- | --- | --- | ---- | --- | --- |
| 8 | 761-M0537-3-AL | .36 | .31 | 761-M0537-3-SS | .69 | .59 | 761-M0537-3-N | .53 | .50 |
| 9 | 761-M0538-3-AL | .37 | .32 | ---- | --- | --- | 761-M0538-3-N | .54 | .51 |
| 10 | 761-M0539-3-AL | .38 | .33 | 761-M0539-3-SS | .70 | .60 | ---- | --- | --- |
| 11 | 761-M0540-3-AL | .39 | .33 | 761-M0540-3-SS | .71 | .61 | ---- | --- | --- |
| 12 | 761-M0541-3-AL | .39 | .34 | ---- | --- | --- | 761-M0541-3-N | .58 | .54 |
| 13 | 761-M0542-3-AL | .41 | .35 | 761-M0542-3-SS | .72 | .62 | 761-M0542-3-N | .59 | .55 |

M4 Thread - 6 mm

| "L" (mm) | Aluminum Material | | | Stainless Steel Material | | | Nylon Material | | |
|-------------|-------------------|------------|-----|--------------------------|------------|-----|------------------|------------|-----|
| | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | |
| | | 1 | 100 | | 1 | 100 | | 1 | 100 |
| 2 | 761-M0531-4-AL | .33 | .28 | ---- | --- | --- | 761-M0531-4-N | .46 | .44 |
| 3 | 761-M0532-4-AL | .33 | .29 | 761-M0532-4-SS | .60 | .51 | 761-M0532-4-N | .48 | .45 |
| 4 | 761-M0533-4-AL | .34 | .29 | 761-M0533-4-SS | .62 | .53 | 761-M0533-4-N | .49 | .46 |
| 5 | 761-M0534-4-AL | .34 | .29 | ---- | --- | --- | 761-M0534-4-N | .50 | .47 |
| 6 | ---- | --- | --- | ---- | --- | --- | 761-M0535-4-N | .52 | .48 |
| 7 | ---- | --- | --- | ---- | --- | --- | 761-M0536-4-N | .52 | .49 |
| 8 | ---- | --- | --- | 761-M0537-4-SS | .69 | .59 | 761-M0537-4-N | .53 | .50 |
| 9 | 761-M0538-4-AL | .37 | .32 | 761-M0538-4-SS | .69 | .59 | ---- | --- | --- |
| 10 | ---- | --- | --- | 761-M0539-4-SS | .70 | .60 | ---- | --- | --- |
| 12 | ---- | --- | --- | ---- | --- | --- | 761-M0541-4-N | .58 | .54 |
| 13 | 761-M0542-4-AL | .41 | .35 | ---- | --- | --- | ---- | --- | --- |

M3 Thread - 8 mm

| "L" (mm) | Aluminum Material | | | Stainless Steel Material | | | Nylon Material | | |
|-------------|-------------------|------------|-----|--------------------------|------------|-----|------------------|------------|-----|
| | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | |
| | | 1 | 100 | | 1 | 100 | | 1 | 100 |
| 2 | 761-M0591-3-AL | .33 | .29 | ---- | --- | --- | 761-M0591-3-N | .42 | .36 |
| 3 | ---- | --- | --- | 761-M0592-3-SS | .65 | .56 | 761-M0592-3-N | .42 | .36 |
| 4 | 761-M0593-3-AL | .35 | .30 | ---- | --- | --- | 761-M0593-3-N | .43 | .37 |
| 5 | 761-M0594-3-AL | .35 | .30 | ---- | --- | --- | ---- | --- | --- |
| 9 | 761-M0598-3-AL | .39 | .34 | ---- | --- | --- | ---- | --- | --- |
| 10 | 761-M0599-3-AL | .40 | .34 | ---- | --- | --- | 761-M0599-3-N | .49 | .42 |
| 12 | 761-M0601-3-AL | .42 | .36 | ---- | --- | --- | ---- | --- | --- |

M4 Thread - 8 mm

| "L" (mm) | Aluminum Material | | | Stainless Steel Material | | | Nylon Material | | |
|-------------|-------------------|------------|-----|--------------------------|------------|-----|------------------|------------|-----|
| | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | |
| | | 1 | 100 | | 1 | 100 | | 1 | 100 |
| 2 | ---- | --- | --- | ---- | --- | --- | 761-M0591-4-N | .42 | .36 |
| 3 | 761-M0592-4-AL | .34 | .29 | ---- | --- | --- | 761-M0592-4-N | .42 | .36 |
| 4 | 761-M0593-4-AL | .35 | .30 | ---- | --- | --- | 761-M0593-4-N | .43 | .37 |
| 5 | 761-M0594-4-AL | .35 | .30 | 761-M0594-4-SS | .71 | .61 | 761-M0594-4-N | .44 | .38 |
| 6 | ---- | --- | --- | ---- | --- | --- | 761-M0595-4-N | .45 | .39 |
| 7 | 761-M0596-4-AL | .37 | .32 | ---- | --- | --- | 761-M0596-4-N | .46 | .39 |
| 8 | ---- | --- | --- | 761-M0597-4-SS | .78 | .67 | ---- | --- | --- |
| 13 | 761-M0602-4-AL | .42 | .36 | ---- | --- | --- | ---- | --- | --- |

M5 Thread - 8 mm

| "L" (mm) | Aluminum Material | | | Stainless Steel Material | | | Nylon Material | | |
|-------------|-------------------|------------|-----|--------------------------|------------|-----|------------------|------------|-----|
| | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | | MOUSER STOCK NO. | Price Each | |
| | | 1 | 100 | | 1 | 100 | | 1 | 100 |
| 3 | ---- | --- | --- | ---- | --- | --- | 761-M0592-5-N | .42 | .36 |
| 5 | 761-M0594-5-AL | .35 | .30 | ---- | --- | --- | 761-M0594-5-N | .44 | .38 |
| 6 | ---- | --- | --- | 761-M0595-5-SS | .74 | .63 | ---- | --- | --- |
| 8 | 761-M0597-5-AL | .37 | .32 | ---- | --- | --- | 761-M0597-5-N | .47 | .40 |
| 10 | 761-M0599-5-AL | .40 | .34 | ---- | --- | --- | 761-M0599-5-N | .49 | .42 |
| 12 | 761-M0601-5-AL | .42 | .36 | 761-M0601-5-SS | .97 | .83 | ---- | --- | --- |
| 13 | 761-M0602-5-AL | .42 | .36 | ---- | --- | --- | ---- | --- | --- |

METRIC ROUND THUMB NUTS

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | RAF Hardware Part No. | Thread Size | A +0.5-0.0 | B +0.5-0.5 | C Ref. | D +0.5-0.5 | E +0.5-0.5 | Price Each | | |
|------------------------|-----------------------|-------------|---------------|---------------|-----------|---------------|---------------|------------|------|------|
| | | | | | | | | 1 | 100 | 500 |
| Brass | | | | | | | | | | |
| 761-M3560-B-12 | M3560-B-12 | M2.5x0.45 | 6 | 3 | 6 | 3 | 5 | .79 | .74 | .64 |
| 761-M3561-B-12 | M3561-B-12 | M3X0.5 | 8 | 3 | 6 | 3 | 6 | .92 | .86 | .74 |
| 761-M3563-B-12 | M3563-B-12 | M4X0.7 | 10 | 3 | 7 | 4 | 9 | 1.18 | 1.11 | .96 |
| 761-M3564-B-12 | M3564-B-12 | M5X0.8 | 13 | 4 | 9 | 5 | 11 | 1.41 | 1.32 | 1.15 |
| Stainless Steel | | | | | | | | | | |
| 761-M3560-SS | M3560-SS | M2.5X0.45 | 6 | 3 | 6 | 3 | 5 | 1.03 | .97 | .84 |
| 761-M3561-SS | M3561-SS | M3X0.5 | 8 | 3 | 6 | 3 | 6 | 1.32 | 1.24 | 1.07 |
| 761-M3563-SS | M3563-SS | M4X0.7 | 10 | 3 | 7 | 4 | 9 | 1.58 | 1.48 | 1.28 |
| 761-M3564-SS | M3564-SS | M5X0.8 | 13 | 4 | 9 | 5 | 11 | 2.56 | 2.40 | 2.08 |
| 761-M3565-SS | M3565-SS | M6X1 | 13 | 4 | 9 | 5 | 12 | 2.56 | 2.40 | 2.08 |
| 761-M3566-SS | M3566-SS | M8X1.25 | 19 | 6 | 12 | 6 | 16 | 5.49 | 5.15 | 4.46 |



RoHS Compliant



Female Round Spacer 6 mm




RoHS Compliant



Female Round Spacer 8 mm



RoHS Compliant

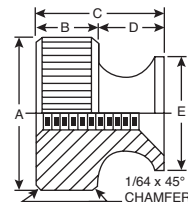

Round Thumb Nut