


# HONEYWELL Pressure Sensors



DIMENSIONS: in. (mm)

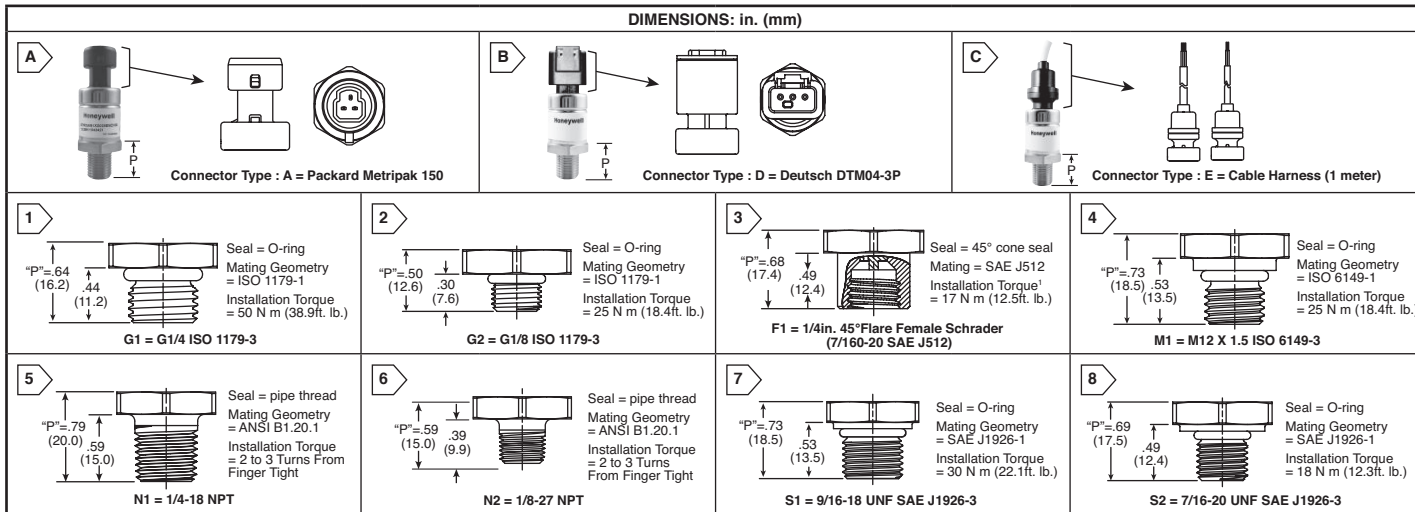

## HONEYWELL PX2 SERIES HEAVY DUTY PRESSURE TRANSDUCER



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HONEYWELL Part No.	Fig.	Connector Type	Pressure Range	Output Function	Price Each		
						1	10	50
<b>Port Type: G1 = G1/A ISO 1179-3</b>								
785-PX2AG1XX010BSCHX	PX2AG1XX010BSCHX	A1	Packard Metripak 150	0-10 bar	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AG1XX016BSCHX	PX2AG1XX016BSCHX	A1	Packard Metripak 150	0-16 bar	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AG1XX025BSCHX	PX2AG1XX025BSCHX	A1	Packard Metripak 150	0-25 bar	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AG1XX010BSAAX	PX2AG1XX010BSAAX	A1	Packard Metripak 150	0-10 bar	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AG1XX016BSAAX	PX2AG1XX016BSAAX	A1	Packard Metripak 150	0-16 bar	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AG1XX025BSAAX	PX2AG1XX025BSAAX	A1	Packard Metripak 150	0-25 bar	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
<b>Port Type: G2 = G1/8 ISO 1179-3</b>								
785-PX2AG2XX010BSCHX	PX2AG2XX010BSCHX	A2	Packard Metripak 150	0-10 bar	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AG2XX016BSCHX	PX2AG2XX016BSCHX	A2	Packard Metripak 150	0-16 bar	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AG2XX025BSCHX	PX2AG2XX025BSCHX	A2	Packard Metripak 150	0-25 bar	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AG2XX010BSAAX	PX2AG2XX010BSAAX	A2	Packard Metripak 150	0-10 bar	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AG2XX016BSAAX	PX2AG2XX016BSAAX	A2	Packard Metripak 150	0-16 bar	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AG2XX025BSAAX	PX2AG2XX025BSAAX	A2	Packard Metripak 150	0-25 bar	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
<b>Port Type: F1 = 1/4 in 45° Flare Female Schrader</b>								
785-PX2AF1XX150PAAAX	PX2AF1XX150PAAAX	A3	Packard Metripak 150	150 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	67.32	55.99	52.33
785-PX2AF1XX150PSAAX	PX2AF1XX150PSAAX	A3	Packard Metripak 150	150 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	67.32	55.99	52.33
785-PX2AF1XX300PAAAX	PX2AF1XX300PAAAX	A3	Packard Metripak 150	300 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	67.32	55.99	52.33
785-PX2AF1XX300PSAAX	PX2AF1XX300PSAAX	A3	Packard Metripak 150	300 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	67.32	55.99	52.33
785-PX2AF1XX500PAAAX	PX2AF1XX500PAAAX	A3	Packard Metripak 150	500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	67.32	55.99	52.33
785-PX2AF1XX500PSCHX	PX2AF1XX500PSCHX	A3	Packard Metripak 150	500 psi	Current 4mA to 20mA	67.32	55.99	52.33
<b>Port Type: M1 = M12 X 1.5 ISO 6149-3</b>								
785-PX2AM1XX100PSCHX	PX2AM1XX100PSCHX	A4	Packard Metripak 150	0-100 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AM1XX250PSCHX	PX2AM1XX250PSCHX	A4	Packard Metripak 150	0-250 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AM1XX500PACHX	PX2AM1XX500PACHX	A4	Packard Metripak 150	0-500 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AM1XX100PSAAX	PX2AM1XX100PSAAX	A4	Packard Metripak 150	0-100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AM1XX250PAAAX	PX2AM1XX250PAAAX	A4	Packard Metripak 150	0-250 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AM1XX500PSAAX	PX2AM1XX500PSAAX	A4	Packard Metripak 150	0-500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
<b>Port Type: N1 = 1/4 - 18 NPT</b>								
785-PX2AN1XX100PAAAX	PX2AN1XX100PAAAX	A5	Packard Metripak 150	100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX100PSAAX	PX2AN1XX100PSAAX	A5	Packard Metripak 150	100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX100PSACX	PX2AN1XX100PSACX	A5	Packard Metripak 150	0-100 psi	Ratiometric 3.3V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX200PSAAX	PX2AN1XX200PSAAX	A5	Packard Metripak 150	200 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX250PAAAX	PX2AN1XX250PAAAX	A5	Packard Metripak 150	250 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX250PSACX	PX2AN1XX250PSACX	A5	Packard Metripak 150	0-250 psi	Ratiometric 3.3V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX500PSAAX	PX2AN1XX500PSAAX	A5	Packard Metripak 150	500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN1XX500PSACX	PX2AN1XX500PSACX	A5	Packard Metripak 150	0-500 psi	Ratiometric 3.3V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2DN1XX100PSAAX	PX2DN1XX100PSAAX	B5	Deutsch DTM04-3P	100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	84.48	81.82	72.70
785-PX2DN1XX100PSCHX	PX2DN1XX100PSCHX	B5	Deutsch DTM04-3P	100 psi	Current 4mA to 20mA	84.48	81.82	72.70
785-PX2DN1XX250PSAAX	PX2DN1XX250PSAAX	B5	Deutsch DTM04-3P	250 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	84.48	81.82	72.70
785-PX2DN1XX250PSCHX	PX2DN1XX250PSCHX	B5	Deutsch DTM04-3P	250 psi	Current 4mA to 20mA	84.48	81.82	72.70
785-PX2DN1XX500PSAAX	PX2DN1XX500PSAAX	B5	Deutsch DTM04-3P	500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	84.48	81.82	72.70
785-PX2DN1XX500PSCHX	PX2DN1XX500PSCHX	B5	Deutsch DTM04-3P	500 psi	Current 4mA to 20mA	84.48	81.82	72.70
785-PX2EN1XX100PSAAX	PX2EN1XX100PSAAX	C5	Cable Harness (1m)	100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	85.82	77.70
785-PX2EN1XX150PSCHX	PX2EN1XX150PSCHX	C5	Cable Harness (1m)	150 psi	Current 4mA to 20mA	89.48	85.82	77.70
785-PX2EN1XX200PSCHX	PX2EN1XX200PSCHX	C5	Cable Harness (1m)	200 psi	Current 4mA to 20mA	89.48	85.82	77.70
785-PX2EN1XX250PSAAX	PX2EN1XX250PSAAX	C5	Cable Harness (1m)	250 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	85.82	77.70
785-PX2EN1XX500PSAAX	PX2EN1XX500PSAAX	C5	Cable Harness (1m)	500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	85.82	77.70
785-PX2EN1XX500PSCHX	PX2EN1XX500PSCHX	C5	Cable Harness (1m)	500 psi	Current 4mA to 20mA	89.48	85.82	77.70
<b>Port Type: N2 = 1/8 - 27 NPT</b>								
785-PX2AN2XX150PAAAX	PX2AN2XX150PAAAX	A6	Packard Metripak 150	150 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AN2XX150PSCHX	PX2AN2XX150PSCHX	A6	Packard Metripak 150	150 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AN2XX250PSCHX	PX2AN2XX250PSCHX	A6	Packard Metripak 150	250 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AN2XX300PSCHX	PX2AN2XX300PSCHX	A6	Packard Metripak 150	300 psi	Current 4mA to 20mA	89.48	72.81	69.34
<b>Port Type: S1 = 9/16-18 UNF SAE J1926-3</b>								
785-PX2AS1XX100PSCHX	PX2AS1XX100PSCHX	A7	Packard Metripak 150	0-100 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AS1XX250PACHX	PX2AS1XX250PACHX	A7	Packard Metripak 150	0-250 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AS1XX500PSCHX	PX2AS1XX500PSCHX	A7	Packard Metripak 150	0-500 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AS1XX100PAAAX	PX2AS1XX100PAAAX	A7	Packard Metripak 150	0-100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AS1XX250PSAAX	PX2AS1XX250PSAAX	A7	Packard Metripak 150	0-250 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AS1XX500PAAAX	PX2AS1XX500PAAAX	A7	Packard Metripak 150	0-500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
<b>Port Type: S2 = 7/16-20 UNF SAE J1926-3</b>								
785-PX2AS2XX100PACHX	PX2AS2XX100PACHX	A8	Packard Metripak 150	0-100 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AS2XX250PSCHX	PX2AS2XX250PSCHX	A8	Packard Metripak 150	0-250 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AS2XX500PSCHX	PX2AS2XX500PSCHX	A8	Packard Metripak 150	0-500 psi	Current 4mA to 20mA	89.48	72.81	69.34
785-PX2AS2XX100PAAAX	PX2AS2XX100PAAAX	A8	Packard Metripak 150	0-100 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AS2XX250PSAAX	PX2AS2XX250PSAAX	A8	Packard Metripak 150	0-250 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34
785-PX2AS2XX500PSAAX	PX2AS2XX500PSAAX	A8	Packard Metripak 150	0-500 psi	Ratiometric 5.0V, 10%Vs to 90%Vs	89.48	72.81	69.34