


HAMMOND Rack and Cabinet Accessories



HAMMOND 19" ALUMINUM RACK PANELS

Features:

- .125" thick
- 19" rack mount panels
- Finished in Smooth Black or Beige (RAL 702) Powder Paint or Natural Finish (paper covered on one side)

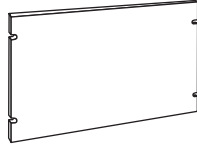

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Length/ (Units)	Price Each			
			1	2	5	10
Smooth Black						
546-PBPA19001BK2	PBPA19001BK2	1.75" (1)	9.29	8.90	8.57	8.27
546-PBPA19003BK2	PBPA19003BK2	3.50" (2)	14.20	13.11	12.62	11.21
546-PBPA19005BK2	PBPA19005BK2	5.25" (3)	20.30	19.45	18.72	16.16
546-PBPA19007BK2	PBPA19007BK2	7.00" (4)	25.34	24.52	22.69	21.12
546-PBPA19008BK2	PBPA19008BK2	8.75" (5)	31.49	30.95	29.87	25.73
546-PBPA19010BK2	PBPA19010BK2	10.50" (6)	33.85	32.71	31.68	28.97
546-PBPA19012BK2	PBPA19012BK2	12.25" (7)	40.52	39.22	38.00	34.74
546-PBPA19014BK2	PBPA19014BK2	14.00" (8)	45.60	43.78	42.14	36.39
546-PBPA19015BK2	PBPA19015BK2	15.75" (9)	49.09	47.03	45.27	39.10
546-PBPA19017BK2	PBPA19017BK2	17.50" (10)	55.78	51.50	49.57	46.50
546-PBPA19019BK2	PBPA19019BK2	19.25" (11)	62.27	59.66	51.71	50.37
546-PBPA19021BK2	PBPA19021BK2	21.00" (12)	69.41	66.50	64.01	57.73
546-PBPA19022BK2	PBPA19022BK2	22.75" (13)	73.50	70.57	67.91	58.66
546-PBPA19024BK2	PBPA19024BK2	24.50" (14)	80.26	77.06	74.17	64.05
546-PBPA19026BK2	PBPA19026BK2	26.25" (15)	86.18	82.74	79.63	68.77
546-PBPA19028BK2	PBPA19028BK2	28.00" (16)	92.08	88.39	85.07	73.48
546-PBPA19029BK2	PBPA19029BK2	29.75" (17)	96.32	92.44	88.98	76.84
546-PBPA19031BK2	PBPA19031BK2	31.50" (18)	99.07	94.92	91.35	78.90
Smooth Beige						
546-PBPA19001CG2	PBPA19001CG2	1.75" (1)	10.14	9.96	9.62	8.28
546-PBPA19003CG2	PBPA19003CG2	3.50" (2)	14.23	13.62	13.11	11.33
546-PBPA19005CG2	PBPA19005CG2	5.25" (3)	21.28	20.92	20.19	17.39
546-PBPA19007CG2	PBPA19007CG2	7.00" (4)	24.41	23.39	22.51	21.12
546-PBPA19008CG2	PBPA19008CG2	8.75" (5)	31.49	30.95	29.87	25.73
546-PBPA19010CG2	PBPA19010CG2	10.50" (6)	33.80	32.42	31.21	26.96
546-PBPA19012CG2	PBPA19012CG2	12.25" (7)	40.52	38.90	37.43	32.33
546-PBPA19014CG2	PBPA19014CG2	14.00" (8)	45.60	43.78	42.14	36.39
546-PBPA19017CG2	PBPA19017CG2	17.50" (10)	55.78	53.55	51.54	44.51
546-PBPA19019CG2	PBPA19019CG2	19.25" (11)	64.63	62.04	59.72	51.58
546-PBPA19021CG2	PBPA19021CG2	21.00" (12)	69.41	66.50	64.01	55.28
546-PBPA19022CG2	PBPA19022CG2	22.75" (13)	73.50	70.57	67.91	58.66
546-PBPA19024CG2	PBPA19024CG2	24.50" (14)	80.26	77.06	74.17	64.05
546-PBPA19026CG2	PBPA19026CG2	26.25" (15)	86.18	82.74	79.63	68.77
546-PBPA19028CG2	PBPA19028CG2	28.00" (16)	92.26	88.39	85.07	73.48
546-PBPA19029CG2	PBPA19029CG2	29.75" (17)	96.32	92.44	88.98	76.84
546-PBPA19031CG2	PBPA19031CG2	31.50" (18)	98.87	94.92	91.35	78.90

Unfinished

546-PBPA19001UNF	PBPA19001UNF	1.75" (1)	10.14	9.96	9.62	8.28
546-PBPA19003UNF	PBPA19003UNF	3.50" (2)	14.91	14.66	14.15	12.19
546-PBPA19005UNF	PBPA19005UNF	5.25" (3)	21.28	20.92	20.19	17.39
546-PBPA19007UNF	PBPA19007UNF	7.00" (4)	24.41	23.39	22.51	21.12
546-PBPA19008UNF	PBPA19008UNF	8.75" (5)	28.89	27.68	26.64	25.00
546-PBPA19010UNF	PBPA19010UNF	10.50" (6)	33.80	32.42	31.21	26.96
546-PBPA19012UNF	PBPA19012UNF	12.25" (7)	39.04	37.41	36.00	33.78
546-PBPA19015UNF	PBPA19015UNF	15.75" (9)	49.00	47.03	45.27	39.10
546-PBPA19017UNF	PBPA19017UNF	17.50" (10)	55.89	53.55	51.54	44.51
546-PBPA19019UNF	PBPA19019UNF	19.25" (11)	64.63	62.04	59.72	51.58
546-PBPA19021UNF	PBPA19021UNF	21.00" (12)	69.27	66.50	64.01	55.28
546-PBPA19022UNF	PBPA19022UNF	22.75" (13)	73.50	70.57	67.91	58.66
546-PBPA19024UNF	PBPA19024UNF	24.50" (14)	80.26	77.06	74.17	64.05
546-PBPA19026UNF	PBPA19026UNF	26.25" (15)	86.18	82.74	79.63	68.77
546-PBPA19028UNF	PBPA19028UNF	28.00" (16)	92.08	88.39	85.07	73.48
546-PBPA19029UNF	PBPA19029UNF	29.75" (17)	96.32	92.44	88.98	76.84
546-PBPA19031UNF	PBPA19031UNF	31.50" (18)	98.87	94.92	91.35	78.90

HAMMOND 19" RACK MOUNT HARDWARE



RoHS Compliant


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Description	Qty. per Pack	Price Each			
				1	2	5	10
546-1421A	1421A	10-32 X 0.75" Phillips oval head screw/plastic washer	4	3.38	3.34	3.22	2.90
546-1421A100B	1421A100B	Nickel plated 10-32 x 0.625" countersunk Phillips head	100	19.53	19.30	18.63	16.75
546-1421A100W	1421A100W	Black plastic cup washer for countersunk 10-32 screws	100	34.02	31.40	27.20	26.86
546-1421E100W	1421E100W	Nickel plated cup washer for countersunk 10-32 screws	100	23.31	22.91	22.12	19.05
546-1421N25	1421N25	10-32 clip nuts for all panel rails	25	14.85	14.22	13.69	11.82

HAMMOND RAIL MOUNT SUPPORT ANGLES

Features:

- 14 gauge steel
- Slot allow up/down or front/back adjustments
- 1.75" x 1.75" to support heavy equipment
- Finished in Textured Black Powder Paint
- Reduces load on front panel

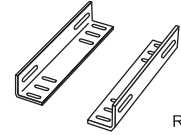

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Length (in.)	Price Each			
			1	2	5	10
546-RASA12BK3	RASA12BK3	9.97	25.36	24.93	24.06	20.72
546-RASA16BK3	RASA16BK3	14.95	27.65	27.18	26.23	22.60
546-RASA22BK3	RASA22BK3	20.95	31.21	30.67	29.60	25.50
546-RASA28BK3	RASA28BK3	28.00	34.11	33.53	28.85	27.87

HAMMOND EQUIPMENT SLIDES

Features:

- 19" rack panel mount (to front and back panel rails)
- Heavy duty, ball bearing mechanism
- Uses only 1U (1.75") of panel height
- Sold in pack of 2




RoHS Compliant


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Slide Length (in.)	Capacity (per pair)	Price Each			
				1	2	5	10
546-RSLIDE12	RSLIDE12	12.00	120 (lbs)	60.58	58.04	55.87	48.24
546-RSLIDE16	RSLIDE16	16.00	130 (lbs)	66.17	65.04	62.77	54.07
546-RSLIDE22	RSLIDE22	22.00	120 (lbs)	67.49	66.33	64.02	55.15

HAMMOND RACK MOUNT POWER PANELS

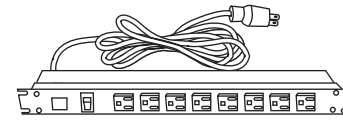

Outlets on Front

 

Outlets on Back

Available in ASA 61 Gray or Black Powder Coat Finish.
 Heavy 14 gauge wire cord - 14/3 SJTW for extreme temperature ranges.
 Integral molded plug (NEMA 5-15P) with straight blade.
 6 outlet models include 2 outlets with extra spacing for clearance of most plug in transformers.
 Includes 15 Amp, 125 VAC circuit breaker to prevent accidental overload.
 Dimensions are 19" x 3" x 1.75".
 UL recognized - under the component program of UL.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	No. of Outlets	On-Off Switch	Pilot Light	Cord Length	Color	Price Each	
							1	2
Outlets on Front								
546-1582H6A1	1582H6A1	6	Yes	-	6'	Gray	57.50	48.65
546-1582H6A1BK	1582H6A1BK	6	Yes	-	6'	Black	57.49	48.65
546-1582H6B1	1582H6B1	6	Yes	-	15'	Gray	61.87	53.76
546-1582H6B1BK	1582H6B1BK	6	Yes	-	15'	Black	61.08	51.68
546-1582H8A1	1582H8A1	8	Yes	-	6'	Gray	64.79	54.80
546-1582H8A1BK	1582H8A1BK	8	Yes	-	6'	Black	64.79	54.80
546-1582H8B1	1582H8B1	8	Yes	-	15'	Gray	68.53	57.98
546-1582H8B1BK	1582H8B1BK	8	Yes	-	15'	Black	68.53	57.98
546-1582T6A1	1582T6A1	6	-	Yes	6'	Gray	59.80	50.60
546-1582T6A1BK	1582T6A1BK	6	-	Yes	6'	Black	59.80	50.60
546-1582T6B1	1582T6B1	6	-	Yes	15'	Gray	63.54	53.76
546-1582T6B1BK	1582T6B1BK	6	-	Yes	15'	Black	62.90	53.75
546-1582T8A1	1582T8A1	8	-	Yes	6'	Gray	64.79	54.80
546-1582T8A1BK	1582T8A1BK	8	-	Yes	6'	Black	64.79	54.80
546-1582T8B1	1582T8B1	8	-	Yes	15'	Gray	68.53	57.98
546-1582T8B1BK	1582T8B1BK	8	-	Yes	15'	Black	68.53	57.98
Outlets on Back								
546-1583H6A1	1583H6A1	6	Yes	-	6'	Gray	56.90	50.60
546-1583H6A1BK	1583H6A1BK	6	Yes	-	6'	Black	59.79	50.60
546-1583H6B1	1583H6B1	6	Yes	-	15'	Gray	61.87	53.76
546-1583H6B1BK	1583H6B1BK	6	Yes	-	15'	Black	61.08	51.68
546-1583H8A1	1583H8A1	8	Yes	-	6'	Gray	64.79	54.80
546-1583H8A1BK	1583H8A1BK	8	Yes	-	6'	Black	64.79	54.80
546-1583H8B1	1583H8B1	8	Yes	-	15'	Gray	68.53	57.99
546-1583H8B1BK	1583H8B1BK	8	Yes	-	15'	Black	69.62	63.61
546-1583T6A1	1583T6A1	6	-	Yes	6'	Gray	59.80	50.60
546-1583T6A1BK	1583T6A1BK	6	-	Yes	6'	Black	59.80	50.60
546-1583T6B1	1583T6B1	6	-	Yes	15'	Gray	63.54	53.76
546-1583T6B1BK	1583T6B1BK	6	-	Yes	15'	Black	63.53	53.75
546-1583T8A1	1583T8A1	8	-	Yes	6'	Gray	64.79	54.80
546-1583T8A1BK	1583T8A1BK	8	-	Yes	6'	Black	62.30	52.70
546-1583T8B1	1583T8B1	8	-	Yes	15'	Gray	68.53	57.98
546-1583T8B1BK	1583T8B1BK	8	-	Yes	15'	Black	68.53	57.98