

WIREMOLD Rack and Cabinet Power Strips



legrand® 19" RACK MOUNTED COMPUTER GRADE SURGE SUPPRESSORS- 20 AMP

 
Wiremold

Specifications:

- Max surge current: 13,000 amps
- Clamping voltage: UL 300 volts
- Electrical rating: 20A, 120V
- EMI/RFI noise reduction: 40db

Features:

- Designed to fit all standard 19" cabinets, carts, and racks
- Matte black steel housing
- Black 12/3 SJT cord with NEMA 5-20P plug
- UL1449 Approved, CSA Approved
- 120 Volt resettable circuit breaker



- Five year warranty
- Surge protection, led indicator
- Dimensions: 19"W x 1.75"H x 2.75"D

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Outlets	On/Off Switch	Cord Length	Price Each	
					1	5
681-R5BZ20	R5BZ20	6 Rear	Yes	6'	115.74	108.48
681-R5BZ20-15	R5BZ20-15	6 Rear	Yes	15'	107.97	101.89
681-R5BZ20X-15	R5BZ20X-15	6 Rear	No	15'	123.63	116.67

legrand® 19" RACK MOUNTED PLUG-IN OUTLET CENTERS-20 AMP

 
Wiremold

Specifications:

- Electrical rating: 20A,120V

Features:

- Designed to fit all standard 19" cabinets, carts, and racks
- Matte black steel housing
- 12/3 SJT cord with NEMA 5-20P plug
- Resettable circuit breaker
- Two year warranty
- Dimensions: 19"W x 1.75"H x 2.75"D
- UL recognized



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Outlets	On/Off Switch	Cord Length	Price Each	
						1	5
681-J06B0B20	J06B0B20	A	6 Rear	Yes	6'	92.15	85.29
681-J06B2B20	J06B2B20	A	6 Rear	Yes	15'	67.18	64.59
681-J06B0B20X	J06B0B20X	A	6 Rear	No	6'	63.23	60.21
681-J06B0B20	J06B0B20	B	6 Front	Yes	6'	71.52	68.73
681-J06B2B20	J06B2B20	B	6 Front	Yes	15'	72.57	69.10
681-J06B0B20X	J06B0B20X	B	6 Front	No	6'	71.52	68.73
681-J06B2B20X	J06B2B20X	B	6 Front	No	15'	72.57	69.10

legrand® SPECIAL APPLICATION 19" RACK MOUNTED POWER STRIPS

 
Wiremold

Specifications:

- Electrical rating: 15A, 120V

Features:

- Designed to fit all standard 19" cabinets, carts, and racks
- Matte black steel housing
- Black 14/3 SJT cord
- UL recognized CSA approved
- 120 Volt, 15 amp resettable circuit breaker
- Dimensions: 19"W x 1.75"H x 2.75"D



- 90° Rotated outlet units are rotated for applications using plug in power supplies
- Two year warranty

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Outlets	On/Off Switch	Description	Cord Length	Price Each	
						1	5
681-J06B0B-90	J06B0B-90	6 Front	Yes	90° Outlets	6'	62.76	59.77
681-J06B0BX	J06B0BX	6 Rear	No	Regular Outlets	6'	58.13	55.89
681-J06B2BX	J06B2BX	6 Rear	No	Regular Outlets	15'	63.38	60.36

legrand® METERREADER™ RETROFIT CURRENT MONITORING DEVICE



Wiremold

The first UL approved product of its kind, the MeterReader™ measures current and displays the reading on the remote unit installed at the front of the IT rack or cabinet.

Features:

- Retrofit current monitoring capability
- Remote display
- 20A or 30A current monitoring
- User configurable
- cULus listed
- All models include remote display, patch cable, and rack mountable faceplate

MOUSER STOCK NO.	Wiremold Part No.	Current Rating	Input/ Output	Input/Output Connector	Price Each	
					1	5
681-METL530	METL530	30A max.	100-127VAC	L5-30P/L5-30R	224.19	219.47
681-METL520	METL520	20A max.	100-127VAC	L5-20P/L5-20R	224.19	219.47
681-METL630	METL630	30A max.	208-250VAC	L6-30P/L6-30R	224.19	219.47
681-METL620	METL620	20A max.	208-250VAC	L6-20P/L6-20R	224.19	219.47

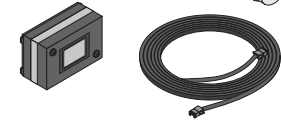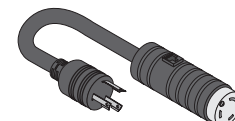

legrand® STANDARD 19" RACK MOUNTED POWER STRIPS

 
 
Wiremold

Specifications:

- Electrical rating: 15A, 120V

Features:

- Designed to fit all standard 19" cabinets, carts, racks
- Matte black steel housing
- Black 14/3 SJT cord
- Resettable circuit breaker
- Two year warranty
- Dimensions: 19"W x 1.75"H x 2.75"D
- UL listed, CSA approved



- Outlets rotated 90°, 4 outlets spaced to accommodate transformers.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Fig.	Outlets	On/Off Switch	Cord Length	Price Each	
						1	5
681-J60B0B	J60B0B	A	6 Front	Yes	6'	53.52	51.45
681-J60B2B	J60B2B	A	6 Front	Yes	15'	68.65	65.99
681-J08B0B	J08B0B	B*	8 Rear	Yes	6'	53.01	50.98
681-J08B2B	J08B2B	B*	8 Rear	Yes	15'	63.19	61.74

legrand® CABINETMATE POWER STRIPS

Wiremold


Features:

- Designed to fit in all types of cabinets
- Gray aluminum housing
- UL listed, CSA approved (15A models only)
- Resettable circuit breaker

- Two year warranty
- 15A units: 14/3 SJT cord with NEMA 5-15P plug
- 20A units: 12/3 SJT cord with NEMA 5-20P plug

Specifications:

- Electrical rating: 120V

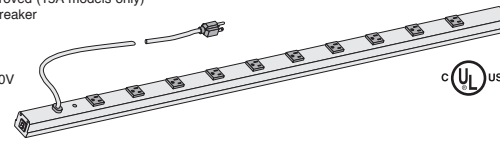

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Outlets	Amps	Length	Cord Length	Price Each	
						1	5
681-4810ULBC	4810ULBC	10	15	48"	6'	57.99	54.99
681-4810ULBD	4810ULBD	10	15	48"	15'	69.10	65.62
681-7011ULBC	7011ULBC	11	15	70"	6'	78.36	75.35
681-7011ULBD	7011ULBD	11	15	70"	15'	83.40	79.30
681-7712ULBC	7712ULBC	12	15	77"	6'	82.83	82.48
681-7712ULBD	7712ULBD	12	15	77"	15'	99.52	94.46
681-4810ULBC20R	4810ULBC20R	10	20	48"	6'	87.53	82.90
681-4810ULBD20R	4810ULBD20R	10	20	48"	15'	99.65	94.38
681-7011ULBC20R	7011ULBC20R	11	20	70"	6'	101.02	95.68
681-7011ULBD20R	7011ULBD20R	11	20	70"	15'	113.12	107.15
681-7712ULBC20R	7712ULBC20R	12	20	77"	6'	102.46	97.07
681-7712ULBD20R	7712ULBD20R	12	20	77"	15'	121.46	115.66


legrand® POWER COMMANDER 30A AND 40A POWER DISTRIBUTION UNITS

Wiremold

Among the first in the industry to meet the new UL60950-1 1st Edition and ITE standards, these PDUs feature UL489 Listed breakers to increase the safety and reliability of distributed power.

Features:

- Meets UL60950-1 1st Edition and ITE standards
- AC Voltage input:
 - 30A units: 100-127V, L5-30P plug
 - 40A units: 200-230V, L14-20P plug
- Narrow aluminum profile: (1 1/2"W x 2 7/8"H)
- Easy access breakers provide overload protection
- Built in mounting rail

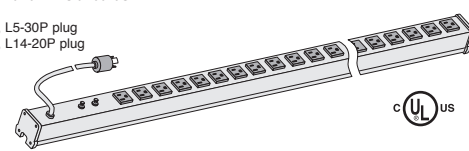

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Wiremold Part No.	Total Current Rating	Outlets	Length	Cord Length	Price Each	
						1	5
681-3A44B2-1	3A44B2-1	30A	24	48"	12'	185.32	177.42
681-3A86B2-1	3A86B2-1	30A	36	70"	12'	215.23	204.06
681-4B44B2-2	4B44B2-2	40A	24	48"	12'	215.84	207.17
681-4B86B2-2	4B86B2-2	40A	36	70"	12'	236.40	226.90

Wiremold Racks & Accessories