


BUD Metal Box Enclosures



BUD NEMA SHEET METAL BOXES 16 Gauge Steel

Design Features:

Designed to meet NEMA 1, 2, 4, 4X, 12, 13 and IP65 ratings. UL listed and tested to UL508-4X requirements. Continuous seam welded 16 ga. steel construction. Cover closes securely with unique key provided. Wall mounting holes located inside for security. Bonding studs for grounding are provided on base and door. Easily machined and modified to your particular requirements.

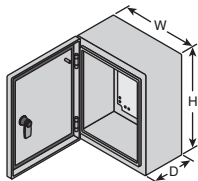

- Finish: Smooth Gray Powder Coat/ Exterior polished, interior natural

Accessories:


- Includes 14 ga. steel, zinc plated removable inner panel

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	2	5	10
Stainless Steel								
563-SNB-3730-SS	SNB-3730-SS	9.84	7.87	5.91	175.77	166.01	156.24	146.48
563-SNB-3731-SS	SNB-3731-SS	11.81	9.84	5.91	228.78	216.07	203.36	190.65
563-SNB-3733-SS	SNB-3733-SS	11.81	11.81	5.91	257.40	243.10	228.80	214.50
563-SNB-3734-SS	SNB-3734-SS	11.81	11.81	7.87	287.73	271.75	255.76	239.78
563-SNB-3735-SS	SNB-3735-SS	15.75	11.81	5.91	323.82	305.83	287.84	269.85
563-SNB-3737-SS	SNB-3737-SS	15.75	15.75	7.87	418.05	394.83	371.80	348.38
563-SNB-3739-SS	SNB-3739-SS	7.87	7.87	3.98	126.99	119.94	112.88	105.83
563-SNB-3740-SS	SNB-3740-SS	9.84	9.84	5.91	196.02	185.13	174.24	163.35
563-SNB-3741-SS	SNB-3741-SS	9.84	7.87	3.98	151.38	142.97	134.56	126.15
563-SNB3730	SNB3730	5.91	7.87	9.84	54.60	40.95	36.43	35.49
563-SNB3731	SNB3731	5.91	9.84	11.81	50.62	46.28	44.02	41.69
563-SNB3732	SNB3732	7.87	9.84	11.81	63.80	47.85	42.57	41.47
563-SNB3733	SNB3733	5.91	11.81	11.81	66.69	50.01	47.67	45.87
563-SNB3734	SNB3734	7.87	11.81	11.81	60.01	57.02	54.03	51.03
563-SNB3735	SNB3735	5.91	11.81	15.75	75.52	71.18	66.84	62.50
563-SNB3736	SNB3736	7.87	11.81	15.75	87.40	85.55	82.29	78.81
563-SNB3737	SNB3737	7.87	15.75	15.75	113.70	99.74	91.70	85.27
563-SNB-3738	SNB-3738	5.91	5.91	7.87	52.30	43.66	41.57	39.48
563-SNB-3739	SNB-3739	3.98	7.87	7.87	49.80	41.58	39.59	37.60
563-SNB-3740	SNB-3740	5.91	9.84	9.84	69.80	58.28	55.49	52.70
563-SNB-3741	SNB-3741	3.98	7.87	9.84	56.20	46.93	44.68	42.43
563-SNB-3743	SNB-3743	7.87	13.98	15.75	118.30	98.78	94.05	89.32

BUD CONVERTA BOXES

.050" aluminum. Welded base and two-sided cover attached with self-tapping screws. Components or controls can be mounted to any surface.

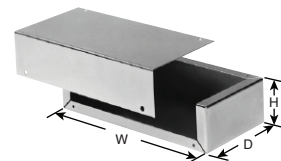


- Finish: Natural

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	5	10	25
563-CU341A	CU-341-A	3.00	4.00	1.50	16.00	13.33	12.50	11.94
563-CU452A	CU-452-A	4.00	5.00	2.00	16.00	13.36	12.05	10.68
563-CU482A	CU-482-A	4.00	8.00	2.00	17.30	14.45	13.00	11.55
563-CU592A	CU-592-A	5.00	9.50	2.50	20.80	17.37	15.65	13.91
563-CU622A	CU-622-A	6.00	12.00	2.50	27.30	22.82	20.58	18.27
563-CU712A	CU-712-A	7.00	15.00	2.50	35.80	29.90	26.90	23.90

BUD SNC SERIES NEMA SHEET METAL BOXES With Lift-off Screw Cover

Similar to the popular SNB series, but provides the option of an alternative secure screw closure. Wall mounting holes inside for security. Bonding studs for grounding are provided on base and door. Designed to meet NEMA 1, 2, 4, 4X and IP65 and UL508-4X. Continuous seam welded 16 ga. steel constructions.

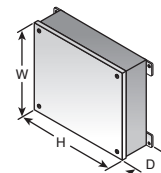

- Finish: Smooth Gray

Accessories:

- Comes with 14 ga. steel, zinc plated removable inner panel and stainless steel wall mounting bracket

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	5	10	25
563-SNC-3750	SNC-3750	5.91	7.87	9.84	59.40	49.50	44.55	39.60
563-SNC-3751	SNC-3751	5.91	9.84	11.81	64.20	53.50	48.15	42.80
563-SNC-3752	SNC-3752	7.87	9.84	11.81	67.10	55.90	50.30	44.70
563-SNC-3753	SNC-3753	5.91	11.81	11.81	84.20	70.14	63.11	56.09
563-SNC-3754	SNC-3754	7.87	11.81	11.81	89.49	74.54	67.10	59.66
563-SNC-3755	SNC-3755	5.91	11.81	15.75	90.00	75.00	70.31	67.16
563-SNC-3757	SNC-3757	7.87	15.75	15.75	124.00	103.33	96.87	92.53


BUD PUSH BUTTON BOXES (STEEL)



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	No. of Holes	Dimensions: in.			Price Each			
			D	W	H	1	5	10	25
22.5mm									
563-SPB-3901	SPB-3901	1	2.75	3.25	3.50	21.90	18.29	16.97	15.33
563-SPB-3902	SPB-3902	2	2.75	3.25	5.75	27.80	23.21	21.55	19.46
563-SPB-3903	SPB-3903	3	2.75	3.25	8.00	32.40	27.05	25.11	22.68
563-SPB-3904	SPB-3904	4	2.75	3.25	10.25	41.30	34.49	32.01	28.91
30.5mm									
563-SPB-3921	SPB-3921	1	2.75	3.25	3.50	21.90	18.29	16.97	15.33
563-SPB-3922	SPB-3922	2	2.75	3.25	5.75	27.80	23.21	21.55	19.46
563-SPB-3923	SPB-3923	3	2.75	3.25	8.00	32.40	27.05	25.11	22.68
563-SPB-3924	SPB-3924	4	2.75	3.25	10.25	41.30	34.49	32.01	28.91

BUD NEMA 1 ENCLOSURES

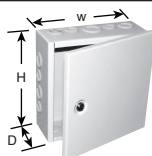


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	2	5	10
563-JBH-4944-KO	JBH-4944-KO	3.5	4	6	12.90	10.77	9.99	9.03
563-JBH-4945-KO	JBH-4945-KO	3.5	6	6	15.70	13.11	12.17	10.99
563-JBH-4953-KO	JBH-4953-KO	4	4	6	12.50	10.43	9.68	8.75
563-JBH-4954-KO	JBH-4954-KO	3	6	6	13.60	11.35	10.53	9.52
563-JBH-4955-KO	JBH-4955-KO	4	6	6	15.30	12.77	11.86	10.71
563-JBH-4956-KO	JBH-4956-KO	4	6	8	17.50	14.61	13.56	12.25
563-JBH-4957-KO	JBH-4957-KO	4	8	8	20.50	17.12	15.88	14.35
563-JBH-4958-KO	JBH-4958-KO	4	8	10	23.50	19.62	18.21	16.45
563-JBH-4959-KO	JBH-4959-KO	6	8	10	27.80	23.21	21.54	19.46
563-JBH-4960-KO	JBH-4960-KO	4	10	10	27.30	22.79	21.15	19.11
563-JBH-4961-KO	JBH-4961-KO	6	10	10	31.80	26.55	24.64	22.26

BUD ALUMINUM DIE CAST NEMA 4X ENCLOSURE With EM/RFI Shielding

Can be mounted without need of removing cover with exposure of internal components. Rugged #ADC-12 alloy die cast aluminum. Thick wall construction provides strength and rigidity for heavy duty applications. One-piece molded outer Silicone gasket provides reliable and long lasting sealing to meet NEMA 4X & IP65 requirements. Second wire-mesh with sponge rubber gasket provides excellent EM/RFI protection. Captive cover assembly screws located outside the sealing area.

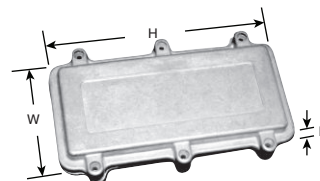

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Dimensions: in.			Price Each			
		D	W	H	1	10	100	200
Natural Finish								
563-ANS-3803	ANS-3803	2.64	3.79	3.79	18.60	15.50	13.95	12.40
563-ANS-3805	ANS-3805	1.77	3.78	7.56	28.40	23.65	21.30	18.90
563-ANS-3807	ANS-3807	2.64	3.78	7.56	30.80	25.65	23.10	20.50
563-ANS-3809	ANS-3809	2.60	6.81	10.79	56.10	46.75	42.10	37.40
563-ANS-3811	ANS-3811	3.94	6.81	10.79	62.80	52.35	47.10	41.90
563-ANS-3813	ANS-3813	1.97	3.94	5.91	25.60	21.35	19.20	17.10
563-ANS-3815	ANS-3815	2.95	3.94	5.91	30.30	25.25	22.75	20.20
563-ANS-3817	ANS-3817	1.97	5.91	7.87	46.80	39.00	35.10	31.20
563-ANS-3819	ANS-3819	2.95	5.91	7.87	51.80	43.15	38.85	34.50
Black Finish								
563-ANS-3801-B	ANS-3801-B	1.77	3.79	3.79	22.10	18.40	16.55	14.70
563-ANS-3805-B	ANS-3805-B	1.77	3.78	7.56	35.10	29.25	26.35	23.40
563-ANS-3807-B	ANS-3807-B	2.64	3.78	7.56	38.80	32.35	29.10	25.90
563-ANS-3809-B	ANS-3809-B	2.60	6.81	10.79	76.05	56.76	51.00	44.93
563-ANS-3811-B	ANS-3811-B	3.94	6.81	10.79	76.00	63.35	57.00	50.70
563-ANS-3813-B	ANS-3813-B	1.97	3.94	5.91	32.20	26.85	24.15	21.50
563-ANS-3815-B	ANS-3815-B	2.95	3.94	5.91	38.20	31.85	28.65	25.50
563-ANS-3819-B	ANS-3819-B	2.95	5.91	7.87	63.70	53.10	47.80	42.50

BUD DIE CAST EXTERNAL MOUNTING BRACKETS

External mounting brackets enable die cast boxes to be wall or panel mounted without opening the box. Package consists of 4 brackets and attaching screws. Can be used with all AN and ANS series Bud die cast boxes except for AN-2901 and AN-2902.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Color	Price Each			
			1	5	10	25
563-ANX-1390	ANX-1390	Natural	3.75	3.57	3.40	3.17
563-ANX-1390-B	ANX-1390-B	Black	6.24	5.94	5.65	5.27
563-ANX-1390-G	ANX-1390-G	Gray	6.24	5.94	5.65	5.27

