


# HAMMOND Extruded Metal Enclosures



## EXTRUDED ALUMINUM CASES

- Designed to house P.C. boards or for equipment interfacing.
- Sized for standard Eurocards. P.C. boards mount horizontally by sliding into internal slots extruded into the enclosure body.
- Body constructed from extruded, anodized aluminum with a minimum thickness of .06" (1.5mm).
- All hardware and rubber feet included

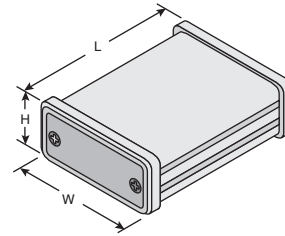

RoHS Compliant

### With Metal End Plates

- Two aluminum end panels
- Two Black ABS Plastic Bezels (your option to install)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.		
		1	5	10	25			1	5	10	25	L	W	H
546-1455C801	1455C801	13.08	11.07	10.66	10.51	546-1455C801BK	1455C801BK	14.06	12.37	11.44	10.75	3.15	2.13	0.91
546-1455C1201	1455C1201	13.96	12.79	11.81	10.96	546-1455C1201BK	1455C1201BK	15.10	13.28	12.97	12.39	4.72	2.13	0.91
546-1455J1201	1455J1201	18.15	16.11	15.35	14.91	546-1455J1201BK	1455J1201BK	20.20	17.75	16.28	15.29	4.72	3.07	1.06
546-1455K1201	1455K1201	18.77	16.52	15.87	14.35	546-1455K1201BK	1455K1201BK	20.60	18.14	17.42	15.74	4.72	3.07	1.69
546-1455L1201	1455L1201	20.94	18.58	17.05	16.02	546-1455L1201BK	1455L1201BK	23.13	20.12	18.61	17.48	4.72	4.06	1.20
546-1455N1201	1455N1201	20.94	18.44	17.05	16.02	546-1455N1201BK	1455N1201BK	22.86	20.12	18.61	17.48	4.72	4.06	2.09
546-1455J1601	1455J1601	20.28	18.59	17.16	16.60	546-1455J1601BK	1455J1601BK	20.95	17.62	16.43	16.09	6.30	3.07	1.06
546-1455K1601	1455K1601	20.90	19.16	17.68	16.42	546-1455K1601BK	1455K1601BK	23.11	20.51	18.98	17.66	6.30	3.07	1.69
546-1455L1601	1455L1601	23.55	20.72	19.17	18.00	546-1455L1601BK	1455L1601BK	26.21	22.79	21.08	19.80	6.30	4.06	1.20
546-1455N1601	1455N1601	23.55	20.90	19.92	18.00	546-1455N1601BK	1455N1601BK	26.21	22.79	21.08	19.80	6.30	4.06	2.09
546-1455L2201	1455L2201	25.89	21.91	20.30	18.98	546-1455L2201BK	1455L2201BK	28.63	24.23	22.44	20.98	8.66	4.06	1.20
546-1455N2201	1455N2201	26.76	24.52	22.64	21.02	546-1455N2201BK	1455N2201BK	29.59	26.04	24.08	22.62	8.66	4.06	2.09
546-1455P1601	1455P1601	23.45	21.23	18.86	17.71	546-1455P1601BK	1455P1601BK	27.09	23.56	21.79	20.46	6.30	4.74	1.20
546-1455Q1601	1455Q1601	27.92	24.94	23.26	21.48	546-1455Q1601BK	1455Q1601BK	30.24	26.29	24.64	22.99	6.30	4.74	2.03
546-1455R1601	1455R1601	27.06	24.81	22.89	21.25	546-1455R1601BK	1455R1601BK	29.33	24.84	22.99	21.50	6.30	6.30	1.20
546-1455T1601	1455T1601	27.46	24.17	23.23	20.99	546-1455T1601BK	1455T1601BK	30.88	27.17	25.13	23.61	6.30	6.30	2.03
546-1455P2201	1455P2201	28.86	25.77	24.05	22.20	546-1455P2201BK	1455P2201BK	36.74	25.17	23.59	22.02	8.66	4.74	1.20
546-1455Q2201	1455Q2201	31.92	28.50	26.60	24.55	546-1455Q2201BK	1455Q2201BK	33.35	28.66	27.38	25.48	8.66	4.74	2.03
546-1455R2201	1455R2201	30.27	26.64	24.65	23.15	546-1455R2201BK	1455R2201BK	32.53	27.54	25.50	23.84	8.66	6.30	1.20
546-1455T2201	1455T2201	30.88	27.17	25.13	23.61	546-1455T2201BK	1455T2201BK	33.20	30.42	28.15	26.20	8.66	6.30	2.03

### With Plastic End Panels


- Includes two-easy-to-machine, Black Solid ABS Plastic end panels (with integral bezel)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.		
		1	5	10	25			1	5	10	25	L	W	H
546-1455A802	1455A802	8.36	7.46	6.96	6.43	546-1455A802BK	1455A802BK	8.36	7.46	6.96	6.92	3.15	2.76	0.47
546-1455B802	1455B802	8.94	8.00	7.45	6.87	546-1455B802BK	1455B802BK	8.94	8.00	7.45	8.07	3.15	2.82	0.75
546-1455C802	1455C802	10.45	9.27	8.84	8.58	546-1455C802BK	1455C802BK	10.45	9.27	8.84	9.48	3.15	2.13	0.91
546-1455A1002	1455A1002	8.76	7.82	7.30	6.73	546-1455A1002BK	1455A1002BK	8.76	7.82	7.30	7.32	3.94	2.76	0.47
546-1455B1002	1455B1002	9.48	8.46	7.90	7.29	546-1455B1002BK	1455B1002BK	9.48	8.46	7.90	8.57	3.94	2.82	0.75
546-1455A1202	1455A1202	9.20	8.22	7.66	7.07	546-1455A1202BK	1455A1202BK	9.20	8.22	7.66	7.10	4.72	2.76	0.47
546-1455B1202	1455B1202	10.00	8.93	8.33	7.69	546-1455B1202BK	1455B1202BK	10.00	8.93	8.33	8.26	4.72	2.82	0.75
546-1455C802	1455C802	10.45	9.27	8.84	8.58	546-1455C802BK	1455C802BK	10.45	9.27	8.84	9.48	3.15	2.13	0.91
546-1455C1202	1455C1202	10.83	9.52	9.16	8.27	546-1455C1202BK	1455C1202BK	10.83	9.52	9.16	9.01	4.72	2.13	0.91
546-1455J1202	1455J1202	13.68	12.50	11.58	11.24	546-1455J1202BK	1455J1202BK	13.68	12.50	11.58	11.47	4.72	3.07	1.06
546-1455K1202	1455K1202	14.30	13.11	12.10	11.23	546-1455K1202BK	1455K1202BK	14.30	13.11	12.10	11.93	4.72	3.07	1.69
546-1455L1202	1455L1202	16.41	14.44	13.35	12.54	546-1455L1202BK	1455L1202BK	16.41	14.44	13.35	13.57	4.72	4.06	1.20
546-1455N1202	1455N1202	16.41	15.03	13.88	13.46	546-1455N1202BK	1455N1202BK	16.41	15.03	13.88	13.57	4.72	4.06	2.09
546-1455J1602	1455J1602	15.81	14.50	13.38	12.99	546-1455J1602BK	1455J1602BK	15.81	14.50	13.38	13.36	6.30	3.07	1.06
546-1455K1602	1455K1602	16.41	15.06	13.88	13.48	546-1455K1602BK	1455K1602BK	16.41	15.06	13.88	13.83	6.30	3.07	1.69
546-1455L1602	1455L1602	19.00	17.40	16.07	15.61	546-1455L1602BK	1455L1602BK	19.00	17.40	16.07	16.34	6.30	4.06	1.20
546-1455N1602	1455N1602	20.90	18.98	17.41	16.08	546-1455N1602BK	1455N1602BK	20.90	18.98	17.41	16.34	6.30	4.06	2.09
546-1455L2202	1455L2202	20.66	17.37	16.20	15.86	546-1455L2202BK	1455L2202BK	20.66	17.37	16.20	17.36	8.66	4.06	1.20
546-1455N2202	1455N2202	20.66	17.37	16.20	15.86	546-1455N2202BK	1455N2202BK	20.66	17.37	16.20	17.48	8.66	4.06	2.09
546-1455P1602	1455P1602	22.30	19.91	18.58	17.15	546-1455P1602BK	1455P1602BK	22.30	19.91	18.58	16.60	6.30	4.74	1.20
546-1455Q1602	1455Q1602	24.48	21.85	20.40	18.83	546-1455Q1602BK	1455Q1602BK	24.48	21.85	20.40	18.76	6.30	4.74	2.03
546-1455R1602	1455R1602	21.19	19.42	17.93	16.65	546-1455R1602BK	1455R1602BK	21.19	19.42	17.93	19.16	6.30	6.30	1.20
546-1455T1602	1455T1602	20.71	17.53	16.24	15.18	546-1455T1602BK	1455T1602BK	20.71	17.53	16.24	17.55	6.30	6.30	2.10
546-1455P2202	1455P2202	25.66	22.92	21.38	19.73	546-1455P2202BK	1455P2202BK	25.66	22.92	21.38	20.31	8.66	4.74	1.20
546-1455Q2202	1455Q2202	28.46	25.42	23.72	21.89	546-1455Q2202BK	1455Q2202BK	28.46	25.42	23.72	22.90	8.66	4.74	2.03
546-1455R2202	1455R2202	24.68	22.61	20.88	19.39	546-1455R2202BK	1455R2202BK	24.68	22.61	20.88	20.01	8.66	6.30	1.20
546-1455T2202	1455T2202	24.30	20.57	19.05	17.81	546-1455T2202BK	1455T2202BK	24.30	20.57	19.05	21.75	8.66	6.30	2.10

### Wallmount Kits for Extruded Aluminum Cases

- Designed to convert the 1455 series enclosures where shelf or wall mounting is required
- Flanges are .064" (1.6mm) thick aluminum foot "L" brackets and attach to each end, replacing the aluminum end panels
- Finish available in both Clear and Black anodized to match enclosure
- Sold in pairs

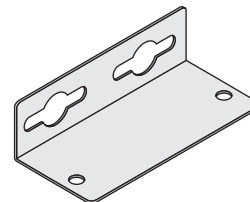

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Use With Enclosure Any Part Above Starting With:
		1	5	10	25			1	5	10	25	
546-1455CF	1455CF	10.54	8.86	8.26	7.72	546-1455CFBK	1455CFBK	10.53	9.92	9.32	8.71	1455C
546-1455JF	1455JF	10.95	10.32	9.69	9.06	546-1455JFBK	1455JFBK	11.54	10.87	10.20	9.54	1455J
546-1455KF	1455KF	11.70	9.91	9.17	8.58	546-1455KFBK	1455KFBK	11.82	10.75	9.98	9.70	1455K
546-1455LF	1455LF	11.66	10.99	10.32	9.65	546-1455LFBK	1455LFBK	12.68	11.70	10.82	10.16	1455L
546-1455NF	1455NF	12.88	10.90	10.10	9.43	546-1455NFBK	1455NFBK	14.08	12.24	11.33	10.64	1455N
546-1455PF	1455PF	13.51	12.72	11.92	11.13	546-1455PFBK	1455PFBK	13.88	13.06	12.25	11.43	1455P
546-1455QF	1455QF	14.39	13.54	12.70	11.85	546-1455QFBK	1455QFBK	14.82	13.95	12.91	12.12	1455Q
546-1455RF	1455RF	13.24	12.47	11.71	10.94	546-1455RFBK	1455RFBK	13.82	13.03	12.23	11.43	1455R
546-1455TF	1455TF	13.29	12.53	11.76	10.99	546-1455TFBK	1455TFBK	15.29	13.30	12.30	11.55	1455T