

HAMMOND Metal Watertight Enclosures

RoHS Compliant This product is RoHS compliant.



EXTRUDED ALUMINUM (CHANNEL MOUNT)


- Features:**
- Designed to house P.C. boards or equipment - for easy enclosure mounting to aluminum channel
 - Rugged one piece body - constructed from extruded aluminum with a minimum thickness of .09" (2.29mm)



Open Front and Rear Bezels with Metal Endplates

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each			
		1	5	10	25
546-1455NC1201	1455NC1201	19.55	18.28	16.99	15.05
546-1455NC1601	1455NC1601	21.96	20.54	19.09	16.91
546-1455NC2201	1455NC2201	25.75	24.07	22.37	19.82

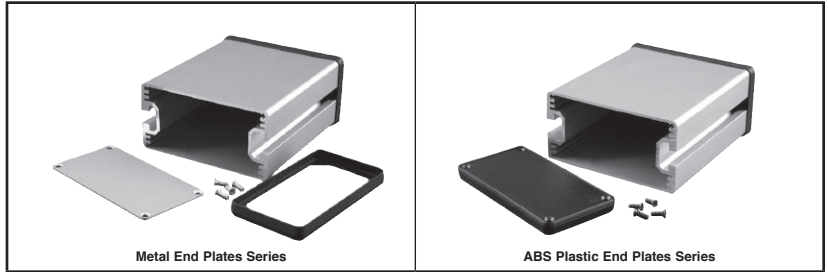

Solid ABS Plastic Front and Rear Bezels

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each			
		1	5	10	25
546-1455NC1202	1455NC1202	16.96	15.86	14.74	13.06
546-1455NC1602	1455NC1602	19.38	18.12	16.84	14.92
546-1455NC2202	1455NC2202	23.18	21.68	20.15	17.85

Accessories

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Hammond Part No.	Description	Price Each			
			1	5	10	25
546-1455TBOLT	1455TBOLT	Qty. two (2) - 8mm X 20 "T" bolts, washers & hex nuts	5.53	5.17	4.80	4.26
546-1455TNUIT	1455TNUIT	Qty. two (2) - 8mm "T" nuts	5.18	4.85	4.50	3.99
546-1455TSNUIT	1455TSNUIT	Qty. two (2) - 8mm "T" nuts & springs	6.84	6.39	5.94	5.26



WATERTIGHT EXTRUDED ALUMINUM CASES

- Features:**
- Watertight - heavy duty extruded enclosures designed to house P.C. boards or for equipment interfacing
 - Sized for standard Eurocards
 - P.C. boards mount horizontally by sliding into internal slots extruded into the enclosure body
 - Rugged body constructed from one piece, extruded aluminum with a minimum thickness of .06" (1.5mm)
 - Extruded aluminum body includes a recessed area for labels or membrane keypad
 - End panels are rugged - yet easy to machine - diecast aluminum with full perimeter self-adhesive gaskets
 - Designed to meet IP 65 ratings
 - Choice of two versions - end panels without flange or with flange (for shelf or wall mounting)

- Includes:**
- Two diecast aluminum end panels - painted in a durable, black satin powder paint
 - Extruded, aluminum body (choice of either clear anodized or black powder paint finish)
 - Two closed cell polyethylene foam - end plate gaskets & rubber "O" rings for assembly screws
 - All hardware and self-adhesive feet

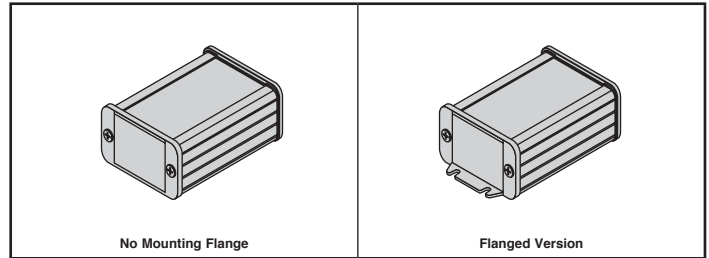

Regular Front and Back End Panels (No Mounting Flange)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.		
		1	5	10	25			1	5	10	25	L	W	H
546-1457C801	1457C801	21.40	18.09	16.79	15.72	546-1457C801BK	1457C801BK	22.13	20.35	19.29	18.46	3.15	2.32	1.21
546-1457K1201	1457K1201	33.92	30.29	28.27	26.09	546-1457K1201BK	1457K1201BK	26.36	23.53	21.97	17.52	4.73	2.32	1.21
546-1457N1201	1457N1201	37.64	33.61	31.37	28.95	546-1457K1601BK	1457K1601BK	37.74	33.71	31.45	29.03	6.30	3.30	1.73
546-1457N1601	1457N1601	41.56	37.11	34.63	31.96	546-1457N1601BK	1457N1601BK	41.56	37.11	34.63	31.96	4.73	4.09	2.15

Flanged Version

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.		
		1	5	10	25			1	5	10	25	L	W	H
546-1457C802	1457C802	24.42	21.81	20.35	18.78	546-1457C802BK	1457C802BK	24.42	21.81	20.35	19.70	3.15	2.32	1.21
546-1457K1202	1457K1202	34.72	31.01	28.93	28.01	546-1457K1202BK	1457K1202BK	34.72	31.01	28.93	28.01	4.73	3.30	1.73
546-1457K1602	1457K1602	38.70	34.55	32.25	30.95	546-1457K1602BK	1457K1602BK	38.70	34.55	32.25	29.76	6.30	3.30	1.73
546-1457N1202	1457N1202	34.65	32.72	31.76	30.80	546-1457N1202BK	1457N1202BK	33.32	31.47	30.54	29.62	4.73	4.09	2.15
546-1457N1602	1457N1602	42.44	37.90	35.37	32.64	546-1457N1602BK	1457N1602BK	42.44	37.90	35.37	32.64	6.30	4.09	2.15



WATERTIGHT EXTRUDED ALUMINUM CASES WITH EMI/RFI PROTECTION

- Features:**
- Watertight - heavy duty extruded enclosures designed to house P.C. boards or for equipment interfacing
 - Sized for standard Eurocards
 - P.C. boards mount horizontally by sliding into internal slots extruded into the enclosure body
 - Rugged body constructed from one piece, extruded aluminum with a minimum thickness of .06" (1.5mm)
 - Extruded aluminum body includes a recessed area for labels or membrane keypad
 - End panels are rugged - yet easy to machine - diecast aluminum with full perimeter self-adhesive EMI/RFI gaskets
 - Designed to meet IP 54 ratings
 - Choice of two versions - end panels without flange or with flange (for shelf or wall mounting)

- Includes:**
- Two diecast aluminum end panels - painted in a durable, black satin powder paint
 - Extruded, aluminum body (choice of either clear anodized or black powder paint finish)
 - Two - end plate EMI/RFI gaskets
 - All hardware and self-adhesive feet

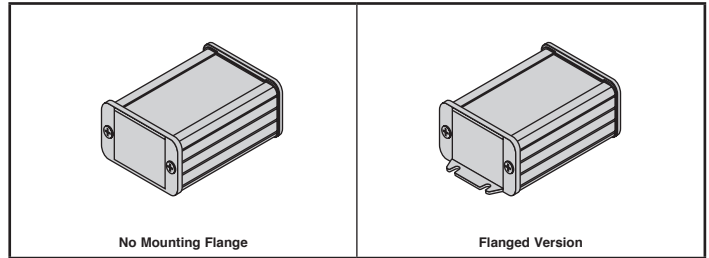

Regular Front and Back End Panels (No Mounting Flange)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.		
		1	5	10	25			1	5	10	25	L	W	H
546-1457C801E	1457C801E	27.64	25.43	24.10	23.06	546-1457C801EBK	1457C801EBK	27.64	25.43	24.10	23.06	3.15	2.32	1.21
546-1457K1201E	1457K1201E	29.65	28.00	27.18	26.36	546-1457K1201EBK	1457K1201EBK	30.82	28.35	26.87	25.71	4.73	2.32	1.21
546-1457K1601E	1457K1601E	36.69	34.65	33.63	32.61	546-1457K1601EBK	1457K1601EBK	36.69	34.65	33.63	32.61	4.73	3.30	1.73
546-1457N1201E	1457N1201E	42.47	40.11	38.93	37.76	546-1457N1201EBK	1457N1201EBK	42.47	40.11	38.93	37.76	6.30	3.30	1.73
546-1457N1601E	1457N1601E	40.71	38.45	37.32	36.19	546-1457N1601EBK	1457N1601EBK	42.33	39.98	38.81	37.63	4.73	4.09	2.15
546-1457N1601E	1457N1601E	48.59	44.69	42.35	40.53	546-1457N1601EBK	1457N1601EBK	48.59	44.69	42.35	40.53	6.30	4.09	2.15

Flanged Version

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each				MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.		
		1	5	10	25			1	5	10	25	L	W	H
546-1457C802E	1457C802E	26.42	24.95	24.22	23.48	546-1457C802EBK	1457C802EBK	28.39	27.62	26.86	25.95	3.15	2.32	1.21
546-1457K1202E	1457K1202E	30.43	28.74	27.89	27.05	546-1457K1202EBK	1457K1202EBK	30.43	28.74	27.89	27.05	4.73	2.32	1.21
546-1457K1602E	1457K1602E	39.05	36.89	35.80	34.72	546-1457K1602EBK	1457K1602EBK	40.37	39.28	38.20	36.89	4.73	3.30	1.73
546-1457N1202E	1457N1202E	45.00	43.79	42.58	41.13	546-1457N1202EBK	1457N1202EBK	45.00	43.79	42.58	41.13	6.30	3.30	1.73
546-1457N1602E	1457N1602E	41.64	39.33	38.17	37.01	546-1457N1602EBK	1457N1602EBK	43.31	40.91	39.70	38.49	4.73	4.09	2.15
546-1457N1602E	1457N1602E	53.04	47.37	44.21	40.80	546-1457N1602EBK	1457N1602EBK	45.91	43.35	42.08	40.80	6.30	4.09	2.15



Hammond Metal Boxes