

HAMMOND Aluminum and Metal Enclosures



ALUMINUM CHASSIS CASES AND COVERS

- Spot welded heavy duty construction chassis
- Cover punched with 4 holes (hardware not provided)
- Natural finish

DIMENSIONS: in.


Aluminum Chassis Cases

MOUSER STOCK NO.	Hammond Part No.	Dimensions: in.			Price Each			
		L	W	H	1	5	10	25
546-1444-6	1444-6	4	4	2	10.53	9.55	8.90	8.27
546-1444-8	1444-8	6	4	2	10.80	9.81	9.15	8.50
546-1444-9	1444-9	8	4	1	11.23	10.28	9.50	8.82
546-1444-10	1444-10	8	4	2	11.52	10.32	9.74	8.93
546-1444-12	1444-12	7	5	2	11.76	10.46	9.95	9.27
546-1444-14	1444-14	9	5	2	14.22	13.04	12.03	11.68
546-1444-15	1444-15	10	6	1	12.40	11.26	10.48	9.76
546-1444-16	1444-16	10	6	2	15.40	14.00	13.03	12.66
546-1444-18	1444-18	13.5	5	2	16.32	14.48	13.80	12.83
546-1444-20	1444-20	17	4	3	27.01	24.52	22.84	21.25
546-1444-22	1444-22	12	8	2	26.89	24.41	22.75	21.15
546-1444-24	1444-24	12	8	3	27.19	24.69	23.01	21.40
546-1444-26	1444-26	16	8	2	27.12	24.61	22.94	21.31
546-1444-28	1444-28	16	8	3	32.29	29.30	27.32	25.37
546-1444-29	1444-29	12	10	2	27.06	24.56	22.89	21.27
546-1444-30	1444-30	17	10	2	31.37	28.48	26.54	24.69
546-1444-32	1444-32	17	10	3	36.71	33.33	31.07	28.86
546-1444-33	1444-33	17	10	4	52.97	48.55	44.81	41.66
546-1444-1053	1444-1053	10	5	3	17.27	15.32	14.61	13.58
546-1444-10825	1444-10825	10	8	2.5	19.54	17.34	16.53	15.37
546-1444-1172	1444-1172	11	7	2	15.45	13.71	13.07	12.15
546-1444-12103	1444-12103	12	10	3	26.36	23.39	22.30	20.73
546-1444-12123	1444-12123	12	12	3	33.63	29.84	28.45	26.45
546-1444-1273	1444-1273	12	7	3	21.81	19.35	18.45	17.16
546-1444-12825	1444-12825	12	8	2.5	24.54	21.77	20.76	19.30
546-1444-1372	1444-1372	13	7	2	19.09	16.94	16.15	15.01
546-1444-14103	1444-14103	14	10	3	31.81	28.23	26.91	25.02
546-1444-1463	1444-1463	14	6	3	25.45	22.58	21.53	20.02
546-1444-1573	1444-1573	15	7	3	26.81	23.79	22.68	21.09
546-1444-1593	1444-1593	15	9	3	30.45	27.02	25.76	23.95
546-1444-17105	1444-17105	17	10	5	55.45	49.19	46.91	43.61
546-1444-17123	1444-17123	17	12	3	34.99	31.05	29.60	27.52
546-1444-17132	1444-17132	17	13	2	35.90	31.85	30.37	28.24
546-1444-17133	1444-17133	17	13	3	41.36	36.69	34.99	32.53
546-1444-17134	1444-17134	17	13	4	49.99	44.35	42.29	39.32
546-1444-17135	1444-17135	17	13	4	63.63	56.45	53.83	50.04
546-1444-17143	1444-17143	17	14	3	46.36	41.13	39.22	36.46
546-1444-17154	1444-17154	17	15	4	62.72	55.65	53.06	49.32
546-1444-17156	1444-17156	17	15	6	88.62	78.63	74.97	69.70
546-1444-17173	1444-17173	17	17	3	54.08	47.98	45.75	42.53
546-1444-17174	1444-17174	17	17	4	69.99	62.10	59.21	55.04
546-1444-1763	1444-1763	17	6	3	29.09	25.81	24.61	22.88
546-1444-1773	1444-1773	17	7	3	30.00	26.61	25.38	23.59
546-1444-1783	1444-1783	17	8	3	28.18	25.00	23.84	22.16
546-1444-45351	1444-45351	4.5	3.5	1	9.09	8.06	7.69	7.15
546-1444-542	1444-542	5	4	2	10.91	9.68	9.23	8.58
546-1444-6415	1444-6415	6	4	1.5	10.91	9.68	9.23	8.58
546-1444-643	1444-643	6	4	3	13.18	11.69	11.15	10.37
546-1444-753	1444-753	7	5	3	15.45	13.71	13.07	12.15
546-1444-772	1444-772	7	7	2	12.73	11.29	10.77	10.01
546-1444-84515	1444-84515	8	4.5	1.5	13.63	12.10	11.53	10.72
546-1444-862	1444-862	8	6	2	13.63	12.10	11.53	10.72
546-1444-9552	1444-9552	9.5	5	2	12.73	11.29	10.77	10.01
546-1444-95525	1444-95525	9.5	5	2.5	15.45	13.71	13.07	12.15
546-1444-9553	1444-9553	9.5	5	3	16.36	14.52	13.84	12.87
546-1444-972	1444-972	9	7	2	13.63	12.10	11.53	10.72

Aluminum Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hammond Part No.	Price Each			
		1	5	10	25
546-1434-6	1434-6	5.08	4.55	4.29	3.94
546-1434-8	1434-8	5.44	4.88	4.59	4.26
546-1434-10	1434-10	5.16	4.63	4.36	4.04
546-1434-12	1434-12	5.16	4.63	4.36	4.04
546-1434-14	1434-14	5.32	4.78	4.49	4.17
546-1434-16	1434-16	5.44	4.88	4.59	4.22
546-1434-18	1434-18	8.16	7.32	6.89	6.33
546-1434-20	1434-20	8.16	7.32	6.89	6.33
546-1434-22	1434-22	8.96	7.81	7.24	6.76
546-1434-24	1434-24	8.79	7.89	7.44	6.91
546-1434-26	1434-26	11.52	10.32	9.74	8.93
546-1434-28	1434-28	11.52	10.32	9.74	8.93
546-1434-29	1434-29	11.52	10.32	9.74	8.93
546-1434-30	1434-30	12.20	10.94	10.32	9.47
546-1434-32	1434-32	12.20	10.94	10.32	9.47
546-1434-33	1434-33	12.20	10.94	10.32	9.47
546-1434-105	1434-105	4.54	4.03	3.84	3.57
546-1434-108	1434-108	8.18	7.26	6.92	6.43
546-1434-117	1434-117	6.36	5.65	5.38	5.00
546-1434-129	1434-129	11.36	10.18	9.61	8.81
546-1434-1212	1434-1212	10.91	9.68	9.23	8.58
546-1434-127	1434-127	6.82	6.05	5.77	5.36
546-1434-22	1434-22	11.52	10.32	9.74	8.93
546-1434-137	1434-137	8.18	7.26	6.92	6.43
546-1434-1410	1434-1410	10.45	9.27	8.84	8.22
546-1434-146	1434-146	8.18	7.26	6.92	6.43
546-1434-157	1434-157	8.64	7.66	7.31	6.79
546-1434-159	1434-159	13.18	11.69	11.15	10.37
546-1434-30	1434-30	11.44	10.26	9.68	8.88
546-1434-1712	1434-1712	14.54	12.90	12.30	11.44
546-1434-1713	1434-1713	15.00	13.31	12.69	11.80
546-1434-1713	1434-1713	15.00	13.31	12.69	11.80
546-1434-1713	1434-1713	15.00	13.31	12.69	11.80
546-1434-1714	1434-1714	15.91	14.11	13.46	12.51
546-1434-1715	1434-1715	16.36	14.52	13.84	12.87
546-1434-1715	1434-1715	16.36	14.52	13.84	12.87
546-1434-1717	1434-1717	18.18	16.13	15.38	14.30
546-1434-1717	1434-1717	18.18	16.13	15.38	14.30
546-1434-176	1434-176	10.00	8.87	8.46	7.86
546-1434-177	1434-177	8.64	7.66	7.31	6.79
546-1434-178	1434-178	10.45	9.27	8.84	8.22
546-1434-4535	1434-4535	4.09	3.63	3.46	3.22
546-1434-54	1434-54	4.09	3.63	3.46	3.22
546-1434-8	1434-8	4.99	4.48	4.21	3.91
546-1434-8	1434-8	4.99	4.48	4.21	3.91
546-1434-12	1434-12	5.32	4.78	4.49	4.17
546-1434-77	1434-77	5.00	4.44	4.23	3.93
546-1434-845	1434-845	6.54	5.81	5.54	5.15
546-1434-86	1434-86	6.82	6.05	5.77	5.36
546-1434-955	1434-955	5.00	4.44	4.23	3.93
546-1434-955	1434-955	5.00	4.44	4.23	3.93
546-1434-955	1434-955	5.00	4.44	4.23	3.93
546-1434-97	1434-97	5.91	5.24	5.00	4.65

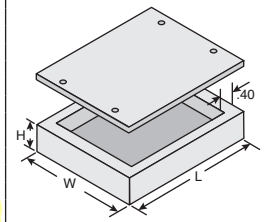

ALUMINUM UTILITY CASES

- .040" thick aluminum
- Four self-tapping screws included
- Unpainted: Protected with plastic skin cover to ensure a high quality finish
- Painted: ASA 61 Gray Baked Enamel Finish. (outside only)

DIMENSIONS: in.

Painted

MOUSER STOCK NO.	Hammond Part No.	Price Each			
		1	5	10	25
546-1411B	1411B	6.70	5.73	5.30	4.90
546-1411C	1411C	6.79	6.08	5.66	4.97
546-1411D	1411D	6.81	5.85	5.70	5.00
546-1411F	1411E	7.50	6.51	6.24	5.75
546-1411G	1411G	7.10	6.35	5.90	5.19
546-1411H	1411H	7.23	6.46	6.02	5.55
546-1411K	1411K	8.30	7.10	6.56	6.06
546-1411L	1411L	10.75	9.24	9.00	7.89
546-1411M	1411M	12.08	10.79	10.06	8.82
546-1411N	1411N	8.81	7.88	7.34	6.76
546-1411P	1411P	15.05	12.93	12.60	11.04
546-1411Q	1411Q	14.67	12.61	12.28	10.76
546-1411R	1411R	24.04	20.66	20.13	17.64
546-1411S	1411S	22.03	18.93	18.45	16.17
546-1411T	1411T	23.04	19.29	17.83	16.49
546-1411U	1411U	29.42	26.27	24.50	22.62
546-1411W	1411W	28.04	24.10	22.27	20.58
546-1411X	1411X	35.23	31.46	29.36	25.73
546-1411Z	1411Z	38.26	32.72	30.23	27.93

Unpainted

MOUSER STOCK NO.	Hammond Part No.	Price Each				Dimensions: in.			
		1	5	10	25	L	W	H	
546-1411BU	1411BU	4.32	3.71	3.43	3.17	2.70	2.20	1.60	
546-1411CU	1411CU	4.63	4.14	3.86	3.39	3.20	2.20	1.10	
546-1411DU	1411DU	5.00	4.46	4.16	3.91	3.20	2.20	1.60	
546-1411EU	1411EU	6.17	5.52	5.14	4.83	4.00	2.20	3.00	
546-1411GU	1411GU	5.40	4.82	4.50	4.22	4.00	2.20	1.60	
546-1411HU	1411HU	5.80	5.18	4.83	4.53	4.00	2.20	2.20	
546-14									