


LMB Chassis, Boxes and Enclosures

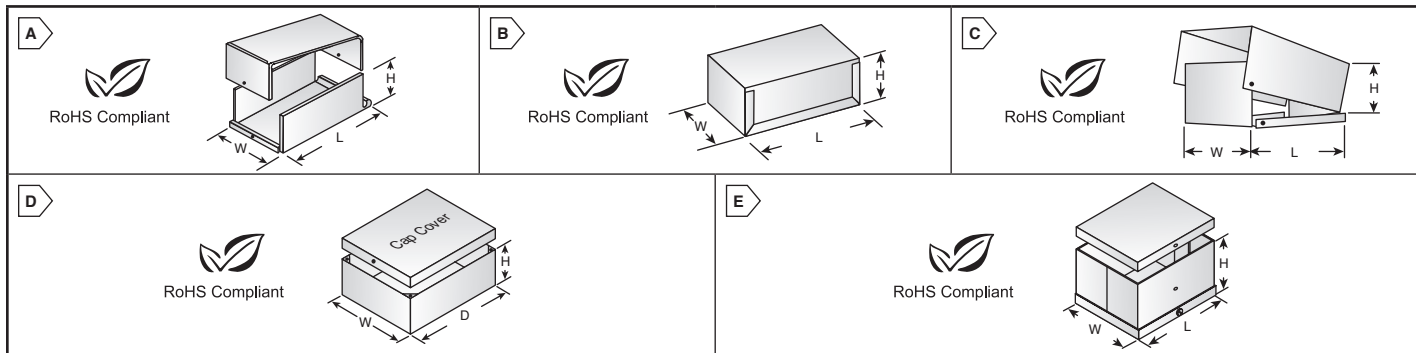

CHASSIS

Interlocking Boxes

- Hammer-tone Grey

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
537-M00-P	M00-P	A	2.25	1.50	1.38	4.37	3.95	3.81	3.68
537-00Z-P	00Z-P	A	2.31	2.13	1.75	4.86	4.38	4.24	4.09
537-000-P	000-P	A	3.25	2.13	1.63	6.63	5.97	5.77	5.57
537-00-P	00-P	A	4.00	2.13	1.63	6.87	6.18	5.99	5.78
537-101-P	101-P	A	4.25	2.25	1.25	6.89	6.20	5.98	5.78
537-108-P	108-P	A	5.00	2.25	2.25	9.60	8.63	8.34	8.06
537-135-P	135-P	A	3.75	3.00	2.13	9.63	8.68	8.38	8.09
537-136-P	136-P	A	5.25	3.00	2.13	11.13	10.02	9.67	9.33
537-138-P	138-P	A	6.25	3.50	2.13	13.88	12.50	12.08	11.67
537-139-P	139-P	A	5.50	3.00	1.25	10.28	9.26	8.95	8.63
537-141-P	141-P	A	6.00	4.00	3.00	17.18	15.46	14.93	14.42
537-142-P	142-P	A	6.00	4.00	5.00	20.88	18.79	18.16	17.54
537-146-P	146-P	A	8.00	6.00	4.50	30.26	27.25	26.33	25.42

Title-Fit Box Chassis

For quantities greater than listed, call for quote.

Painted Gray (Screws Included)									
MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
537-TF-773-P	TF-773-P	B	3.50	2.13	1.63	7.10	6.40	6.18	5.97
537-TF-776-P	TF-776-P	B	4.00	2.00	2.75	8.71	7.86	7.59	7.33
537-TF-779-P	TF-779-P	B	5.00	4.00	3.00	12.68	11.42	11.03	10.66
537-TF-780-P	TF-780-P	B	5.25	3.00	2.13	11.20	10.07	9.74	9.40
537-TF-781-P	TF-781-P	B	6.00	5.00	4.00	17.25	15.52	15.00	14.49
537-TF-784-P	TF-784-P	B	10.00	6.00	3.50	24.90	22.40	21.65	20.92
537-TF-787P	TF-787-P	B	12.00	7.00	4.00	34.32	30.89	29.86	28.82
Unpainted (Screws Included)									
537-TF-770	TF-770	B	2.75	2.13	1.63	4.74	4.26	4.12	3.98
537-TF-772	TF-772	B	3.25	2.13	1.13	4.74	4.26	4.12	3.98
537-TF-775	TF-775	B	4.00	2.25	2.25	6.47	5.82	5.62	5.43
537-TF-777	TF-777	B	4.25	2.25	1.50	5.35	4.82	4.67	4.49
537-TF-778	TF-778	B	5.00	2.25	2.25	6.93	6.25	6.04	5.83
537-TF-779	TF-779	B	5.00	4.00	3.00	9.68	8.72	8.43	8.13
537-TF-780	TF-780	B	5.25	3.00	2.13	7.62	6.88	6.64	6.41
537-TF-781	TF-781	B	6.00	5.00	4.00	13.53	12.19	11.77	11.37
537-TF-782	TF-782	B	7.00	5.00	3.00	13.70	12.34	11.93	11.51
537-TF-783	TF-783	B	8.00	6.00	3.50	16.67	14.99	14.50	13.99
537-TF-784	TF-784	B	10.00	6.00	3.50	19.72	17.75	17.16	16.56
537-TF-787	TF-787	B	12.00	7.00	4.00	27.37	24.65	23.82	23.00

Jiffy Box Chassis

- Unpainted, snap together

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
537-J-870	J-870	B	2.75	2.13	1.63	4.74	4.26	4.12	3.98
537-J-871	J-871	B	2.75	2.13	2.75	5.35	4.82	4.67	4.49
537-J-872	J-872	B	3.25	2.13	1.13	4.74	4.26	4.12	3.98
537-J-873	J-873	B	3.50	2.13	1.63	5.11	4.60	4.45	4.28
537-J-877	J-877	B	4.25	2.25	1.50	5.35	4.82	4.67	4.49
537-J-879	J-879	B	5.00	4.00	3.00	9.68	8.72	8.43	8.13
537-J-880	J-880	B	5.25	3.00	2.13	7.62	6.88	6.64	6.41
537-J-881	J-881	B	6.00	5.00	4.00	13.53	12.19	11.77	11.37
537-J-882	J-882	B	7.00	5.00	3.00	13.70	12.34	11.93	11.51

Crown Royal (C-R) Series

- Light blue top, gray bottom

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
537-CR-321	CR-321-P	C	3.25	2.13	1.63	9.29	8.36	8.08	7.79
537-CR-332	CR-332-P	C	3.75	3.00	2.13	11.80	10.62	10.26	9.91
537-CR-400	CR-400-P	C	4.00	2.00	2.75	11.34	10.20	9.87	9.53
537-CR-422	CR-422-P	C	4.00	2.25	2.25	11.11	10.00	9.67	9.32
537-CR-425	CR-425-P	C	4.25	2.25	1.25	9.49	8.54	8.25	7.97
537-CR-442	CR-442-P	C	4.00	4.00	2.00	12.90	11.61	11.22	10.84
537-CR-531	CR-531-P	C	5.50	3.00	1.25	12.46	11.22	10.85	10.47
537-CR-532	CR-532-P	C	5.25	3.00	2.13	12.94	11.65	11.25	10.86
537-CR-632	CR-632-P	C	6.25	3.50	2.13	15.83	14.25	13.77	13.29
537-CR-643	CR-643-P	C	6.00	4.00	3.00	19.25	17.33	16.76	16.18
537-CR-753	CR-753-P	C	7.00	5.00	3.00	23.53	21.18	20.47	19.76
537-CR-800	CR-800-P	C	8.00	3.00	2.75	19.22	17.31	16.72	16.14
537-CR-864	CR-864-P	C	8.00	6.00	4.50	31.38	28.23	27.30	26.35
537-CR-1042	CR-1042-P	C	10.00	4.00	2.20	24.20	21.78	21.05	20.33

CAP COVER CHASSIS

- Special welded corners for sturdier chassis
- Manufactured from aircraft aluminum type 3003, H-14
- Finish: plain aluminum
- Cap construction permits all space inside chassis to be utilized

Chassis (Without Cover)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
537-572	572	D	5.00	7.00	2.00	14.80	13.33	12.87	12.45
537-573	573	D	5.00	7.00	3.00	16.37	14.74	14.25	13.75
537-5103	5103	D	5.00	10.00	3.00	21.32	19.19	18.55	17.90
537-7123	7123	D	7.00	12.00	3.00	22.73	20.46	19.77	19.10
537-8103	8103	D	8.00	10.00	3.00	22.08	19.87	19.21	18.54
537-8123	8123	D	8.00	12.00	3.00	24.48	22.04	21.30	20.58
537-10123	10123	D	10.00	12.00	3.00	26.49	23.85	23.04	22.25
537-12173	12173	D	12.00	17.00	3.00	48.29	43.46	42.01	40.56
537-13173	13173	D	13.00	17.00	3.00	50.41	45.38	43.87	42.35

Chassis Cap Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Fits Chassis	Price Each			
				1	10	50	100
537-572C	572C	D	537-572 and 537-573	4.72	4.10	4.10	3.96
537-5103C	5103C	D	537-5103	6.32	5.50	5.50	5.32
537-772C	772C	D	537-772	6.08	5.29	5.29	5.12
537-792C	792C	D	537-792	8.18	7.12	7.12	6.86
537-7123C	7123C	D	537-7123	9.23	8.02	8.02	7.74
537-842C	842C	D	537-842	4.72	4.10	4.10	3.96
537-8103C	8103C	D	537-8103	9.17	7.98	7.98	7.70
537-8123C	8123C	D	537-8123	11.21	9.77	9.77	9.41
537-10123C	10123C	D	537-10123	11.02	9.58	9.58	9.25
537-10173C	10173C	D	537-10173	19.00	18.17	18.17	17.54
537-12173C	12173C	D	537-12173	21.07	18.33	18.33	17.70
537-13173C	13173C	D	537-13173	24.16	21.02	21.02	20.30

ENCLOSURES

Utility Boxes

- Finish: plain aluminum
- Manufactured from aircraft aluminum type 3003-H 14

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
537-UC-970	UC-970	E	4.00	4.00	2.00	13.18	11.87	11.48	11.08
537-UC-971	UC-971	E	5.00	4.00	3.00	14.55	13.10	12.67	12.23
537-UC-972	UC-972	E	6.00	5.00	4.00	19.03	17.14	16.57	16.00
537-UC-973A	UC-973A	E	6.00	6.00	3.00	19.17	17.26	16.68	16.10
537-UC-976	UC-976	E	10.00	8.00	7.00	45.53	40.98	39.61	38.24
537-UC-977	UC-977	E	12.00	7.00	6.00	43.79	39.42	38.10	36.78
537-UC-979	UC-979	E	12.00	11.00	8.00	69.36	62.43	60.35	58.27
537-UC-980	UC-980	E	15.00	9.00	7.00	68.97	62.07	60.00	57.93

Non-Skid Foot (Black)

Note: Four (4) required for each box (plugs into screw holes)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Description	Price Each			
			1	10	50	100
537-F2	F2	Black elastomer; fits all LMB enclosures	.26	.24	.23	.22