


Enclosures and Consoles

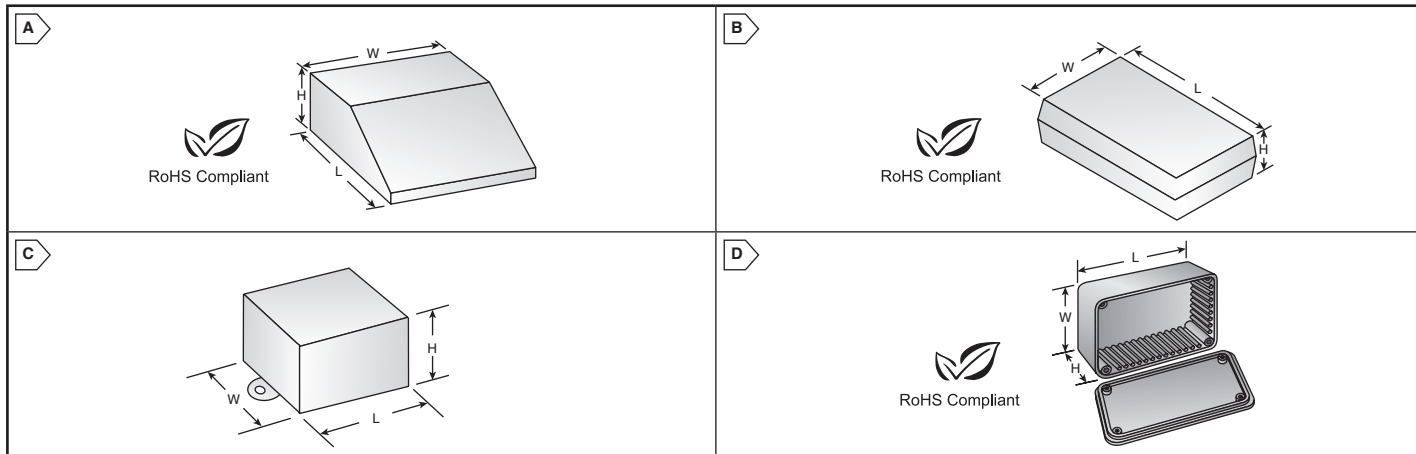

ALUMINUM MODULAR DESKTOP CONSOLES

The length of the flat top is 1/2 of the total length.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
Unpainted (Includes Rubber Feet)									
537-MDC321-01	MDC321	A	3.00	2.00	1.50	6.55	5.90	5.71	5.51
537-MDC432-01	MDC432	A	4.00	3.00	2.00	8.81	7.94	7.67	7.40
537-MDC532-01	MDC532	A	5.00	3.00	2.00	10.16	9.15	8.83	8.52
537-MDC642-01	MDC642	A	6.00	4.00	2.25	12.13	10.92	10.56	10.19
537-MDC752-01	MDC752	A	7.00	5.00	2.50	13.99	12.59	12.17	11.75
537-MDC862-01	MDC862	A	8.00	6.00	2.75	18.39	16.56	15.99	15.44
537-MDC973-01	MDC973	A	9.00	7.00	3.00	20.24	18.23	17.60	16.99
537-MDC1183-01	MDC1183	A	11.00	8.00	3.50	39.21	35.31	34.16	32.94
537-MDC13104-01	MDC13104	A	13.00	10.00	4.00	41.08	36.98	35.74	34.51
537-MDC15155-01	MDC15155	A	15.00	15.00	4.50	66.98	60.29	58.28	56.27
Painted Beige / Ivory (Includes Rubber Feet)									
537-MDC321-BI	MDC321-BI	A	3.00	2.00	1.50	10.18	9.17	8.85	8.55
537-MDC432-BI	MDC432-BI	A	4.00	3.00	2.00	13.78	12.39	11.98	11.58
537-MDC532-BI	MDC532-BI	A	5.00	3.00	2.00	15.38	13.84	13.36	12.91
537-MDC642-BI	MDC642-BI	A	6.00	4.00	2.25	18.27	16.44	15.88	15.34
537-MDC752-BI	MDC752-BI	A	7.00	5.00	2.50	20.39	18.36	17.74	17.12
537-MDC862-BI	MDC862-BI	A	8.00	6.00	2.75	26.07	23.47	22.67	21.90
537-MDC973-BI	MDC973-BI	A	9.00	7.00	3.00	29.09	26.18	25.31	24.44
537-MDC1042-BI	MDC1042-BI	A	10.00	4.50	2.50	26.92	24.23	23.43	22.61
537-MDC1183-BI	MDC1183-BI	A	11.00	8.00	3.50	39.20	35.30	34.11	32.93
537-MDC13104-BI	MDC13104-BI	A	13.00	10.00	4.00	51.64	46.47	44.92	43.37
537-MDC15155-BI	MDC15155-BI	A	15.00	15.00	4.50	81.97	73.78	71.33	68.85

ENCLOSURES AND LIDS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Price Each			
			L	W	H	1	10	50	100
Drawn Miniature Boxes - Unplated									
537-M01	M01	C	1.25	1.00	1.00	1.79	1.60	1.56	1.49
537-M10	M10	C	1.75	1.25	0.88	1.79	1.60	1.56	1.49
537-M17	M17	C	2.00	1.75	1.00	1.79	1.60	1.56	1.49
537-M18	M18	C	2.00	2.00	1.25	1.79	1.60	1.56	1.49
Lids - Unplated (Match Lid Part Number to Box Part Number)									
537-M01-L	M01-L	C	1.13	1.00	---	1.21	1.10	1.06	1.02
537-M10-L	M10-L	C	1.75	1.25	---	1.21	1.10	1.06	1.02
537-M17-L	M17-L	C	2.00	1.75	---	1.21	1.10	1.06	1.02
537-M18-L	M18-L	C	2.00	2.00	---	1.21	1.10	1.06	1.02
Drawn Miniature Boxes - Cadmium Plated (M23 Thru M27 Do Not Have Mounting Ears)									
537-M01-PLTD	M01-PLTD	C	1.13	1.00	0.94	3.10	2.80	2.70	2.62
537-M06-PLTD	M06-PLTD	C	1.50	1.13	0.75	3.10	2.80	2.70	2.62
537-M10-PLTD	M10-PLTD	C	1.75	1.25	0.88	3.10	2.80	2.70	2.62
537-M11-PLTD	M11-PLTD	C	2.00	1.25	0.75	3.10	2.80	2.70	2.62
537-M12-PLTD	M12-PLTD	C	2.00	1.25	1.00	3.10	2.80	2.70	2.62
537-M15-PLTD	M15-PLTD	C	2.00	1.75	0.50	3.10	2.80	2.70	2.62
537-M16-PLTD	M16-PLTD	C	2.00	1.75	0.75	3.10	2.80	2.70	2.62
537-M17-PLTD	M17-PLTD	C	2.00	1.75	1.00	3.30	2.98	2.87	2.79
537-M18-PLTD	M18-PLTD	C	2.00	2.00	1.25	3.10	2.80	2.70	2.62
537-M21-PLTD	M21-PLTD	C	2.50	2.00	1.25	3.83	3.46	3.33	3.24
537-M23-PLTD	M23-PLTD	C	3.88	2.38	0.88	4.66	4.21	4.06	3.94
537-M24-PLTD	M24-PLTD	C	2.00	1.75	0.75	3.10	2.80	2.70	2.62
537-M25-PLTD	M25-PLTD	C	3.06	3.06	2.63	11.26	10.15	9.79	9.46
537-M26-PLTD	M26-PLTD	C	4.63	2.38	2.25	11.79	10.97	10.26	9.56
Lids - Cadmium Plated (Match Lid Part Number to Box Part Number)									
537-M01-L-PLTD	M01-L-PLTD	C	1.13	1.00	---	1.89	1.71	1.65	1.58
537-M06-L-PLTD	M06-L-PLTD	C	1.50	1.13	---	1.89	1.71	1.65	1.58
537-M10-L-PLTD	M10-L-PLTD	C	1.75	1.25	---	1.89	1.71	1.65	1.58
537-M11-L-PLTD	M11-L-PLTD	C	2.00	1.25	---	1.89	1.71	1.65	1.58
537-M12-L-PLTD	M12-L-PLTD	C	2.00	1.25	---	1.89	1.71	1.65	1.58
537-M15-L-PLTD	M15-L-PLTD	C	2.00	1.75	---	1.89	1.71	1.65	1.58
537-M16-L-PLTD	M16-L-PLTD	C	2.00	1.75	---	1.89	1.71	1.65	1.58
537-M17-L-PLTD	M17-L-PLTD	C	2.00	1.75	---	1.89	1.71	1.65	1.58
537-M18-L-PLTD	M18-L-PLTD	C	2.00	2.00	---	1.89	1.71	1.65	1.58
537-M21-L-PLTD	M21-L-PLTD	C	2.50	2.00	---	2.81	2.71	2.60	2.41
537-M23-L-PLTD	M23-L-PLTD	C	3.88	2.38	---	1.89	1.71	1.65	1.58
537-M24-L-PLTD	M24-L-PLTD	C	2.00	1.75	---	1.89	1.71	1.65	1.58
537-M25-L-PLTD	M25-L-PLTD	C	3.06	3.06	---	3.62	3.26	3.15	3.04
537-M26-L-PLTD	M26-L-PLTD	C	4.63	2.38	---	3.62	3.26	3.15	3.04

HIGH-IMPACT ABS ENCLOSURES, STANDARD

Color Code Chart

- Scratch resistant grain finish
- Card guides for vertical mounting of circuit boards
- 9 volt battery compartment (500 Series)
- Internal mounting bosses for horizontal circuit boards

To order add applicable suffix for desired color to Mouser Stock No.

Color	Black	Gray	Almond
Suffix	BK	GY	AL

Note: All dimensions are outside measurements

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	LMB Part No.	Fig.	Dimensions: in.			Vert. Card Pos.	Mtg. Post	Price Each			
			L	W	H			1	10	50	100
537-400-I-	400-I-	B	3.60	2.25	1.00	---	---	6.61	5.95	5.76	5.55
537-401-	401-	B	3.60	2.25	1.50	2	4	6.51	5.85	5.66	5.46
537-402-	402-	B	4.38	3.25	1.50	3	4	8.69	7.82	7.56	7.29
537-403-	403-	B	5.62	3.25	1.50	4	4	11.17	10.06	9.71	9.40
537-404-	404-	B	6.87	4.87	1.50	5	8	11.53	10.39	10.03	9.69
537-408-	408-	B	6.87	4.87	2.00	5	8	14.34	12.91	12.47	12.04
537-410-	410-	B	4.38	3.25	2.50	3	4	9.81	8.84	8.54	8.24
537-411-	411-	B	5.62	3.25	2.50	4	4	12.98	11.70	11.30	10.91
537-412-	412-	B	6.87	4.87	2.50	5	8	15.07	13.56	13.10	12.66
537-413-	413-	B	9.50	6.34	1.50	---	---	21.43	19.28	18.63	17.99
537-501-	501-	B	4.11	2.61	1.50	1	4	7.15	6.44	6.23	6.01
537-502-	502-	B	4.38	3.25	1.50	3	4	9.36	8.44	8.15	7.87
537-503-	503-	B	5.62	3.25	1.50	3	4	12.79	11.51	11.13	10.75

plastic CASES

Note: All dimensions are outside measurements
* Height is with lid on.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Dimensions: in.			PCB Guides	Price Each				
		L	W	H*		1	10	50	100	200
Black Plastic Project Boxes with Lids										
400-1541-GR	D	3	2	1	No	3.06	2.55	2.32	2.11	1.94
400-1551-GR	D	4 3/8	2 1/4	7/8	No	3.65	3.04	2.76	2.51	2.31
400-1561-GR	D	4	3	1 5/8	Yes	4.66	3.89	3.53	3.21	2.96
400-1571-GR	D	5 7/8	3 7/8	2 1/4	Yes	8.09	6.74	6.13	5.57	5.12
Gray Molded ABS Plastic Cases										
400-1552-GR	D	5.1	2.5	1.8	Yes	5.28	4.80	4.36	3.96	3.64
400-1572-GR	D	7.3	4.5	2.6	Yes	8.94	8.13	7.39	6.72	6.18