


BUD Hand Held Plastic Enclosures



RoHS Compliant This product is RoHS compliant.

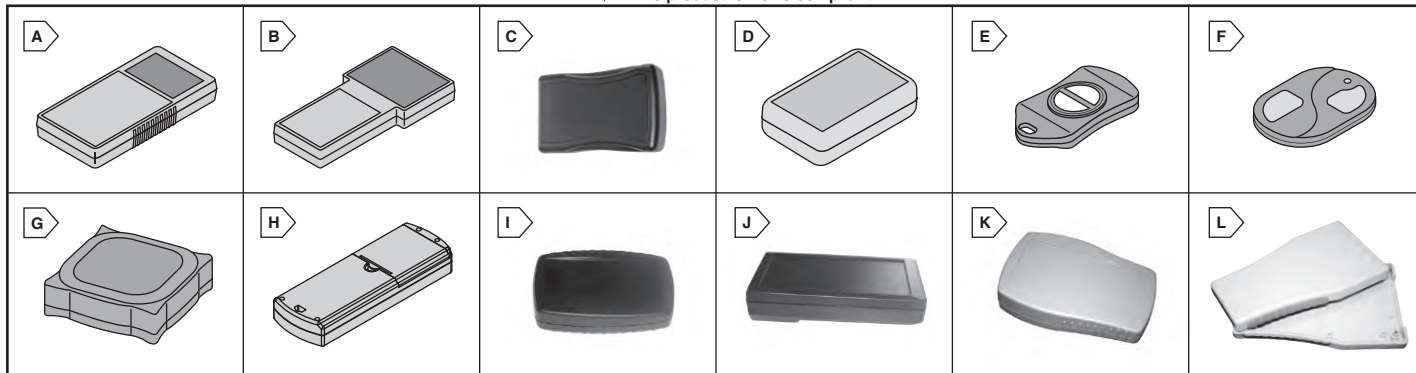


BUD GRABBERS HAND HELD BOXES

- Style A:**
- Available with/without 2.84" x 1.38" LCD cut-out in the display area
 - Has a 9V/AA battery compartment
- Style B:**
- Available with/without 4.00" x 1.75" LCD cut-out in the display area.
 - Available with/without a 9V/AA battery compartment
- Style C:**
- Rectangular with 9 V/AA battery compartment, removable end panel
 - Made of high impact ABS plastic, black
- Style F:**
- Pocket-sized with molded-in ring suitable for key ring applications
- Style G:**
- Available with/without a 2.84" x 2.03" LCD cutout in the display area
 - Available with/without a 9V/AA battery compartment
 - Wall mounting plate/tilt stand included

- Style H:**
- Built-in clear LED light pipe for status monitoring
- Style I:**
- Mar resistant textured surface with PCB mounting bosses
- Style J:**
- Compact, ergonomic design
 - Integral battery compartment, 4AA batteries.
 - Internal PCB mounting bosses
 - Recessed top suitable for label or keypad
- Style K:**
- Includes battery compartment and battery contacts
 - Flushed textures top
 - Made with flame retardant, high impact ABS plastic
- Style L:**
- Available with/without battery compartment
 - Made of high impact ABS plastic
 - Designed with ribbed rounded sides that provides a secure and comfortable grasp

- Style M:**
- Has extra deep pocket on one end that helps provide a better view
 - Made of high impact ABS plastic
- Style N:**
- Available with/without battery compartment
 - Designed with ribbed round sides that provides a secure and comfortable grasp
 - Made with flame retardant, high impact ABS plastic
- Style O:**
- Available with/without battery compartment
 - "T" and rectangular shaped providing more room for internal components
 - Designed with soft ribbed rounded sides that provide secure and comfortable grasp
 - Made with high impact, resistant, black or gray, ABS plastic
 - Recessed top suitable for label of keypad
 - Contact kits are included


customize it.

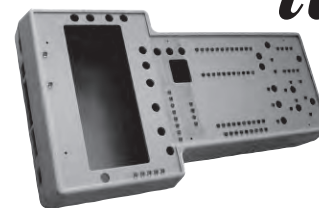

Contact a Mouser Service Representative for a custom design solution

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Fig.	Style	Color	LCD Cut-out	Battery Compartment	Buttons	Flammability Rating	Dimensions: in. H x W x D	Price Each			
										1	5	10	25
563-HH-3400-BC	HH-3400-BC	A	A	Gray	No	Yes	No	UL94V-0	7.09 x 3.94 x 1.57	15.30	12.74	12.12	11.50
563-HH-3401-BC	HH-3401-BC	A	A	Gray	Yes	Yes	No	UL94V-0	7.09 x 3.94 x 1.57	15.10	12.59	11.97	11.35
563-HH-3420	HH-3420	B	B	Gray	No	No	No	UL94V-0	9.33 x 5.16 x 1.71	19.00	15.84	15.04	14.25
563-HH-3420-BC	HH-3420-BC	B	B	Gray	No	Yes	No	UL94V-0	9.33 x 5.16 x 1.71	19.90	16.59	15.77	14.94
563-HH-3421	HH-3421	B	B	Gray	Yes	No	No	UL94V-0	9.33 x 5.16 x 1.71	18.50	15.44	14.67	13.89
563-HH-3421-BC	HH-3421-BC	B	B	Gray	Yes	Yes	No	UL94V-0	9.33 x 5.16 x 1.71	19.50	16.24	15.44	14.65
563-HH-3524	HH-3524	C	K	Black	No	Yes	No	UL94V-0	4.63 x 2.85 x 1.00	9.80	8.20	7.80	7.40
563-HH-3524	HH-3524	C	K	Black	No	Yes	No	UL94V-0	5.50 x 3.25 x 1.00	9.53	9.06	8.62	8.20
563-HH-3430-BCB	HH-3430-BCB	D	C	Black	No	Yes	No	UL94V-0	5.31 x 2.76 x .94	5.50	4.60	4.37	4.15
563-HH-3430-BCG	HH-3430-BCG	D	C	Gray	No	Yes	No	UL94V-0	5.31 x 2.76 x .94	5.50	4.60	4.37	4.15
563-HH-3431-BCB	HH-3431-BCB	D	C	Black	No	Yes	No	UL94V-0	4.13 x 2.95 x 1.04	6.25	5.26	4.90	4.65
563-HH-3431-BCG	HH-3431-BCG	D	C	Gray	No	Yes	No	UL94V-0	4.13 x 2.95 x 1.05	6.25	5.26	5.15	4.65
563-HH-3492	HH-3492	E	F	Gray	No	No	2	UL94-HB	2.23 x 1.29 x .45	5.30	4.41	4.14	3.95
563-HH-3496-B	HH-3496-B	B	G	Black	No	No	No	UL94V-0	8.27 x 4.33 x 1.59	16.10	13.39	12.04	12.00
563-HH-3496-G	HH-3496-G	B	G	Gray	No	No	No	UL94V-0	8.27 x 4.33 x 1.59	16.10	13.39	12.04	12.00
563-HH-3497-BC-B	HH-3497-BC-B	B	G	Black	No	Yes	No	UL94V-0	8.27 x 4.33 x 1.59	16.50	13.75	13.07	12.40
563-HH-3497-BC-G	HH-3497-BC-G	B	G	Gray	No	Yes	No	UL94V-0	8.27 x 4.33 x 1.59	16.50	13.75	13.07	12.40
563-HH-3499-BC-B	HH-3499-BC-B	B	G	Black	Yes	Yes	No	UL94V-0	8.27 x 4.33 x 1.59	16.50	13.74	12.37	12.30
563-HH-3499-BC-G	HH-3499-BC-G	B	G	Gray	Yes	Yes	No	UL94V-0	8.27 x 4.33 x 1.59	16.50	13.74	12.37	12.30
563-HH-3502	HH-3502	F	H	Black	No	No	2	UL94-HB	2.72 x 1.84 x 1.25	5.30	4.41	4.14	3.95
563-HH-3550	HH-3550	G	I	Black	No	No	No	UL94-5VA	4.5 x 4.5 x 1.5	9.30	8.51	7.74	7.53
563-HH-3570-B	HH-3570-B	H	J	Black	No	Yes	No	UL94-HB	7.15 x 2.56 x 1.09	7.30	6.10	5.80	5.50
563-HH-3570-G	HH-3570-G	H	J	Gray	No	Yes	No	UL94-HB	7.15 x 2.56 x 1.09	7.30	6.10	5.80	5.50
563-HH-3580-B	HH-3580-B	I	L	Black	No	No	No	UL94V-0	5.71 x 2.20 x 1.26	7.10	5.90	5.60	5.30
563-HH-3580-BCB	HH-3580-BCB	I	L	Black	No	Yes	No	UL94V-0	5.71 x 2.20 x 1.26	8.20	6.85	6.49	6.14
563-HH-3600-B	HH-3600-B	J	M	Black	No	No	No	UL94V-0	5.98 x 3.26 x 1.31	7.40	6.20	5.90	5.60
563-HH-3610-B	HH-3610-B	K	N	Black	No	No	No	UL94V-0	6.69 x 5.16 x 1.38	8.10	6.74	6.42	6.10
563-HH-3610-BCB	HH-3610-BCB	K	N	Black	No	Yes	No	UL94V-0	6.69 x 5.16 x 1.38	9.20	7.70	7.32	6.95
563-HH-3510-B	HH-3510-B	L	O	Black	No	No	No	UL94V-0	6.28 x 3.69 x .90	9.85	8.15	7.35	6.50
563-HH-3510-G	HH-3510-G	L	O	Gray	No	No	No	UL94V-0	6.28 x 3.69 x .90	9.85	8.15	7.35	6.50
563-HH-3510-BCB	HH-3510-BCB	L	O	Black	No	Yes	No	UL94V-0	6.28 x 3.69 x .90	10.50	8.75	7.90	7.00
563-HH-3510-BCG	HH-3510-BCG	L	O	Gray	No	Yes	No	UL94V-0	6.28 x 3.69 x .90	10.50	8.75	7.90	7.00

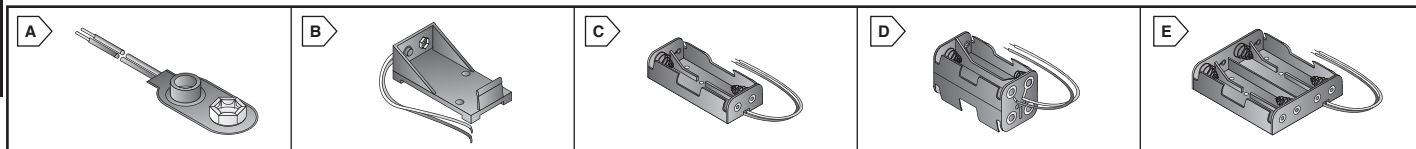

Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bud Part No.	Fig.	Description	Color	Material	Leads	Size/Capacity	Price Each			
								1	5	10	25
563-HH-3442-C	HH-3442-C	-	AA Contact Kit	-	-	-	-	.58	.44	.425	.41
563-HH-3449	HH-3449	A	9V Battery Clip	Black	Flexible Vinyl	6" Long	One 9V	1.20	1.00	.95	.90
563-HH-3634	HH-3634	B	9V Battery Holder	Black	Polypropylene Plastic	-	One 9V	2.40	2.00	1.90	1.80
563-HH-3630	HH-3630	C	(2) AAA Battery Holder	Black	Polypropylene Plastic	6" Long	Two AAA	1.48	1.41	1.34	1.28
563-HH-3631	HH-3631	D	(4) AAA Battery Holder	Black	Polypropylene Plastic	6" Long	Four AAA	2.90	2.42	2.30	2.18
563-HH-3632	HH-3632	C	(2) AA Battery Holder	Black	Polypropylene Plastic	6" Long	Two AA	1.70	1.42	1.35	1.28
563-HH-3633	HH-3633	E	(4) AA Battery Holder	Black	Polypropylene Plastic	6" Long	Four AA	2.90	2.42	2.30	2.18