


SERPAC Enclosures and Cases

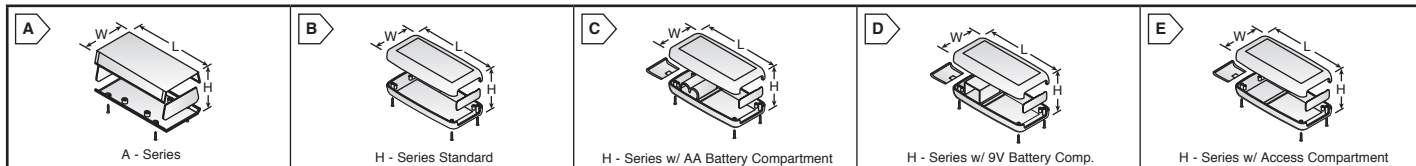

SERPAC A - SERIES

There are 3 colors available, replace the () in the part number with:

A for Almond or B for Black or G for Gray

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
Standard								
635-A-20-	A-20-	A	4.25	2.60	0.87	4.56	3.61	3.29
635-A-21-	A-21-	A	4.25	2.60	1.12	5.78	4.54	4.13
635-A-27-	A-27-	A	5.31	3.35	1.51	6.73	5.66	5.14
635-A-31-	A-31-	A	5.30	5.10	1.71	7.36	5.78	5.26
635-A-42-	A-42-	A	7.10	5.00	11.57	12.89	10.00	9.11
With 9V Battery Compartment								
635-A-21-9V-	A-21-9V-	A	4.25	2.60	1.12	7.31	5.74	5.22
635-A-27-9V-	A-27-9V-	A	5.31	3.14	1.51	10.52	8.27	7.52
635-A-31-9V-	A-31-9V-	A	5.30	5.10	1.71	12.89	10.13	9.21
635-A-41-9V-	A-41-9V-	A	7.10	5.00	1.30	9.23	7.25	6.59
635-A-42-9V-	A-42-9V-	A	7.10	5.00	1.62	14.97	11.76	10.70

Optional End Panels for A Series Enclosures

Available in Clear (CL), Infrared (IR), DB9 Cutout, DB25 Cutout, and 9V Battery Cutout

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	For Enclosure	Price Each		
			1	10	25
635-2003-CL	2003-CL	A-20	1.29	.75	.729
635-2003-IR	2003-IR	A-20	1.43	.82	.793
635-2003-DB9	2003-DB9	A-20	1.65	.95	.92
635-2003-DB25	2003-DB25	A-20	1.53	.88	.853
635-2005-CL	2005-CL	A-21	1.29	1.21	1.04
635-2005-IR	2005-IR	A-21	1.41	1.32	1.13
635-2005-DB25	2005-DB25	A-21	1.51	1.41	1.21
635-2006-9V	2006-9V	A-21	1.41	.80	.771
635-2010IR	2010-IR	A-27	1.61	.91	.873
635-2010DB9	2010-DB9	A-27	1.96	1.63	1.57
635-2010DB25	2010-DB25	A-27	2.07	1.19	1.14
635-2011-9V	2011-9V	A-27	1.52	.86	.836
635-2015-CL	2015-CL	A-31	2.90	2.62	2.38
635-2015-IR	2015-IR	A-31	2.64	1.47	1.41
635-2015-DB9	2015-DB9	A-31	2.51	1.44	1.40
635-2015-DB25	2015-DB25	A-31	2.51	1.44	1.40
635-2020-CL	2020-CL	A-41	2.22	1.24	1.19
635-2020-IR	2020-IR	A-41	3.11	1.73	1.67
635-2020-DB9	2020-DB9	A-41	2.20	1.26	1.22
635-2020-DB25	2020-DB25	A-41	2.20	1.26	1.22
635-2024-CL	2024-CL	A-42	3.13	1.74	1.65
635-2024IR	2024-IR	A-42	2.64	1.47	1.41
635-2024-DB9	2024-DB9	A-42	2.76	1.59	1.54
635-2025-9V	2025-9V	A-42	2.31	1.30	1.24

SERPAC H - SERIES SOLID COLORS

There are 3 colors available, replace the () in the part number with:

A for Almond or B for Black or G for Gray

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
Standard								
635-H-45-	H-45-	B	3.90	2.20	.94	10.14	9.21	8.39
With AA Battery Compartment								
635-H-65AA-	H-65-AA-	C	4.94	2.75	.94	4.89	3.84	3.50
635-H-67AA-	H-67-AA-	C	4.94	2.75	1.28	9.58	7.78	6.58
635-H-75-4AA-	H-75-4AA-	C	7.20	3.65	1.26	7.89	6.39	5.41
With 9V Battery Compartment								
635-H-659V-	H-65-9V-	D	4.94	2.75	.94	4.76	3.73	3.40
635-H-679V-	H-67-9V-	D	4.94	2.75	1.28	4.84	3.80	3.46
635-H-75-9V-	H-75-9V-	D	7.20	3.65	1.26	5.98	4.70	4.27
With Access Compartment								
635-H-65AC-	H-65-AA-AC-	E	4.94	2.75	.94	4.44	3.48	3.17
635-H-67AC-	H-67-AA-AC-	E	4.94	2.75	1.28	4.53	3.55	3.23

SERPAC H - SERIES TRANSLUCENT COLORS

There are 4 colors available, replace the () in the part number with:

BL for Blue or GR for Green or RD for Red or GY for Gray

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each		
			L	W	H	1	10	25
635-H-65AATR-	H-65-AA-TR-	C	4.94	2.75	.94	8.39	6.59	5.99
635-H-659VTR-	H-65-9V-TR-	D	4.94	2.75	.94	8.13	6.39	5.80

Optional End Panels for H Series Enclosures

Available in Clear (CL), Infrared (IR), and Red (R)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Price Each		
		1	10	25
635-2104-IR	2104-IR	2.27	1.44	1.39
635-2104-R	2104-R	3.25	2.00	1.93
635-2105-CL	2105-CL	2.54	1.49	1.43
635-2105IR	2105-IR	3.18	1.97	1.90
635-2105-R	2105-R	2.68	1.64	1.59
635-2106IR	2106-IR	2.64	1.62	1.56
635-2106R	2106-R	2.84	1.73	1.67
635-2107-CL	2107-CL	2.87	1.73	1.67
635-2107-IR	2107-IR	3.82	2.22	2.14
635-2107-R	2107-R	4.08	2.38	2.30

SERPAC I SERIES - INDUSTRIAL ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Color	Price Each		
			L	W	H		1	10	25
635-I352HL-TGBG	I352HL, TGBG	A	10.00	8.00	6.00	Gray Top, Gray Bottom	62.40	51.84	49.60
635-I352HL-TCBC	I352HL, TCBC	A	10.00	8.00	6.00	Clear Top, Clear Bottom	62.40	51.84	49.60
635-I352S-TGBG	I352S, TGBG	A	11.75	9.98	7.45	Gray Top, Gray Bottom	62.40	51.84	49.60
635-I352S-TCBC	I352S, TCBC	A	11.75	9.98	7.45	Gray Top, Gray Bottom	62.40	51.84	49.60
635-I352HS-TGBG	I352HS, TGBG	A	11.75	9.98	7.45	Gray Top, Gray Bottom	62.40	51.84	49.60
635-I352HS-TCBC	I352HS, TCBC	A	11.75	9.98	7.45	Clear Top, Clear Bottom	62.40	51.84	49.60

SERPAC RB SERIES - INSTRUMENT ENCLOSURES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Color	Price Each		
			L	W	H		1	10	25
635-RB22-1TC1BC	RB22-1TC1BC	B	2.55	1.97	1.38	Clear Top, Clear Bottom	10.35	9.52	8.69
635-RB22-1TC1BG	RB22-1TC1BG	B	2.55	1.97	1.38	Gray Top, Gray Bottom	10.35	9.52	8.69
635-RB22-1TG1BG	RB22-1TG1BG	B	2.55	1.97	1.38	Gray Top, Gray Bottom	10.35	9.52	8.69
635-RB22-1TC1BB	RB22-1TC1BB	B	2.55	1.97	1.38	Clear Top, Black Bottom	10.35	9.52	8.69
635-RB22-1TB1BB	RB22-1TB1BB	B	2.55	1.97	1.38	Top Black, Black Bottom	10.35	9.52	8.69
635-RB33-1TC0BC	RB33-1TC1BC	B	3.22	3.15	2.17	Clear Top, Clear Bottom	11.06	10.47	9.36
635-RB33-1TC1BG	RB33-1TC1BG	B	3.22	3.15	2.17	Gray Top, Gray Bottom	11.06	10.47	9.36
635-RB33-1TG1BG	RB33-1TG1BG	B	3.22	3.15	2.17	Gray Top, Gray Bottom	11.06	10.47	9.36
635-RB33-1TC1BB	RB33-1TC1BB	B	3.22	3.15	2.17	Clear Top, Black Bottom	11.06	10.47	9.36
635-RB33-1TB1BB	RB33-1TB1BB	B	3.22	3.15	2.17	Top Black, Black Bottom	11.06	10.47	9.36
635-RB53-1TC1BC	RB53-1TC1BC	B	4.72	3.15	2.17	Clear Top, Clear Bottom	18.41	17.41	16.11
635-RB53-1TC-BG	RB53-1TC1BG	B	4.72	3.15	2.17	Gray Top, Gray Bottom	18.41	17.41	16.11
635-RB53-1TG1BG	RB53-1TG1BG	B	4.72	3.15	2.17	Gray Top, Gray Bottom	18.41	17.41	16.11
635-RB53-1TC1BB	RB53-1TC1BB	B	4.72	3.15	2.17	Clear Top, Black Bottom	18.41	17.41	16.11
635-RB53-1TB1BB	RB53-1TB1BB	B	4.72	3.15	2.17	Top Black, Black Bottom	18.41	17.41	16.11

SERPAC SE - SERIES EQUIPMENT CASES

There are 4 colors available, replace the () in the part number with:


GM for Gunmetal (Dark Gray) or B for Black or

CY for Caution Yellow or IQ for International Orange

* GM not available

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Serpac Part No.	Fig.	Dimensions: in.			Price Each
			L	W	H	
* 635-R-120-B	SE-120-	C	8.70	7.45	3.89	17.36
635-R-300-	SE-300-	C	10.80	9.85	4.50	48.10
635-R-520-	SE-520-	C	14.85	12.15	6.85	75.83
635-R-710-	SE-710-	C	19.75	15.53	5.41	114.95
635-R-720-	SE-720-	C	19.75	15.53	7.48	119.03

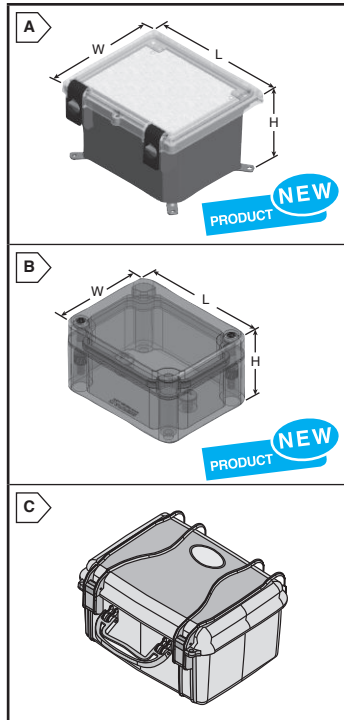

Serpac Plastic Boxes