


EMERSON NETWORK POWER Switching Power Supplies

EMERSON Network Power

RoHS Compliant This product is RoHS compliant.
DIMENSIONS: mm

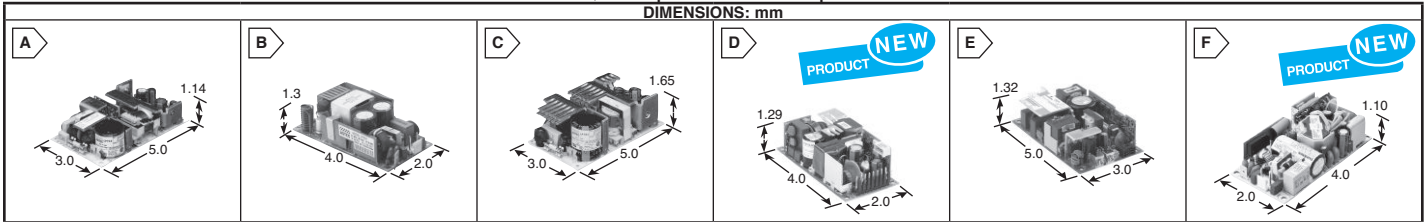

ASTECLPS25 SERIES, 25W SINGLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load*	Price Each		
						1	10	25
826-LPS22	LPS22	A	5V	0A	5A	34.45	32.82	32.23
826-LPS23	LPS23	A	12V	0A	2.1A	36.16	34.45	33.83

ASTECLPS40 SERIES, 40W SINGLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load*	Price Each		
						1	10	25
826-LPS41	LPS41	A	3.3V	0A	8A	39.31	38.25	37.02
826-LPS42	LPS42	A	5V	0A	8A	48.90	45.21	43.94
826-LPS43	LPS43	A	12V	0A	3.3A	46.58	43.07	41.86
826-LPS44	LPS44	A	15V	0A	2.6A	46.58	43.07	41.86
826-LPS45	LPS45	A	24V	0A	1.7A	46.58	43.07	41.86
826-LPS48	LPS48	A	48V	0A	0.9A	46.58	43.07	41.86

ASTECLPS50 SERIES, 50W SINGLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load*	Price Each		
						1	10	25
826-LPS52	LPS52	B	5V	0A	11A	50.49	44.78	41.68
826-LPS53	LPS53	B	12V	0A	5A	50.34	47.27	46.02
826-LPS54	LPS54	B	15V	0A	4A	52.86	49.64	48.32
826-LPS55	LPS55	B	24V	0A	2.5A	50.34	47.27	46.02

Medical Version

826-LPS52-M	LPS52-M	B	5V	0A	11A	59.35	56.88	54.45
826-LPS54-M	LPS54-M	B	15V	0A	4A	59.35	56.88	54.45
826-LPS55-M	LPS55-M	B	24V	0A	2.5A	59.35	56.88	54.45

ASTECLPS60 SERIES, 60W SINGLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load*	Price Each		
						1	10	25
826-LPS62	LPS62	C	5V	0A	12A	49.37	47.02	45.34
826-LPS63	LPS63	C	12V	0A	5A	49.38	47.02	45.34
826-LPS64	LPS64	C	15V	0A	4A	61.47	57.63	54.66
826-LPS65	LPS65	C	24V	0A	2.5A	61.47	57.63	54.66
826-LPS68	LPS68	C	48V	0A	1.3A	51.49	49.02	47.26

ASTECLPS100 SERIES, 80-150W SINGLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Max Load w/ Conv. Cooling	Max Load w/ 30CFM Forced Air	Price Each		
						1	10	25
826-LPS102-M	LPS102-M	D	5V	16A	24A	90.57	85.04	81.33
826-LPS103-M	LPS103-M	D	12V	8.3A	12.5A	90.57	85.04	81.33
826-LPS104-M	LPS104-M	D	15V	6.7A	10A	90.57	85.04	81.38
826-LPS105-M	LPS105-M	D	24V	4.2A	6.3A	90.57	85.04	81.33
826-LPS108-M	LPS108-M	D	48V	2.1A	3.1A	90.57	85.04	81.33
826-LPS109-M	LPS109-M	D	54V	1.85A	2.8A	90.57	85.04	81.33

Accessories

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Description	Price Each		
			1	10	25
826-70-841-025	70-841-025	Power Connector Kit	9.75	8.04	7.72

ASTECLPS200 SERIES, 125-250W SINGLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Max Load w/ Conv. Cooling	Max Load w/ 30CFM Forced Air	Price Each		
						1	10	25
826-LPS202-M	LPS202-M	E	5V	20.0A	40.0A	128.49	110.36	105.42
826-LPS204-M	LPS204-M	E	15V	8.3A	16.6A	122.37	105.10	100.40
826-LPS208-M	LPS208-M	E	48V	2.6A	5.2A	122.37	105.10	100.40
826-LPS254-CF	LPS254-CF	E	15V	0.50A	16.7A	319.17	279.27	264.31
826-LPS255-CF	LPS255-CF	E	24V	0.32A	10.4A	319.17	279.27	264.31

ASTECLPQ200 SERIES, 125-350W QUAD OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Max Load w/ Conv. Cooling	Max Load w/ 30CFM Forced Air	Price Each		
						1	10	25
826-LPQ201-M	LPQ201-M	E	+3V +5V +12V -12V	13.0A 13.0A 5.0A 1.0A	18.0A 18.0A 9.0A 2.0A	164.58	158.52	149.86
826-LPQ202-M	LPQ202-M	E	+5V +12V +24V -12V	13.0A 5.0A 1.5A 1.0A	18.0A 9.0A 3.0A 2.0A	156.74	150.97	142.72
826-LPQ352-CEF	LPQ352-CEF	E	+5V +12V -12V 3.3 - 24V	5A 0A 0A 1A	50A 12A 6A 6A	427.32	412.60	394.00
826-LPQ353-CEF	LPQ353-CEF	E	+5V +15V -15V 3.3 - 24V	5A 0A 0A 1A	50A 12A 6A 6A	448.06	418.78	413.36

ASTECLPT25 SERIES, 25 WATTS TRIPLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load	Price Each		
						1	10	25
826-LPT22	LPT22	A	5V 12V -12V	0.3A 0.1A 0A	3A 1.5A 0.5A	41.10	38.68	34.13
826-LPT23	LPT23	A	5V 12V -12V	0.4A 0A 0A	4A 0.5A 0.5A	35.95	34.98	33.39

ASTECLPT40 SERIES, 40 WATTS TRIPLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load	Price Each		
						1	10	25
826-LPT41	LPT41	A	+3.3V +5V +12V	0.5A 0A 0A	4A 1.5A 0.5A	58.73	52.23	48.86
826-LPT42	LPT42	A	+5V +12V -12V	0.4A 0.2A 0A	4A 2A 0.5A	43.31	37.17	35.44
826-LPT43	LPT43	A	+5V +12V -12V	0.5A 0A 0A	6A 0.5A 0.5A	48.23	43.12	40.06
826-LPT44	LPT44	A	+5V +12V -5V	0.4A 0.2A 0A	4A 2A 0.5A	43.12	40.33	38.94
826-LPT45	LPT45	A	+5V +15V -15V	0.4A 0.2A 0A	4A 2A 0.5A	48.23	43.12	40.06
826-LPT46	LPT46	A	+5V +24V +12V	0.4A 0.1A 0A	4A 1A 0.5A	38.94	37.90	36.44
826-LPT47	LPT47	A	-5V +24V -12V	4A 2A 0A	4A 1.0A 0.5A	45.64	42.58	39.24

NPT40M SERIES, 45W TRIPLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load	Price Each		
						1	10	25
826-NPT42-M	NPT42-M	F	+5V +12V -12V	0.5A 0.1A 0A	5A 2.5A 0.5A	48.23	43.12	40.06
826-NPT43-M	NPT43-M	F	+5V +15V -15V	0.5A 0.1A 0A	5A 2A 0.5A	45.22	41.94	41.00
826-NPT44-M	NPT44-M	F	+5V +24V +12V	0.5A 0.1A 0A	5A 1.0A 0.5A	45.22	41.94	41.00

ASTECLPT50 SERIES, 50W TRIPLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load	Price Each		
						1	10	25
826-LPT52	LPT52	B	+5V +12V -12V	0.5A 0.1A 0A	8A 3A 0.5A	55.86	49.96	46.24
826-LPT53	LPT53	B	+5V +15V -15V	0.5A 0.1A 0A	8A 2.4A 0.5A	55.86	49.96	46.24
826-LPT54	LPT54	B	+5V +24V +12V	0.5A 0.1A 0A	8A 1.5A 0.5A	55.86	49.96	46.24
826-LPT52-M	LPT52-M	B	+5V +12V -12V	0.5A 0.1A 0A	8A 3A 0.5A	68.75	61.50	56.91
826-LPT54-M	LPT54-M	B	+5V +24V +12V	0.5A 0.1A 0A	8A 1.5A 0.5A	68.75	61.50	56.91

ASTECLPT60 SERIES, 60W TRIPLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load	Price Each		
						1	10	25
826-LPT62	LPT62	C	+5V +12V -12V	0.7A 0.3A 0A	7A 3A 0.7A	56.25	49.53	46.34
826-LPT63	LPT63	C	+5V +15V -15V	0.7A 0.3A 0A	7A 2.8A 0.7A	69.23	60.96	56.65
826-LPT64	LPT64	C	+5V +12V -5V	0.7A 0.3A 0A	7A 3A 0.7A	69.23	60.96	56.65
826-LPT65	LPT65	C	+5V +24V +12V	0.7A 0.1A 0A	7A 1.5A 0.7A	65.95	58.07	53.96

ASTECLPT100 SERIES, 80-150W TRIPLE OUTPUT

* With Convection Cooling For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Astec Part No.	Fig.	Output Voltage	Minimum Load	Maximum Load	Price Each		
						1	10	25
826-LPT101-M	LPT101-M	E	+3.3V +5V 12V	13A 5A 1A	18A 9A 2.3A	108.72	93.38	89.21
826-LPT102-M	LPT102-M	E	+5V +12V -12V	13A 5A 1A	18A 9A 2A	108.72	93.38	89.21
826-LPT103-M	LPT103-M	E	+5V +15V -15V	13A 4A 1A	18A 7.2A 1.5A	103.54	88.93	84.96
826-LPT104-M	LPT104-M	E	+5V +24V +12V	13A 1.5A 1A	18A 3A 2.3A	103.54	88.93	84.96

Power Supplies Astec