

POWER-ONE AC-DC and DC-DC Power Supplies



RoHS Compliant This product is RoHS compliant.

FRONT END POWER SUPPLIES

- Ideal server form factor optimizes space, efficiency, and load variations
- Overtemperature, overload, and overvoltage protection
- Compact Size enables mounting in both 1u and 2u height
- 2 Speed fan for low noise at low ambient temperature
- 12 Interface status and monitoring

AC-DC Power Supply

- High Efficiency
- Input Voltage: 90-264VAC with PFC
- Input Frequency: 47-63Hz
- Status LEDs

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Power-One Part No.	Fig.	Input Voltage VAC	Output 1		Output 2		Rated Power	Price Each		
				Vo nom	Io max	Vo nom	Io max		1	10	25
784-SFP650-12BG	SFP650-12BG	A	90-264	12V	53.3A	3.3V	3A	650W	419.63	393.75	381.05

AC-DC Power Supplies

- High Efficiency
- Two outputs (one highcurrent output)
- Input Voltage: 85-264VAC
- Supervisory signaling
- High Density Design
- 4" x 1.58" x 8.5" cassette

For quantities greater than listed, call for quote.

FNP Series											
MOUSER STOCK NO.	Power-One Part No.	Fig.	Input Voltage VAC	Output 1 Vo nom	Output 1 Io max	Output 2 Vo nom	Output 2 Io max	Rated Power	Price Each		
784-FNP300-1012G	FNP300-1012G	B	85-264	12V	25A	12V	0.7A	310W	225.00	212.83	207.24
784-FNP300-1024G	FNP300-1024G	B	85-264	24V	12.5A	12V	0.7A	310W	228.06	216.07	212.67
784-FNP300-1048G	FNP300-1048G	B	85-264	48V	6.25A	12V	0.7A	310W	228.38	220.50	216.56

AC-DC Power Supply

- High Efficiency
- On/Off Enable switch
- Input Voltage: 90-264VAC with PFC
- Input Frequency: 47-63Hz
- Status LED's
- High Density
- 10.5 to 16.1 w/in 3

For quantities greater than listed, call for quote.

784-FNP1000-48G	FNP1000-48G	C	90-264	48V	21A	12V	0.5A	1000W	475.02	458.64	450.45
---------------------------------	-------------	---	--------	-----	-----	-----	------	-------	--------	--------	--------

AC-DC Power Supplies

- Best-in-class, 80 PLUS certified "Platinum" efficiency
- Parallel operation with active digital current sharing
- High density design: 25.6 W/in3
- Full digital controls for improved performance



For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Power-One Part No.	Fig.	Input Voltage VAC	Output Voltage	Width	Airflow	Input	Rated Power	Price Each		
									1	10	25
784-PFE1100-12-054NA	PFE1100-12-054NA	D	90-264	12V	54mm	normal	AC	1100W	387.20	365.20	330.00
784-PFE850-12-054NA	PFE850-12-054NA	D	90-264	12V	54mm	normal	AC	850W	316.80	298.80	270.00
784-PFE600-12-054NA	PFE600-12-054NA	D	90-264	12V	54mm	normal	AC	600W	223.52	210.82	190.50

DC-DC Power Supply

- High Efficiency
- Status LEDs
- Wide DC input range (-40 to -75 VDC)
- PC interface status control

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Power-One Part No.	Fig.	Input Voltage VAC	Output 1		Output 2		Rated Power	Price Each		
				Vo nom	Io max	Vo nom	Io max		1	10	25
784-SFD1200-12BG	SFD1200-12BG	E	-40 to -75	12V	99.2V	3.35V	3A	1200W	499.00	405.39	376.20

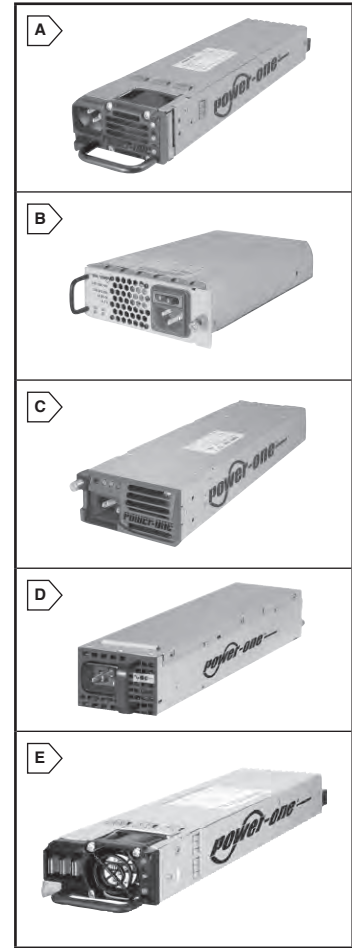

AC-DC LINEAR POWER SUPPLIES

- ±0.05% Output regulation
- 100% Burn-in
- Low Output Ripple
- Remote Sense Provided

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Power-One Part No.	Case Style	Remote Sensor Provided	Dimensions: in.	Output 1	Output 2	Output 3	Price Each		
								1	10	25
Single Output										
784-HB5-3/OVP-AG	HB5-3/OVP-AG	B	Yes	4.87 x 4.00 x 2.10	5V@3.0A	---	---	54.59	51.13	49.48
784-HC5-6/OVP-AG	HC5-6/OVP-AG	C	Yes	5.62 x 4.87 x 2.95	5V@6.0A	---	---	83.00	77.23	74.86
784-HD5-12/OVP-AG	HD5-12/OVP-AG	D	Yes	9.00 x 4.87 x 3.28	5V@12.0A	---	---	127.99	120.31	115.45
784-HA15-0.9-AG	HA15-0.9-AG	B	No	4.87 x 4.00 x 2.10	12V@0.9A	---	---	49.00	47.00	45.00
784-HB12-1.7-AG	HB12-1.7-AG	B	Yes	4.87 x 4.00 x 2.10	12V@1.7A	---	---	51.50	47.54	46.15
784-HB15-1.5-AG	HB15-1.5-AG	B	Yes	4.87 x 4.00 x 2.10	15V@1.5A	---	---	52.00	49.00	48.00
784-HC12-3.4-AG	HC12-3.4-AG	C	Yes	5.62 x 4.87 x 2.95	12V@3.4A	---	---	76.00	71.29	68.15
784-HN12-5.1-AG	HN12-5.1-AG	N	Yes	7.00 x 4.87 x 3.28	12V@5.1A	---	---	106.00	100.00	97.00
784-HD12-6.8-AG	HD12-6.8-AG	D	Yes	9.00 x 4.87 x 3.28	12V@6.8A	---	---	120.99	112.87	108.97
784-F15-15-AG	F15-15-AG	F	Yes	16.75 x 4.88 x 5.00	12V@16.0A	---	---	277.00	260.00	252.00
784-HC15-3-AG	HC15-3-AG	C	Yes	5.62 x 4.87 x 2.95	15V@3.0A	---	---	76.00	71.29	68.15
784-HB24-1.2-AG	HB24-1.2-AG	B	Yes	4.87 x 4.00 x 2.10	24V@1.2A	---	---	53.13	48.58	47.52
784-HC24-2.4-AG	HC24-2.4-AG	C	Yes	5.62 x 4.87 x 2.95	24V@2.4A	---	---	76.00	71.29	68.15
784-HN24-3.6-AG	HN24-3.6-AG	N	Yes	7.00 x 4.87 x 3.28	24V@3.6A	---	---	88.82	82.01	79.54
784-HD24-4.8-AG	HD24-4.8-AG	D	Yes	9.00 x 4.87 x 3.28	24V@4.8A	---	---	105.95	102.78	100.57
784-HE5-18/OVP-AG	HE5-18/OVP-AG	E	Yes	14.00 x 4.87 x 3.53	5V@18.0A	---	---	192.00	180.00	172.00
784-HE24-7.2-AG	HE24-7.2-AG	E	Yes	14.00 x 4.87 x 3.53	24V@7.2A	---	---	166.01	154.46	149.86
784-F24-12-AG	F24-12-AG	F	Yes	16.75 x 4.88 x 5.00	24V@12.0A	---	---	277.01	259.71	252.76
784-HC28-2-AG	HC28-2-AG	C	Yes	5.62 x 4.87 x 2.95	28V@2.0A	---	---	66.09	64.19	62.93
Dual Output										
784-HAA15-0.8-AG	HAA15-0.8-AG	AA	Yes	6.50 x 4.00 x 2.10	15V@0.8A	-15V@0.8A	---	65.00	60.89	58.45
784-HAA24-0.6-AG	HAA24-0.6-AG	AA	Yes	6.50 x 4.00 x 2.10	24V@0.6A	-24V@0.6A	---	70.00	66.00	64.00
784-HBB15-1.5-AG	HBB15-1.5-AG	BB	Yes	7.00 x 4.87 x 2.95	12V@1.7A	-12V@0.7A	---	83.00	77.23	74.86
784-HCC5-6/OVP-AG	HCC5-6/OVP-AG	CC	Yes	9.38 x 4.87 x 3.28	5V@6.0A	-5V@6.0A	---	148.00	138.00	135.00
784-HCC15-3-AG	HCC15-3-AG	CC	Yes	9.38 x 4.87 x 3.28	12V@3.4A	-12V@3.4A	---	148.49	136.12	128.95
784-HDD15-5-AG	HDD15-5-AG	E	Yes	14.00 x 4.87 x 3.53	15V@5.0A	-15V@5.0A	---	204.00	192.00	186.00
784-HAD15-0.4-AG	HAD15-0.4-AG	B	No	4.87 x 4.00 x 2.10	15V@0.4A	-15V@0.4A	---	48.65	47.25	45.50
Triple Output										
784-HBAA-40-W-AG	HBAA-40-W-AG	BAA	Yes	10.25 x 4.00 x 2.95	5V@3.0A	12V@1.0A	-5V@0.4A	103.00	99.70	96.51
784-HCAA-60W-AG	HCAA-60W-AG	D	Yes	9.00 x 4.87 x 3.28	5V@6.0A	12V@1.0A	-12V@1.0A	136.00	123.28	118.54
784-HCBB-75W-AG	HCBB-75W-AG	CBB	Yes	11.00 x 4.87 x 3.28	5V@6.0A	12V@1.7A	-12V@1.7A	139.00	131.93	128.70
784-HDCC-150W-AG	HDCC-150W-AG	DCC	Yes	15.00 x 4.88 x 4.55	5V@12.0A	15V@3.0A	-15V@3.0A	248.00	230.00	225.00
784-HTAA-16W-AG	HTAA-16W-AG	AA	No	6.50 x 4.00 x 2.10	5V@2.0A	12V@0.4A	-12V@0.4A	86.45	78.69	75.00

AC-DC OVERVOLTAGE PROTECTION OPTION

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Power-One Part No.	Includes	Price Each		
			1	10	25
784-OVP-12G	OVP-12G	6.4-34V For use with peak current linear power supplier models	12.53	12.22	12.03