


SOLAHD Linear Power Supplies

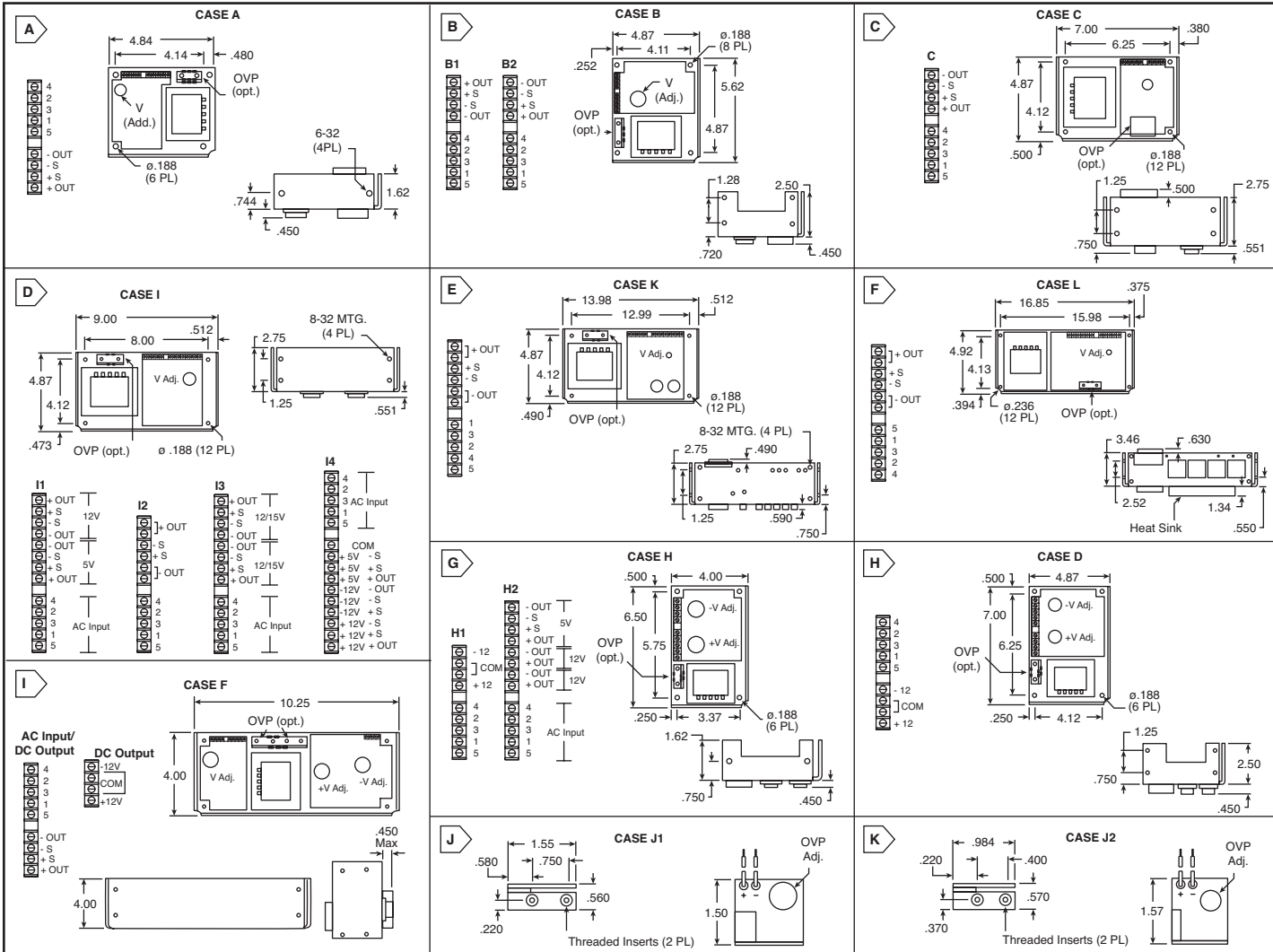

DIMENSIONS: in.

RoHS Compliant This product is RoHS compliant.



SOLAHD SILVER LINE SERIES - SINGLE & MULTI-OUTPUT LINEARS


The Silver Line series follows the industry accepted foot-print for open frame, linear power supplies. SolaHD improves on this design by offering standard screw terminal connections and optional covers for safety considerations.

Features:

- Two Year Warranty
- Low Noise, Extremely Quiet DC Output
- Universal Input and Approvals (115/230VAC)
- For Noise Sensitive or Analog Circuitry
- Short Circuit Protected
- Built-in OVP on 5V Models and Optional on 12, 15, and 24V Models
- Easy-To-Install Screw Terminal Connections
- Automatic Resetting Overload Protection
- Industry Standard Footprint
- Fast Transient Response, Ideal for Test Applications



RoHS Compliant

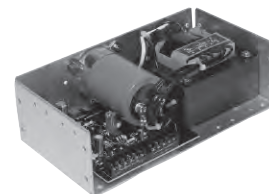

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	SolaHD Part No.	Fig.	Case Style	Output 1	Output 2	Output 3	Built-In OVP	Price Each		
								1	5	10
Single Output										
663-SLS-05-030-1T	SLS-05-030-1T	A	A	5V @ 3A*	---	---	Yes	59.40	57.23	55.60
663-SLS-05-060-1T	SLS-05-060-1T	B	B1	5V @ 6A*	---	---	Yes	90.74	87.20	83.93
663-SLS-12-017T	SLS-12-017T	A	A	12V @ 1.7A or 15V @ 1.5A *	---	---	No	60.91	58.55	56.34
663-SLS-12-034T	SLS-12-034T	B	B1	12V @ 3.4A *	---	---	No	86.86	83.47	80.34
663-SLS-24-012T	SLS-24-012T	A	A	24V @ 1.2A *	---	---	No	63.49	61.75	59.32
663-SLS-24-024T	SLS-24-024T	B	B2	24V @ 2.4A *	---	---	No	90.53	88.05	84.57
663-SLS-24-036T	SLS-24-036T	C	C	24V @ 3.6A *	---	---	No	131.05	127.46	122.43
663-SLS-24-048T	SLS-24-048T	D	I2	24V @ 4.8A *	---	---	No	168.70	162.49	157.88
663-SLS-24-072T	SLS-24-072T	E	K	24V @ 7.2A *	---	---	No	191.85	186.60	179.23
663-SLS-24-120T	SLS-24-120T	F	L	24V @ 12.0A*	---	---	No	250.15	240.40	231.39
Dual Output										
663-SLD-12-1010-12T	SLD-12-1010-12T	G	H1	12V @ 1A or 15V @ .8A	-12V @ 1A or -15V @ .8A	---	No	73.22	70.53	68.54
663-SLD-12-1818-12T	SLD-12-1818-12T	H	D	12V @ 1.8A or 15V @ 1.5A	-12V @ 1.8A or -15V @ 1.5A	---	No	102.40	98.41	94.72
663-SLD12-3434-12T	SLD-12-3434-12T	D	I3	12V @ 3.4A*	-12V @ 3.4A *	---	No	145.45	141.34	138.28
663-SLD12-6034-05T	SLD12-6034-05T	D	I1	5V @ 6A *	12V @ 3.4A *	---	V1	154.70	150.35	147.08
663-SLD15-3030-15T	SLD15-3030-15T	D	I3	15V @ 3A *	-15V @ 3A *	---	No	148.62	144.54	138.84
Triple Output										
663-SLT12-20404-12T	SLT12-20404-12T	G	H2	5V @ 2A	12V @ .4A or 15V @ .4A	-12V @ .4A or -15V @ .4A	V1	93.85	91.21	89.23
663-SLT12-31010-12T	SLT12-31010-12T	I	F	5V @ 3A *	12V @ 1A or 15V @ .8A *	-12V @ 1A or -15V @ .8A *	V1	122.93	118.40	115.04
Over Voltage Protector (OVP)										
663-SLO-12-000-1	SLO-12-000-1	J	J1	6.2V to 34V Adjustable @ 8A	For Cases B through K			17.99	17.41	16.11
663-SLO-12-000-TB	SLO-12-000-TB	K	J2	6.2V to 34V Adjustable @ 8	For Case A or Cases B through K (when used with a cover)			16.45	15.97	15.34