

ELPAC AC Adapters and Power Supplies

ICCNEXERGY 20 WATT EXTERNAL ADAPTER

Specifications:

- High Efficiency
- Fully Regulated DC Output
- Size: Dimensions: 3.45" (L) x 2.04" (W) x 1.30" (H)
- LED Indicator
- Output Connector: 760: Barrel Type (2.5x5.5x9.5mm)
- Six Foot DC Output Cord
- 85-264VAC
- AC Input Cord Included
- Safety Approval - EN60950-1 Class II
- Level V
- 5 Year Warranty



PRODUCT NEW



DIMENSIONS: in.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Efficiency	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
Class I - AC Input Connector 3 Pin IEC320 C14 Receptacle								
680	FWA020005B-10B	5V	4.0A	80%	35.31	33.05	30.99	27.04
680	FWA020009B-10B	9V	2.22A	83%	33.84	31.68	29.70	25.92
680	FWA020012B-10B	12V	1.67A	84%	32.20	30.15	28.27	24.67
680	FWA020024B-10B	24V	0.84A	86%	30.53	28.58	26.80	23.39
Class II - AC Input Connector 2 Pin IEC320 C8 Receptacle								
680	FWA020005A-10B	5V	4.0A	80%	35.68	33.41	31.32	27.33
680	FWA020009A-10B	9V	2.22A	83%	33.76	31.61	29.63	25.86
680	FWA020012A-10B	12V	1.67A	84%	31.79	29.76	27.90	24.35
680	FWA020024A-10B	24V	0.84A	86%	30.53	28.58	26.80	23.39

ICCNEXERGY 30 WATT SINGLE OUTPUT ADAPTER



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Power	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
30 Watt Adapter (4.25L x 2.50W x 1.30H)								
680	FWC3009-760F	9V	3.33A	30W	45.65	42.00	39.57	37.15
680	FWC3012-760F	12V	2.5A	30W	44.89	41.15	35.73	33.84
680	FWC3015-760F	15V	2.0A	30W	40.16	36.28	33.51	31.17
680	FWC3024-760F	24V	1.25A	30W	42.18	40.10	34.00	32.12

ICCNEXERGY 50 WATT SINGLE OUTPUT ADAPTER




For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Power	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
50 Watt Adapters (5.0L x 3.0W x 1.30H)								
680	FWC5012-760F	12V	4.15A	50W	47.72	45.24	42.76	40.79
680	FWC5018-760F	18V	2.75A	50W	47.53	44.15	40.78	37.92
680	FWC5024-760F	24V	2.10A	50W	52.98	47.71	42.44	39.47

ICCNEXERGY 65-72 WATT SINGLE OUTPUT ADAPTER

Specifications:

- High Efficiency
- High Power Density 4.9W/in³
- Hold-up Time >25ms at full load
- Safety Approval - EN60950-1 Class I
- ENERGY STAR Level V
- EISA Compliant
- CEC Compliant
- Input Connector: IEC 320 C14 Receptacle
- Output Connector: Din-5 Male Pins
- Standard Output Cable: 9V=4ft; 12V, 18V, & 24V = 6ft
- 5 Year Warranty

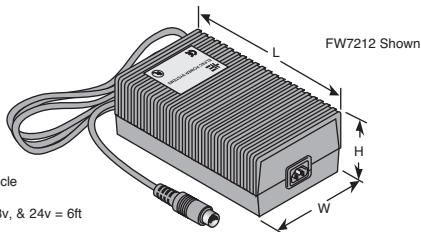

FW7212 Shown



DIMENSIONS: in.


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Power	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
65 Watt Adapter (5.02L x 2.20W x 1.37H)								
680	FWA065009A-11B	9.0V	8.0A	65W	60.55	54.32	50.03	47.56
680	FWA065012A-11B	12V	6.0A	65W	53.36	50.72	47.42	44.12
680	FWA065015A-11B	15V	4.8A	65W	58.91	57.33	52.12	49.55
680	FWA065024A-11B	24V	3.0A	65W	62.12	55.73	51.86	49.30

ICCNEXERGY SINGLE OUTPUT REGULATED POWER SUPPLIES

Specifications:

- Input Voltage: 85-264VAC
- Input Connector: 2 Pin NEMA 5/15 plug
- Output Connector: Barrel Type (2.5x5.5x9.5mm center positive)
- Six Foot DC Output Cord
- 5 Year Warranty

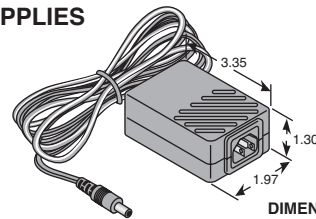

DIMENSIONS: in.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Power	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
18 Watt Adapter (3.35" L x 1.97" W x 1.30" H)								
680	FW1805-760F	5V	3A	18W	31.20	27.24	24.43	22.72
680	FW1824-760F	24V	0.8A	18W	32.87	28.39	25.59	23.00
30 Watt Adapter (4.25" L x 2.50" W x 1.30" H)								
680	FW3012-760F	12V	2.5A	30W	40.25	37.12	32.47	30.87
680	FW3015-760F	15V	2.0A	30W	45.17	41.70	38.25	36.06
680	FW3024-760F	24V	1.3A	30W	43.88	40.41	37.72	35.46

ICCNEXERGY 100 WATT SINGLE OUTPUT ITE DESKTOP POWER SUPPLY

Specifications:

- High Efficiency: Level V
- High Power Density: 4.2W/in³
- Hold-up Time: >48ms at full load
- Output connector: 18V, 24V, 48V = Din-5 12V, 15V = Din-8
- Power factor correction
- LED indicator
- Class 1
- 5 Year Warranty



DIMENSIONS: in.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Power	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
100 Watt Adapter (7.09L x 2.27W x 1.52H)								
680	FWC100012A-12B	12V	8.3A	100W	79.35	74.23	72.14	70.16
680	FWC100015A-12B	15V	6.6A	100W	79.35	74.23	72.14	70.16
680	FWC100018A-11B	18V	5.5A	100W	81.12	75.88	73.76	71.73
680	FWC100024A-11B	24V	4.1A	100W	78.34	73.29	71.22	69.27
680	FWC100048A-11B	48V	2.0A	100W	79.36	74.24	72.16	70.19

ICCNEXERGY 150 WATT SWITCH MODE POWER SUPPLY

Specifications:

- High Efficiency
- Fully Regulated DC Output
- Lifetime Expectation >5 years
- Hold-up Time >12ms at full load
- Safety Approval - EN60950-1 Class
- ENERGY STAR Level V
- 5 Year Warranty
- Output Connector - Din-8 Male Pins
- 4 ft. DC Output cord for 12V and 15V
- 6 ft. DC Output cord for 18V and 24V
- Level V



DIMENSIONS: in.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Power	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
150 Watt Adapter (7.43L x 2.45W x 1.52H)								
680	FWA150012A-12B	12V	12.5A	150W	101.12	97.86	89.27	80.69
680	FWA150015A-12B	15V	10A	150W	105.91	97.67	88.43	82.24
680	FWA150018A-12B	18V	8.3A	150W	106.25	101.85	93.55	85.25
680	FWA150024A-12B	24V	6.3A	150W	106.67	103.23	95.37	87.52
680	FWA150048A-11B	48V	3.2A	150W	97.01	91.78	85.39	81.33

ICCNEXERGY 220 WATT EXTERNAL ADAPTER

Specifications:

- Level V, EISA, EuP Directive Compliant
- High Efficiency
- High Power Density 5.9W/in³
- Hold-up Time > 25ms at full load
- 5-Year Limited Warranty
- LED Status Indicator
- IPX1 Rated



DIMENSIONS: in.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Output Voltage	Output Current	Efficiency	Price Each			
Mfr.	Mfr. Part No.				1	5	10	25
680	FWA220012A-13B	12V	18.3A	89%	148.90	139.39	130.68	114.05
680	FWA220018A-13B	18V	12.2A	90%	148.93	139.43	130.71	114.08
680	FWA220024A-12B	24V	9.2A	90%	146.60	137.25	128.67	112.29
680	FWA220048A-11B	48V	4.6A	91%	138.88	130.01	121.89	106.37