


PHIHONG AC Adapters and LED Drivers



This page of product is compliant.

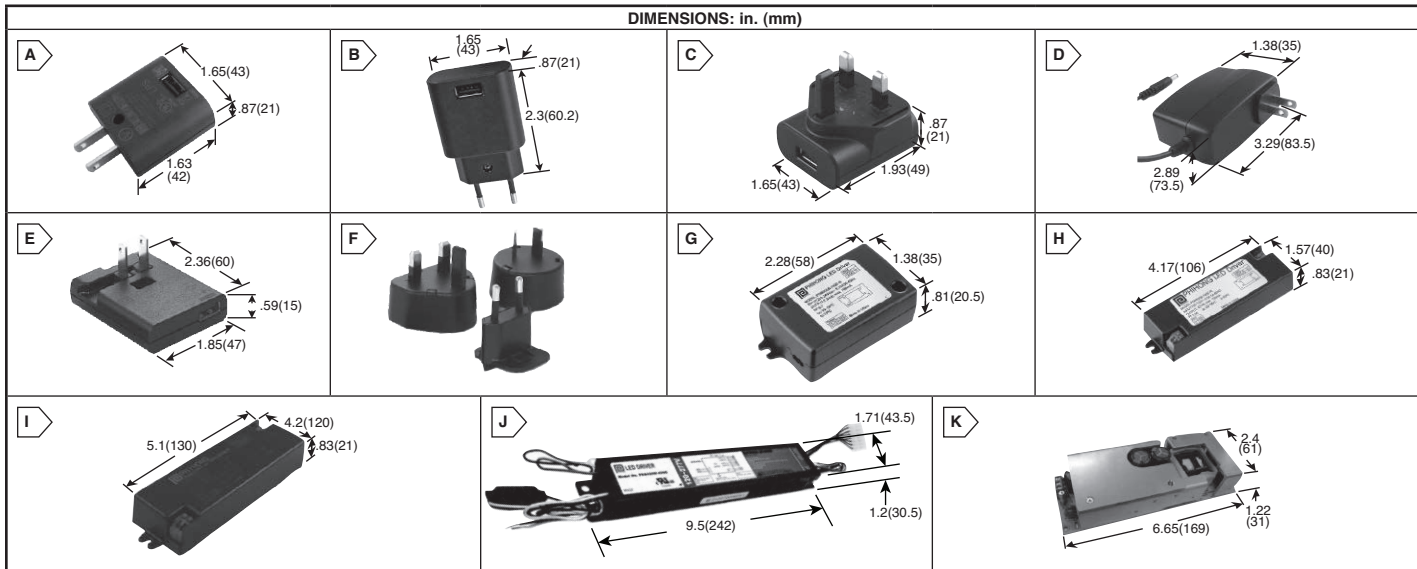

PHIHONG PSM03A 2.75 WATT FIXED BLADE USB CHARGER

Specifications:

- AC input voltage: 90-264VAC
- Efficiency: 63.7% min. avg.
- Output connector: USB A
- Level V Compliant
- 5 star stand by power LO.03W
- No Y cap



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Phihong Part No.	Fig.	DC Output Voltage	Load		Ripple P-P (max.)	Regulation L-L	Price Each			
				Min.	Max.			1	5	25	100
US Plug • CUL / UL Approval											
552-PSM03A-050Q-3-R	PSM03A-050Q-3-R	A	5V	0A	0.55A	100mV	±5%	4.46	4.23	4.03	3.82
European Plug • CE Approval											
552-PSM03E-050Q-3-R	PSM03E-050Q-3-R	B	5V	0A	0.55A	100mV	±5%	5.24	4.94	4.68	4.54
UK Plug • CE Approval											
552-PSM03K-050Q-3-R	PSM03K-050Q-3-R	C	5V	0A	0.55A	100mV	±5%	5.42	5.11	4.84	4.69

PHIHONG PSA24A 24 WATT WALL PLUG-IN ADAPTER

Specifications:

- AC input voltage: 90-264VAC
- Efficiency: 80% min. avg.
- Output connector: 2.1x5.5mm, center positive
- Level V Compliant
- Over-voltage, over-current protection



For quantities greater than listed, call for quote.

552-PSA-24A-120-R	PSA24A-120(P)-R	D	12V	0A	2.0A	150mV	±5%	16.96	15.96	14.96	13.60
-------------------	-----------------	---	-----	----	------	-------	-----	-------	-------	-------	-------

PHIHONG F-SERIES 3-10 WATT FOLDING BLADE ADAPTERS

Specifications:

- AC input voltage: 90-264VAC
- Efficiency: 68% min. avg.
- Output connector: USB A
- Level V Compliant
- Erp Directive 2009/125/EC level 2 annex Ib Compliant



For quantities greater than listed, call for quote.

*D+/D- † Drop Compensation

PSA03F Series		Fig.	DC Output Voltage	Min.	Max.	Ripple P-P (max.)	Regulation L-L	Price Each			
MOUSER STOCK NO.	Phihong Part No.							1	5	25	100
552-PSA03F-050Q-R	PSA03F-050Q-R	E	5V	0A	0.6A	100mV	±5%	6.77	6.43	6.11	5.81
PSA05F Series		Fig.	DC Output Voltage	Min.	Max.	Ripple P-P (max.)	Regulation L-L	Price Each			
MOUSER STOCK NO.	Phihong Part No.							1	5	25	100
552-PSA05F-050-R	PSA05F-050Q-H	E	5V	0A	1.0A	100mV	±5%	7.90	7.50	7.00	6.67
* 552-PSA05F-050Q-AG-R	PSA05F-050Q(AG)-R	E	5V	0A	1A	100mV	±5%	7.66	7.27	6.91	6.49
PSA10F Series		Fig.	DC Output Voltage	Min.	Max.	Ripple P-P (max.)	Regulation L-L	Price Each			
MOUSER STOCK NO.	Phihong Part No.							1	5	25	100
552-PSA10F-050Q-R	PSA10F-050Q-R	E	5V	0A	2A	100mV	±5%	14.46	13.02	11.71	10.54
† 552-PSA10F-050Q(D)-R	PSA10F-050Q(D)-R	E	5V	0A	2A	100mV	±5%	14.46	13.02	11.71	10.54
* 552-PSA10F-050Q(S)-R	PSA10F-050Q(S)-R	E	5V	0A	2A	100mV	±5%	14.46	13.02	11.71	10.54

PHIHONG F-SERIES AC PLUG

For PSA05F Series (Adapters Sold Separately)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Phihong Part No.	Fig.	Description	Price Each			
				1	5	25	100
552-FPB-R	FPB-H	F	Brazil Plug	1.12	1.03	.944	.891
552-FPC-R	FPC-H	F	China Plug	.95	.874	.801	.756
552-FPH-R	FPH-R	F	Korea Plug	1.12	1.03	.944	.891
552-FPI-R	FPI-R	F	India Plug	1.48	1.38	1.28	1.19
552-FPE-R	FPE-R	F	European Plug	1.12	1.03	.978	.898



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Phihong Part No.	Fig.	Description	Price Each			
				1	5	25	100
552-FPN-R	FPN-H	G	Argentina Plug	1.94	1.78	1.63	1.54
552-FPK-R	FPK-R	G	UK Plug	1.40	1.31	1.21	1.12
552-FPS-R	FPS-R	G	Australian Plug	1.60	1.49	1.38	1.28
552-FPKIT-R	FPKIT-R	G	Kit w/ Euro, UK, Aus. plugs	3.58	3.32	3.08	2.84

PHIHONG 6-90 WATT LED DRIVERS

Features:

- OV P and short circuit protection
- UL8750 Compliant
- Brownout/Brownout Recovery



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Phihong Part No.	Fig.	DC Output Voltage Range			Output Current Range			Max Power	Price Each			
			Min.	Type.	Max.	Min.	Typ.	Max.		1	5	25	100
AC Input Voltage: 90-132VAC • Non-Dimmable Driver • Constant Current													
552-PDA006B-700C-H	PDA006B-700C-H	G	2.5V	-	7.5V	650A	700A	750A	5.6W	15.53	14.25	13.06	12.34
552-PDA010B-700C-H	PDA010B-700C-H	H	7.5V	-	12V	650A	700A	750A	9W	35.73	32.79	30.06	28.37
552-PDA015B-350C-H	PDA015B-350C-H	I	17.5V	-	42V	300A	350A	400A	16.8W	44.23	40.59	37.21	35.13
552-PDA030B-700C-H	PDA030B-700C-H	I	15V	-	42V	650A	700A	750A	31.5W	70.87	65.03	59.61	56.28
AC Input Voltage: 108-304VAC • Dimmable • Constant Current • 4 Channel Output													
552-PDA037W-350G-R	PDA037W-350G-R	J	22V	24.5V	26.5V	333mA	350mA	368mA	37W	81.79	70.17	59.18	53.18
552-PDA050W-450G-R	PDA050W-450G-R	J	22V	24.5V	26.5V	430mA	453mA	476mA	49W	91.79	82.23	74.27	59.69
AC Input Voltage: 90-304VAC • Open Frame LED Driver Non-Dimming • Constant Voltage													
552-PSM090-240P-R	PSM090-240P-R	K	22.8V	24V	25.2V	0.2A	-	3.75A	90W	103.71	95.17	87.24	82.36