


CORCOM Power Filters

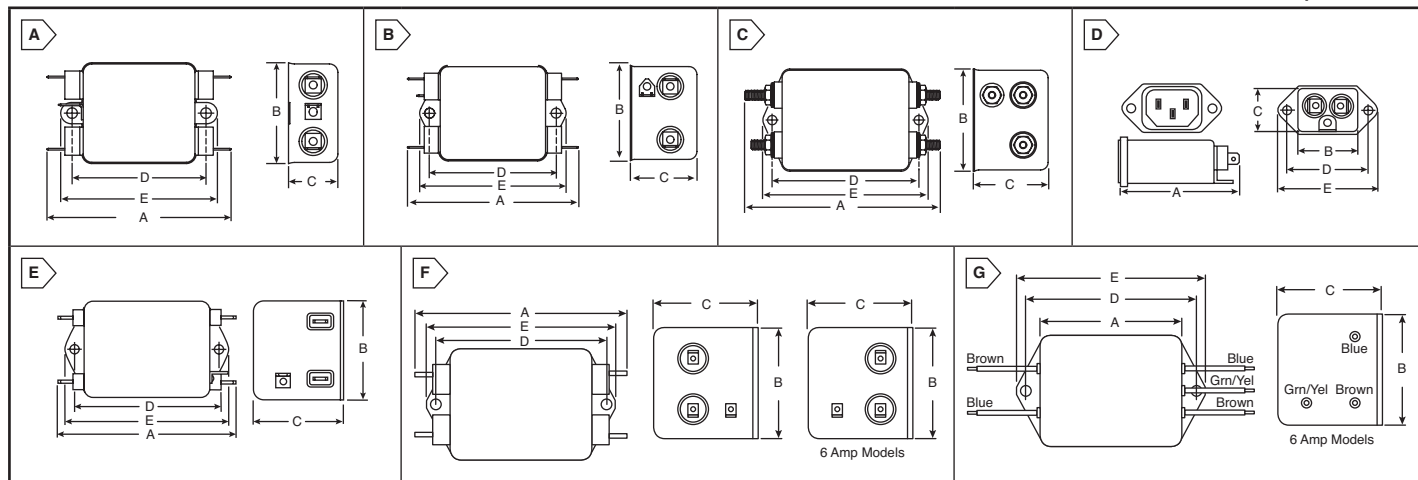

SB SERIES

High Performance B Series Power Line Filters

• 6 to 30 Amps; 250 Volts AC/250 Volts DC; 50/60Hz

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Corcom Part No.	Fig.	Amps	Input/Output Style	Dimensions: in. (mm)					Price Each			
					A (max)	B (max)	C (max)	D ±.015 (±.38)	E (max)	1	25	50	100
Low Leakage (<0.5mA) Current Designation													
592-6ESB1	6ESB1	A	6	.250 terminals	3.36 (85.34)	1.82 (46.23)	.91 (23.11)	2.375 (60.325)	2.78 (70.61)	13.96	12.70	11.65	10.74
592-10ESB1	10ESB1	B	10	.250 terminals	3.36 (85.34)	1.82 (46.23)	1.28 (32.51)	2.375 (60.325)	2.78 (70.61)	14.67	13.36	12.27	11.33
592-10ESB6	10ESB6	C	10	Threaded Bolt	3.47 (88.14)	1.82 (46.23)	1.53 (38.86)	2.375 (60.325)	2.78 (70.61)	20.01	18.23	16.73	15.46
592-20ESB1	20ESB1	B	20	.250 terminals	3.85 (97.79)	2.07 (52.58)	1.31 (33.27)	2.938 (74.625)	3.35 (85.09)	20.00	18.21	16.72	15.45
592-20ESB6	20ESB6	C	20	Threaded Bolt	4.0 (101.6)	2.07 (52.58)	1.53 (38.86)	2.938 (74.625)	3.35 (85.09)	25.43	23.16	21.26	19.65
592-30ESB6	30ESB6	C	30	Threaded Bolt	4.92 (124.97)	2.07 (52.58)	1.53 (38.86)	3.947 (100.254)	4.33 (109.98)	48.56	39.64	38.40	37.16
Standard Leakage Current Designation													
592-6VSB1	6VSB1	A	6	.250 terminals	3.36 (85.34)	1.82 (46.23)	.91 (23.11)	2.375 (60.325)	2.78 (70.61)	11.97	10.90	10.01	9.24
592-10VSB1	10VSB1	B	10	.250 terminals	3.36 (85.34)	1.82 (46.23)	1.28 (32.51)	2.375 (60.325)	2.78 (70.61)	13.36	12.17	11.17	10.32
592-20VSB1	20VSB1	B	20	.250 terminals	3.85 (97.79)	2.07 (52.58)	1.31 (33.27)	2.938 (74.625)	3.35 (85.09)	22.20	20.18	18.18	16.80
592-20VSB6	20VSB6	C	20	Threaded Bolt	4.0 (101.6)	2.07 (52.58)	1.53 (38.86)	2.938 (74.625)	3.35 (85.09)	27.38	24.94	22.89	21.16

EC SERIES FILTERS

High Performance Compact RFI Power Line Filters with IEC Connectors

• 3 to 10 Amps; 120/250 Volts AC; 50/60Hz

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Corcom Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-3EC1	3EC1	D	3	2.62 (66.5)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	18.25	17.73	16.08	15.55
592-6EC1	6EC1	D	6	2.62 (66.5)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	18.62	17.57	16.20	15.06
592-10EC1	10EC1	D	10	2.62 (66.5)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	19.60	18.40	17.09	15.79

T SERIES FILTERS

High Performance RFI Power Line Filters for Switching Power Supplies

• 6 to 20 Amps; 120/250 Volts AC; 50/60Hz

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Corcom Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-6ET1	6ET1	E	6	3.85 (97.4)	2.15 (54.6)	1.81 (46.0)	2.938 (74.63)	3.38 (85.9)	35.83	33.07	30.72	28.66
592-10ET1	10ET1	E	10	4.69 (119.1)	2.27 (57.7)	1.80 (45.7)	4.063 (103.2)	4.47 (113.5)	54.58	50.66	46.87	43.84
592-10VT1	10VT1	E	10	4.69 (119.1)	2.27 (57.7)	1.80 (45.7)	4.063 (103.2)	4.47 (113.5)	54.80	47.72	44.37	41.40

Q SERIES FILTERS

High Performance RFI Filters for Switching Power Supplies

• 1 to 20 Amps; 120/250 Volts AC; 50/60Hz

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Corcom Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-3VQ1	3VQ1	F	3	3.85 (97.8)	2.07 (52.6)	1.78 (45.2)	2.938 (74.63)	3.34 (84.8)	47.00	44.38	40.94	38.05
592-3VQ3	3VQ3	G	3	2.56 (65.0)	2.07 (52.6)	1.78 (45.2)	2.938 (74.63)	3.34 (84.8)	44.94	43.15	40.90	37.52
592-6EQ1	6EQ1	F	6	4.98 (126.5)	2.27 (57.7)	1.80 (45.7)	4.063 (103.2)	4.47 (113.5)	72.82	68.77	63.50	58.95
592-6EQ3	6EQ3	G	6	3.69 (93.7)	2.27 (57.7)	1.80 (45.7)	4.063 (103.2)	4.47 (113.5)	63.68	60.12	55.45	51.49
592-20EQ1	20EQ1	F	20	6.66 (168.1)	2.07 (52.6)	2.28 (57.9)	5.625 (142.9)	6.00 (153.2)	93.15	87.84	81.13	75.40
592-20VQ1	20VQ1	F	20	6.66 (168.1)	2.07 (52.6)	2.28 (57.9)	5.625 (142.9)	6.03 (153.2)	89.14	84.07	76.94	71.84