

APC J TYPE POWER CONDITIONERS WITH BATTERY BACKUP


• Output Connections: (2) NEMA 5-15R

PRODUCT **NEW**



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	APC Part No.	No. of Outlets	Model	Dimensions: H x W x D in.	Output Capacity	Price Each
679-J35B	J35B	8	Power Conditioners with Battery Backup	97.60 x 431.80 x 406.40	1500VA / 865w	605.00

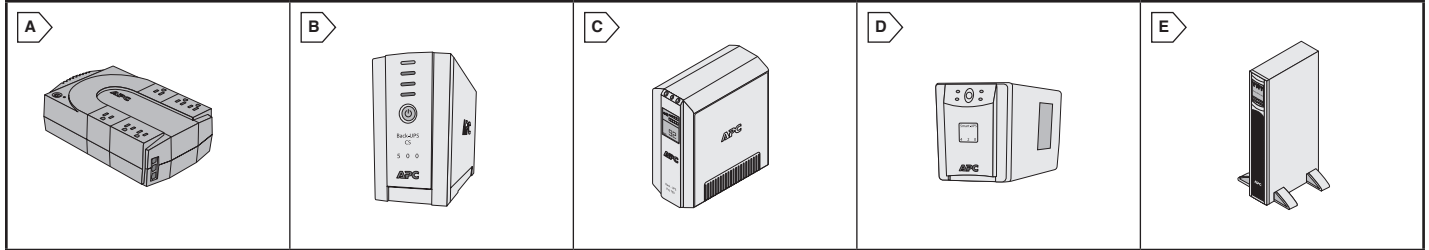

APC BACK-UPS


Back up power solutions from desktop to datacenter to custom-built industrial UPS system

- Input / Output Volts = 120V / 20V
- Input Plug - NEMA 5-15P
- SMT2200 - NEMA 5-20P
- SMT3000 - NEMA L5-30P

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	APC Part No.	Fig.	No. of Outlets	Model	Dimensions: H x W x D in.	Output Power Capacity	Recommended Replacement Battery	Backup Time Half/Full Load	Price Each
679-BE450G	BE450G	A	8	Back-UPS ES	3.50 x 7.00 x 12.00	450VA / 257W	- - -	11.6min / 2.5 min.	64.40
679-BE550G	BE550G	A	8	Back-UPS ES	3.50 x 7.00 x 12.00	550VA / 330W	APCRBC110	13.5min / 3.3 min.	74.03
679-BE750G	BE750G	A	10	Back-UPS ES	3.48 x 7.09 x 13.49	750VA / 450W	RBC17	11.3min. / 2.3 min.	105.00
679-BK350	BK350	B	6	Back-UPS CS	6.50 x 3.60 x 11.20	350VA / 210W	RBC2	18.1min. / 4.7 min.	104.00
679-BK500	BK500	B	6	Back-UPS CS	6.50 x 3.60 x 11.20	500VA / 300W	RBC2	13.9min. / 3.4 min.	129.63
679-BR700G	BR700G	C	6	Power-Saving Back-UPS RS	7.48 x 3.58 x 12.20	700VA / 420W	RBC17	12.0min. / 3.0 min.	141.58
679-BR1000G	BR1000G	C	8	Power-Saving Back-UPS RS	9.84 x 3.94 x 15.04	1000VA / 600W	APCRBC123	20.0 min. / 7.0 min.	170.00
679-BR1500G	BR1500G	B	10	Power-Saving Back-UPS RS	14.60 x 3.40 x 13.10	1500VA / 865W	RBC33	15.4min. / 5.1 min.	262.50
679-SC420	SC420	D	4	Smart-UPS SC	6.60 x 4.70 x 14.50	420VA / 260W	RBC2	13.5min. / 5.5 min.	141.40
679-SC620	SC620	D	4	Smart-UPS SC	6.60 x 4.70 x 14.50	620VA / 390W	RBC4	15.7min. / 5.5 min.	200.04
679-SMT750	SMT750	C	6	Power-Saving Smart-UPS	6.30 x 5.40 x 14.10	750VA / 500W	RBC48	15.9min. / 4.6 min.	329.29
679-SMT1000	SMT1000	C	8	Power-Saving Smart-UPS	8.50 x 6.70 x 17.30	1000VA / 670W	RBC6	20.6min. / 6.1 min.	459.00
679-SMT1500	SMT1500	C	8	Power-Saving Smart-UPS	8.50 x 6.70 x 17.30	1440VA / 980W	RBC7	23.9min. / 6.7 min.	569.50
679-SMT2200	SMT2200	C	*10	Power-Saving Smart-UPS	17.00 x 7.70 x 21.50	2200VA / 1980W	RBC55	24.0min. / 7.0 min.	939.27
679-SMT3000	SMT3000	C	*10	Power-Saving Smart-UPS	17.00 x 7.70 x 21.50	3000VA / 2700W	RBC55	14.0min. / 6.0 min.	1230.65
679-SMX750	SMX750	E	8	Power-Saving Smart-UPS	17.00 x 3.50 x 19.30	750VA / 600W	APCRBC116	24.0min. / 12.0 min.	520.53
679-SMX1000	SMX1000	E	8	Power-Saving Smart-UPS	17.00 x 3.50 x 19.30	1000VA / 800W	APCRBC116	20.0min. / 8.0 min.	636.60
679-SMX1500RM2U	SMX1500RM2U	E	8	Power-Saving Smart-UPS	3.50 x 17.00 x 19.30	1500VA / 1200W	APCRBC115	14.0min. / 5.0 min.	794.60

*10 Output Connections: (8) NEMA 5-12R & (2) NEMA 5-20R

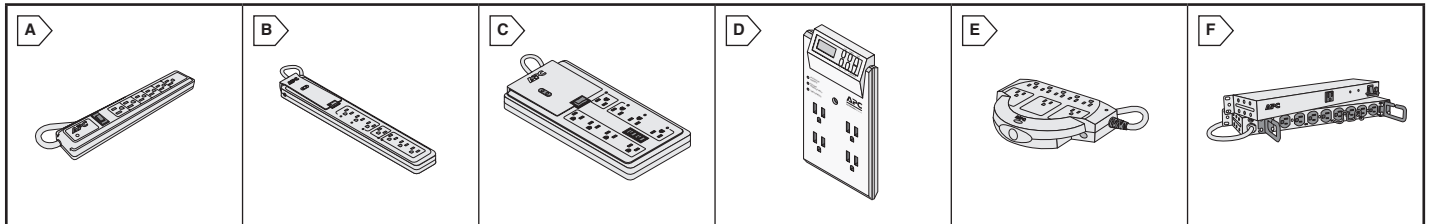


APC SURGE PROTECTION AND CONDITIONING

Safeguard your equipment from everyday power surges, lightning strikes and other power anomalies

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	APC Part No.	Fig.	No. of Outlets	Category	Description	Price Each
679-P7T	P7T	A	7	Basic Surge Protectors - A	490 joules, data line protection, 6' cord, black	15.86
679-P7GB	P7GB	B	7	Power-Saving Essential SurgeArrest	1020 joules, "power-saving" outlets, data line protection, 4' cord, white	26.23
679-P8GT	P8GT	C	8	Power-Saving Home/Office SurgeArrest	with phone protection	29.99
679-P4GC	P4GC	D	4	Power-Saving Surge Protectors	1020 joules, LCD Timer controls all 4 outlets	18.90
679-P6GC	P6GC	D	6	Power-Saving Surge Protectors	1020 joules, LCD timer controls 5 outlets. 1 continous	20.00
679-PRO8	PRO8	E	8	SurgeArrest Professional	320 joules, beige	24.99
679-NET9RMBLK	NET9RMBLK	F	9	SurgeArrest Rack Mountable	1700 joules, horizontal or vertical mount, beige	98.00


APC LINE-R-HIGH PERFORMANCE POWER CONDITIONING

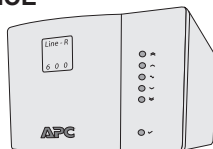

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	APC Part No.	Description	Price Each
679-LE600	LE600	600VA, 4NEMA 5-15R	46.19
679-LE1200	LE1200	1200VA, 4 NEMA 5-15R	56.84

APC PROTECTNET DATA LINE PROTECTORS

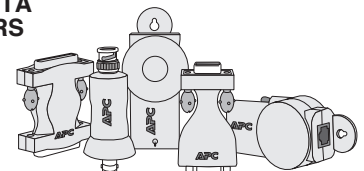

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	APC Part No.	Description	Price Each
679-PNET1GB	PNET1GB	RJ45 10/100/1000 Base-T ethernet prot.	22.37