

TRIPP LITE Power Protection and Mobile Power Solutions




RoHS Compliant This page of product is compliant.

PROTECT IT!™ SURGE SUPPRESSORS

Features:


- Protect all computers & home/office electronics
- Economical, reliable protection against damaging surges, spikes, and line noise
- Select models offer tel/modem, coaxial and/or ethernet surge protection
- Up to \$250,000 Ultimate Lifetime Insurance

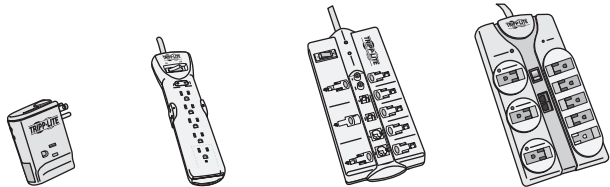

*NEW ECO-SURGE! Energy-saving outlet configuration reduces energy waste by cutting AC power to unused peripherals.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Joules	Cord Length	Price Each
545-TLP404	TLP404	4	390	4'	9.34
545-TLP602	TLP602	6	180	2'	7.84
545-TLP604TEL	TLP604TEL	6 + TEL/DSL	720	4'	12.31
545-TLP606	TLP606	6	720	6'	12.32
545-TLP808	TLP808	8	1440	8'	25.75
545-TLP808TELV	TLP808TELV	8 + TEL/DSL + COAX	2160	8'	43.98
* 545-TLP808NETG	TLP808NETG	8 + TEL/DSL	2160	8'	74.00
545-TLP810SAT	TLP810SAT	8 + TEL/DSL + 2 COAX	3240	10'	54.46
* 545-TLP1210SATG	TLP1210SATG	12 + TELa/DSL + 2 COAX	3600	10'	105.94
545-STRIKER	STRIKER	7	1080	6'	14.25
545-SUPER7	SUPER7	7	2160	7'	21.64
545-TRAVELER3USB	TRAVELER3USB	3 + 2 USB PORTS	540	18"	25.99

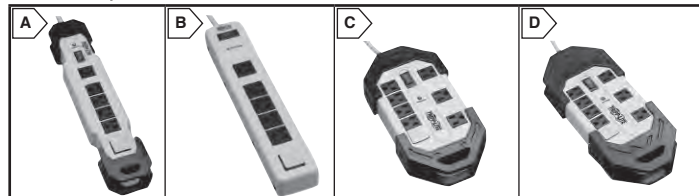

PROTECT IT!™ SAFETY SURGE SUPPRESSORS

Protect It!™ Safety Series Surge Suppressors and Power IT Safety Power Strips, provide industrial-strength surge and line-noise protection for a variety of tools and appliances.

Features:

- LED
- Transformer
- Input 120V (15A)
- Metal housings with safety OSHA yellow color
- Up to 3600 joules of surge protection
- Cord wrap with hang holes on select models
- Include outlet safety covers
- Up to \$100,000 Ultimate Lifetime Insurance

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Fig.	Outlets	Cord Length	Price Each
545-TLM609SA	TLM609SA	A	6	9'	36.90
545-TLM615SA	TLM615SA	A	6	15'	45.09
545-TLM626SA	TLM626SA	B	6	6'	23.92
545-TLM812SA	TLM812SA	C	8	12'	43.73
545-TLM825SA	TLM825SA	D	8	25'	63.27

POWER IT!™ SAFETY POWER STRIPS

- with out LED light


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Fig.	Outlets	Cord Length	Price Each
545-TLM609NS	TLM609NS	A	6	9'	28.70
545-TLM626NS	TLM626NS	B	6	6'	21.17
545-TLM815NS	TLM815NS	C	8	15'	43.73
545-TLM609GF	TLM609GF	A	6	9'	56.71
545-TLM812GF	TLM812GF	C	8	12'	64.23
545-TLM825GF	TLM825GF	D	8	25'	75.16

WABER BY TRIPP & POWER STRIPS

Features:

 - Ideal for industrial, office, school, and lab applications
- A seamless steel case with baked-on finish on select models
- Available in keyhole(K) or flange(F) mount



6SP

Outlet Strips

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Mounting Options	Body Length	Cord Length	Price Each
545-3SP	3SP	3	K/F	8.6"	6'	22.00
545-4SPDX	4SPDX	4	K	7.38"	6'	18.85
545-602	602	5	K/F	8.6"	6'	20.00
545-602-15	602-15	5	K/F	8.6"	15'	29.00
545-6NX6	6NX6	6	K	12.5"	6'	17.31
545-6SP	6SP	6	K/F	13.7"	6'	28.50
545-6SPDX	6SPDX	6	K	12.5"	6'	22.69
545-6SPDX-15	6SPDX-15	6	K	12.5"	15'	29.23
545-UL24CB-15	UL24CB-15	6	K/F	12.5"	15'	37.00
545-UL24RA-15	UL24RA-15	6 (90°)	K/F	12.5"	15'	38.00
545-UL620-15	UL620-15	6 (20A)	K/F	12.5"	15'	87.00
545-UL800CB-15	UL800CB-15	10	K/F	17.5"	15'	59.00

UTILITY POWER STRIPS WITH HOSPITAL GRADE RECEPTACLES

Features:

- Hospital-grade (HG) plug and receptacles
- Rackmount (1U) and strip formats
- PS-615-HGULTRA features GFCI protection



* UL60601-1/60950-1 Compliance


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Cord Length	Price Each
545-PS415HG	PS-415-HG	4	15'	70.38
545-PS-415-HGULTRA	PS-415-HGULTRA*	4	15'	109.74

POWER STRIPS AND POWER DISTRIBUTION UNITS

Features:

 - Mount in rack enclosures, along walls, or on desks or workbenches
- Rugged, all-metal cases stand up to the most demanding environments
- 1U rackmount models mount horizontally in a standard 19 inch rack




For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Length	Cord Length	Price Each
545-PS2408	PS2408	8	24"	15'	53.86
545-PS3612	PS3612	12	36"	15'	56.68
545-PS4816	PS4816	16	48"	15'	65.52
545-PS6020	PS6020	20	60"	15'	73.88
545-PS7224	PS7224	24	72"	15'	79.77
545-PS7224-20	PS7224-20	24 (20A)	72"	15'	98.47
545-PS3612-20HW	PS3612-20HW	12 (20A)	36"	Hardwire	51.87
1U Rackmount Models					
545-RS-1215	RS-1215	6 Front / 6 Rear	19"	15'	65.50
545-RS1215-20	RS-1215-20	6 Front / 6 Rear (20A)	19"	15'	88.86
545-RS1215-RA	RS-1215-RA	6 Front / 6 Rear (Right Angle)	19"	15'	66.24
545-RS0615-R	RS-0615-R	6 Rear	19"	15'	64.05
545-RS0615-F	RS-0615-F	6 Front	19"	15'	62.55
Power Distribution Units					
545-PDU1220	PDU1220	1 Front / 12 Rear (20A)	19"	15'	156.25

ISOBAR® PREMIUM SURGE SUPPRESSORS

Features:

- The world's most trusted premium surge suppressor - more than 15 million in use worldwide
- Isolated filter banks eliminate interference between connected equipment
- All-metal housings won't burn, melt or crack
- ULTRA models include diagnostic LED's
- Rackmount models fit standard 19" (1U) rack space
- Up to \$50,000 Ultimate Lifetime Insurance

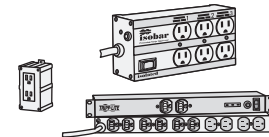

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Tripp Lite Part Number	Outlets	Joules	Cord Length	Price Each
545-ISOBAR8ULTRA	ISOBAR8ULTRA	8	3840	12'	85.81
545-ISOBAR4ULTRA	ISOBAR4ULTRA	4	3330	6'	59.60
545-ISOBAR6	ISOBAR6	6	3330	6'	58.25
545-ISOTEL-6ULTRA	ISOTEL6ULTRA	6+(2) tel/DSL	3330	6'	82.94
Hospital Grade with Hospital Plug & Receptacles					
545-ISOBAR6ULTRAHG	ISOBAR6ULTRAHG	6	3330	15'	134.39
Rackmount Models					
545-ISOBAR12ULTRA	ISOBAR12ULTRA	12	3840	15'	170.36
545-DRS1215	DRS-1215	14	3840	15'	79.20
Direct Plug-in Models					
545-ISOBLOK2-0	ISOBLOK2-0	2	1410	direct plug-in	31.24
545-ULTRABLOK428	ULTRABLOK428	2	1410	direct plug-in	41.89

Tripp Lite Power Protection