

# WIREMOLD Surge Suppressors, Strips and Outlet Centers

**WIREMOLD**


legrand

## WIREMOLD COMMERCIAL DESKTOP POWER CENTERS

legrand

**Specifications:**

- 15 Amp rating
- 12 ft., 12 AWG cord
- 2 mounting methods included

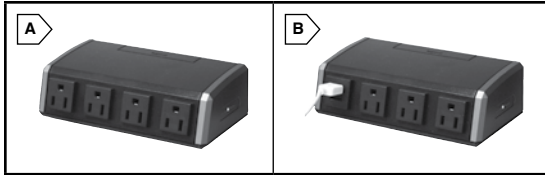

**Features:**

- Add power where needed
- Optional USB charging outlets
- Ideal for desk or work table
- Accommodates round hole openings from 1 1/2" to 3"
- Surge protection built-in



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Price Each	
Mfr.	Mfr. Part No.			1	5
681	—WSC400-S	A	4 Outlets with Circuit Breaker	46.50	44.93
681	—WSC320-S	B	3 Outlets, 2 USB Outlets	56.29	54.56

## WIREMOLD COMPUTER GRADE SURGE SUPPRESSORS

 
legrand

**Specifications:**

- Max surge current: 13,000A 681-PR610 6500A
- Clamping voltage: UL 300V 681-PR610 390V
- Electrical rating: 15A, 120V
- EM/RFI noise reduction: 40db

**Features:**

- Surge indicator light
- Resettable circuit breaker
- White housing
- Five year warranty
- UL1449 Approved, CSA certified



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Outlets	Length	Case	Cord Length	Phone Fax Protected	On/Off Switch	Price Each	
Mfr.	Mfr. Part No.							1	5
681	—M6BZ	6	13"	Aluminum	6'	-----	Lighted	43.98	42.58
681	—M6BZ-15	6	13"	Aluminum	15'	-----	Lighted	46.05	44.16

## WIREMOLD COMPACT PLUG-IN OUTLET CENTERS


legrand

**Specifications:**

- Electrical rating: 15A, 120V

**Features:**

- Resettable circuit breaker
- 14/3 SJT cord
- Gray aluminum housing except where noted
- UL listed, CSA approved
- Two year warranty

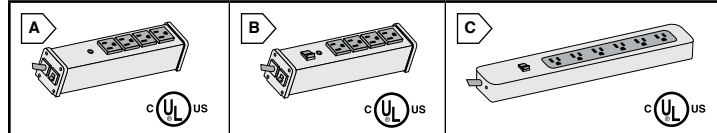

\*White Plastic Housing For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Outlets	Length	Mounting Type	Cord Length	Switch/ Pilot Light	Price Each	
Mfr.	Mfr. Part No.							1	5
681	—UL101BC	A	4	9 1/4"	Snap/Slide	6'	No	21.33	20.91
681	—UL101BD	A	4	9 1/4"	Snap/Slide	15'	No	26.75	26.23
681	—UL104BC	B	4	9 1/4"	Snap/Slide	6'	Yes	28.17	27.63
681	—UL104BD	B	4	9 1/4"	Snap/Slide	15'	Yes	34.08	32.61
681	—UL207BC	B	6	12 1/4"	Snap/Slide	6'	Yes	34.34	32.93
681	—UL207BD	B	6	12 1/4"	Snap/Slide	15'	Yes	43.70	42.79
681	—P6 *	C	6	12"	Keyhole	6'	Yes	10.41	9.83
681	—P6-15 *	C	6	12"	Keyhole	15'	Yes	17.20	16.98

## WIREMOLD INDUSTRIAL PLUG-IN OUTLET CENTERS

 
legrand

**Features:**

- 14/3 SJT cord
- Gray aluminum housing
- UL listed, CSA approved
- Two year warranty

**Specifications:**

- Electrical rating: 15A, 120V



For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Outlets	Length	Mounting Type	Cord Length	Switch/ Pilot Light	Price Each	
Mfr.	Mfr. Part No.						1	5
681	—UL300BC	8	24"	Snap/Slide	6'	Yes	56.76	55.97
681	—UL300BD	8	24"	Snap/Slide	15'	Yes	52.66	51.64
681	—UL401BC	8	48"	Snap/Slide	6'	Yes	58.37	57.25
681	—UL402BC	16	48"	Snap/Slide	6'	Yes	70.79	70.51
681	—UL402BD	16	48"	Snap/Slide	15'	Yes	72.40	69.66
681	—UL2065BD	24	72"	Snap/Slide	15'	Yes	89.62	87.82

## WIREMOLD INTERNATIONAL PLUG-IN OUTLET CENTER

 legrand

**Features:**

- Five 250V, IEC 320 outlets
- 10A single pole circuit breaker
- Gray finish
- Power cord not included (use 173-63101)
- Length: 11"



For quantities greater than listed, call for quote.


MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
681	—IEC5	5 250V, IEC320 Outlets	46.93	44.77

## WIREMOLD MEDICAL/DENTAL GRADE OUTLET CENTERS

 legrand

**Features:**

- Electrical Rating 12A, 125V
- Green dot outlets
- 14/3 SJT white cord
- Receptacle center-to-center
- White aluminum housing
- Two year warranty
- Suitable for use where Article 517 of the NEC requires hospital grade outlets



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Outlets	Length	Cord Length	Price Each	
Mfr.	Mfr. Part No.				1	5
681	—ULM4-6	4	10 3/4"	6'	90.71	86.67
681	—ULM4-15	4	10 3/4"	15'	99.75	94.51
681	—ULM6-6	6	13 1/4"	6'	111.16	106.38
681	—ULM6-15	6	13 1/4"	15'	119.22	117.36

## WIREMOLD SPECIAL USE PLUG-IN OUTLET CENTERS

 
legrand

**Specifications:**

- Electrical rating: 15A, 120V

**Features:**

- Green dot outlets
- 14/3 SJT white cord
- Resettable circuit breaker
- UL Listed, CSA approved
- White aluminum housing
- Two year warranty



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Outlets	Length	Cord Length	Price Each	
Mfr.	Mfr. Part No.				1	5
681	—ULBH4-6	4	10 3/4"	6'	54.38	53.83
681	—ULBH4-15	4	10 3/4"	15'	62.52	61.18
681	—ULBH6-6	6	13 1/4"	6'	75.84	75.39
681	—ULBH6-15	6	13 1/4"	15'	73.72	71.38

## WIREMOLD HEAVY DUTY PLUG-IN OUTLET CENTERS-20 AMP

 
legrand

**Specifications:**

- Electrical rating: 20A, 120V, 60Hz, 2500 watts continuous

**Features:**

- White aluminum housing
- UL listed
- Resettable circuit breaker
- 12/3 SJT black cord with NEMA 5-20P plug
- Two year warranty



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Outlets	Length	Cord Length	Switch/ Pilot Light	Price Each	
Mfr.	Mfr. Part No.					1	5
681	—ULB420-6	4	10 3/4"	6'	Yes	86.62	83.28
681	—ULB420-15	4	10 3/4"	15'	Yes	93.66	89.98
681	—ULB620-6	6	13 1/4"	6'	Yes	89.72	86.26
681	—ULB620-15	6	13 1/4"	15'	Yes	89.13	85.76

## WIREMOLD CENTEREX POWERCENTERS


legrand

**Specifications:**

- Electrical rating: 15A, 120V

**Features:**

- UL listed, CSA approved
- Resettable circuit breaker

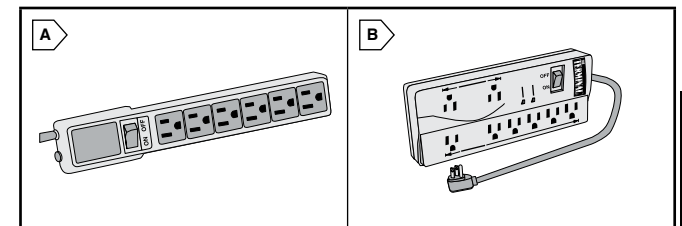

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Outlets	Surge	Cord Length	Price Each	
Mfr.	Mfr. Part No.					1	5
681	—63100	A	6	No	33"	8.00	7.30
681	—77000N	B	8	Yes	6'	27.00	24.37