


Consumer and Sealed Lead-Acid Battery Finder

3V LITHIUM COIN CELLS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Manufacturer	Capacity	Dimensions: mm	Price Each		
				1	10	25
658-CR1025	Panasonic	30	10.0 x 2.5	1.14	1.01	.94
614-CR1025	Renata	30	10.0 x 2.5	1.03	.98	.93
658-CR1216	Panasonic	25	12.5 x 1.6	1.11	1.02	.90
614-CR1216	Renata	30	12.5 x 1.6	1.08	1.03	.98
639-CR1220	FDK	35	12.0 x 2.0	1.38	1.20	1.09
658-CR1220	Panasonic	35	12.5 x 2.0	1.81	1.59	1.36
614-CR1220	Renata	48	12.5 x 2.0	.82	.78	.75
614-CR1225	Renata	48	12.5 x 2.5	.98	.94	.89
658-CR1616	Panasonic	55	16.0 x 1.6	.81	.72	.68
614-CR1616	Renata	50	16.0 x 1.6	.82	.78	.75
658-CR1620	Panasonic	75	16.0 x 2.0	.96	.88	.80
614-CR1620	Renata	68	16.0 x 2.0	.89	.85	.82
658-CR1632	Panasonic	140	16.0 x 3.2	1.31	1.19	1.13
614-CR1632	Renata	137	16.0 x 3.2	1.85	1.76	1.67
639-CR2016	FDK	75	20.0 x 1.6	.61	.49	.40
658-CR2016	Panasonic	90	20.0 x 1.6	.45	.42	.40
639-CR2025	FDK	150	20.0 x 2.5	.61	.49	.40
658-CR2025	Panasonic	165	20.0 x 2.5	.66	.60	.59
614-CR2025-MFR	Renata	165	20.0 x 2.5	.60	.58	.56
639-CR2032	FDK	240	20.0 x 3.2	.61	.49	.40
658-CR2032	Panasonic	225	20.0 x 3.2	.45	.42	.40
614-CR2032-MFR	Renata	225	20.0 x 3.2	.82	.78	.75
614-CR2320	Renata	150	23.0 x 2.0	1.29	1.23	1.18
614-CR2325	Renata	190	23.0 x 2.5	1.41	1.35	1.27
658-CR2330	Panasonic	265	23.0 x 3.0	1.57	1.45	1.36
658-CR2354	Panasonic	560	23.0 x 5.4	1.67	1.57	1.51
639-CR2430	FDK	270	24.0 x 3.0	1.99	1.73	1.57
614-CR2430	Renata	285	24.5 x 3.0	1.57	1.49	1.42
658-CR2450	Panasonic	620	24.5 x 5.0	1.13	1.01	.90
614-CR2450N	Renata	540	24.5 x 5.0	2.20	2.09	1.99
658-CR2477	Panasonic	1000	24.5 x 7.7	3.30	3.09	2.98
614-CR2477N	Renata	950	24.5 x 7.7	2.90	2.77	2.64
658-CR3032	Panasonic	500	30.0 x 3.2	2.76	2.55	2.39

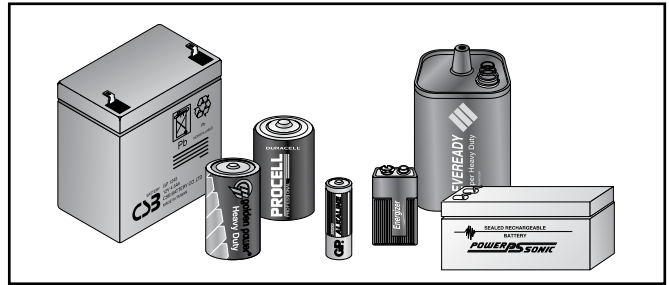

SEALED LEAD-ACID (RECHARGEABLE)

** Negative = .187" Faston, Positive = .250" Faston



Volt	Nominal Capacity @ 20 Hr. Rate A.H.	Terminal Type	MOUSER STOCK NO.	Manufacturer	Price Each
4	4.5	.250" Faston	547-PS-445	Power Sonic	15.73
4	9.0	.250" Faston	547-PS-490	Power Sonic	22.67
6	0.5	Wire Leads	547-PS-605	Power Sonic	22.97
6	1.0	.187" Faston	547-PS-610	Power Sonic	16.04
6	1.2	.187" Faston	547-PS-612H	Power Sonic	9.63
6	1.3	.187" Faston	632-GH613	CSB	7.08
6	1.3	.187" Faston	658-LCR061R3P	Panasonic	18.26
6	3.3	.187" Faston	632-GH633	CSB	11.02
6	3.4	.187" Faston	547-PS-630	Power Sonic	17.04
6	3.4	.187" Faston	658-LC-R063R4P	Panasonic	26.75
6	4.5	.187" Faston	632-GH645	CSB	8.90
6	4.5	.187" Faston	632-GP645	CSB	12.25
6	4.5	.187" Faston	547-PS-640	Power Sonic	11.68
6	4.5	.187" Faston	658-LCR064R5P	Panasonic	15.84
6	5.0	.187" Faston	547-PS650LF	Power Sonic	25.71
6	5.0	Spring	547-PS-650LS	Power Sonic	22.59
6	6.5	**	547-PS-665	Power Sonic	22.53
6	7.0	.187" Faston	547-PS-670	Power Sonic	16.18
6	7.2	.187" Faston	658-LCR067R2P	Panasonic	26.06
6	7.2	.250" Faston	658-LCR067R2P1	Panasonic	26.06
6	7.2	.187" Faston	632-GP672	CSB	13.77
6	8.0	.187" Faston	547-PS-682	Power Sonic	24.99
6	12.0	.187" Faston	547-PS-6100	Power Sonic	26.37
6	12.0	.187" Faston	632-GH6120	CSB	18.12
6	12.0	.187" Faston	632-GP6120	CSB	18.75
6	12.0	.187" Faston	658-LCR0612P	Panasonic	36.09
6	12.0	.250" Faston	658-LCR0612P1	Panasonic	45.46
6	12.0	.250" Faston	632-GP6120F2	CSB	22.70
6	12.0	**	547-PS-6120	Power Sonic	25.92
6	20.0	Nut and bolt	547-PS-6200	Power Sonic	67.93
6	36.0	.250" Faston	547-PS-6360	Power Sonic	86.13
12	0.8	Mate-N-Lok	547-PS-1208	Power Sonic	22.71
12	1.2	.187" Faston	547-PS-1212	Power Sonic	18.99
12	1.3	.187" Faston	632-GH1213	CSB	11.75
12	1.3	.187" Faston	658-LC-R121R3P	Panasonic	28.28
12	2.5	.187" Faston	547-PS-1220	Power Sonic	31.00
12	2.2	.187" Faston	632-GP1222	CSB	17.35
12	2.2	.187" Faston	658-LC-R122R2P	Panasonic	33.13
12	2.9	.187" Faston	547-PS1229	Power Sonic	31.01
12	3.4	.187" Faston	547-PS-1230	Power Sonic	29.16
12	3.4	.187" Faston	632-GH1234	CSB	17.70
12	3.4	.187" Faston	658-LC-R123R4P	Panasonic	39.49
12	4.5	.187" Faston	632-GP1245	CSB	17.79
12	5.0	.187" Faston	547-PS1250F1	Power Sonic	17.88
12	5.0	.250" Faston	547-PS1250F2	Power Sonic	20.70
12	7.0	.187" Faston	632-GH1270	CSB	19.00
12	7.0	.187" Faston	547-PS-1270	Power Sonic	23.11
12	7.2	.187" Faston	632-GP1272	CSB	22.69
12	7.2	.250" Faston	632-GP1272F2	CSB	22.69
12	7.2	.187" Faston	658-LCR127R2P	Panasonic	39.26
12	7.2	.250" Faston	658-LCR127R2P1	Panasonic	39.26
12	8.0	.187" Faston	547-PS-1282	Power Sonic	59.15
12	9.0	.250" Faston	547-PS-1290	Power Sonic	36.61
12	9.0	.250" Faston	547-PS-12100	Power Sonic	48.73
12	10.5	.250" Faston	547-PS12100H-F2	Power Sonic	37.17
12	12.0	.250" Faston	632-GP1210F2	CSB	42.64
12	12.0	.250" Faston	547-PS-12120	Power Sonic	49.53
12	17.0	Nut and bolt	658-LCRD1217P	Panasonic	85.32
12	17.0	Nut and bolt	632-GP12170	CSB	59.29
12	17.5	Nut and bolt	547-PS-12180	Power Sonic	65.35
12	18.0	.250" Faston	547-PS-12180F	Power Sonic	70.43
12	26.0	Nut and bolt	632-EVX12260	CSB	91.92
12	26.0	.250" Faston	547-PS-12260	Power Sonic	102.11
12	26.0	Nut and bolt	632-GP12260	CSB	87.09
12	28.0	Nut and bolt	658-LCX1228P	Panasonic	123.32
12	28.0	Nut and bolt	547-PS12280	Power Sonic	133.75
12	33.0	Nut and bolt	658-LCLA1233P	Panasonic	175.93
12	34.0	Nut and bolt	632-EVX12340	CSB	99.46
12	35.0	Nut and bolt	547-PS-12350	Power Sonic	123.63
12	40.0	Nut and bolt	632-GP12400	CSB	138.56
12	75.0	Nut and bolt	547-PS-12750	Power Sonic	246.18
12	100.0	Nut and bolt	547-PS121000	Power Sonic	289.85

NON-RECHARGEABLE



Size	Volt	mAh	Chemistry	MOUSER STOCK NO.	Manufacturer	Price Each
AAA	1.5	1,100	Alkaline	613-PC2400	Duracell Procell	.75
AAA	1.5	1,150	Alkaline	613-MN2400	Duracell	1.18
AAA	1.5	-	Alkaline	658-LR03XWA	Panasonic	.40
AA	1.5	2,450	Alkaline	613-PC1500	Duracell Procell	.70
AA	1.5	2,850	Alkaline	613-MN1500	Duracell	1.88
AA	1.5	NR	Alkaline	613-MX1500	Duracell M3 Ultra	1.52
AA	1.5	-	Alkaline	658-LR6XWA	Panasonic	.40
C	1.5	7,100	Alkaline	613-PC1400	Duracell Procell	1.43
C	1.5	7,800	Alkaline	613-MN1400	Duracell	2.83
C	1.5	---	Alkaline	658-LR14XWA	Panasonic	1.20
D	1.5	14,000	Alkaline	613-PC1300	Duracell Procell	1.68
D	1.5	15,000	Alkaline	613-MN1300	Duracell	2.27
D	1.5	---	Alkaline	658-LR20XWA	Panasonic	1.90
9V	9	565	Alkaline	613-PC1604	Duracell Procell	2.47
9V	9	580	Alkaline	613-MN1604	Duracell	3.38
9V	9	---	Alkaline	658-6LR61XWA	Panasonic	1.98
Lantern	6	13,000	Alkaline	613-MN908	Duracell	13.51

RECHARGEABLE

Size	Volt	mAh	Chemistry	MOUSER STOCK NO.	Manufacturer	Price Each
AAA	1.2	250	Nickel-Cadmium	547-PS-AAA	Power Sonic	2.06
AAA	1.2	700	Nickel Metal Hydride	658-HHR75AAA/B	Panasonic	3.15
AAA	1.2	720	Nickel Metal Hydride	658-HHR70AAAJ	Panasonic	2.90
AAA	1.2	750	Nickel Metal Hydride	639-HR-4U	FDK	2.70
AA	1.2	600	Nickel-Cadmium	547-PS-AA	Power Sonic	2.08
AA	1.2	1,500	Nickel Metal Hydride	658-HHR150AA	Panasonic	3.63
AA	1.2	2,000	Nickel Metal Hydride	658-HHR210AA/B	Panasonic	4.25
A	1.2	2100	Nickel Metal Hydride	658-HHR210A	Panasonic	4.90
4/5A	1.2	2,000	Nickel Metal Hydride	658-HHR200A	Panasonic	5.38
C	1.2	3,300	Nickel Metal Hydride	658-HHR300CH	Panasonic	10.65
D	1.2	4,000	Nickel-Cadmium	547-PS-DL	Power Sonic	11.58
4/5SC	1.2	1,900	Nickel Metal Hydride	658-HHR200SCP	Panasonic	6.90
SC	1.2	2,500	Nickel Metal Hydride	658-HHR250SCH	Panasonic	10.10
SC	1.2	3,050	Nickel Metal Hydride	658-HHR300SCP	Panasonic	9.23

Please also see our offering of Battery Holders, Chargers, Computer, and Specialty Batteries