

Rechargeable Batteries and Chargers

POWERSONIC NICKEL-CADMIUM BATTERIES

Nominal Voltage: 1.2V

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Size	Description	Capacity 5 Hr. Rate (mAh)	Std. Charge		Price Each			
				(mA)	(Hrs)	1	10	20	50
547-PS-AAA	AAA	Std. button top	250	22	15	2.06	1.88	1.73	1.66
547-PSAAA-T	AAA	With solder tabs	250	22	15	2.28	2.09	1.94	1.88
547-PS-AA	AA	Std. button top	600	60	15	2.08	1.87	1.70	1.65
547-PS-AA/FT	AA	Flat top	600	60	15	2.47	2.22	2.03	1.96
547-PSAA-T	AA	With solder tabs	600	60	15	2.89	2.63	2.42	2.33
547-PS-SC	SC	Flat top	1500	150	15	4.94	4.37	3.99	3.86
547-PS-SC-T	SC	With solder tabs	1500	150	15	5.73	4.95	4.54	4.41
547-PS-C	C	Flat top	2000	200	15	9.46	8.51	7.68	7.42
547-PS-C-T	C	With solder tabs	2000	200	15	10.30	9.30	8.42	8.16
547-PS-D	D	Flat top	4000	400	15	8.09	7.61	6.79	6.37
547-PS-DL	D	Std. button top	4000	400	15	11.58	10.36	9.38	9.06

GP NICKEL-CADMIUM BATTERIES


- Long Life
- Sealed, Strong, Leakproof Construction
- Excellent Discharge Characteristics

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Size	Volts	Capacity (mAh)	Price Each			
				1	10	25	100
573-60AAK	AA	1.2	600	2.40	2.23	2.04	1.80
573-100AAK	AA	1.2	1000	4.72	4.22	3.92	3.02

GP 3.6V BATTERY PACKS

- Features:
- Termination: Solder Tab
 - For Cordless Devices

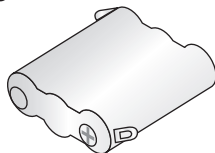

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Size	Volts	Capacity (mAh)	Price Each			
				1	10	25	100
573-30AAK3B1P	3 x 2/3 AA	Ni-Cad	300	6.96	6.27	5.57	5.31

FDK NICKEL METAL HYDRIDE BATTERIES

- Operating Temperature Range:
- Charge: 0°C - 40°C
 - Discharge: 0°C - 50°C
 - Storage: -20°C - 50°C

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Size	Volts	Capacity mAh	Dimensions: in. Diameter x Height	Price Per Pkg.		
					1	10	50
Consumer Top							
* 639-HR-4U	AAA	1.2	750	0.41 x 1.75	2.70	2.40	2.30
Flat Top							
639-HR-AAAU	AAA	1.2	720	0.41 x 1.75	3.64	3.42	3.30
639-HR-AAC	AA	1.2	1100	0.56 x 1.99	4.99	4.60	4.28
639-HR-AAU	AA	1.2	1500	0.56 x 1.99	5.88	5.40	4.66
639-HR-AUX	A	1.2	2700	0.67 x 1.97	6.98	6.34	5.81
Solder Tabs							
639-HRAAU-ST	AAA	1.2	720	0.41 x 1.75	3.51	3.30	3.10
639-HRAU-ST	AA	1.2	1500	0.56 x 1.99	6.57	6.03	5.20

* OEM Label Packaging

© Copyright 2012 Mouser Electronics

ENERGIZER ACCU RECHARGEABLE NICKEL METAL-HYDRIDE BATTERIES

- Designed for high-drain devices
- Batteries charge up to 1,000 times
- Provides up to 70% more power than standard NiCd

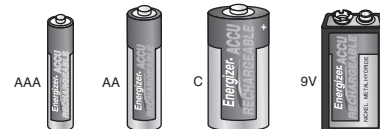


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Size	Nominal Voltage	Capacity (mAh)	Batteries Per Pkg.	Price Per Pkg.		
					1	12	48
525-NH12BP-4	AAA	1.2	850	4	17.37	15.44	14.48
525-NH15BP-4	AA	1.2	2500	4	17.37	15.44	14.48
525-NH35BP-2	C	1.2	2500	2	11.51	10.22	9.60
525-NH22NBP	9V	7.2	150	1	11.51	10.22	9.60


ACCU RECHARGEABLE NIMH AND NICD BATTERY CHARGERS

A

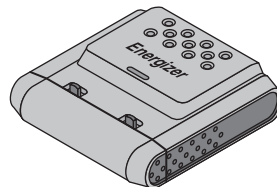


- Charges NiMH batteries only
- LED indicator shows when charging is complete
- Comes with 2 AA and 2 AAA batteries

B

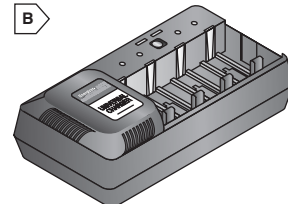

- LED indicator shows when charging is complete
- CHFCV charges NiMH battery only
- CHG-6P charges NiMH and NiCd batteries only

C

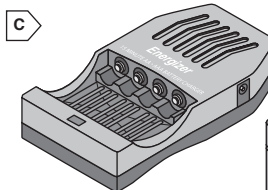


- Charges NiMH batteries only
- LED indicator shows when charging is complete
- Comes with 4 AA batteries or 2 AA / 2 AAA
- Charges in 15 minutes

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each	
			1	6
525-CHDCWB-4	A	Charges 2-4 AAA or AA batteries	27.10	25.50
525-CHFCV	B	Charges 2-4 AAA, AA, C, or D, or 1-2 9V batteries	38.98	29.99
639-CHG-6P	B	Charges 2-4 AAA, AA, C, or D, or 1-2 9V batteries	21.47	19.80
525-CH15MNCP4	C	Charges 1-4 AAA or AA batteries	51.73	47.27

GP NICKEL METAL HYDRIDE BATTERIES

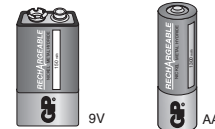

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Size	Volts	Cap. (mAh)	Price Each			
				1	10	25	100
573-GP160AA	AA	1.2	1600	3.81	3.51	3.25	2.83
573-GP17R8H	9V	8.4	170	13.00	11.39	10.20	9.74

© Copyright 2012 Mouser Electronics