


# EAGLE PLASTIC DEVICES Battery Holders and Snaps



This product is RoHS compliant.

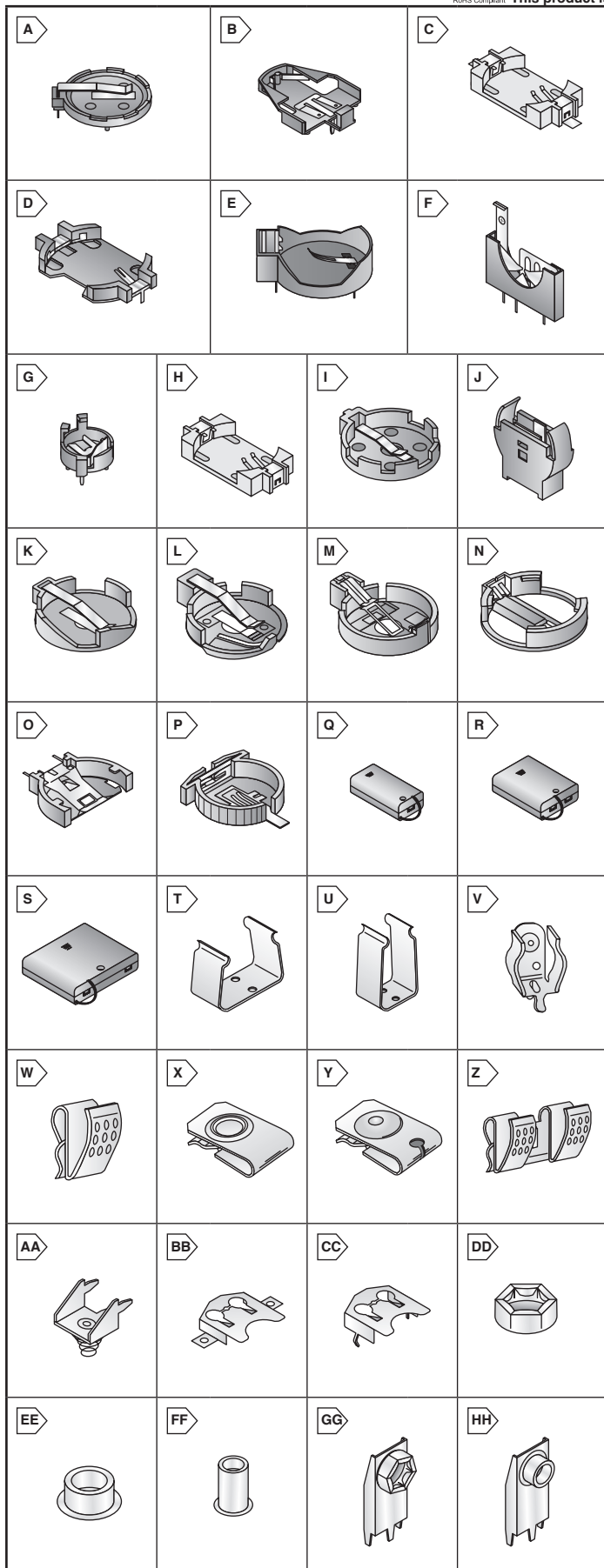

## COIN CELL BATTERY HOLDERS

MOUSER STOCK NO.	Fig.	Battery Size	Description	Price Each			
				1	25	50	100
122-2520-GR	A	20mm	Thru-hole black single cell	.91	.76	.61	.50
122-2523-GR	A	23mm	Thru-hole black single cell	.77	.69	.64	.53
122-2620-GR	B	20mm	Thru-hole black single cell	.91	.76	.61	.50
122-2820-GR	C	20mm	Surface mount beige	.75	.67	.607	.549
122-0420-GR	D	20mm	Surface mount black	1.20	1.05	.92	.83
122-0520-GR	D	20mm	Thru-hole black single cell	.94	.88	.83	.74
122-2420-GR	E	20mm	Thru-hole black single cell	.91	.76	.61	.50
122-4320-GR	F	20mm	Vertical thru-hole black single cell	1.16	1.05	.92	.79
122-1020-GR	C	20mm	Surface mount gold contacts	.96	.80	.646	.529
122-2312-GR	G	12.5mm	Thru-hole black single cell	.99	.89	.82	.66
122-2313-GR	G	12.5mm	Thru-hole black dual cell	.99	.89	.82	.66
122-2920-GR	H	20mm	Thru-hole white single cell	.86	.72	.65	.59
122-00224-GR	I	24.5mm	Thru-hole black single cell	.86	.72	.65	.59
122-7420-GR	J	20mm	Thru-hole black single cell	.86	.72	.65	.59
122-2582-GR	K	20mm	Thru-hole black dual cell	.94	.88	.83	.74
122-7520-GR	L	20mm	Thru-hole black single cell	.64	.53	.48	.44
122-7620-GR	M	20mm	Thru-hole black single cell	.91	.76	.61	.50
122-2512-GR	N	20mm	Thru-hole black single cell	.64	.53	.48	.44
122-2612-GR	O	20mm	Vertical thru-hole black single cell	.91	.76	.61	.50
122-2912-GR	P	12.5mm	Surface mount gold contacts	.94	.88	.83	.74

## BATTERY HOLDERS WITH COVERS AND SWITCH

- Color: Black
- Nickel plated hardware
- 6" leads tinned 3/16"

MOUSER STOCK NO.	Fig.	No. of Cells	Battery Size	Description	Price Each			
					1	25	50	100
12BH9V/CS-GR	Q	1	9V	With cover & switch	1.84	1.31	1.22	1.09
12BH9VA/C-GR	Q	1	9V	With cover	.91	.76	.69	.63
12BH9VP/C-GR	Q	1	9V	With cover	1.00	.83	.764	.69
12BH325/C-GR	Q	2	AA	With cover	1.34	.94	.85	.785
12BH325/CS-GR	Q	2	AA	With cover & switch	1.34	1.22	1.11	1.01
12BH331/C-GR	R	3	AA	With cover	1.11	1.00	.919	.837
12BH331/CS-GR	R	3	AA	With cover & switch	1.45	1.21	1.10	1.00
12BH348/C-GR	S	4	AA	With cover	1.34	1.22	1.11	1.01
12BH348/CS-GR	S	4	AA	With cover & switch	1.55	1.29	1.17	1.06
12BH361/C-GR	S	6	AA	With cover	1.37	1.15	1.04	.95
12BH421/C-GR	Q	2	AAA	With cover	.69	.64	.54	.50
12BH421/CS-GR	Q	2	AAA	With cover & switch	1.16	.96	.88	.80
12BH431/C-GR	R	3	AAA	With cover	1.03	.86	.79	.72
12BH431/CS-GR	R	3	AAA	With cover & switch	1.32	1.10	1.00	.91
12BH431B/C-GR	R	3	AAA	With cover	.95	.79	.72	.65
12BH441/C-GR	S	4	AAA	With cover	1.13	.94	.792	.717
12BH441/CS-GR	S	4	AAA	With cover & switch	1.32	1.10	1.00	.91
12SBH221A-GR	R	2	C	With cover	1.83	1.73	1.59	1.42
12SBH221AS-GR	R	2	C	With cover & switch	2.09	1.99	1.75	1.58

## METAL BATTERY HOLDERS/CLIPS

Steel, Nickel Plated

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	25	50	100
12BH071-GR	T	9V battery holder horizontal	.46	.34	.272	.238
12BH079-GR	T	9V battery holder horizontal	.42	.31	.245	.212
12BH080-GR	U	9V battery holder vertical	.38	.26	.239	.191
12BH095-GR	U	9V battery holder vertical	.44	.31	.28	.25
12BH980-GR	U	9V battery holder vertical	.49	.36	.29	.26
12BH092-GR	V	AA, AA battery clip	.19	.15	.14	.13
12BH082-GR	V	AAA battery clip PC mount	.19	.15	.14	.13
12BH209-GR	W	AA battery clip negative	.13	.12	.109	.099
12BH228-GR	X	AA battery clip positive	.14	.12	.106	.095
12BH204-GR	W	AAA battery clip negative	.17	.14	.10	.08
12BH238-GR	Y	AAA battery clip positive	.16	.11	.10	.08
12BH202-GR	Z	AAA dual snap-on clip	.27	.19	.15	.11
12BH629-GR	AA	AA,AAA PC spring contact	.38	.34	.32	.21
12BH002-GR	BB	20MM coin cell holder SM	.38	.34	.32	.21
12BH003-GR	CC	20MM coin cell holder PC	.38	.34	.32	.21

## MINI BATTERY SNAPS AND RIVETS

- Standard 9 volt size (.5" snap spacing)
- Available with 4, 5 or 6 prong contacts
- Black (except where noted)
- Available in 22AWG, 24AWG, and 26AWG stranded lead wires
- Male snap: .225" (O.D.)
- Female snap: .205" (I.D.)
- Rivets can be applied to PC boards, battery holders/packs, etc.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	100	1000	10000
12BC269-GR	DD	Mini battery female snap	.06	.06	.058	.049
12BC261-GR	EE	Mini battery male snap	.04	.036	.033	.03
12BC524-GR	FF	Mini rivet for snap	.03	.03	.026	.021
12BC220-GR	GG	Female snap-in battery terminal	.22	.20	.18	.16
12BC210-GR	HH	Male snap-in battery terminal	.22	.20	.18	.16