


EAGLE PLASTIC DEVICES 9V Battery Snaps



RoHS Compliant This product is RoHS compliant.

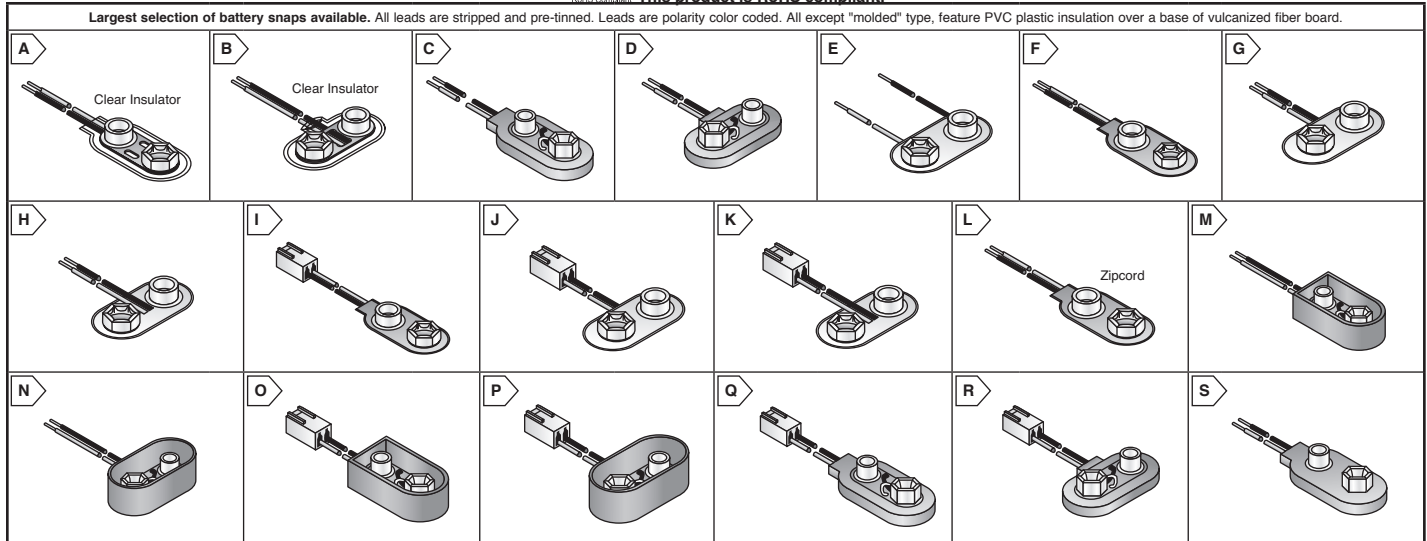

STANDARD BATTERY SNAPS

Snaps

- 6 prong contacts



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
12BC310-GR	A	26AWG	4	.39	.28	.25	.23
12BC309-GR	A	26AWG	6	.39	.28	.25	.23
12BC311-GR	B	26AWG	4	.41	.29	.265	.244
12BC312-GR	C	26AWG	6	.44	.37	.34	.32
12BC313-GR	D	26AWG	6	.44	.37	.34	.32
123-BS-M-A-GR	E	26AWG	6	.56	.41	.33	.288
121-0426/I-GR	F	26AWG	4	.34	.25	.20	.17
121-0526/I-GR	F	26AWG	5	.31	.24	.227	.206
121-0626/I-GR	F	26AWG	6	.34	.25	.20	.17
121-0826/I-GR	F	26AWG	8	.38	.28	.22	.19
121-1026/I-GR	F	26AWG	10	.38	.28	.22	.19
121-1226/I-GR	F	26AWG	12	.38	.28	.22	.19
121-0424/I-GR	F	24AWG	4	.38	.28	.22	.19
121-0624/I-GR	F	24AWG	6	.38	.28	.22	.19
121-0422/I-GR	F	22AWG	4	.38	.28	.22	.19
121-0622/I-GR	F	22AWG	6	.38	.28	.22	.19
121-1022/I-GR	F	22AWG	10	.41	.30	.25	.23
121-0426/T-GR	G	26AWG	4	.41	.30	.25	.23
121-0526/T-GR	G	26AWG	5	.41	.30	.25	.23
121-0626/T-GR	G	26AWG	6	.41	.30	.25	.23
121-0826/T-GR	G	26AWG	8	.41	.30	.25	.23
121-1026/T-GR	G	26AWG	10	.41	.30	.25	.23
121-0426/O-GR	H	26AWG	4	.41	.30	.25	.23
121-0626/O-GR	H	26AWG	6	.41	.30	.25	.23
121-0424/O-GR	H	24AWG	4	.41	.30	.25	.23
121-0624/O-GR	H	24AWG	6	.41	.30	.25	.23
121-0422/O-GR	H	22AWG	4	.41	.30	.25	.23
121-0622/O-GR	H	22AWG	6	.41	.30	.25	.23

Snaps With 2 Pole Socket Wire Termination

- Mates with Molex P/N 22-11-2022
- 6 prong contacts



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
121-0426/IM-GR	I	26AWG	4	.44	.37	.34	.31
121-0626/IM-GR	I	26AWG	6	.44	.37	.34	.31
121-0426/TM-GR	J	26AWG	4	.44	.37	.34	.31
121-0426/OM-GR	K	26AWG	4	.44	.37	.34	.31

- Zipcord lead colors: black and white
- 6 prong contacts



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
12BC015-GR	L	24AWG	4	.44	.31	.28	.25
12BC010-GR	L	24AWG	6	.44	.31	.28	.25
12BC016-GR	L	24AWG	10	.44	.31	.28	.25

MOLDED BATTERY SNAPS

4000 Series

- UL1007 26AWG wire stripped and tinned 5mm
- 6 prong brass nickel plated snap



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-4006-GR	M	26AWG	6	.41	.29	.26	.24
123-4016-GR	N	26AWG	6	.41	.29	.26	.24

4000 Series with 2 Pole Socket Wire Termination

- Mates with Molex P/N 22-11-2022



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-4006/M-GR	O	26AWG	6	.54	.45	.41	.37
123-4016/M-GR	P	26AWG	6	.54	.45	.41	.37

5000 Series



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-5004-GR	C	26AWG	4	.43	.30	.24	.22
123-5006-GR	C	26AWG	6	.43	.30	.24	.22
123-5008-GR	C	26AWG	8	.43	.30	.24	.22
123-5114-GR	D	26AWG	4	.43	.30	.24	.22
123-5116-GR	D	26AWG	6	.43	.30	.24	.22
123-5118-GR	D	26AWG	8	.43	.30	.24	.22

5000 Series With 2 Pole Socket Wire Termination

- Mates with Molex P/N 22-11-2022



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-5004/M-GR	Q	26AWG	4	.56	.46	.423	.381
123-5006/M-GR	Q	26AWG	6	.53	.44	.40	.36
123-5114/M-GR	R	26AWG	4	.53	.44	.40	.36
123-5116/M-GR	R	26AWG	6	.53	.44	.40	.36

6000 Series

- 6 prong brass nickel plated snaps



RoHS Compliant

MOUSER STOCK NO.	Fig.	Wire Size	Lead Length (in.)	Price Each			
				1	25	50	100
123-6004-GR	S	24AWG	4	.78	.52	.47	.43
123-6006-GR	S	24AWG	6	.78	.52	.47	.43
123-6010-GR	S	24AWG	10	.98	.65	.61	.55