


SIMPSON Analog Panel Meters

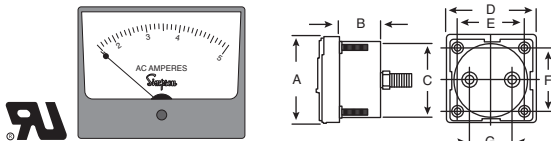

ANALOG PANEL METERS

- Features:**
- Clear, acrylic window for wide angle visibility
 - Rugged black phenolic case
 - Black spade pointer for easy distant viewing
 - Additional ranges available



Meter Size	Dimensions: in.						
	A	B	C	D	E	F	G
1-1/2"	1.76	0.86	1.50	1.75	1.31	1.31	1.00
2-1/2"	2.47	1.15	2.17	2.47	1.88	1.88	1.00
3-1/2"	3.25	1.22	2.73	3.25	2.25	2.25	1.50
4-1/2"	4.00	1.20	2.75	4.68	4.00	3.56	1.50

Wide-Vue Series

For quantities greater than listed, call for quote.

Size	1-1/2"			2-1/2"			3-1/2"			4-1/2"						
	MOUSER STOCK NO.	Simpson Part No.	Price Each	MOUSER STOCK NO.	Simpson Part No.	Price Each	MOUSER STOCK NO.	Simpson Part No.	Price Each	MOUSER STOCK NO.	Simpson Part No.	Price Each				
AC Voltmeter With Iron Vane Movement																
0-10				529-09670	09670	110.64	102.46	529-10170	10170	115.16	106.64	529-10270	10270	124.72	117.49	
0-25				529-09680	09680	80.45	77.23	529-10190	10190	115.17	106.65	529-10290	10290	124.73	117.50	
0-150				529-09700	09700	80.86	77.63	529-10220	10220	91.20	84.13	529-10320	10320	125.31	118.04	
0-300				529-09710	09710	85.31	80.57	529-10240	10240	90.89	83.84	529-10340	10340	124.90	117.66	
0-500				529-09715	09715	134.03	126.25	529-10250	10250	114.23	107.88	529-10350	10350	161.38	149.37	
AC Ammeters With Iron Vane Movement																
0-1				529-02560	02560	74.54	71.57	529-03130	03130	83.18	78.51	529-03260	03260	87.80	82.87	
0-3				529-02575	02575	78.93	74.99	529-03160	03160	83.18	78.52	529-03290	03290	87.81	82.88	
0-5				529-02580	02580	73.51	69.40	529-03170	03170	83.23	78.56	529-03300	03300	87.84	82.90	
0-10				529-02590	02590	74.78	71.80	529-03180	03180	83.46	78.78	529-03310	03310	88.08	83.14	
0-10								529-35073	35073	110.18	102.01	529-35077	35077	116.30	107.67	
0-15				529-02599	02599	72.46	69.57	529-03190	03190	83.57	78.89	529-03320	03320	88.20	83.25	
0-25				529-02609	02609	81.66	77.09	529-03200	03200	86.01	81.18	529-03330	03330	113.97	108.55	
0-30				529-02615	02615	81.65	77.08	529-03205	03205	81.25	78.00	529-03335	03335	90.64	85.55	
0-50				529-02619	02619	76.10	71.84	529-35075	35075	97.92	93.25	529-35079	35079	116.30	107.67	
0-100				529-02622	02622	102.21	95.84	529-03220	03220	83.22	79.07	529-03350	03350	92.24	87.86	
0-200				529-02626	02626	79.06	74.64	529-03240	03240	80.32	75.91	529-03370	03370	85.29	80.51	
0-300				529-02627	02627	79.06	74.64	529-03250	03250	83.22	78.55	529-03380	03380	87.84	82.91	
DC Voltmeters																
0-10	529-09541	09541	84.06	79.86	529-09560	09560	111.90	106.58	529-09740	09740	116.20	109.46	529-09890	09890	125.22	117.97
0-15	529-09542	09542	84.05	79.85	529-09570	09570	86.28	81.44	529-09750	09750	116.04	109.30	529-09900	09900	125.05	117.81
0-25	529-09543	09543	87.22	82.33	529-09580	09580	115.90	107.30	529-09760	09760	112.62	106.09	529-09910	09910	125.02	117.78
0-30	529-09544	09544	89.86	85.37	529-09590	09590	109.63	101.50	529-09770	09770	116.03	109.30	529-09920	09920	125.02	117.78
0-50	529-09545	09545	94.34	89.84	529-09600	09600	83.78	79.07	529-09780	09780	115.98	109.25	529-09930	09930	125.05	125.05
0-100	529-09546	09546	117.16	108.47	529-09610	09610	115.90	107.30	529-09790	09790	112.78	107.39	529-09940	09940	121.71	115.91
0-150	529-09547	09547	117.17	108.48	529-09620	09620	86.28	81.44	529-09800	09800	116.03	109.29	529-09950	09950	125.02	117.78
0-500	529-09549	09549	137.79	125.09	529-09640	09640	120.87	111.91	529-09840	09840	101.54	93.73	529-09990	09990	130.28	122.74
Taut Band DC Microammeters																
0-10				529-04303	04303	206.61	191.32	529-04359	04359	221.87	205.43	529-04459	04459	237.27	219.70	
0-25	529-04602	04602	185.48	171.72	529-04306	04306	189.15	175.11	529-04371	04371	194.11	179.74	529-04471	04471	210.14	194.58
0-100	529-04604	04604	130.53	122.97	529-04321	04321	119.42	114.70	529-04391	04391	102.49	97.01	529-04491	04491	152.84	141.52
DC Microammeters																
0-50	529-04294	04294	130.89	123.30	529-04310	04310	105.49	99.63	529-04380	04380	107.20	101.25	529-04480	04480	115.47	109.70
0-100	529-04295	04295	123.73	116.55	529-04320	04320	114.18	108.75	529-04390	04390	90.48	86.86	529-04490	04490	123.76	114.24
0-200	529-04296	04296	88.66	84.22	529-04330	04330	111.03	102.81	529-04400	04400	120.70	111.75	529-04500	04500	124.09	118.18
25-0-25	529-04298	04298	138.48	130.45					529-04420	04420	136.58	130.08	529-04520	04520	151.34	140.13
50-0-50	529-04302	04302	123.80	116.62	529-04350	04350	125.14	117.88	529-04430	04430	92.10	87.72	529-04530	04530	142.48	134.22
100-0-100	529-04300	04300	105.56	100.97	529-04351	04351	88.86	84.42	529-04440	04440	91.87	87.29	529-04540	04540	128.37	120.92
DC Milliameters																
0-1	529-06163	06163	83.00	78.85	529-06175	06175	92.83	88.18	529-06310	06310	80.35	76.32	529-06470	06470	120.93	111.96
0-5	529-06164	06164	110.89	102.68	529-06190	06190	109.04	100.97	529-06330	06330	112.56	104.21				
0-15	529-06166	06166	110.90	102.69	529-06210	06210	105.70	100.67	529-06350	06350	112.71	104.35	529-06502	06502	121.12	112.14
0-25	529-06167	06167	113.17	104.77	529-06220	06220	109.85	101.72	529-06370	06370	115.94	107.34	529-06530	06530	123.01	115.88
0-50	529-06168	06168	112.91	104.53	529-06230	06230	109.84	101.71	529-06380	06380	88.89	84.45	529-06540	06540	123.01	115.88
0-100	529-06169	06169	112.93	104.55	529-06240	06240	106.35	101.29	529-06390	06390	88.89	84.45	529-06550	06550	123.05	115.91
0-200	529-06171	06171	112.93	104.55	529-06260	06260	109.90	101.77	529-06410	06410	116.01	107.40	529-06570	06570	123.25	115.53
0-300	529-06173	06173	109.61	101.47	529-06280	06280	81.64	76.77	529-06430	06430	115.95	107.35	529-06590	06590	123.13	115.99
0-500	529-06174	06174	112.89	104.51	529-06290	06290	84.65	80.42	529-06440	06440	86.37	81.52	529-06600	06600	123.11	115.97
DC Ammeters																
0-1	529-02431	02431	80.99	76.94	529-02440	02440	84.52	79.77	529-02640	02640	88.84	88.84	529-02820	02820	90.72	85.63
0-2	529-02432	02432	87.02	82.18	529-02460	02460	84.60	79.85	529-02660	02660	86.31	81.47				
0-3	529-02433	02433	87.00	82.65	529-02470	02470	84.62	79.87	529-02670	02670	88.89	83.91	529-02850	02850	95.70	90.32
0-5	529-02434	02434	109.27	104.06	529-02480	02480	88.48	82.94	529-02680	02680	111.74	106.43	529-02860	02860	123.92	116.16
0-10	529-02435	02435	87.69	82.77	529-02490	02490	84.60	79.85	529-02690	02690	88.89	83.91	529-02870	02870	95.71	90.34
0-15	529-02436	02436	80.98	76.44	529-02500	02500	77.59	74.49	529-02700	02700	88.89	83.91	529-02880	02880	120.34	114.61
0-25	529-02437	02437	81.62	77.04	529-02510	02510	84.59	79.84	529-02710	02710	84.06	79.35	529-02890	02890	123.96	116.20
0-50	529-02438	02438	86.93	82.05	529-02530	02530	109.54	102.69	529-02730	02730	86.31	81.47	529-02910	02910	108.47	100.13
0-100								529-02740	02740	83.73	79.02	529-02920	02920	95.62	90.25	
0-200								529-02750	02750	79.69	75.21	529-02940	02940	90.72	85.63	
0-300								529-02770	02770	84.52	79.77	529-02950	02950	95.62	90.25	
0-500								529-02780	02780			529-02				