


B&K PRECISION Multimeters

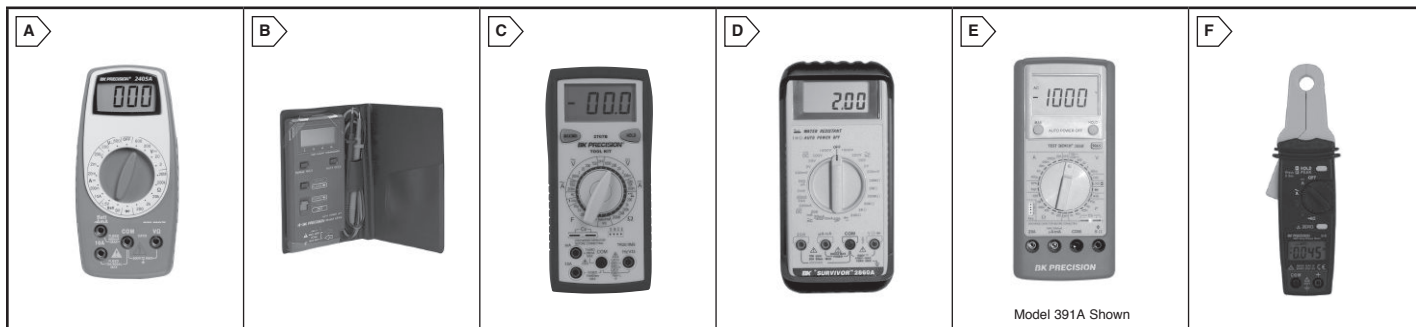

Model 391A Shown

BK PRECISION ANALOG AND DIGITAL MULTIMETERS

MOUSER STOCK NO.	BK Precision Part No.	Fig.	DCV Accuracy	Ranging	Display LCD	Analog Bar Graph	Data Hold	Memory	Cap	Frequency	Logic	Tran Gain	Temp.	Auto Off	Warranty	Price Each
615-2405A	2405A	A	2	Manual	2000	No	No	No	No	No	Yes	No	No	No	1 Year	32.00
615-2700	2700	B	1.3	Auto	3200	Yes	Yes	No	No	No	No	No	No	Yes	1 Year	39.00
615-2703C	2703C	C	0.5	Manual	3 1/2	No	No	No	No	No	No	No	No	No	1 Year	46.00
615-2407A	2407A	A	1.2	Auto	3200	Yes	Yes	No	No	No	Yes	No	No	Yes	1 Year	59.00
615-2704C	2704C	C	0.5	Manual	3 1/2	No	No	No	Yes	No	No	Yes	No	No	1 Year	66.00
615-2706B	2706B	C	0.5	Manual	3 1/2	No	No	No	Yes	No	No	Yes	Yes	No	1 Year	86.00
615-2707B	2707B	C	0.5	Manual	3 1/2	No	No	No	Yes	Yes	Yes	Yes	No	No	1 Year	95.00
615-2703C	2703C	C	1.2	Manual	3 1/2	No	No	No	No	No	No	No	No	No	1 Year	46.00
615-2705B	2705B	C	2	Auto	3 3/4	No	No	No	No	No	No	No	No	Yes	1 Year	68.00
615-2708B	2708B	C	2	Auto	3 3/4	Yes	No	No	No	No	No	No	No	Yes	1 Year	99.00
615-2709B	2709B	C	2	Auto	3 3/4	No	No	No	Yes	Yes	No	No	No	Yes	1 Year	105.00
615-2860A	2860A	D	0.5	Manual	3 1/2	No	No	No	No	No	No	No	No	Yes	5 Years	105.00
615-388B	388B	E	0.5	Manual	4000	No	No	No	Yes	Yes	Yes	Yes	No	Yes	3 Years	139.00
615-389A	389A	E	0.25	Auto	4000	Yes	Yes	Yes	Yes	Yes	No	No	No	Yes	3 Years	159.00
615-390A	390A	E	0.1	Auto	4000	Yes	Yes	Yes	Yes	Yes	No	No	Yes	Yes	3 Years	179.00
615-391A	391A	E	0.05	Manual	4 1/2	No	Yes	No	No	Yes	Yes	No	No	Yes	3 Years	199.00
615-316	316	F	1	Auto	3 1/2	No	Yes	No	No	No	No	No	No	Yes	1 Year	169.00

BK PRECISION DMM ACCESSORIES

MOUSER STOCK NO.	BK Precision Part No.	Description	Price Each
615-TL-130A	TL-130A	General Purpose DMM Kit Includes soft, flexible silicone lead wire easy movement and Tri-Fold Velcro Pouch for convenient storage.	69.00
615-TL-50	TL-50	Maxi-Pro DMM Kit is voltage and current rated for either electronic or electrical applications. All components compliant to IEC61010-031	69.00
615-1944391	194-043-9-001	Fuse for DMM 388-391 - Package of 4	14.80
615-1944491	194-044-9-001	Fuse 2A for DMM's - Package of 4	7.40
615-1944591	194-045-9-001	Fuse 0.5A for DMM 389-391 - Package of 4	5.92
615-2001	TL-1	Standard test leads, economical replacement test leads, TL-1 has safety shrouded banana plugs	8.50
615-2002	TL-2A	Deluxe test lead set, IEC61010 1000V CATIII rating silicone lead wire length 60" black alligator clip included. Threaded tips fits TL-3	20.80
615-2003	TL-3	Probe Accessory kit black and red pairs alligator clip, red only spring hook clips 4" sharp extension tips No. 10 spade lugs	36.00
615-2129B	LC-29B	DMM case, light weight, durable Cordura nylon, protects your instruments, room to hold your test leads	17.75
615-2144	HV-44A	High-voltage probe/meter 0-40,000V	119.00

BK PRECISION BENCH MULTIMETERS

4 1/2 Digit True RMS Bench Digital Multimeter

The 2831E takes typical multimeter measurements such as volts, ohms, and amps with great accuracy and stability and was designed for cost conscious users requiring a basic and dependable meter with a broad range of extra features offered at a value price.

Features:

- True RMS for accurate interpretation of any waveform signal
- Great overload protection on all ranges
- Current measurements up to 20A AC/DC
- 0.03% basic VDC accuracy
- Dual VFD Display
- AC + DC True RMS
- USB interface
- SCPI compatible



MOUSER STOCK NO.	BK Precision Part No.	Description	Price Each
615-2831E	2831E	True RMS Bench Digital Multimeter	339.00

5 1/2 Digit Dual Display Bench DMM with 0.012% Basic Accuracy

Applications:

The Dual Display Multimeter model 5491/5492 is a 5 1/2 digit multimeters with selectable count resolutions up to 120,000 count. It is designed for bench-top, field service, and system applications with a high performance to price ratio. One set of TL 36 Test Leads and AC 01 caps for TL 36 are included with each 5492.

Features:

- Selectable count resolutions of 120,000, 40,000 and 4,000 count
- Selectable 2 wire and 4 wire resistance measurements
- Measure frequency to 1MHz with 0.01Hz best resolution
- RS-232 interface
- GPIB option available



PRODUCT **NEW**

MOUSER STOCK NO.	BK Precision Part No.	Description	Price Each
615-5491B	5491B	50K Count RMS Bench Digital Multimeter	409.00
615-5492B	5492B	5 1/2 Digit True RMS Bench Multimeter	649.00
615-5492BGPIB	5492BGPIB	5 1/2 Digit True RMS Bench Multimeter with GPIB	789.00

BK PRECISION DUAL DISPLAY HANDHELD LCR METERS

Features:

- 40,000 count primary display and 10,000 count secondary display
- L/C/R/Z/ Primary measurements (Z with 879B)
- D/Q/θ/ESR Secondary measurements (θ/ESR with 879B)
- 0.5% basic accuracy
- Fast Auto Range design for rapid, easy component measurements
- Mini USB interface (cable included)

MOUSER STOCK NO.	BK Precision Part No.	Display Type	Function	Ranging	Display Count	Price Each
615-878B	878B	LCD, Dual	Henrys, Farads, Ohms	Auto	40000	249.00
615-879B	879B	LCD, Dual	Henrys, Farads, Ohms	Auto/Manual	19999	299.00

