

FLUKE Multimeters and Kits

FLUKE®

FLUKE 233 FLUKEVIEW REMOTE DISPLAY MULTIMETER

Includes:

- Test leads
- Alligator clips
- 80BK-A temperature probe
- Manual
- CD-ROM
- AA batteries

Optional Accessories:

- TPak magnetic hanging kit
- i410 AC/DC current clamp
- 80PK-9 general purpose probe (Type K)
- 80AK-A thermocouple adapter
- C35 soft carry case



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-233	233	Remote Display TRMS DMM	299.95

FLUKE 287 FLUKEVIEW FORMS COMBO KIT

Kit Includes:

- Fluke-287 True-RMS Electronics Logging Multimeter with TrendCapture
- FlukeView Forms Software and cable
- 80BK-A thermocouple Probe
- CAT III 1000V 10A Modular test leads (reds, black)
- CAT III 1000V 10A Modular test probes (reds, black)
- CAT II 300V 5A Alligator Clips (red, black)
- Soft case for meter protection and accessory storage



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-287/FVF	287/FVF	Fluke 287 and FlukeView Forms Combo Kit	618.95

FLUKE ELECTRONICS DMM COMBO KIT


Kit Includes:

179 Multimeter:

- Includes 80BK-A
- True-rms AC voltage and current
- 6000 count display
- Frequency, capacitance, and resistance capabilities
- Backlight

Deluxe Accessory Combo:

- TL224 test leads
- AC280 grabbers
- TL910 fine pitch leads and probes
- C35 lightweight soft case

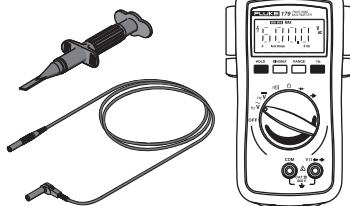

MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-179/EDA2	179/EDA2	Electronics multimeter & deluxe accessory combo kit	316.95

FLUKE 179/IMSK INDUSTRIAL MULTIMETER SERVICE KIT

Kit Includes:

- True RMS Multimeter with temperature frequency, capacitance
- 322 AC 400A Current Clamp
- 80BK-A thermocouple bead probe
- TL75 test leads
- AC72 Alligator Clips
- Limited Lifetime warranty on 179 and 2-year warranty on Fluke-322

Accessories:

- C115 soft carrying case
- TPak ToolPak, meter hanging kit



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-179/IMSK	179/IMSK	179 DMM with 322 Clamp, Kit	332.95

FLUKE INDUSTRIAL ELECTRONICS DMM COMBO KIT


Kit Includes:

179 Multimeter:

- Includes 80BK-A
- True-rms AC voltage and current
- 6000 count display
- Frequency, capacitance, and resistance capabilities
- Backlight

Accessories:

- TL224 test leads
- AC220 retractable alligators
- TP220 industrial probes
- 1AC-11 voltage detector
- C35 lightweight soft case

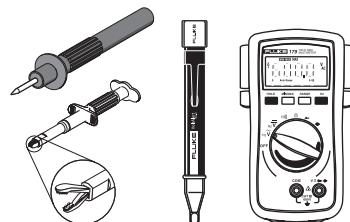

MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-179/ACI	179/ACI-II	Electrician's multimeter, voltage tester, & accessories	316.95

FLUKE 27 II AND 28 II DIGITAL MULTIMETERS

Includes:

- Holster
- Test leads
- 80BK-A temperature probe (28 II)
- Manual
- CD-ROM
- Three AA batteries (installed)

Optional Accessories:

- PV 350 pressure vacuum module
- i200 AC current clamp
- i410 AC/DC current clamp
- 80K-6 high voltage probe



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-27-II	27-II	Rugged IP67 Industrial TRMS	441.95
676-28-II	28-II	Rugged IP67 Industrial TRMS	451.95

FLUKE 289 LOGGING MULTIMETER AND VIEW FORMS COMBO KIT

Overlay logged data from six meters or six time periods to find cause and effect relationships, create tables, and reports

Includes:

- Fluke 289 True-rms Industrial Logging Multimeter with TrendCapture
- FlukeView Forms Software and cable
- 80BK-A integrated DMM thermocouple probe
- TL71 Silicone Test Lead Set
- AC72 Alligator Clips
- TPak Magnetic Meter Hanger
- C289 Durable and lightweight Soft Case



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-289/FVF	289/FVF	Fluke 289 and FlukeView Forms Combo Kit	649.95

FLUKE 289/IMSK INDUSTRIAL MULTIMETER SERVICE KIT

Kit Includes:

- 289V Advanced data logging multimeter
- i400 AC 400A current clamp
- TL71 silicone test leads
- AC72 alligator clips
- Limited lifetime warranty on 289 and 1-year warranty on accessories

Accessories:

- C280 soft case
- TPak ToolPak, meter hanging kit
- 80BK-A integrated DMM temperature probe
- FVF-SC2 FlukeView forms software with cable.



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-289/IMSK	289/IMSK	Industrial Logging with I400, Kit	649.95

FLUKE 87 V/E2 INDUSTRIAL ELECTRICIAN COMBO KIT

Kit Includes:

- 87V Industrial Multimeter
- C35 Lightweight soft case to provide optimal protection and accessory storage
- TL224 1.5 m silicone leads resist heat
- TP238 Removable probes with 4mm of exposed metal for use on industrial circuits
- AC220 Retractable long reach alligator clips
- ToolPak Magnetic hanger to position and hold meter to steel surfaces
- 80BK-A K-type temperature probe



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-87-5/E2	87-5/E2	87V/E industrial multimeter with holster & accessories	451.95

FLUKE 87-5/IMSK INDUSTRIAL ELECTRICIAN COMBO KIT

Kit Includes:

- 87V industrial multimeter
- 1.5 m heat resistant silicone test leads
- Removable test probes with 4 mm of exposed metal for use on industrial circuits
- Retractable long reach alligator clips
- Magnetic hanger to position and hold meter to steel surfaces
- Temperature probe

Accessories:

- TL75 test leads
- AC72 alligator clips
- Holster
- 9V battery (installed)
- Temperature probe (87V only)
- CD-ROM (user's manual and technical notes)
- Operator's guide



MOUSER STOCK NO.	Fluke Part No.	Description	Price Each
676-87-5/IMSK	87-5/IMSK	Industrial DMM with I400, Kit	441.95