

POMONA Test Clips and Cable Assemblies



Pomona SMA PLUG 50 OHM CABLE

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
RG174/U							
565	—4846-K-24	A	SMA male (plug) to SMA male (plug), 50Ω	24	47.50	45.60	42.25
565	—4846-K-48	A	SMA male (plug) to SMA male (plug), 50Ω	48	47.50	45.60	42.25
565	—4846-K-60	A	SMA male (plug) to SMA male (plug), 50Ω	60	47.50	45.60	42.25
RG316/U							
565	—4846-BB-24	A	SMA male (plug) to SMA male (plug), 50Ω	24	54.00	51.84	48.03
565	—4846-BB-48	A	SMA male (plug) to SMA male (plug), 50Ω	48	54.00	51.84	48.03
565	—4846-BB-60	A	SMA male (plug) to SMA male (plug), 50Ω	60	54.00	51.84	48.03
RG142B/U							
565	—4846X24	A	SMA male (plug) to SMA male (plug), 50Ω	24	70.00	67.20	62.27
565	—4846X48	A	SMA male (plug) to SMA male (plug), 50Ω	48	70.00	67.20	62.27
565	—4846-X-60	A	SMA male (plug) to SMA male (plug), 50Ω	60	70.00	67.20	62.27
565	—72926-C-40	A	IEC Insulated BNC Male 50Ω Cable	40	14.00	13.44	12.45
565	—5144-48-0	B	SMD Microtip Test Probe	48	14.12	13.46	12.78

Pomona BNC PLUG TO SMA PLUG 50OHM TEFLON INSULATED CABLE

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
RG316/U							
565	—4935-BB-24	C	BNC male (plug) to SMA male (plug), 50Ω	24	48.50	46.56	43.14
565	—4935-BB-48	C	BNC male (plug) to SMA male (plug), 50Ω	48	48.50	46.56	43.14
565	—4935-BB-60	C	BNC male (plug) to SMA male (plug), 50Ω	60	48.50	46.56	43.14

Pomona MOLDED BREAKOUTS


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565	—4969	D	BNC female to 20AWG leads	5.9	7.48	7.07	6.71
565	—2630	E	BNC female to mini alligator clips	5.0	10.69	10.19	9.93
565	—2631	E	BNC female to minigrabber clips	5.9	11.28	10.75	10.45
565	—3788	F	BNC female to Minigrabber test clips	5.5	11.45	9.69	9.21
565	—3789	F	BNC male to Minigrabber test clips	5.5	13.17	12.66	12.23
565	—3221	G	BNC female to stacking pin tip plugs	5.5	13.20	12.81	12.16
565	—3073	H	BNC female to multi-stacking banana plugs	5.4	10.68	9.19	9.09
565	—4970	I	BNC male to 20AWG leads	5.9	10.50	10.03	9.34
565	—5187-C-36	J	Minigrabber test clips to BNC male RG58C/U	36.0	20.00	19.20	17.79

Pomona BNC TO BNC WITH MOLDED STRAIN RELIEF

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Length (in.)	Price Each		
Mfr.	Mfr. Part No.				1	25	50
RG58C/U							
565	—2249-C-12	K	BNC male to BNC male, 50Ω	12	16.25	15.60	14.45
565	—2249-C-24	K	BNC male to BNC male, 50Ω	24	16.25	15.60	14.45
565	—2249-C-36	K	BNC male to BNC male, 50Ω	36	16.25	15.60	14.45
565	—2249-C-48	K	BNC male to BNC male, 50Ω	48	20.25	19.44	18.01
565	—2249-C-60	K	BNC male to BNC male, 50Ω	60	20.25	19.44	18.01
565	—2249-C-72	K	BNC male to BNC male, 50Ω	72	20.25	19.44	18.01
565	—2249-C-120	K	BNC male to BNC male, 50Ω	120	24.00	23.04	21.35
565	—2249-C-144	K	BNC 500HM RG58C	144	26.50	25.44	23.57
565	—2249-C-180	K	BNC male to BNC male, 50Ω	180	29.50	28.32	26.24
565	—2249-C-240	K	BNC 500HM RG58C	240	34.50	33.12	30.69
565	—2249-C-300	K	BNC 500HM RG58C	300	40.00	38.40	35.58
565	—2249-C-360	K	BNC 500HM RG58C	360	45.00	43.20	40.03
565	—2249-C-600	K	BNC 500HM RG58C	600	59.00	56.64	52.48
RG223							
565	—2249-Y-12	K	BNC male to BNC male, 50Ω	12	25.00	24.00	22.24
565	—2249-Y-24	K	BNC male to BNC male, 50Ω	24	25.00	24.00	22.24
565	—2249-Y-36	K	BNC male to BNC male, 50Ω	36	26.50	25.44	23.57
565	—2249-Y-48	K	BNC male to BNC male, 50Ω	48	28.00	26.88	24.90
565	—2249-Y-60	K	BNC male to BNC male, 50Ω	60	30.50	29.28	27.13
565	—2249-Y-72	K	BNC male to BNC male, 50Ω	72	32.00	30.72	28.46
565	—2249-Y-180	K	BNC 500HM RG223	180	57.00	54.72	50.70
565	—2249-Y-240	K	BNC 500HM RG223	240	62.00	59.52	55.15
RG59B/U							
565	—2249-E-12	K	BNC male to BNC male, 75Ω	12	17.25	16.56	15.34
565	—2249-E-24	K	BNC male to BNC male, 75Ω	24	17.25	16.56	15.34
565	—2249-E-36	K	BNC male to BNC male, 75Ω	36	17.25	16.56	15.34
565	—2249-E-48	K	BNC male to BNC male, 75Ω	48	20.25	19.44	18.01
565	—2249-E-60	K	BNC male to BNC male, 75Ω	60	20.25	19.44	18.01
565	—2249-E-72	K	BNC male to BNC male, 75Ω	72	20.25	19.44	18.01
565	—2249-E-360	K	BNC 750HM RG59B	360	45.00	43.20	40.03
565	—2249-E-480	K	BNC 750HM RG59B	480	52.00	49.92	46.25
RG174/U							
565	—2249-K-6	K	BNC 750HM RG174	6	24.50	23.52	21.79
565	—2249-K-12	K	BNC male to BNC male, 50Ω	12	24.50	23.52	21.79
565	—2249-K-24	K	BNC male to BNC male, 50Ω	24	24.50	23.52	21.79
565	—2249-K-36	K	BNC male to BNC male, 50Ω	36	24.50	23.52	21.79
565	—2249-K-48	K	BNC male to BNC male, 50Ω	48	26.50	25.44	23.57
565	—2249-K-60	K	BNC male to BNC male, 50Ω	60	26.50	25.44	23.57
565	—2249-K-72	K	BNC male to BNC male, 50Ω	72	28.50	27.36	25.35
565	—2249-K-180	K	BNC 750HM RG174	180	36.00	34.56	32.02
565	—2249-K-480	K	BNC 750HM RG175	480	54.00	51.84	48.03

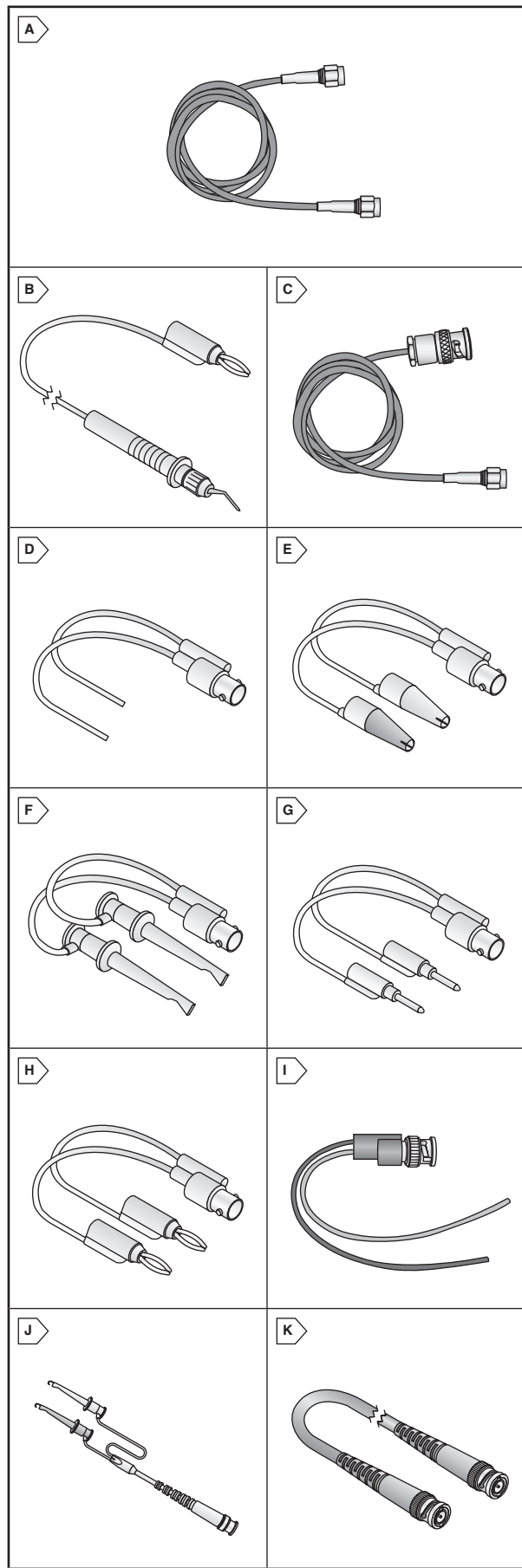

Pomona Test Connectors