

POMONA Test Lead Kits and Probe Sets




Pomona TEST PROBE KIT

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
565—6235		SMD Microtip Test Probe Set	25.42	
565—5292-48		BNC Shielded Test Probe Kit	45.52	
565—72928		SMD Multi-Use Test Kit	132.88	
565—72935		SMD High Density Circuit Test Kit	195.02	
565—72902		Micro SMD Grabber Test Clips Kit	200.89	
565—CK73041		Calibration Kit	714.30	

Pomona DELUXE MULTI-USE DMM MAXI-KIT

Kit Includes:

- Silicone 4' leads with right angle plug
- Modular probe set with standard tips
- Full set of 5 replaceable tips
- Retractable tip test probe set
- Test lead coupler set
- Medium alligator clip set
- Large alligator clip set
- Bare spade lugs
- IC probe tip adapter
- Minigrabber® test clip leads
- Minipincer® test clip leads
- Nylon storage pouch

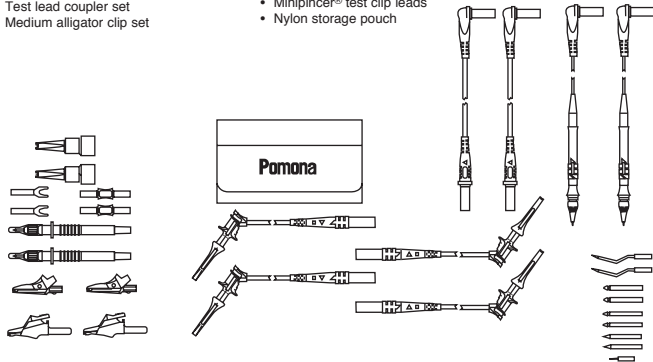


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
565—5677B		Deluxe Multi-Use DMM Maxi-Kit	121.86	114.88

Pomona ELECTRICAL DMM TEST LEAD KIT

Kit Includes:

- Silicone 4' leads with right angle plug
- Modular probe set with standard tips
- Extended probe tip adapters
- Medium alligator clip set
- Large alligator clip set
- Insulated spade lugs
- Nylon storage pouch

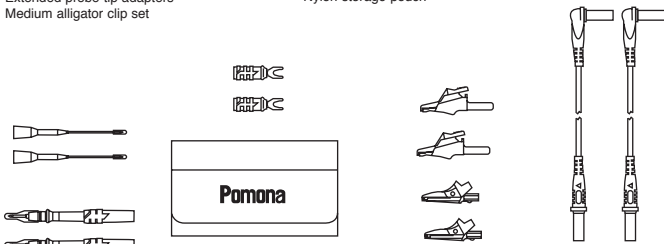


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
565—5673B		Electrical DMM Test Lead Kit	56.21	52.99

Pomona PRECISION ELECTRONIC PROBE SET

Specifications:

 - Compact design for tight test situations
- Probe set includes 5 spring-loaded tips for constant contact
- Silicone insulated leads resist abrasion and heat
- Comfort-grip textured surface



Features:

- Replaceable 0.04" (1.52mm) pogo-pin tips
- Small outline for tight test situations
- Replaceable pogo-pin tips
- Fits all meters including Fluke, HP (Agilent), Keithley, Wavetek (Metterm), and others


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
565—6341		Precision Electronic Probe Set	36.36	34.63
565—6342		Probe Set with Sharp Point Gold	20.57	19.90
565—6275		Probe Set with Sharp Stainless Steel	18.41	17.16
565—6354		Replacement Probe Tips	18.94	18.04

Pomona DMM TEST LEAD SET

Specifications:

 - CAT III
- 1,000V
- Silicone insulated 4 ft. leads
- Comfort-grip textured surface
- Durable 0.08" tips for long life



Features:

- Monolithic probes with fixed tips
- Comfort grip probe
- Fits most DMMs from Fluke, HP (Agilent), Wavetek (Metterm), Amprobe, Greenlee and others


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
565—5519A		DMM Test Lead Set	13.85	12.78
565—5898		Stainless Steel Heavy Duty Tip	14.13	13.17

Pomona KELVIN LEAD SET WITH KELVIN CLIPS

Features:

 - Gold plated Kelvin clip jaws allow 4-wire resistive measurements
- Silicone insulated 3.3' (1m) test lead
- safety sheathed straight DMM plugs for convenient bench use
- Clips firmly grip test points for low-loss connection



Rating:

For CE compliance: not intended for hand held use at voltages above 33 Vrms/ 70 VDC

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Description	Price Each	
Mfr.	Mfr. Part No.		1	5
565—6730		Kelvin Lead Set with Kelvin Clips	119.71	116.23

Pomona REPLACEMENT PASSIVE OSCILLOSCOPE PROBES

Pomona's oscilloscope probes are designed, rated and specified to match the bandwidth of your instrument. This gives you a full voltage read-out through the entire rated bandwidth of the probe. These monolithic passive voltage probes feature high performance for greater test flexibility. Complete accessory kit included. Finally, a probe that gives you the full range you're paying for.



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Attenuation	Bandwidth MHz	Risetime ns	Input Resistance MΩ	Capacitance pF	Compensation Range pF	Max Input Voltage	Price Each	
Mfr.	Mfr. Part No.								1	5
565—6266		X1/X10	20/60	17.5/5.83	1/10	65/11	NA/10-60	300	42.99	39.66
565—4550B		X1/X10	15/100	23.33/3.5	1/10	64/10.5	NA/10-60	300	64.00	64.00
565—5806A		X1/X10	20/200	17.5/1.75	1/10	77/11.5	NA/10-60	300	71.00	71.00
565—5827A		X100	200	1.75	10	5.5	15-50	300	114.00	114.00
565—6069A		X10	250	1.4	10	10	10-30	300	66.00	66.00