


WELLER® Soldering and Rework Stations

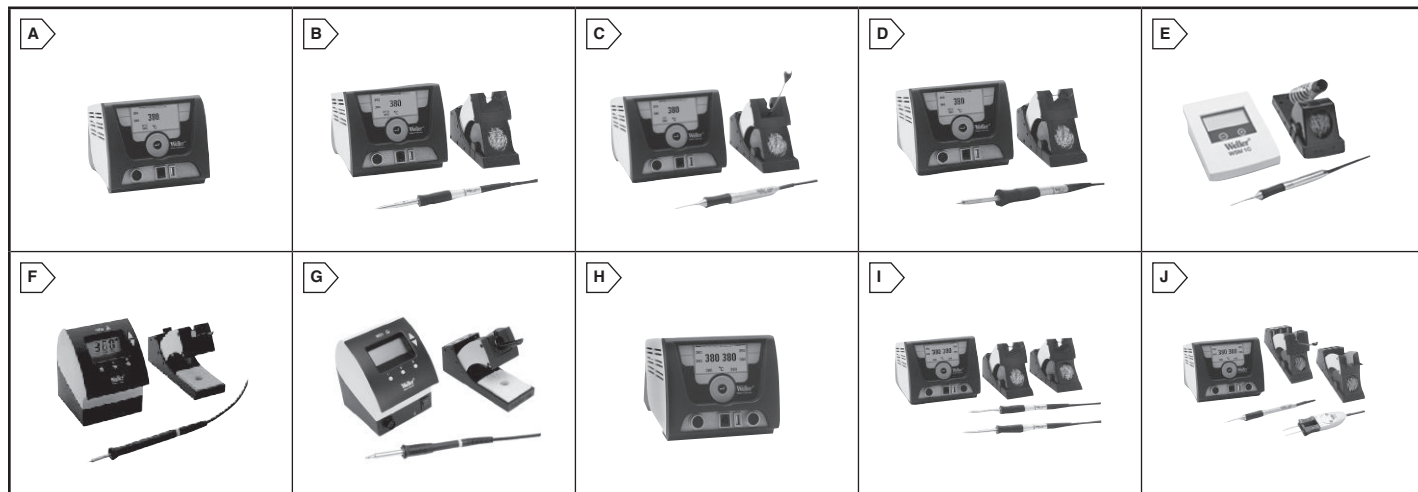

WX1 SOLDERING STATION

Specifications:

- Main Voltage: 120V, 50Hz
- Dimensions: (in.) 6.69 L x 5.94 W x 5.12 H
- Temperature Range: 150°F to 999°F



WX2 SOLDERING STATION

Specifications:

- Dimensions: (in.) 6.69 L x 5.94 W x 5.12 H
- Power Watt: 240W



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
578—WX1	A	120V 120W Control Unit W/WX120 Soldering pencil XTB Tip	350.00
578—WX1010	B	120V WXP120 WDH10 Soldering Station	579.00
578—WX1011	C	120V, WXMP, WDH50 Soldering Station	529.00
578—WX1012	D	120V, WXP65, WDH10 Soldering Station	499.00
578—WSM1	E	WSM 1C Soldering Station Digital	381.90
578—WSM1C	E	WSM 1C Cordless Rechargeable Soldering Station	468.00
Soldering Iron and Tips			
578—T0052921199	-	Soldering Iron WXP65	169.00
578—T0052921299	-	Soldering Iron WXP65/WDH10	194.00
578—T0054485099	-	Soldering Tip XNT, 1,0.25mm	7.50
578—T0054485199	-	Soldering Tip XNT, A, 1.6mm	7.50
578—T0054485299	-	Soldering Tip XNT, 1S, 0.20mm	7.50
578—T0054485399	-	Soldering Tip XNT, D 4.0mm	15.50
578—T0054485499	-	Soldering Tip XNT GW	13.50
578—T0054485599	-	Soldering Tip XNT 4, 1.2mm	7.50
578—T0054485699	-	Soldering Tip XNT 6, 1.6mm	7.50
578—T0054485799	-	Soldering Tip XNT B, 2.4mm	7.50
578—T0054485899	-	Soldering Tip XNT C, 3.2 mm	7.50
578—T0054485999	-	Soldering Tip XNT H, 0.8mm	8.25
578—T0054486099	-	Soldering Tip XNT K, 1.2mm	8.25
578—T0054486299	-	Soldering Tip XNT 1SC, 0.4x0, 15mm	14.50
578—T0054486399	-	Soldering Tip XNT KN, 2.0mm	14.50
Accessories			
578—T0058751880	-	Charger for WSM1/C	12.90
578—T0058765711	-	Barrel for WXP120	25.00

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
578—WX2	H	120V, 240W High Powered Dual Port Digital Power Unit	375.00
578—WX2020	I	120V, 200W High Powered Digital Soldering Station (2) WXP120 Pencils	790.00
578—WX2021	J	120V, 200W High Powered Digital Soldering Station WXMP and WXMT	900.00
Tweezers, Safety Rest, Soldering Pencil and Chisel Tips			
578—T0051317799	-	WXMT Micro-Desending Tweezers No Tip Cartridge	189.00
578—T0051317899	-	WXMT Micro-Desending Tweezers RTW2 Tip Set, WDH 60 Stand	259.00
578—T0051515899	-	WDH31 Safety Rest for WP200 and WXP200	80.00
578—T0051516999	-	WDH60 Safety Rest for WXMT	80.00
578—T0052920199	-	WXP120 Solder Pencil, 120W,24V for WX1 and WX2	199.00
578—T0052920299	-	WXP120 Solder Pencil w/WDH10T Stanf, 120W,24V for WX1 and WX2	259.00
578—T0052920399	-	WXMP Iron Micro—Soldering	139.00
578—T0052920499	-	WXMP With WDH 50	199.00
578—T0052920599	-	WXP 200/200W	199.00
578—T0052920699	-	WXP 200 with WDH 31	249.00
578—T0054480199	-	XHT D Chisel 5x1.2 Tip	13.00
578—T0054480299	-	XHT E Chisel 7.6x1.5 Tip	13.00
578—T0054480499	-	XHT C Chisel 3.2x1.2 Tip	13.00
Accessories			
578—T0058764710	-	WX Cable Connection	12.00
578—T0058764711	-	WX Adapter for PC	20.00
578—T0058764712	-	WX Adapter for WFE/WHP	20.00

DIGITAL SOLDERING STATIONS

WD1001, Digital Soldering Station with WMP Soldering Pencil

Features:

- Heating element is in the tip
- Super fast heat up
- Non burnable silicone cord
- Tip temperature is adjustable
- Superior thermal recovery
- ESD safe

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
578—WD1001	F	85W Digital Station	343.00
Soldering Pencil			
578—WMP	-	65W Soldering Pencil	122.00

WD1002 Station Includes WP80 Pencil

Quick heat up, fast recovery, and more reliable than ever. A new generation of digital electronically controlled soldering stations for fast efficient soldering.

Specifications:

- 85 Watt
- 120V (input)/24V (output)
- Temperature Range: 150°F to 850°F

Features:

- UL Listed, ESD Safe
- Uses economical LT series tips

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
578—WD1002	G	85W Digital Station	343.00
Soldering Pencil			
578—WP80	-	Soldering Pencil	122.00

NT Series Tips for WMP Pencil

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
578—NTA	-	.063 x .331 Chisel Tip	10.90
578—NTB	-	.94 x .289 Chisel Tip	10.90
578—NTC	-	.126 x .305 Chisel Tip	10.90
578—NTD	-	.157 x .305 Chisel Tip	21.60
578—NTH	-	.031 x .331 Chisel Tip	11.40
578—NTK	-	.047 x .331 Chisel Tip	11.40
578—NT1	-	.010 x .291 Micro Chisel Tip	10.90
578—NT4	-	.047 x .391 Round Tip	10.90
578—NT6	-	.063 x .372 Chisel Tip	10.90
578—NTAX	-	.063 x .339 Bent Chisel Tip	15.60
578—NTGW	-	.079 x .528 Cylindrical Tip	18.50
578—NT1S	-	.010 x .333 Micro Tip	10.90
578—NT1X	-	.016 x .321 Bent Round Tip	12.80

LT Series Tips for WP80 Iron

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each
578—LT-I	-	.25mm round	4.31
578—LT-IS	-	.2mm round	4.20
578—LT-AS	-	1.6mm round	4.20
578—LT-B	-	2.4mm chisel	4.62
578—LT-C	-	3.2mm chisel	3.90
578—LT-H	-	.8mm chisel	3.90
578—LT-CS	-	3.2mm round	4.60
578—LT-D	-	4.6mm chisel	3.90
578—LT-K	-	1.2mm chisel	3.90
578—LT-A	-	1.6mm chisel	3.90