

# ON SEMICONDUCTOR Power Management Tools

ON Semiconductor®



Power Management


ON Semiconductor

NEW AT Mouser

NEW AT Mouser

NEW AT Mouser

Product may be RoHS Compliant. Check mouser.com for RoHS status.

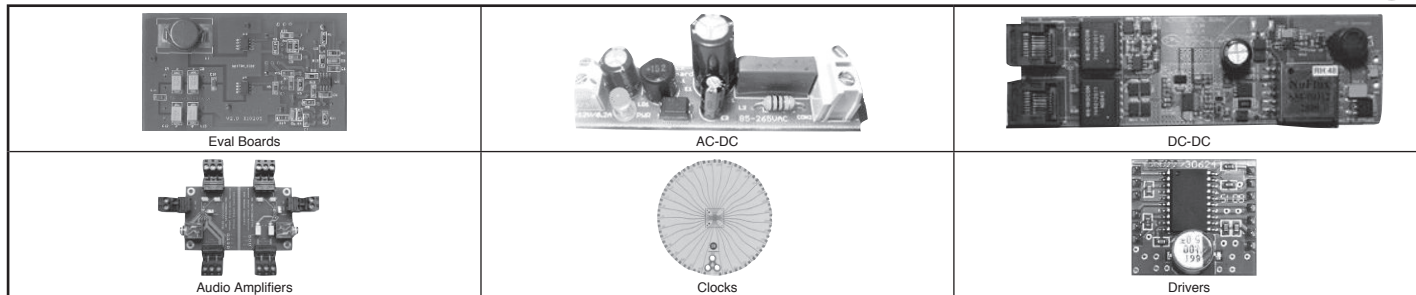

MOUSER STOCK NO.		Description	Price Each	MOUSER STOCK NO.		Description	Price Each
Mfr.	Mfr. Part No.			Mfr.	Mfr. Part No.		
863	CAT4201AGEVB	CAT4201 LED Driver Evaluation Board	90.75	863	NCP1034BCK5VGEVB	NCP1034 Sync Buck Evaluation Board	122.00
863	CCRGEVB	CCR Evaluation Board	152.00	863	NCP1081SPCGEVB	NCP1081 Hpower POE-PD Splitter	250.00
863	CS5171B3TGEVB	CS5171/3 Demo BD Boost	89.05	863	NCP1083QBCGEVB	NCP1083 High Power POE-PD Module	187.50
863	ECLSOIC8EVB	SOIC-8 High Freq. Evaluation Board	137.00	863	NCP1207AADAPGEVB	NCP1207A 2W Adapter Evaluation Board	125.00
863	LA0152CSGVEVB	LA0152CS-TLM-H, Photo sensor Eval Board	32.47	863	NCP1237PRINTGEVB	NCP1237 Printer Adapter Evaluation Board	205.70
863	LB11685AVGVEVB	LB11685AV-TLM-H, 3P motor driver Eval Board	64.94	863	NCP1252TSFWDGEVB	NCP1252 AC-DC Evaluation Board	290.00
863	LB11696VGEVB	LB11696V-TLM-E, PWM pre-driver IC Eval Board	64.94	863	NCP12715W Adapter Evaluation Board	NCP1271 5W Adapter Evaluation Board	100.00
863	LB11868VGEVB	LB11868V-TLM-H, 1P bipolar motor pre-driver Eval Board	64.94	863	NCP1337ADAPGEVB	NCP1337 60W Adapter Evaluation Board	150.00
863	LB1836MEVB	LB1836M-TLM-E, 2-ch low-volt, low sat. volt type Eval Board	45.45	863	NCP1351LEDGEVB	NCP1351 20W Constant Cur LED DRV	100.00
863	LB1838MEVB	LB1838M-TRM-E, 2-ch volt. type Eval Board	45.45	863	NCP1380BGEVB	NCP1380 QR Cont Evaluation Board	223.85
863	LB1909MCGEVB	LB1909MC-BH, Low sat. V stepping motor driver IC Eval Board	64.94	863	NCP1380DGEVB	NCP1380D QR Cont Evaluation Board	223.85
863	LB1930MCGEVB	LB1930MC-AH, Low sat. V 1-ch H-bridge Eval Board	64.94	863	NCP1400A19V19EVB	NCP1400A 1.9V/100mA DC-DC Eval Board	62.50
863	LB1930MGEVB	LB1930M-TLM-H, Low sat. V 1-ch H-bridge Eval Board	45.45	863	NCP1400A33V33EVB	NCP1400A 3.3V/100mA DC-DC Eval Board	62.50
863	LB1948MCGEVB	LB1948MC-AH, 2-ch low sat. volt F/Rev motor driver Eval Board	64.94	863	NCP1410GEVB	NCP1410 250mA Detector Evaluation Board	37.50
863	LB1973JAGEVB	LB1973JA-AH, 2-ch H-bridge Eval Board	64.94	863	NCP1421EVB	NCP1421 600mA DC-DC Evaluation Board	62.50
863	LC717A00ARGEVB	LC717A00AR-NH, capacitance-digital-converter LSI Eval Board	175.32	863	NCP1423EVB	NCP1423 400mA DC-DC Evaluation Board	62.50
863	LM2595ADPBCKGEVB	LM2595ADJ D2PAK Buck Demo Board	62.50	863	NCP1521BEVB	NCP1521 Step Down Conv Evaluation Board	100.00
863	LV4904VGEVB	LV4904V, 2-class-D amplifier Eval Board	64.94	863	NCP1529ASNT1GEVB	NCP1529 Step-Down Evaluation Board	145.00
863	LV4924VHGEVB	LV4924VH, 2-ch full-bridge driver digital power amp Eval Board	64.94	863	NCP1529MUTBGEVB	NCP1523 1A High Eff. Step Down Conv	125.00
863	LV5068VGEVB	LV5068V, 1-ch buck switching regulator Eval Board	64.94	863	NCP1562-100WEVBG	NCP1562 100W 48V DC-DC Evaluation Board	125.00
863	LV5683PGEVB	LV5683P, multi-V reg. USB tuner Eval Board	64.94	863	NCP1593AGEVB	NCP1593 Synch Buck Reg Evaluation Board	48.40
863	LV8044LPGEVB	LV8044LP, 6-ch motor driver IC digital still camera Eval Board	64.94	863	NCP1593BGEVB	NCP1593 Synch Buck Reg Evaluation Board	48.40
863	LV8075LPGEVB	LV8075LP, low V DC motor driver Eval Board	45.45	863	NCP1595AGEVB	NCP1595AG PWM Evaluation Board	60.50
863	LV8080LPGEVB	LV8080LP, 2-ch constant-current driver Eval Board	45.45	863	NCP1605FORWGEVB	NCP1605 15W Forward Evaluation Board	250.00
863	LV8136VGEVB	LV8136V, 3P PWM system pre-driver IC Eval Board	64.94	863	NCP1608BOOSTGEVB	NCP1608 Boost PFC Evaluation Board	129.62
863	LV8400VGEVB	LV8400V, 1-ch motor driver IC Eval Board	45.45	863	NCP1631PFCGEVB	NCP1631 PFC Evaluation Board	229.90
863	LV8402GPEVB	LV8402GP, 2-ch forward/reverse motor driver IC Eval Board	45.45	863	NCP1654PFCGEVB	NCP1654 Power Fact Evaluation Board	175.00
863	LV8411GREVB	LV8411GR, H-bridge motor driver IC Eval Board	45.45	863	NCP1910GEVB	NCP1910G PFC Demo Board	312.50
863	LV8413GPEVB	LV8413GP, H-bridge x 2-ch motor driver IC Eval Board	45.45	863	NCP2809BGEVB	NCP2809 Adj. Stereo Audio Evaluation Board	112.50
863	LV8417CSGVEVB	LV8417CS, 1-ch H-bridge motor driver IC Eval Board	64.94	863	NCP2823AGEVB	NCP2823A Amp Evaluation Board	104.00
863	LV8498CTGVEVB	LV8498CT-TE-L-H, voice coil motors Eval Board	64.94	863	NCP2890EVB	NCP2890 1W Audio Power Evaluation Board	62.50
863	LV8548MGEVB	LV8548M, 2-ch low sat. V, F/Rev motor driver IC Eval Board	45.45	863	NCP2892AEVB	NCP2892A 1.3W Audio Power Amplifier	62.50
863	LV8549MGEVB	LV8549M, 2-ch low sat. V, F/Rev motor driver IC Eval Board	45.45	863	NCP3011GEVB	NCP3011 PWM Evaluation Board	66.00
863	LV8711TGEVB	LV8711T, PWM stepping motor driver Eval Board	45.45	863	NCP3020AGEVB	NCP3020 PWM Evaluation Board	96.00
863	LV8712TGEVB	LV8712T, microstepping motor driver IC with transistor Eval Board	45.45	863	NCP3020BGEVB	NCP3020A PWM Evaluation Board	96.00
863	LV8713TGEVB	LV8713T, microstepping motor driver IC with transistor Eval Board	45.45	863	NCP3063BSTEXGVEVB	NCP3063 BST Demo Board EXT FET	100.00
863	LV8731VGEVB	LV8731V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3063DIPBCKEVB	NCP3063 Buck Regulator Evaluation Board	100.00
863	LV8732VGEVB	LV8732V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3063SMDBSTEVB	LQFP32 High Frequency Evaluation Board	62.50
863	LV8734VGEVB	LV8734V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3065BBGVEVB	NCP3065 Buck-Boost MR16 Eval Board	113.05
863	LV8735VGEVB	LV8735V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3065D3SLDGEVB	MC34063A Evaluation Board	100.00
863	LV8736VGEVB	LV8736V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3065SOBCKGEVB	MC34063A Evaluation Board	100.00
863	LV8740VGEVB	LV8740V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3065SOBSTGEVB	MC34063A Evaluation Board	100.00
863	LV8741VGEVB	LV8741V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3066DFSEGEVB	MC34063A Evaluation Board	100.00
863	LV8746VGEVB	LV8746V, 2-ch H-bridge stepping motor driver Eval Board	45.45	863	NCP3066SCBSTGEVB	NB4N527S 3.3V Evaluation Board	100.00
863	LV8760TGEVB	LV8760T, H-bridge driver Eval Board	45.45	863	NCP3125AGEVB	NCP3125 Evaluation Board	56.25
863	LV8761VGEVB	LV8761T, H-bridge driver Eval Board	45.45	863	NCP3155AGEVB	NCP3155 Buck Cont Evaluation Board	72.60
863	LV8762TEVB	LV8761T, 1-ch H-bridge driver Eval Board	45.45	863	NCP3163BCKGEVB	NCP3163 Buck Evaluation Board	72.60
863	LV8771VHGEVB	LV8771VH, PWM current control stepping motor driver Eval Board	64.94	863	NCP3170UGEVB	NCP3170 Sync PWM Buck Evaluation Board	72.60
863	LV8772GEVB	LV8772 PWM Evaluation Board	42.35	863	NCP349GEVB	NCP1083 POE-PD Module with Vaux	37.50
863	LV8772GEVB	LV8772, microstep stepping motor driver Eval Board	45.45	863	NCP4894FCEVB	NCP1207A 2W Adapter Evaluation Board	75.00
863	LV8773GEVB	LV8773, 2-CH bridge driver Eval Board	45.45	863	NCP5005GEVB	NCP1216 Non Isolated Buck LED DRI	37.50
863	LV8804FVGEVB	LV8804FV, 3P sensorless motor driver IC Eval Board	64.94	863	NCP5222GEVB	NCP5222 Buck Cont Evaluation Board	108.90
863	LV8805SVGEVB	LV8805SV-TLM-H, 3P motor driver Eval Board	64.94	863	NCP5425DOEVB	NCP1400A ANA Evaluation Board	93.75
863	LV8860VGEVB	LV8860V, driver IC using single-phase fan motor Eval Board	64.94	863	NCP565V12EVB	NCP1421 High Current LED Evaluation Board	75.00
863	MC33063DFBCKGEVB	MC33063 DFN SD Demo Board	62.50	863	NCP565VADJEVB	NCP1422 800mA DC-DC Evaluation Board	75.00
863	MC34063LBGEVB	MC34063 Boost Evaluation Board	42.35	863	NCP690MNA2T2GEVB	NCP1521 Step Down Conv Evaluation Board	44.45
863	NB3H83905CDGVEVB	NB3H83905 SOIC-16 Evaluation Board	500.00	863	NCP6289MN18T2GEVB	NCP1523B Step Down DC-DC Evaluation Board	44.45
863	NB3N3020DTGVEVB	NB3N3020 Clock Multiplier Evaluation Board	484.00	863	NCS2200AGEVB	NCS2200A UDFN-6 Evaluation Board	42.35
863	NB3N5573DTGVEVB	NB3N5573 Clock Generator Evaluation Board	484.00	863	NCS2564ATBGEVB	NCD2564 4-Ch Video Evaluation Board	175.45
863	NB3N65027DTGVEVB	NB3N65027 Clock Synthesizer Evaluation Board	60.50	863	NCS8353MNGEVB	NCS8353 Audio Amp Evaluation Board	151.25
863	NCL30000LED1GEVB	NCL30000 LED Driver Evaluation Board	107.20	863	NCS8353MNGEVB	NCP1654 Power Fact Evaluation Board	82.55
863	NCL30000LED2GEVB	NCL30000 LED Triac Evaluation Board	107.20	863	NCS8851BDBGEVB	NCV8851B Sync Buck Evaluation Board	84.70
863	NCL30000LED3GEVB	NCL30000 LED Triac Evaluation Board	107.20	863	NCV8871BSTGEVB	NCV8871 Non-Sync Boost Evaluation Board	105.27
863	NCL30001LEDGEVB	NCL30001 LED Driver Evaluation Board	203.00	863	NCV8871FLYGEVB	NCV8871 Non-Sync Boost Evaluation Board	104.06
863	NCL30051LEDGEVB	NCL30051 PFC Evaluation Board	163.35	863	NCV8871LYGEVB	NCV8871 Fly Evaluation Board	102.85
863	NCL30105LEDGEVB	NCL30105 LED Buck Driver Evaluation Board	121.00	863	NCV8871SEPGVEVB	NCV8871 SEPIC Converter Evaluation Board	102.85
863	NCN1154MUTGEVB	NCN1154 Audio Switch Evaluation Board	90.75	863	NLSF595EVB	NCP2892A 1.3W Audio Power Amplifier	63.50
863	NCN4555GEVB	NCN4555 Evaluation Board	84.70	863	NLUD4001EVB	NCP2990 1.3W Audio Amplifier Eval Board	63.50
863	NCN8025AMNGEVB	NCN8025A Evaluation Board	121.00	863	STK672-040EVB	STK672-040-E, stepping motor driver hybrid IC Eval Board	32.47
863	NCP1013ADAPGEVB	NCP1013 Adapter Evaluation Board	102.85	863	STK672-050EVB	STK672-050-E, stepping motor driver hybrid IC Eval Board	32.47
863	NCP1013LEDGEVB	NCP1013 LED Driver Evaluation Board	137.25	863	STK672-060EVB	STK672-060-E, stepping motor driver hybrid IC Eval Board	32.47
863	NCP1014LEDGTGEVB	NCP1014X LED Driver Evaluation Board	129.62	863	STK681-300GEVB	STK681-300, F/Rev motor driver Eval Board	32.47
863	NCP1014STBUCGEVB	NCP1014 Positive Output Buck Evaluation Board	63.50	863	STK681-310GEVB	STK681-310, F/Rev motor driver Eval Board	32.47
863	NCP1027ATXGEVB	NCP1027 ATX PSU Evaluation Board	181.25	863	STK681-320GEVB	STK681-320, F/Rev motor driver Eval Board	32.47
863	NCP1030GEVB	NCP1030 Evaluation Board	86.45	863	STK681-332GEVB	STK681-332-E, hybrid IC use in current control F/Rev Eval Board	32.47
863	NCP1031POEEVB	NCP1031 Reg Cont Evaluation Board	145.00	863	STK681-352GEVB	STK681-352-E, F/Rev Eval Board	32.47
				863	XOCLCC6EVB	NCP3063 DFN Boost Demo Board	63.50